

Decorative lighting



Philips Lightolier Decorative – a product line up that makes it easy to find a visual compliment to your space.

The decorative luminaires are designed to complement the architecture with elegant lines and forms that add elements of light for visual interest to the space or, when used repetitively, as a rhythm of light.

We offer numerous ADA-compliant wall mounted designs, pendants in a variety of styles and scale, as well as a wide array of architectural ceiling mount fixtures. Integral emergency battery packs are also available in wall, ceiling, and pendant luminaires.

The implementation of LED technology across our fixture lines provides our products with superior and state of the art performance, related to life, light output and color stability and consistency.

Flexible design, modular construction, and multi-voltage ballasts enable us to supply architectural requirements rapidly and reliably.

We focus on delivering a wide range of standard products but will modify designs for large-scale projects.

Contents

Architectural decorative	>	6.2
Transitional	>	6.40
Contemporary	>	6.52
Traditional	>	6.80
Basic	>	6.86
Wet location	>	6.94

Architectural decorative



Corridor

LED luminaire

The Philips Lightolier Architectural Decorative design team introduces its first performance driven LED corridor application. The fixture utilizes phosphor film technology, providing superior color stability and consistency, while maintaining a clean visual finish, elegant lines and forms, and an exceptional rhythm of light, to any corridor application.




Corridor

Corridor Lights*

Cat. no.	Finish	Wattage	CCT	Voltage
CDL27SAU	Satin AL	20W Max	2700K	120/
CDL27WHU	White			277V
CDL30SAU	Satin AL	20W Max	3000K	120/
CDL30WHU	White			277V
CDL35SAU	Satin AL	20W Max	3500K	120/
CDL35WHU	White			277V
CDL40SAU	Satin AL	20W Max	4000K	120/
CDL40WHU	White			277V

* Reference specification sheet CDL for all available Decorative accessories.

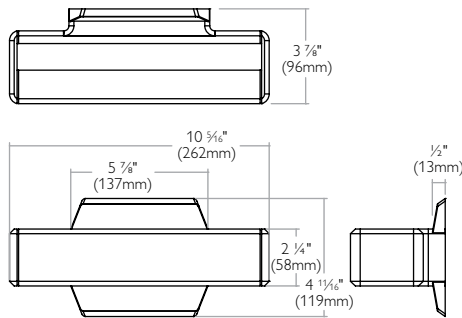

The use of J-Box mounting (hardware provided) is an optional alternative to the conduit cable and direct to wall installation. The J-Box cover dimensions are shown above.

Features

- ADA compliant
- CRI in the high 80's
- Utilizes two linear FR4 circuit boards
- ELU dimming capability



White sleeve wave accessory

Cat. no.	Description
CDLS01	White sleeve straight accessory
CDLS02	White sleeve wave accessory
CDLA	Acrylic flat diffuser
CDLG	Glass flat diffuser

* The white sleeve accessories are paintable.



Vetro 4 3/4" pendants

PM series

Clean lines, elegant proportions, honest use of materials, and a basic element of light. To be suspended in space or mounted flush to a ceiling. The basic construction elements consist of an extruded and cast aluminum housing, triple layered hand blown glass.

Features

Power head housing: Two-piece die cast and extruded aluminum.

Glass


Inner: Hand-Blown Triplex glass maximizes diffusion of light evenly along length of glass.

Outer: Extruded and Hand-Blown clear glass.

Lampholders

Incandescent: Mini-can (E11) Base, nickel plated screw shell.

Compact fluorescent: 4-pin, 26/32 watt base: GX24q-3

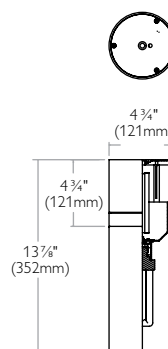

Suspension kits

Cord and Cable: Supplied with 18-3 SVT straight clear jacketed steel braided power cord and metal aircraft cable and includes aluminum canopy. Also included are solid aluminum lobster claws to neatly secure the clear jacket power cord to the aircraft cable.

Stem: Supplied with (3) 18 GA. wire, 3/8" diameter satin aluminum stem and matching die cast aluminum canopy.

Surface Mount Kit: Mounts the PM Series only to the ceiling.

Close-to-Ceiling: Supplied with 3" stem and matching die cast aluminum canopy.

Track mount: Kit includes clear jacketed steel braided power cord and metal aircraft cable. Finish of adapter body is silver powder coat. Adapter mounts to Philips Lightolier Lytespan Track.

All units are cULus listed, suitable for damp locations.

Ordering information for PM series


Power head	Inner glass	Outer glass	Lamp	Volts	Finish
PM32SA	PG01	NA	CFL 26/32W	120V-277V	Satin Aluminum
PM32MX1SA	PG01	NA	Mark X Dimming 26/32W	120V	Satin Aluminum
PM32MX2SA	PG01	NA	Mark X Dimming 26/32W	277V	Satin Aluminum
PM150SA	PG01	NA	T-4 Mini-Can 150W	120V	Satin Aluminum
PM01L27SA1	PG01	NA	LED 10W 27K	120V	Satin Aluminum
PM01L27SA2	PG01	NA	LED 10W 27K	277V	Satin Aluminum
PM01L30SA1	PG01	NA	LED 10W 30K	120V	Satin Aluminum
PM01L30SA2	PG01	NA	LED 10W 30K	277V	Satin Aluminum
PM01L35SA1	PG01	NA	LED 10W 35K	120V	Satin Aluminum
PM01L35SA2	PG01	NA	LED 10W 35K	277V	Satin Aluminum
PM01L40SA1	PG01	NA	LED 10W 40K	120V	Satin Aluminum
PM01L40SA2	PG01	NA	LED 10W 40K	277V	Satin Aluminum
PM02L27SA1	PG01	NA	LED 20W 27K	120V	Satin Aluminum
PM02L27SA2	PG01	NA	LED 20W 27K	277V	Satin Aluminum
PM02L30SA1	PG01	NA	LED 20W 30K	120V	Satin Aluminum
PM02L30SA2	PG01	NA	LED 20W 30K	277V	Satin Aluminum
PM02L35SA1	PG01	NA	LED 20W 35K	120V	Satin Aluminum
PM02L35SA2	PG01	NA	LED 20W 35K	277V	Satin Aluminum
PM02L40SA1	PG01	NA	LED 20W 40K	120V	Satin Aluminum
PM02L40SA2	PG01	NA	LED 20W 40K	277V	Satin Aluminum

Must order Power Head and Glass separately.
For Inner Acrylic option, order **PA01**.


Vetro 4 3/4" pendants

PM series

A simple but dynamic luminaire whose appearance will change along with the viewing angle and the incidence of light. The basic construction elements consist of an extruded and cast aluminum housing, triple layered hand blown glass. The fixture is encased by a cylinder of clear polished glass which is supported by a set of solid aluminum machined arms.

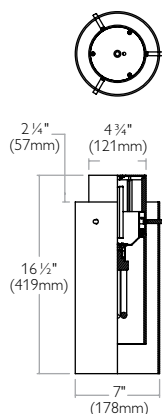

For the above configuration, order **GL01** for Outer Glass option or **GL01A** for Outer Acrylic option.

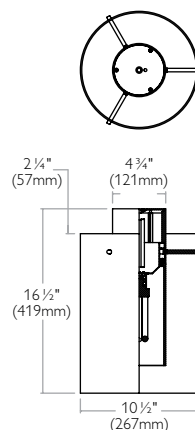

For the above configuration, order **GL02** for Outer Glass option or **GL02A** for Outer Acrylic option.

Mounting options for PM series

Cat. no.	Finish	Description
SK01	Satin Aluminum	120" Length, Cable/Cord
SK02	Satin Aluminum	300" Length, Cable/Cord
SMK	Satin Aluminum	Surface mount- PM32SA Only
ST01	Satin Aluminum	36" Length, 3/8" Stem
ST02	Satin Aluminum	60" Length, 3/8" Stem
CTC	Satin Aluminum	Close to Ceiling
TM01	Silver	Track Mounting Kit 1- Adapter System

All Suspension kits conform to California Earthquake Codes.
Also all suspension kits, except **SMK** and **CTC** are field cuttable.



Vetro 2 3/8" pendants

PS series

A blend of slender and classic proportions. Clean lines with an extruded and cast aluminum housing, and triple layered hand blown glass. This is a fixture to be used as a solitary pendant, or suspended in patterns. Provides elegant proportions, ambient illumination, and a soft glow to a space. A sophisticated pendant presented under glass. Layers, space, light, and basic geometry provide the depth and visual interest suited to enhance a variety of architectural styles.

Glass

Inner: Hand-Blown Triplex glass maximizes diffusion of light evenly along length of glass.



Outer: Extruded and Hand-Blown clear glass.

Additional options

To order the OSRAM 4-pin twin tube 41K lamp, please use Philips Lightolier **56964**.

For Fixtures that use 13W Quad tube lamp, add **Q** to the suffix. Example **PS13QSA**.

All units are cULus listed, suitable for damp locations.

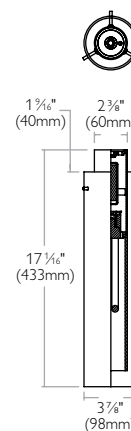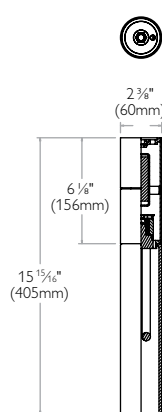

For the above configuration order **GLS01** for Outer Glass option or **GLS01A** for Outer Acrylic option.

Ordering information for PS series

Power head	Inner glass	Outer glass	Lamp	Volts
PS13SA	SG01L	NA	4-pin Electric Twin Tube 13W	120V
PS132SA	SG01L	NA	4-pin Electric Twin Tube 13W	277V
PS50SA	SG01L	NA	T-4 Mini-Can 50W	120V
PS01L27SAU	SG01L	NA	LED 6W 27K	120V-277V
PS01L30SAU	SG01L	NA	LED 6W 30K	120V-277V
PS01L35SAU	SG01L	NA	LED 6W 35K	120V-277V
PS01L40SAU	SG01L	NA	LED 6W 40K	120V-277V

Must order Power Head and Glass separately.

For Inner Acrylic option, order **SA01L**.

Mounting options for PM series

Cat. no.	Finish	Description
SK01	Satin Aluminum	120" Length, Cable/Cord
SK02	Satin Aluminum	300" Length, Cable/Cord
ST01	Satin Aluminum	36" Length, 3/8" Stem
ST02	Satin Aluminum	60" Length, 3/8" Stem
CTC	Satin Aluminum	Close to Ceiling
TM01	Silver	Track Mounting Kit 1- Adapter System

All suspension kits conform to California Earthquake Codes.

Also, all suspension kits except **CTC** are field cuttable.

Vetro ADA wall sconce

PW series

The cylindrical portion of the power compartment gently nests within the cast aluminum wall bracket to keep the wall fixture in compliance with ADA guidelines. Three layers of hand blown glass gently diffuse either the compact fluorescent, or the incandescent light source.



Ordering information for PW series

Chassis	Inner glass	Outer glass	Lamp	Volts
PW13SA	SG01L	NA	4-pin Electric Twin Tube 13W	120V
PW132SA	SG01L	NA	4-pin Electric Twin Tube 13W	277V
PW50SA	SG01L	NA	T-4 Mini-Can 50W	120V
PW01L27SAU	SG01L	NA	LED 6W 27K	120V-277V
PW01L30SAU	SG01L	NA	LED 6W 30K	120V-277V
PW01L35SAU	SG01L	NA	LED 6W 35K	120V-277V
PW01L40SAU	SG01L	NA	LED 6W 40K	120V-277V

Must order Wall Chassis and Glass separately.
For Inner Acrylic option, order **SA01L**.

Features

ADA Compliant wall sconce

Power housing: Two-piece die cast aluminum.

Glass: Hand-Blown Triplex glass maximizes diffusion of light evenly along length of glass.

Additional options

To order the OSRAM 4-pin twin tube 41K lamp, please use Philips Lightolier **56964**.


For Fixtures that use 13W Quad tube lamp, add **Q** to the suffix. Example **PW13QSA**.




Ordering information for PW series

Chassis	Inner glass	Outer glass	Lamp	Volts
PW13SA	SG02L	NA	4-pin Electric Twin Tube 13W	120V
PW132SA	SG02L	NA	4-pin Electric Twin Tube 13W	277V
PW50SA	SG02L	NA	T-4 Mini-Can 50W	120V
PW01L27SAU	SG02L	NA	LED 6W 27K	120V-277V
PW01L30SAU	SG02L	NA	LED 6W 30K	120V-277V
PW01L35SAU	SG02L	NA	LED 6W 35K	120V-277V
PW01L40SAU	SG02L	NA	LED 6W 40K	120V-277V

Must order Wall Chassis and Glass separately.
For Inner Acrylic option, order **SA02L**.

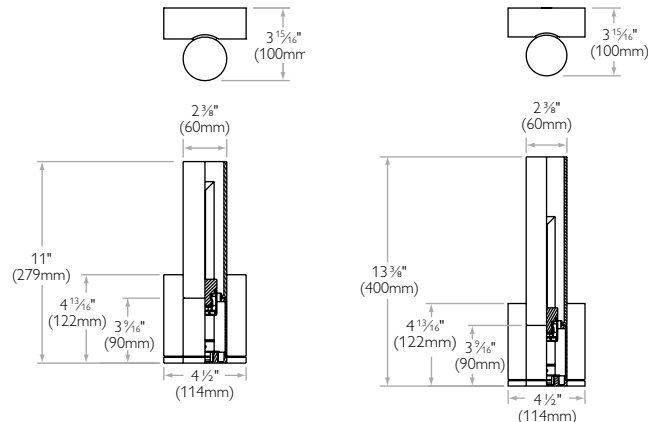

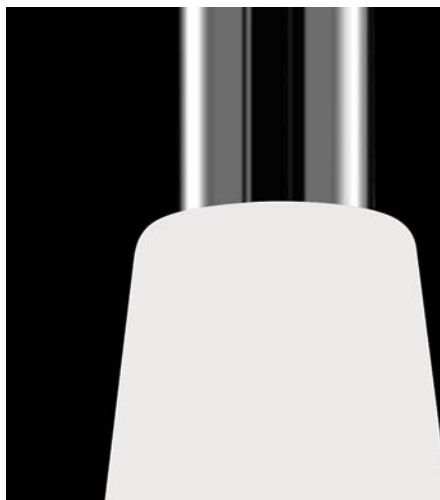

Vetro 5 1/2" conical pendants

PS series

A combination of two basic geometric forms, the cylinder and the cone. A source of ambient illumination and an object of visual interest. The FA01 presented under a conical section of glass.

Glass

Inner: Hand-Blown Triplex glass maximizes diffusion of light evenly along length of glass.



Outer: Extruded and Hand-Blown clear glass.

Additional options

To order the OSRAM 4-pin twin tube 41K lamp, please use Philips Lightolier **56964**.

For fixtures that use 13W Quad tube lamp, add **Q** to the suffix. Example **PS132QSA**.

All units are cULus listed, suitable for damp locations.

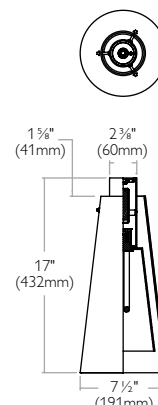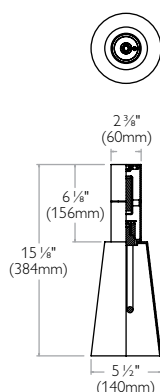

For the above configuration, order **GLS02** for Outer Glass option

Ordering information for PS series

Power head	Inner glass	Outer glass	Lamp	Volts
PS13SA	SG03L	NA	4-pin Electric Twin Tube 13 W	120V
PS132SA	SG03L	NA	4-pin Electric Twin Tube 13 W	277V
PS26SA	SG03L	NA	Quad 26W	120V
PS262SA	SG03L	NA	Quad 26W	277V
PS50SA	SG03L	NA	T-4 Mini-Can 50W	120V
PS01L27SAU	SG03L	NA	LED 6W 27K	120V-277V
PS01L30SAU	SG03L	NA	LED 6W 30K	120V-277V
PS01L35SAU	SG03L	NA	LED 6W 35K	120V-277V
PS01L40SAU	SG03L	NA	LED 6W 40K	120V-277V

Must order Power Head and Glass separately.

Mounting options for PS series



Cat. no.	Finish	Description
SK01	Satin Aluminum	120" Length, Cable/Cord
SK02	Satin Aluminum	300" Length, Cable/Cord
ST01	Satin Aluminum	36" Length, 3/8" Stem
ST02	Satin Aluminum	60" Length, 3/8" Stem
CTC	Satin Aluminum	Close to Ceiling
TM01	Silver	Track Mounting Kit 1- Adapter System

All suspension kits conform to California Earthquake Codes.
Also, all suspension kits except **CTC** are field cuttable.

Vetro 7⁵/₁₆" pendants

PS series

The FS01 presented under a conical section of glass. Basic shapes combine to form a geometric presence.

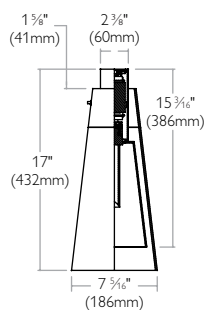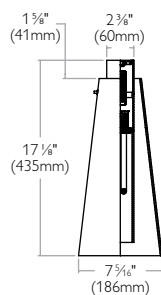

For the above configuration, order **GLS03** for Outer Glass option

Glass

Inner: Hand-Blown Triplex glass maximizes diffusion of light evenly along length of glass.

Outer: Extruded and Hand-Blown clear glass.

Additional options

To order the Osram 4-pin twin tube 41K lamp, please use Philips Lightolier **56964**.

For fixtures that use 13W Quad tube lamp, add **Q** to the suffix. Example **PS13QSA**.

Ordering information for PS series

Power head	Inner glass	Outer glass	Lamp	Volts
PS13SA	SG01L	GL02	4-pin Electric Twin Tube 13 W	120V
PS132SA	SG01L	GL02	4-pin Electric Twin Tube 13 W	277V
PS26SA	SG01L	GL02	Quad 26W	120V
PS262SA	SG01L	GL02	Quad 26W	277V
PS50SA	SG01L	GL02	T-4 Mini-Can 50W	120V
PS01L27SAU	SG01L	GL02	LED 6W 27K	120V-277V
PS01L30SAU	SG01L	GL02	LED 6W 30K	120V-277V
PS01L35SAU	SG01L	GL02	LED 6W 35K	120V-277V
PS01L40SAU	SG01L	GL02	LED 6W 40K	120V-277V

Must order Power Head and Glass separately.
For Inner Acrylic option, order **SA01L**

Vetro decorative downlight

D01, D02, D03, D13, D04, & D14 series

A definitive design statement utilizing balance and proportions. With uncompromising style and the look of clean, spare elegance, Vetro Downlights open a world of creative potential. Designed for stand-out style or a reserved minimal look, the Downlights offer unlimited scope for a broad variety of applications – all within the same design family.



Crescent Wells Fargo
Photograph: Nick Merrick © Hedrich Blessing

Vetro decorative downlight


D01 series

A solid translucent form with aluminum beveled insert and minimal satin ring. A clean geometric form combines a solid translucence with diverging layers and internal reflections to create interest in light. Subtle light patterns are revealed as light emanates in differing ways when viewed from different angles. The layered lighting delivers a contrasting bright with an inner glow offset by the matte satin ring. Any space is enhanced by placement and position.




4" LED

D4A01: Vetro decorative accessory

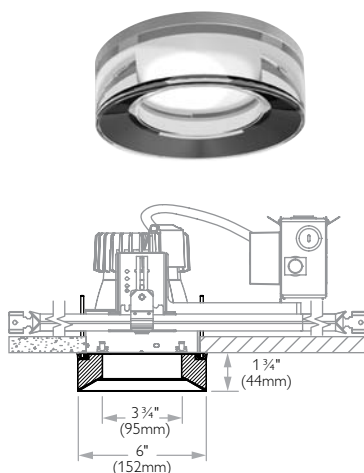


6" LED

D6A01: Vetro decorative accessory

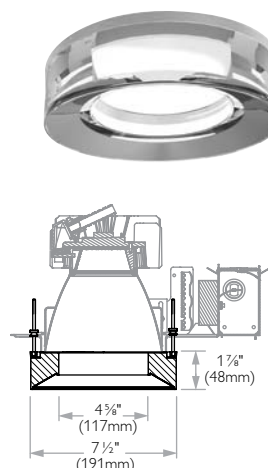

7" LED

D7A01: Vetro decorative accessory

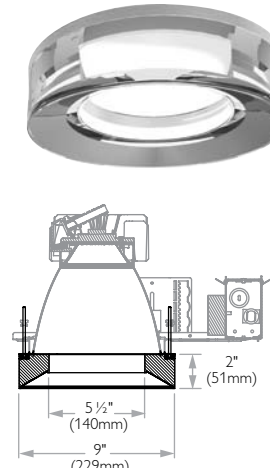

Ordering information for LED

For the 4" LED

D4A01 + C4L05 or C4L10 Series

Calculite Frame-In Kits
and Flangeless Trims
(sold separately)

For the 6" LED

D6A01 + C6L Series

Calculite Frame-In Kits
and Flangeless Trims
(sold separately)

For the 7" LED

D7A01 + C7L Series

Calculite Frame-In Kits
and Flangeless Trims
(sold separately)

Ordering information for HID & CFL

For CFL and Metal Halide options below, reference "Calculite trim and frame-in kit compatibility" on page 6.17 for applicable Calculite frame-in kit and trim ordering information and options.

Ordering example:

D4A01 + 8011CL + 4118VU = Complete fixture

8011CL Calculite trim sold separately and 4118VU Calculite frame sold separately

4" CFL

D4A01: Vetro decorative accessory

6" CFL

D6A01: Vetro decorative accessory

7" CFL

D7A01: Vetro decorative accessory

4" Metal halide

D4A01: Vetro decorative accessory

6" Metal halide

D6A01: Vetro decorative accessory

3" Evolution

D3MR01: Trim kit and decorative accessory (CL Reflector)

4" Evolution

D4MR01: Trim kit and decorative accessory (CL Reflector)

Note: For 3" and 4" Evolution combinations only, Decorative accessory includes Entire Trim Kit. For 4" CFL, 6" CFL, 7" CFL, 4" Metal Halide, 6" Metal Halide, the Calculite Trim Kit must be ordered separately. All combinations require the appropriate Calculite Frame-In Kit. Consult factory for metal halide availability. All units are cULus listed, suitable for damp locations.




Vetro decorative downlight

D02 series

Solid translucent disk with frosted interior and minimal satin ring. Light is released in layered complexity from this semi-recessed luminaire. A solid form of decorative transparency teamed with frosted layers and lighting present an elegant look. Light floats upward to create a soft ceiling wash which adds yet more interest and definition to a space.


4" LED

D4A02: Vetro decorative accessory

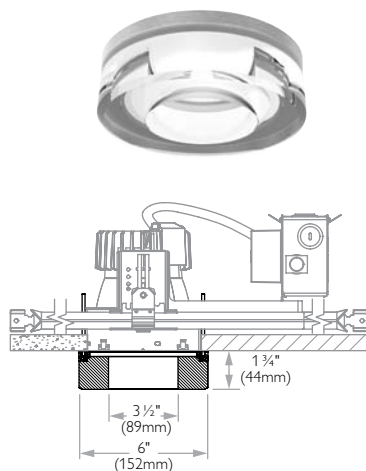


6" LED

D6A02: Vetro decorative accessory

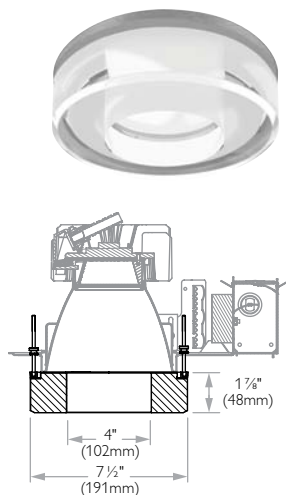

7" LED

D7A02: Vetro decorative accessory

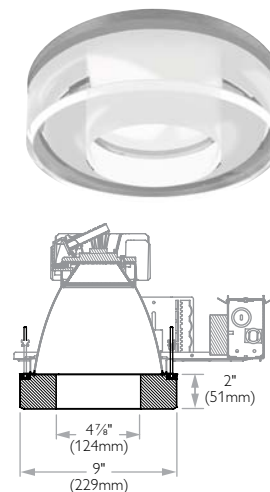

Ordering information for LED

For the 4" LED
D4A02 + C4L05 or C4L10 Series
 Calculte Frame-In Kits
 and Flangeless Trims
 (sold separately)

For the 6" LED
D6A02 + C6L Series
 Calculte Frame-In Kits
 and Flangeless Trims
 (sold separately)

For the 7" LED
D7A02 + C7L Series
 Calculte Frame-In Kits
 and Flangeless Trims
 (sold separately)

Ordering information for HID & CFL

For CFL and Metal Halide options below, reference "Calculte trim and frame-in kit compatibility" on page 6.17 for applicable Calculte frame-in kit and trim ordering information and options.

Ordering example:
D4A02 + 8011CL + 4118VU = Complete fixture
 8011CL Calculte trim sold separately and 4118VU Calculte frame sold separately

4" CFL
D4A02: Vetro decorative accessory

6" CFL
D6A02: Vetro decorative accessory

7" CFL
D7A02: Vetro decorative accessory

4" Metal halide
D4A02: Vetro decorative accessory

6" Metal halide
D6A02: Vetro decorative accessory

3" Evolution
D3MR02: Trim kit and decorative accessory (CL Reflector)

4" Evolution
D4MR02: Trim kit and decorative accessory (CL Reflector)

Note: For 3" and 4" Evolution combinations only, Decorative accessory includes Entire Trim Kit. For 4" CFL, 6" CFL, 7" CFL, 4" Metal Halide, 6" Metal Halide, the Calculte Trim Kit must be ordered separately. All combinations require the appropriate Calculte Frame-In Kit. Consult factory for metal halide availability. All units are cULus listed, suitable for damp locations.

Vetro decorative downlight


D03 series

Angled double opal glass accessory with satin aluminum ring. The ultimate in elegance, the flared luminaire delivers soft, glowing light diffused by frosted opal glass. The setting of satin aluminum adds a distinct design element.




4" LED

D4A03: Vetro decorative accessory

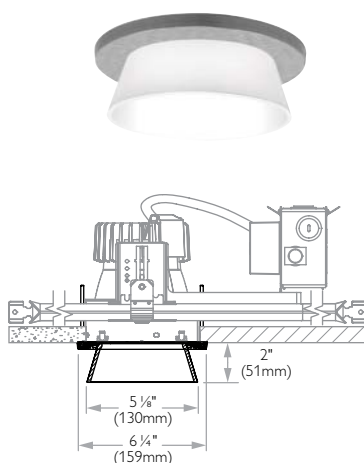


6" LED

D6A03: Vetro decorative accessory

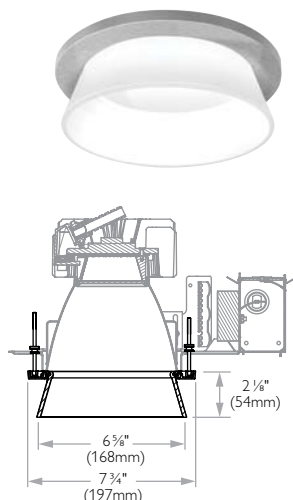

7" LED

D7A03: Vetro decorative accessory

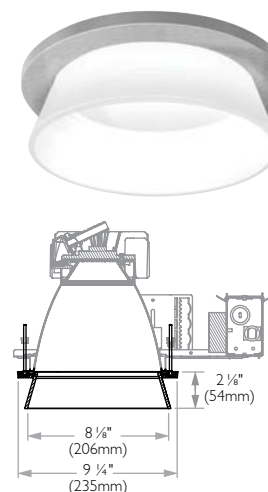

Ordering information for LED

For the 4" LED

D4A03 + C4L05 or C4L10 Series
Calculite Frame-In Kits and Flangeless Trims
(sold separately)

For the 6" LED

D6A03 + C6L Series Calculite
Frame-In Kits and Flangeless Trims
(sold separately)

For the 7" LED

D7A03 + C7L Series Calculite
Frame-In Kits and Flangeless Trims
(sold separately)

Ordering information for HID & CFL

For CFL and Metal Halide options below, reference "Calculite trim and frame-in kit compatibility" on page 6.17 for applicable Calculite frame-in kit and trim ordering information and options.

Ordering example:

D4A03 + 8011CL + 4118VU = Complete fixture

8011CL Calculite trim sold separately and 4118VU Calculite frame sold separately

4" CFL

D4A03: Vetro decorative accessory

6" CFL

D6A03: Vetro decorative accessory

7" CFL

D7A03: Vetro decorative accessory

4" Metal halide

D4A03: Vetro decorative accessory

6" Metal halide

D6A03: Vetro decorative accessory

3" Evolution

D3MR03: Trim kit and decorative accessory (CL Reflector)

4" Evolution

D4MR03: Trim kit and decorative accessory (CL Reflector)

Note: For 3" and 4" Evolution combinations only, Decorative accessory includes Entire Trim Kit. For 4" CFL, 6" CFL, 7" CFL, 4" Metal Halide, 6" Metal Halide, the Calculite Trim Kit must be ordered separately. All combinations require the appropriate Calculite Frame-In Kit. Consult factory for metal halide availability. All units are cULus listed, suitable for damp locations.




Vetro decorative downlight

D13 series

Angled double opal glass in angled clear glass with satin aluminum ring. The striking design of opal encased in clear angled glass creates a stunning luminaire with exceptional interest. The simple pin supports on the satin aluminum ring add an understated element to the design.


4" LED

D4A13: Vetrolite decorative accessory

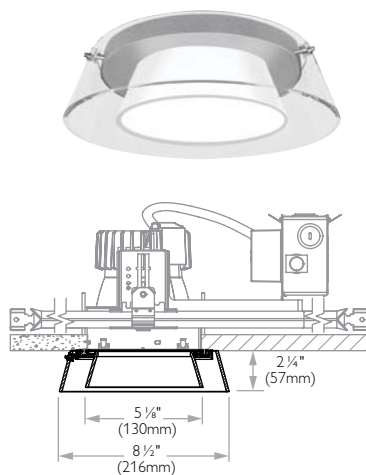


6" LED

D6A13: Vetrolite decorative accessory

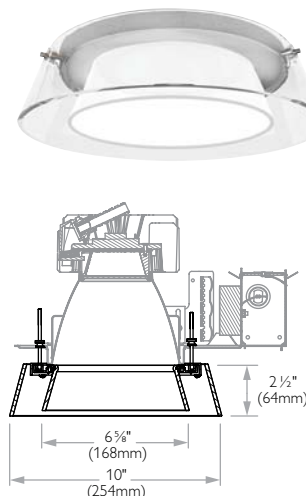

7" LED

D7A13: Vetrolite decorative accessory

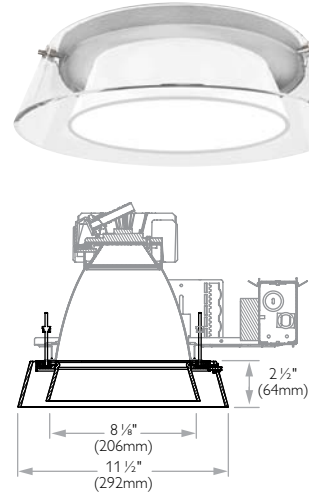

Ordering information for LED

For the 4" LED
D4A13 + C4L05 or C4L10 Series
 Calculite Frame-In Kits
 and Flangeless Trims
 (sold separately)

For the 6" LED
D6A13 + C6L Series
 Calculite Frame-In Kits
 and Flangeless Trims
 (sold separately)

For the 7" LED
D7A13 + C7L Series
 Calculite Frame-In Kits
 and Flangeless Trims
 (sold separately)

Ordering information for HID & CFL

For CFL and Metal Halide options below, reference "Calculite trim and frame-in kit compatibility" on page 6.17 for applicable Calculite frame-in kit and trim ordering information and options.

Ordering Example:
D4A13 + 8011CL + 4118VU = Complete Fixture
 8011CL Calculite trim sold separately and 4118VU Calculite frame sold separately

4" CFL
D4A13: Vetrolite decorative accessory

6" CFL
D6A13: Vetrolite decorative accessory

7" CFL
D7A13: Vetrolite decorative accessory

4" Metal halide
D4A13: Vetrolite decorative accessory

6" Metal halide
D6A13: Vetrolite decorative accessory

3" Evolution
D3MR13: Trim kit and decorative accessory (CL Reflector)

4" Evolution
D4MR13: Trim kit and decorative accessory (CL Reflector)

Note: For 3" and 4" Evolution combinations only, Decorative accessory includes Entire Trim Kit. For 4" CFL, 6" CFL, 7" CFL, 4" Metal Halide, 6" Metal Halide, the Calculite Trim Kit must be ordered separately. All combinations require the appropriate Calculite Frame-In Kit. Consult factory for metal halide availability. All units are cULus listed, suitable for damp locations.

Vetro decorative downlight


D04 series

Opal glass accessory with satin aluminum ring. Perfectly smooth opalescent cylinder highlights the clean design. A satin aluminum ring adds to the finely engineered look.




4" LED

D4A04: Vetro decorative accessory

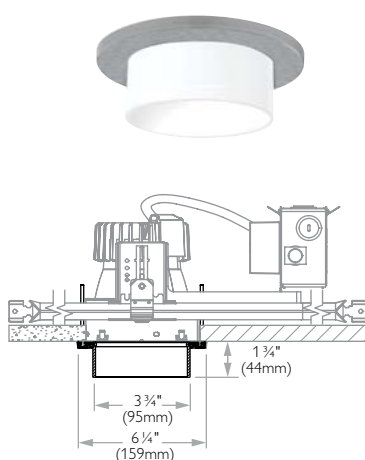


6" LED

D6A04: Vetro decorative accessory

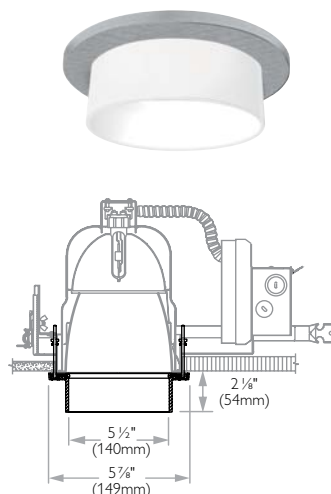

7" LED

D7A04: Vetro decorative accessory

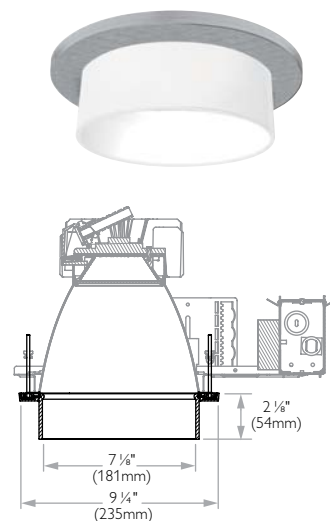

Ordering information for LED

For the 4" LED

D4A04 + C4L05 or C4L10 Series

Calculite Frame-In Kits and Flangeless Trims

(sold separately)

For the 6" LED

D6A04 + C6L Series

Calculite Frame-In Kits and Flangeless Trims

(sold separately)

For the 7" LED

D7A04 + C7L Series

Calculite Frame-In Kits and Flangeless Trims

(sold separately)

Ordering information for HID & CFL

For CFL and Metal Halide options below, reference "Calculite trim and frame-in kit compatibility" on page 6.17 for applicable Calculite frame-in kit and trim ordering information and options.

Ordering Example:

D4A04 + 8011CL + 4118VU = Complete Fixture

8011CL Calculite trim sold separately and 4118VU Calculite frame sold separately

4" CFL

D4A04: Vetro decorative accessory

6" CFL

D6A04: Vetro decorative accessory

7" CFL

D7A04: Vetro decorative accessory

4" Metal halide

D4A04: Vetro decorative accessory

6" Metal halide

D6A04: Vetro decorative accessory

3" Evolution

D3MR04: Trim kit and decorative accessory (CL Reflector)

4" Evolution

D4MR04: Trim kit and decorative accessory (CL Reflector)

Note: For 3" and 4" Evolution combinations only, Decorative accessory includes Entire Trim Kit. For 4" CFL, 6" CFL, 7" CFL, 4" Metal Halide, 6" Metal Halide, the Calculite Trim Kit must be ordered separately. All combinations require the appropriate Calculite Frame-In Kit. Consult factory for metal halide availability. All units are cULus listed, suitable for damp locations.




Vetro decorative downlight

D14 series

Opal glass in clear glass with satin aluminum ring. The perfectly illuminated design of opal encased in a layer of clear glass lends an added element of design for heightened interest. Simple pin supports on the satin aluminum ring create an understated visual element.


4" LED

D4A14: Vetrol decorative accessory

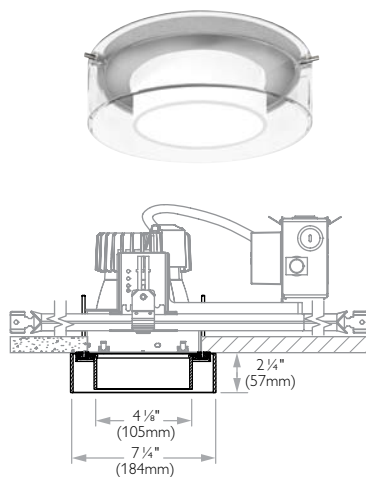


6" LED

D6A14: Vetrol decorative accessory

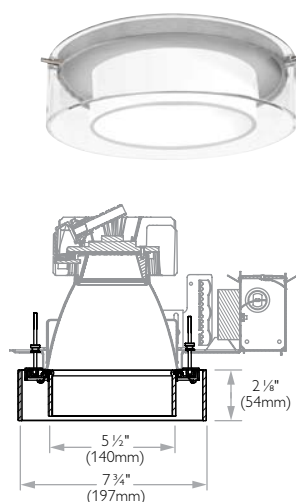

7" LED

D7A14: Vetrol decorative accessory

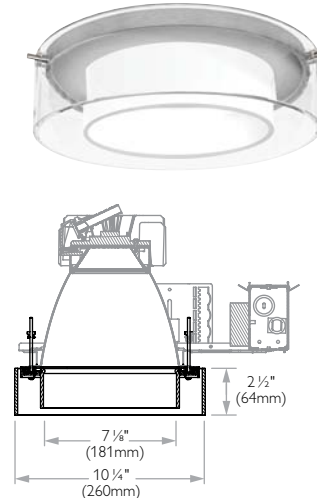

Ordering information for LED

For the 4" LED
D4A14 + C4L05 or C4L10 Series
 Calculte Frame-In Kits
 and Flangeless Trims
 (sold separately)

For the 6" LED
D6A14 + C6L Series
 Calculte Frame-In Kits
 and Flangeless Trims
 (sold separately)

For the 7" LED
D7A14 + C7L Series
 Calculte Frame-In Kits
 and Flangeless Trims
 (sold separately)

Ordering information for HID & CFL

For CFL and Metal Halide options below, reference "Calculte trim and frame-in kit compatibility" on page 6.17 for applicable Calculte frame-in kit and trim ordering information and options.

Ordering Example:
D4A14 + 8011CL + 4118VU = Complete Fixture
 8011CL Calculte trim sold separately and 4118VU Calculte frame sold separately

4" CFL
D4A14: Vetrol decorative accessory

6" CFL
D6A14: Vetrol decorative accessory

7" CFL
D7A14: Vetrol decorative accessory

4" Metal halide
D4A14: Vetrol decorative accessory

6" Metal halide
D6A14: Vetrol decorative accessory


3" Evolution
D3MR14: Trim kit and decorative accessory (CL Reflector)

4" Evolution
D4MR14: Trim kit and decorative accessory (CL Reflector)

Note: For 3" and 4" Evolution combinations only, Decorative accessory includes Entire Trim Kit. For 4" CFL, 6" CFL, 7" CFL, 4" Metal Halide, 6" Metal Halide, the Calculte Trim Kit must be ordered separately. All combinations require the appropriate Calculte Frame-In Kit. Consult factory for metal halide availability. All units are cULus listed, suitable for damp locations.

Vetro decorative downlight

Calculate trim and frame-in kit compatibility

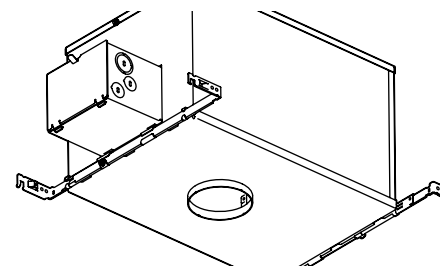

4" CFL

Ordering information

- 1 **D4A01:** Vetro decorative accessory
- 2 Order Trim Separately: 8011CL
- 3 For use with Frame-In Kits: 4118VU Family

4" Metal Halide

Ordering information

- 1 For HID:
D4A01: Vetro decorative accessory
- 2 Order Trim Separately: C4T4VWCL
- 3 For use with Frame-In Kits:
C420T4EU; VC439T4E1; VC439T4E2
- 1 For 4" PAR20 Metal halide:
D4A01: Vetro decorative accessory
- 2 Order Trim: C4P20MHCL
- 3 Order Frame-In Kit: C439P20E1 / E2

39W max. consult factory for other options.

3" Evolutions

Ordering information

- 1 **D3MR04:** Trim kit and decorative accessory (CL reflector)
- 2 For use with Frame-In Kits:
C3LV; C3AICLV; C3ALV; C3LVE1; C3LVE2;
C3ALVE1; C3ALVE2; C3AICLVE1

6" CFL

Ordering information

- 1 For Vertical CFL:
D6A01: Vetro decorative accessory
- 2 Order Trim Separately: 8021CL; 8031CL; 8091PCL
- 3 For use with Frame-In Kits: S6132BU Family
- 1 For 13W Horizontal CFL:
D6A01: Vetro decorative accessory
- 2 Order Trim Separately: 8025CL
- 3 For use with Frame-In Kits: 6213HU Family
- 1 For 18W Horizontal CFL:
D6A01: Vetro decorative accessory
- 2 Order Trim Separately: 8056CL, 8096PCL
- 3 For use with Frame-In Kits: 6218HU Family

6" Metal Halide

Ordering information

- 1 For HID:
D6A01: Vetro decorative accessory
- 2 Order Trim Separately: C6T6VWCL
- 3 For use with Frame-In Kits: C639T6E1; C639T6E2
- 1 For 6" PAR30 Metal halide:
D6A01: Vetro decorative accessory
- 2 Order Trim: C6P30MHCL
- 3 Order Frame-In Kit: C639MHE1 / E2; C639MHU

39W max. consult factory for other options.

4" Evolutions

Ordering information

- 1 **D3MR04:** Trim kit and decorative accessory (CL reflector)
- 2 For use with Frame-In Kits:
C4LV; C4ALV; C4AICLV

7" CFL

Ordering information

- 1 For Vertical CFL:
D7A01: Vetro decorative accessory
- 2 Order Trim Separately: 8022CL; 8037CL; 8097PCL
- 3 For use with Frame-In Kits: S7142BU Family
- 1 For 2 Lamp Horizontal CFL:
D7A01: Vetro decorative accessory
- 2 Order Trim Separately: 8056CL, 8096PCL
- 3 For use with Frame-In Kits: 7218HU, S7226HU Fam.
- 1 For 1 Lamp Horizontal CFL:
D7A01: Vetro decorative accessory
- 2 Order Trim Separately: 8056CL
- 3 For use with Frame-In Kits: 7126HU Family



Optimo surface mount

Round & square series

Optimo, available in three main sizes: 12", 16", 22", utilizes basic geometry of round and squares. Opal composite diffusers are injection molded polycarbonate and polished acrylic for sleek luminous planes on the forward face. Each luminaire utilizes energy efficient, electronic compact fluorescent lamps that offer the most even and architecturally desirable illumination.

Each luminaire has a solidly manufactured, true aluminum body. This design is superior in both mechanical durability and results in a sleeker visual offering. Optimo truly combines form and function. The end result is a varied array of design tools available to enhance the most discerning interiors.

Optimo is designed with the luminaire floating off the mounting plane, creating a ribbon of standard white light to the back of each body. Accessory kits are available in three additional shades: garnet, sapphire, and citrine. The total effect creates a weightless design entity that adds a sophisticated element to the space.



Optimo round reveal



RR series

Classic satin aluminum housing displays a continuous Side Spill Reveal of light.
Opal composite diffusers provide a clean geometric interest of light.

Ordering information: Order Diffuser + Backplate for a complete fixture.

RR12AL

Round reveal · 12-inch

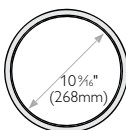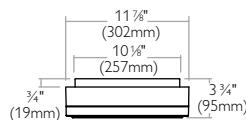

Circline lamp

56949 22W Circline 3000K

56951 22W Circline 3500K

ADA Compliant

Diffuser assembly

RR12AL

Housing: 12" Side Spill Reveal Satin Aluminum

Diffuser: White Chamfered Injection Molded Polycarbonate

CFL Backplate

R122U

Backplate: 12" Round

Ballast: 120V-277V

Lamp: 22W Circline

(2GX13 Base)

LED Backplate

R01L12

Backplate: 12" Round

Power Supply: 120V electronic

(24V DC Output)



Lamp: 4.5W White LED Boards

Accessory color kit (includes all 3 colors)

RACC12 ● Citrine ● Garnet ● Sapphire

RR16AL

Round reveal · 16-inch

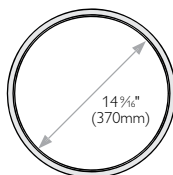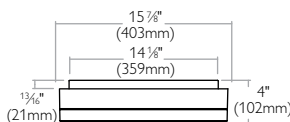

Circline lamp

56949 22W Circline 3000K

56951 22W Circline 3500K

56958 40W Circline 3000K

56965 40W Circline 3500K

ADA Compliant

Diffuser assembly

RR16AL

Housing: 16" Side Spill Reveal Satin Aluminum

Diffuser: White Chamfered Injection Molded Polycarbonate

CFL Backplate

R16140U*

Backplate: 16" Round

Ballast: 120V-277V

Lamp: 40W Circline

(2GX13 Base)

R2240U

Backplate: 16" Round

Ballast: 120V-277V

Lamp: 22W & 40W

Circline (2GX13 Base)

R318U

Backplate: 16" Round

Ballast: 120V-277V

Lamp: (3) 18W Twin

Tube (2G11 Base)

LED Backplate

R01L16

Backplate: 12" Round

Power Supply: 120V electronic (24V DC Output)



Lamp: 4.5W White LED Boards

Accessory color kit (includes all 3 colors)

RACC16 ● Citrine ● Garnet ● Sapphire

RR22AL

Round reveal · 22-inch

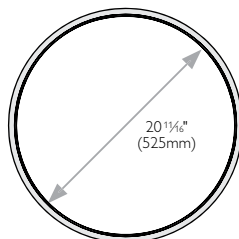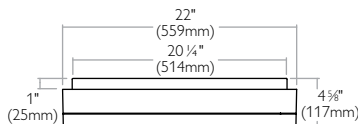

Diffuser assembly

RR22AL

Housing: 16" Side Spill Reveal Satin Aluminum

Diffuser: White Chamfered Injection Molded Polycarbonate

CFL Backplate

R2436U

Backplate: 22" Round

Ballast: 120V-277V

Lamp: (2) 24W and

(2) 36W Twin Tube

(2G11 Base)

R222436U*

Backplate: 22" Round

Ballast: 120V-277V

Lamp: (2) 24W and

(1) 36W Twin Tube

(2G11 Base)

LED Backplate

R01L22

Backplate: 22" Round

Power Supply:

120V electronic

(24V DC Output)

Lamp: 4.5W White

LED Boards

Accessory color kit (includes all 3 colors)

RACC22 ● Citrine ● Garnet ● Sapphire

Please consult specification sheets for **EM** and additional lamping options.

* Add **E** to SKU for emergency option.



Optimo round taper


RT series

True aluminum body transition adds a contemporary element to a space.
Ornate diffusers offer even illumination for a sleek visual offering.

Ordering information: Order Diffuser + Backplate for a complete fixture.

RT12AL

Round taper · 12-inch

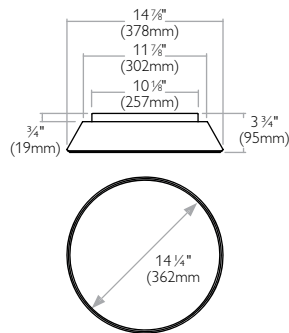

Circline lamp

56949 22W Circline 3000K

56951 22W Circline 3500K

ADA Compliant

Diffuser assembly

RT12AL

Housing: 12" Tapered Satin Aluminum

Diffuser: White Chamfered Injection Molded Polycarbonate

CFL Backplate

R122U

Backplate: 12" Round

Ballast: 120V-277V

Lamp: 22W Circline
(2GX13 Base)

LED Backplate

R01L12

Backplate: 12" Round

Power Supply: 120V electronic
(24V DC Output)


Lamp: 4.5W White LED Boards

Accessory color kit (includes all 3 colors)

RACC12 ● Citrine ● Garnet ● Sapphire

RT16AL

Round taper · 16-inch

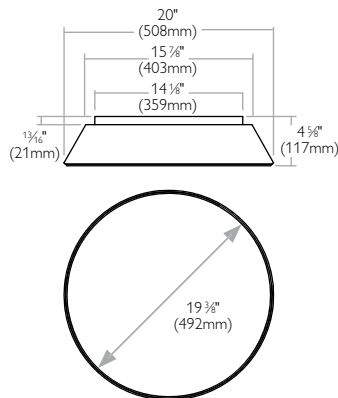

Circline lamp

56949 22W Circline 3000K

56951 22W Circline 3500K

56958 40W Circline 3000K

56965 40W Circline 3500K

Diffuser assembly

RT16AL

Housing: 16" Tapered Satin Aluminum

Diffuser: White Chamfered Injection Molded Polycarbonate

CFL Backplate

R16140U*

Backplate: 16" Round

Ballast: 120V-277V

Lamp: 40W Circline
(2GX13 Base)

R2240U

Backplate: 16" Round

Ballast: 120V-277V

Lamp: 22W & 40W
Circline (2GX13 Base)

R318U

Backplate: 16" Round

Ballast: 120V-277V

Lamp: (3) 18W Twin
Tube (2G11 Base)

LED Backplate

R01L16

Backplate: 12" Round

Power Supply: 120V electronic (24V DC Output)

Lamp: 4.5W White LED Boards

Accessory color kit (includes all 3 colors)

RACC16 ● Citrine ● Garnet ● Sapphire

Optimo round curve

RC series


Polished diffusers offer sleek luminous planes on the forward face.
Die-cast aluminum body offers a weightless design.



Ordering information: Order Diffuser + Backplate for a complete fixture.

RC12AL

Round curve · 12-inch

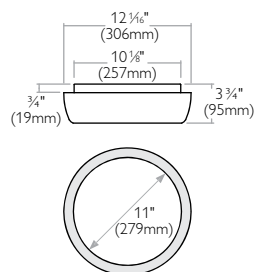

Circline lamp

56949 22W Circline 3000K
56951 22W Circline 3500K
ADA Compliant

Diffuser assembly

RC12AL

Housing: 12" Curved Satin Aluminum
Diffuser: Opal Flat Acrylic

CFL Backplate

R122U

Backplate: 12" Round
Ballast: 120V-277V
Lamp: 22W Circline
(2GX13 Base)

LED Backplate

R01L12


Backplate: 12" Round
Power Supply: 120V electronic
(24V DC Output)
Lamp: 4.5W White LED Boards

Accessory color kit (includes all 3 colors)

RACC12 Citrine Garnet Sapphire

RC16AL

Round curve · 16-inch

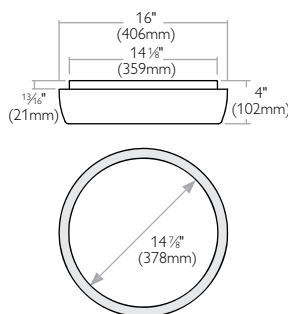

Circline lamp

56949 22W Circline 3000K
56951 22W Circline 3500K
56958 40W Circline 3000K
56965 40W Circline 3500K
ADA Compliant

Diffuser assembly

RC16AL

Housing: 16" Curved Satin Aluminum
Diffuser: Opal Flat Acrylic

CFL Backplate

R16140U*

Backplate: 16" Round
Ballast: 120V-277V
Lamp: 40W Circline
(2GX13 Base)

R2240U

Backplate: 16" Round
Ballast: 120V-277V
Lamp: 22W & 40W
Circline (2GX13 Base)

R318U

Backplate: 16" Round
Ballast: 120V-277V
Lamp: (3) 18W Twin
Tube (2G11 Base)

LED Backplate

R01L16


Backplate: 12" Round
Power Supply: 120V electronic (24V DC Output)
Lamp: 4.5W White LED Boards

Accessory color kit (includes all 3 colors)

RACC16 Citrine Garnet Sapphire

RC22AL

Round curve · 22-inch

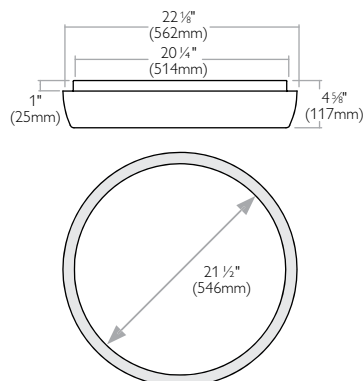

Diffuser assembly

RC22AL

Housing: 22" Curved Satin Aluminum
Diffuser: Opal Flat Acrylic

CFL Backplate

R2436U

Backplate: 22" Round
Ballast: 120V-277V
Lamp: (2) 24W and
(2) 36W Twin Tube
(2G11 Base)

R222436U*

Backplate: 22" Round
Ballast: 120V-277V
Lamp: (2) 24W and
(1) 36W Twin Tube
(2G11 Base)

LED Backplate

R01L22

Backplate: 22" Round
Power Supply:
120V electronic
(24V DC Output)
Lamp: 4.5W White
LED Boards

Accessory color kit (includes all 3 colors)

RACC22 Citrine Garnet Sapphire

Please consult specification sheets for **EM** and additional lamping options.

* Add **E** to SKU for emergency option.



Optimo square reveal


SR series

Side Spill Reveal of light offers an added level of architectural sophistication to a space. Designed for even illumination.

Ordering information: Order Diffuser + Backplate for a complete fixture.

SR12AL

Square reveal · 12-inch

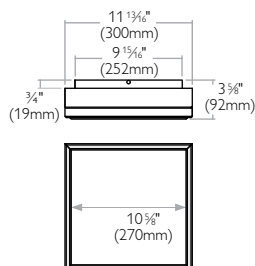

Circline lamp

56949 22W Circline 3000K

56951 22W Circline 3500K

ADA Compliant

Diffuser assembly

SR12AL

Housing: 12" Side Spill Reveal Satin Aluminum

Diffuser: White Chamfered Injection Molded Polycarbonate

CFL Backplate

S122U

Backplate: 12" Round

Ballast: 120V-277V

Lamp: 22W Circline

(2GX13 Base)

LED Backplate

S01L12

Backplate: 12" Round

Power Supply: 120V electronic

(24V DC Output)


Lamp: 4.5W White LED Boards

Accessory color kit (includes all 3 colors)

SACC12 ● Citrine ● Garnet ● Sapphire

SR16AL

Square reveal · 16-inch

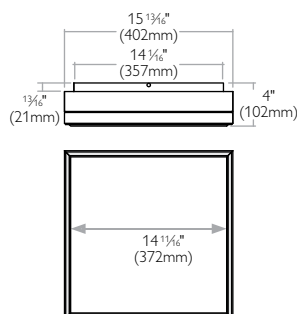

Circline lamp

56949 22W Circline 3000K

56951 22W Circline 3500K

56958 40W Circline 3000K

56965 40W Circline 3500K

ADA Compliant

Diffuser assembly

SR16AL

Housing: 16" Side Spill Reveal Satin Aluminum

Diffuser: White Chamfered Injection Molded Polycarbonate

CFL Backplate

S16140U*

Backplate: 16" Round

Ballast: 120V-277V

Lamp: 40W Circline

(2GX13 Base)

S2240U

Backplate: 16" Round

Ballast: 120V-277V

Lamp: 22W & 40W

Circline (2GX13 Base)

LED Backplate

S01L16

Backplate: 12" Round

Power Supply:

120V electronic

(24V DC Output)

Lamp: 4.5W White


LED Boards

Accessory color kit (includes all 3 colors)

SACC16 ● Citrine ● Garnet ● Sapphire

SR22AL

Square reveal · 22-inch

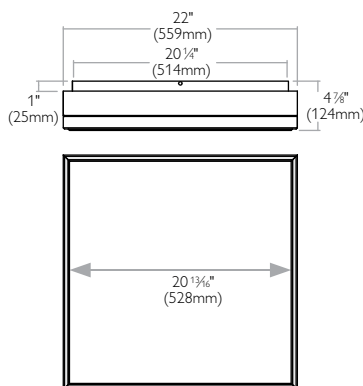

Diffuser assembly

SR22AL

Housing: 22" Side Spill Reveal Satin Aluminum

Diffuser: White Chamfered Injection Molded Polycarbonate

CFL Backplate

S336U

Backplate: 22" Round

Ballast: 120V-277V

Lamp: (3) 36W

Twin Tube

(2G11 Base)

S22324U*

Backplate: 22" Round

Ballast: 120V-277V

Lamp: (3) 24W

Twin Tube

(2G11 Base)

LED Backplate

S01L22

Backplate: 22" Round

Power Supply:

120V electronic

(24V DC Output)

Lamp: 4.5W White

LED Boards


Accessory color kit (includes all 3 colors)

SACC22 ● Citrine ● Garnet ● Sapphire

Optimo square taper

ST series


The tapered detail adds a distinct design element, simple but expressive. Standard back reveal of white light creates an accentuated level of class.

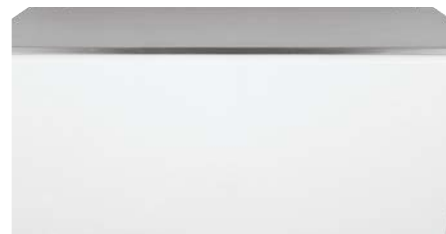

Ordering information: Order Diffuser + Backplate for a complete fixture.

ST12AL

Square taper · 12-inch

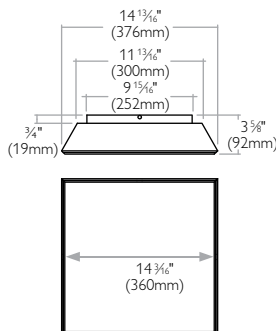

Circline lamp

56949 22W Circline 3000K
56951 22W Circline 3500K

ADA Compliant

Diffuser assembly

ST12AL

Housing: 12" Tapered Satin Aluminum

Diffuser: White Chamfered Injection Molded Polycarbonate

CFL Backplate

S122U

Backplate: 12" Round

Ballast: 120V-277V

Lamp: 22W Circline
 (2GX13 Base)

LED Backplate

S01L12

Backplate: 12" Round

Power Supply: 120V electronic
 (24V DC Output)


Lamp: 4.5W White LED Boards

Accessory color kit (includes all 3 colors)

SACC12 ● Citrine ● Garnet ● Sapphire

ST16AL

Square taper · 16-inch

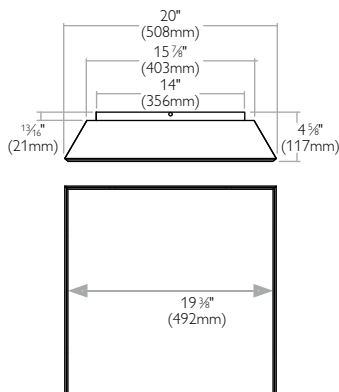

Circline lamp

56949 22W Circline 3000K

56951 22W Circline 3500K

56958 40W Circline 3000K

56965 40W Circline 3500K

Diffuser assembly

ST16AL

Housing: 16" Tapered Satin Aluminum

Diffuser: White Chamfered Injection Molded Polycarbonate

CFL Backplate

S16140U*

Backplate: 16" Round

Ballast: 120V-277V

Lamp: 40W Circline
 (2GX13 Base)

S2240U

Backplate: 16" Round

Ballast: 120V-277V

Lamp: 22W & 40W
 Circline (2GX13 Base)

LED Backplate

S01L16

Backplate: 12" Round

Power Supply:

120V electronic
 (24V DC Output)

Lamp: 4.5W White LED Boards

Accessory color kit (includes all 3 colors)

SACC12 ● Citrine ● Garnet ● Sapphire



Optimo curved square reveal


CSR series

Curved Optimo is both a simple and pure design tool. Elegant ribbon of light to the back of each body.

Ordering information: order diffuser + backplate for a complete fixture.

CSR12AL

Curved square reveal · 12-inch

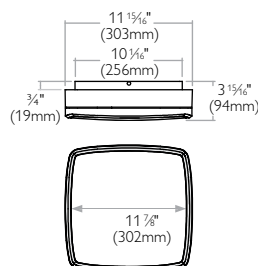

Circline lamp

56949 22W Circline 3000K
56951 22W Circline 3500K

ADA Compliant

Diffuser assembly

CSR12AL

Housing: 12" Side Spill Reveal Curved Satin Aluminum
 Diffuser: White Injection Molded Polycarbonate

CFL Backplate

S122U

Backplate: 12" Round
 Ballast: 120V-277V
 Lamp: 22W Circline
 (2GX13 Base)

LED Backplate

S01L12


Backplate: 12" Round
 Power Supply: 120V electronic
 (24V DC Output)
 Lamp: 4.5W White LED Boards

Accessory color kit (includes all 3 colors)

SQACC12 ● Citrine ● Garnet ● Sapphire

CSR16AL

Curved square reveal · 16-inch

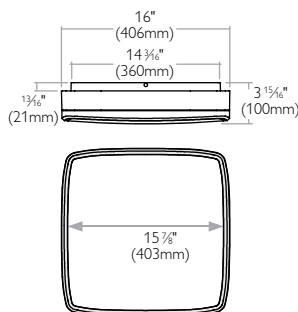

Circline lamp

56949 22W Circline 3000K
56951 22W Circline 3500K
56958 40W Circline 3000K
56965 40W Circline 3500K

Diffuser assembly

CSR16AL

Housing: 16" Side Spill Reveal Curved Satin Aluminum
 Diffuser: White Injection Molded Polycarbonate

CFL Backplate

S16140U*

Backplate: 16" Round
 Ballast: 120V-277V
 Lamp: 40W Circline
 (2GX13 Base)

S2240U

Backplate: 16" Round
 Ballast: 120V-277V
 Lamp: 22W & 40W
 Circline (2GX13 Base)

LED Backplate

S01L16

Backplate: 16" Round
 Power Supply:
 120V electronic
 (24V DC Output)
 Lamp: 4.5W White
 LED Boards

Accessory color kit (includes all 3 colors)


SQACC16 ● Citrine ● Garnet ● Sapphire

* Add **E** to SKU for emergency option.


Please consult specification sheets for **EM** and additional lamping options.

Optimo deconstructed


Round & square series

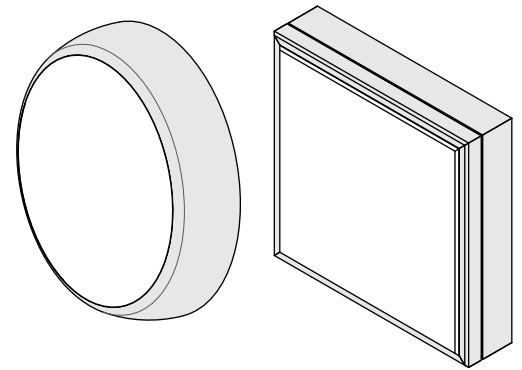

Round series

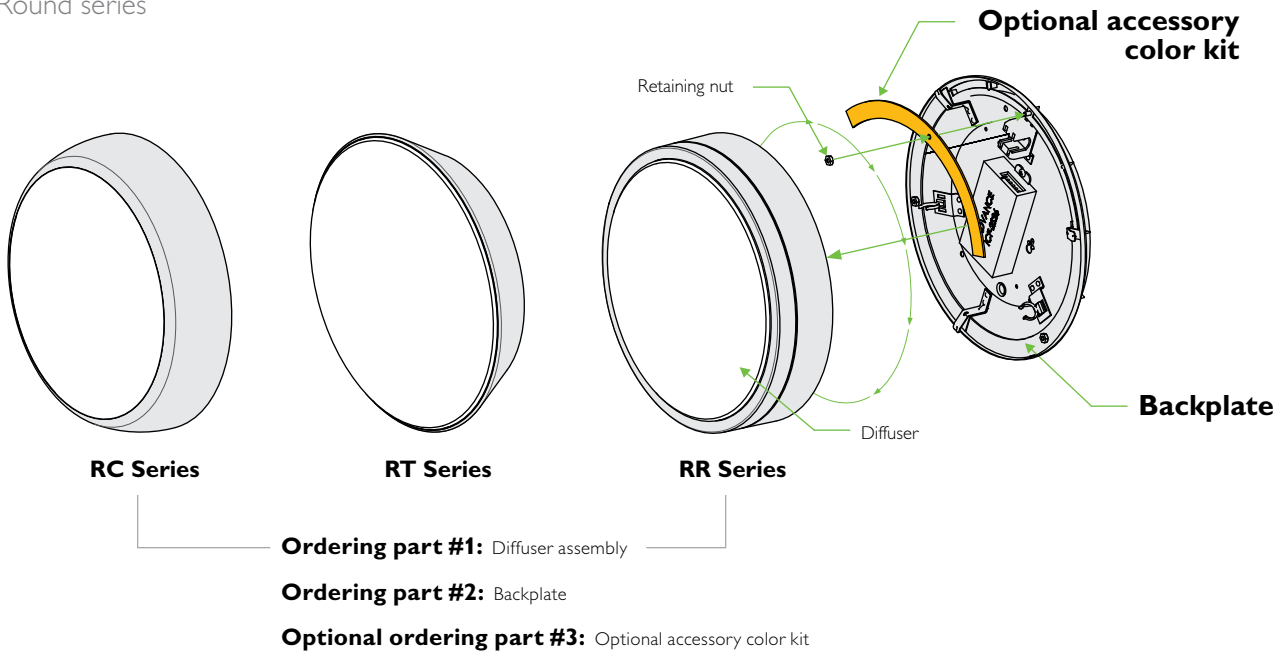

Square series

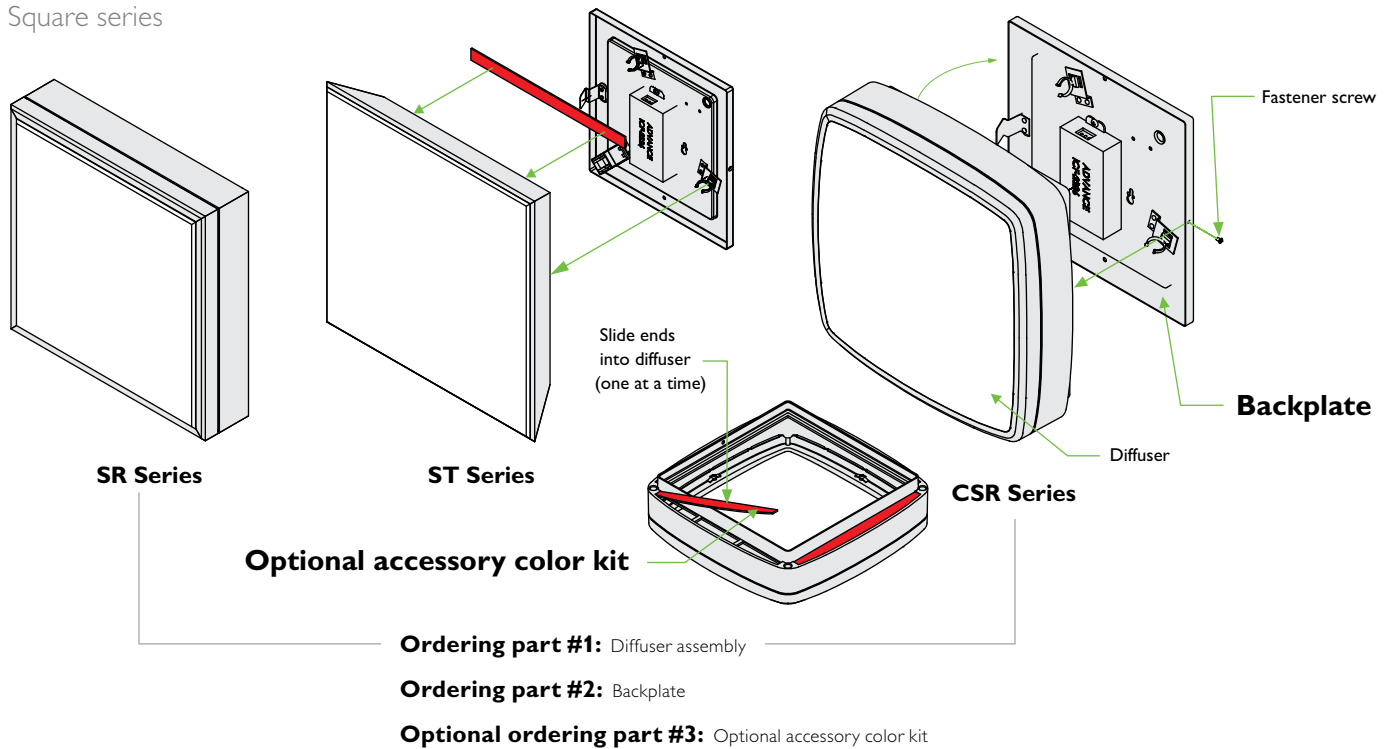



Brisa surface mounted ADA

Bow, Curve and Planar series

Brisa offers three discrete designs—Bow, Curve and Planar—ideal for numerous architectural requirements. Minimal, distinct forms define the collection. Proportions range from intimate to dramatic. Quality materials embody the designs. Opal glass evenly diffuses light while clear float glass highlights reflections. Brushed aluminum creates dramatic profiles and lines.

The minimal, clean aesthetic provides timeless options in light. Brisa provides a diverse set of tools for the Architect, Lighting Designer and Interior Designer. The designs stand alone as feature elements or blend seamlessly into the environment. Mounting options are ample—wall or ceiling, horizontal or vertical. Brisa is ADA compliant. Energy efficient T5 lamping meets today's sustainability needs. The Brisa package provides solutions with light.

All units are cULus listed, suitable for damp locations. Emergency units are UL listed for dry location only.



Bow series



Curve series



Planar series


Brisa surface mounted ADA

Bow series



9" Wide

FB9114: Fluorescent bow · 3 x 14W

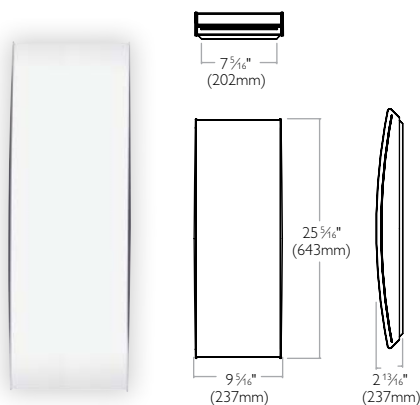


Multiple lamp

Housing	Description	Volts	Lamp	Diffuser	Description	Finish	Dim.
FB9314U	Surface mount	120V-277V	(3) T5	FBA9	Acrylic Bow	Opal	9" x 24"
FB9314UEM	Surface mount / emergency	120V-277V	(3) T5	FBG9	Glass Bow	Opal	9" x 24"
FB9314LEC1	Surface mount / dimming*	120V	(3) T5	Note: Must order both housing and diffuser for complete fixture. * Lutron Eco-10 Dimming.			
FB9314LEC2	Surface mount / dimming*	277V	(3) T5				
FB9314UDA	Surface mount / dali dimming	120V-277V	(3) T5				

Note: **FB9314LEC1** & **FB9314LEC2** are wall mount only.

5" Wide

FB5114: Fluorescent bow · 14W

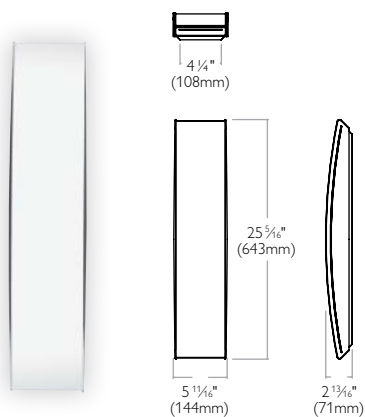

Single lamp


Housing	Description	Volts	Lamp	Diffuser	Description	Finish	Dim.
FB5114U	Surface mount	120V-277V	(1) T5	FBA5	Acrylic bow	Opal	5" x 24"
FB5114UEM	Surface mount / emergency	120V-277V	(1) T5	FBG5	Glass bow	Opal	5" x 24"
FB5114LEC1	Surface mount / dimming*	120V	(1) T5	Note: Must order both housing and diffuser for complete fixture. * Lutron Eco-10 Dimming.			
FB5114LEC2	Surface mount / dimming*	277V	(1) T5				
FB5114UDA	Surface mount / dali dimming	120V-277V	(1) T5				

Multiple lamp

Housing	Description	Volts	Lamp
FB5214U	Surface mount	120V-277V	(2) T5
FB5214LEC1	Surface mount / dimming*	120V	(2) T5
FB5214LEC2	Surface mount / dimming*	277V	(2) T5
FB5214UDA	Surface mount / dali dimming	120V-277V	(2) T5

3" Wide

FB3114: Fluorescent bow · 14W

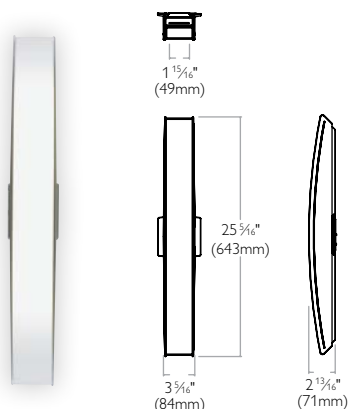

Single lamp

Housing	Description	Volts	Lamp
FB3114E1	Surface mount	120V	(1) T5
FB3114E2	Surface mount	277V	(1) T5

Note: Bow 3" Series includes die-cast junction box cover.


Diffuser	Description	Finish	Dim.
FBA3	Acrylic Bow	Opal	3" x 24"
FBG3	Glass Bow	Opal	3" x 24"

Note: Must order both housing and diffuser for complete fixture.
* Lutron Eco-10 Dimming.

J-Box cover

1 1/4" wide · FB Covers

FB3 Series includes die-cast junction box cover.

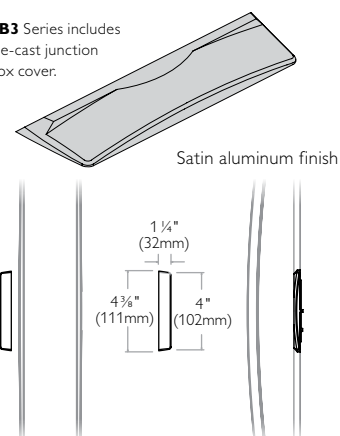

All units are cULus listed, suitable for damp locations. Emergency units are UL listed for dry location only.




Brisa surface mounted ADA

Curved series

48" Long

FC28: Fluorescent curve · 28W

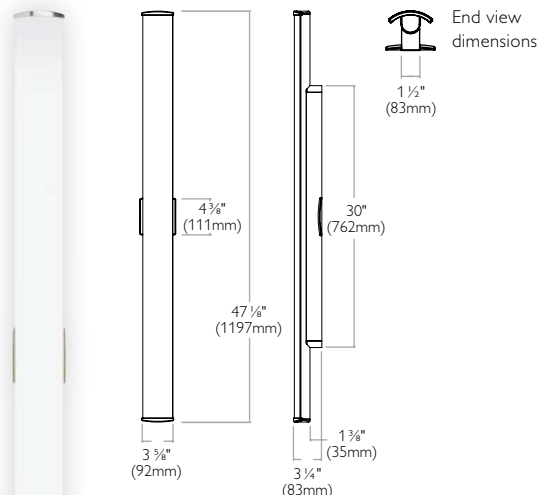

Single lamp


Housing	Description	Volts	Lamp
FC28U	Surface mount	120V-277V	(1) T5
FC28LEC1	Surface mount / dimming*	120V	(1) T5
FC28LEC2	Surface mount / dimming*	277V	(1) T5

Diffuser	Description	Finish	Dimensions
FCA3	Acrylic curve	Opal	4" x 48"
FCG3	Glass curve	Opal	4" x 48"

Note: Must order both housing and diffuser for complete fixture.
* Lutron Eco-10 Dimming.

36" Long

FC21: Fluorescent curve · 21W

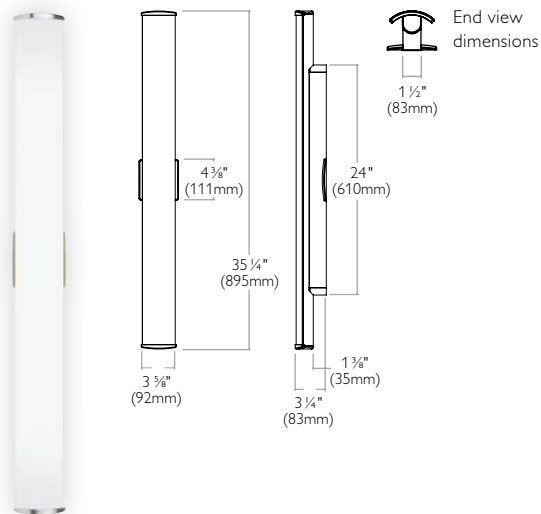

Single lamp


Housing	Description	Volts	Lamp
FC21U	Surface mount	120V-277V	(1) T5
FC21LEC1	Surface mount / dimming*	120V	(1) T5
FC21LEC2	Surface mount / dimming*	277V	(1) T5

Diffuser	Description	Finish	Dimensions
FCA2	Acrylic curve	Opal	4" x 36"
FCG2	Glass curve	Opal	4" x 36"

Note: Must order both housing and diffuser for complete fixture.
* Lutron Eco-10 Dimming.

24" Long

FC14: Fluorescent curve · 14W

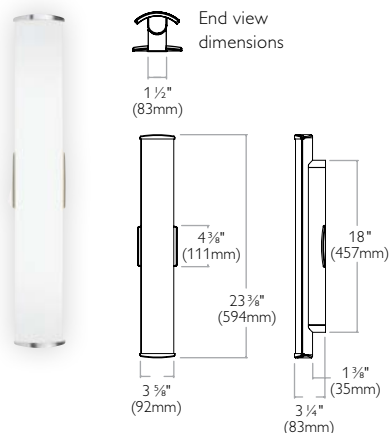

Single Lamp

Housing	Description	Volts	Lamp
FC14U	Surface mount	120V-277V	(1) T5



Diffuser	Description	Finish	Dimensions
FCA1	Acrylic curve	Opal	4" x 24"
FCG1	Glass curve	Opal	4" x 24"

Note: Must order both housing and diffuser for complete fixture.
* Lutron Eco-10 Dimming.

J-Box cover

1 1/4" wide · FC Covers

FC Series includes die-cast junction box cover.

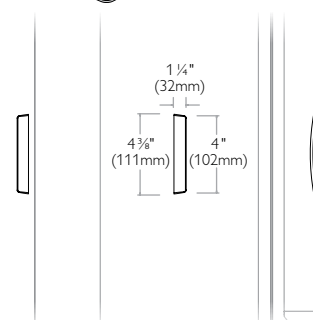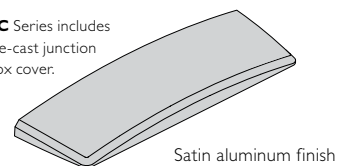

All units are cULus listed, suitable for damp locations. Emergency units are UL listed for dry location only.


Brisa surface mounted ADA

Planar series



48" Long

FP28: Fluorescent planar · 28W

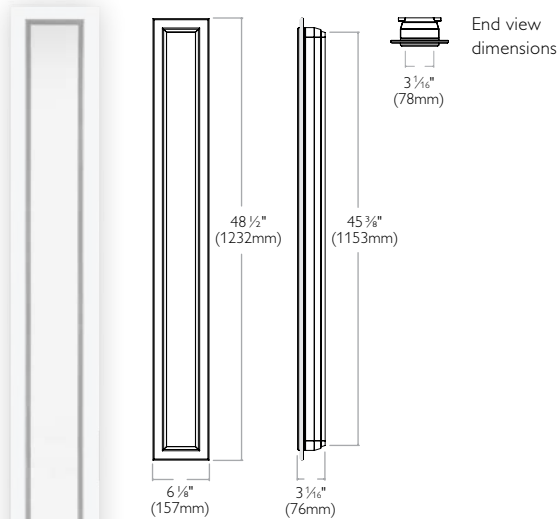

Single lamp


Housing	Description	Volts	Lamp
FP28U	Surface mount	120V-277V	(1) T5
FP28UEM	Surface mount / emergency	120V-277V	(1) T5
FP28LEEC1	Surface mount / dimming*	120V	(1) T5
FP28LEEC2	Surface mount / dimming*	277V	(1) T5
FP28UDA	Surface mount / dali dimming	120V-277V	(1) T5

Diffuser	Description	Finish	Dimensions
FPA3	Acrylic planar	Opal	6" x 48"
FPG3	Glass planar	Opal	6" x 48"

Note: Must order both housing and diffuser for complete fixture.
* Lutron Eco-10 Dimming.

36" Long

FP21: Fluorescent planar · 21W

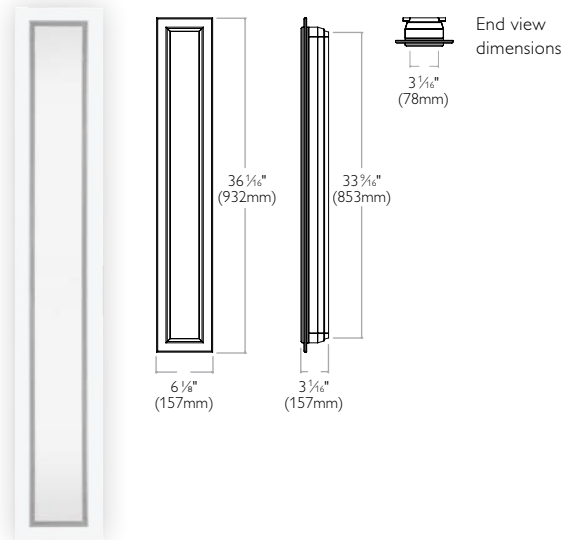

Single lamp


Housing	Description	Volts	Lamp
FP21U	Surface mount	120V-277V	(1) T5
FP21UEM	Surface mount / emergency	120V-277V	(1) T5
FP21LEEC1	Surface mount / dimming*	120V	(1) T5
FP21LEEC2	Surface mount / dimming*	277V	(1) T5
FP14UDA	Surface mount / dali dimming	120V-277V	(1) T5

Diffuser	Description	Finish	Dimensions
FPA2	Acrylic planar	Opal	6" x 36"
FPG2	Glass planar	Opal	6" x 36"

Note: Must order both housing and diffuser for complete fixture.
* Lutron Eco-10 Dimming.

24" Long

FP14: Fluorescent planar · 14W

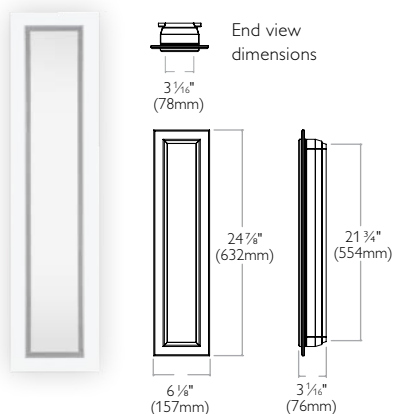

Single lamp

Housing	Description	Volts	Lamp
FP14U	Surface mount	120V-277V	(1) T5
FP14UEM	Surface mount / emergency	120V-277V	(1) T5
FP14LEEC1	Surface mount / dimming*	120V	(1) T5
FP14LEEC2	Surface mount / dimming*	277V	(1) T5
FP14UDA	Surface mount / dali dimming	120V-277V	(1) T5



Diffuser	Description	Finish	Dimensions
FPA1	Acrylic planar	Opal	6" x 24"
FPG1	Glass planar	Opal	6" x 24"

Note: Must order both housing and diffuser for complete fixture.
* Lutron Eco-10 Dimming.

J-Box cover

3/4" wide · FP Covers

FP Series includes die-cast junction box cover.

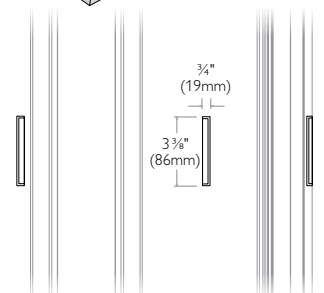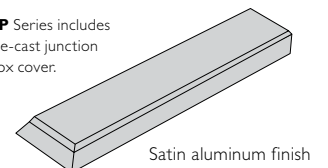





Soli surface mounted ADA

T5 series

ADA compliant, energy efficient T5 linear fluorescent lamping, two diffuser options. Units can be wall mounted vertically, horizontally, or on the ceiling. The finish is a powder coat paint. Soli is light in equilibrium: a pure linear statement that accents interior elements through light and silhouette. Light filters through and reflects off the curvature of the etched glass, spilling onto the surrounding surface. A single brilliant line in the center of the silhouetted body maintains the balance between light and dark.

2' Long

 T5 Surface mounted

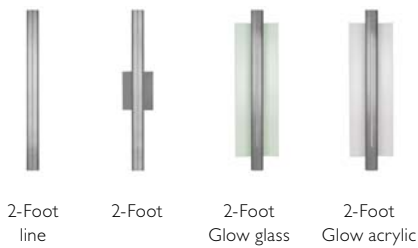



Catalog number	Description	Lamp (qty/type)	Ballast	Voltage
48021ALU	2-Foot line	1 x 14W T5 LF	Electronic	120V-277V
48021AL24U	2-Foot line HO	1 x 24W T5 LFHO	Electronic	120V-277V
40874	2-Foot glow glass			
40914	2-Foot glow acrylic			

Note: Order glass/diffuser separately.

LF = Linear fluorescent.
HO = High output lamp.

3' Long

 T5 Surface mounted

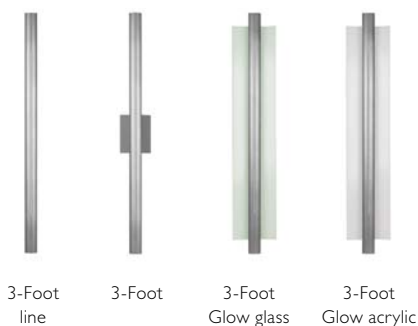



Catalog number	Description	Lamp (qty/type)	Ballast	Voltage
48022ALU	3-Foot line	1 x 21W T5 LF	Electronic	120V-277V
48022AL39U	3-Foot line HO	1 x 39W T5 LF HO	Electronic	120V-277V
40875	3-Foot glow glass			
40915	3-Foot glow acrylic			

Note: Order glass/diffuser separately.

LF = Linear fluorescent.
HO = High output lamp.

4' Long

 T5 Surface mounted

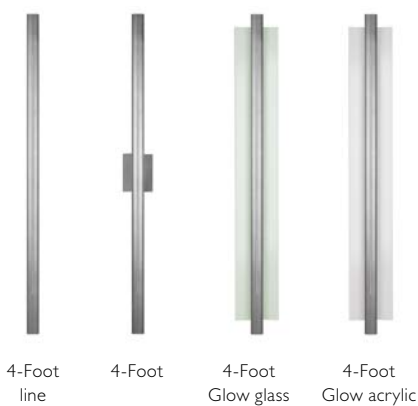

Catalog number	Description	Lamp (qty/type)	Ballast	Voltage
48023ALU	4-Foot line	1 x 28W T5 LF	Electronic	120V-277V
48023AL54U	4-Foot line HO	1 x 54W T5 LF HO	Electronic	120V-277V
40876	4-Foot glow glass			
40916	4-Foot glow acrylic			

Note: Order glass/diffuser separately.

Catalog number	Description	Lamp (qty/type)	Ballast	Voltage
48023ALUE	Emergency	1 x 28W T5	Electronic	120V-277V
48023AL54UE	Emergency HO	1 x 54W T5 HO	Electronic	120V-277V

Note: Bodine® integral emergency pack rated for 90 minutes of operation.

Catalog number	Description	Lamp (qty/type)	Ballast	Voltage
48023AL54MX1*	Dimming HO	1 x 54W T5 HO	Electronic	120V
48023AL54MX2*	Dimming HO	1 x 54W T5 HO	Electronic	277V
48023AL28DA	DALI	1 x 28W T5	Electronic	120V-277V
48023AL54DA	DALI HO	1 x 54W T5 HO	Electronic	120V-277V

Note: Order glass/diffuser separately.

* Advance Mark X

LF = Linear fluorescent.
HO = High output lamp.

Digital Addressable Lighting Interface (DALI)

DALI is an open communication protocol used by multiple control and ballast manufacturers for digital control. Part of the Philips Lightolier IGEN Product Series.


Soli surface mounted ADA

Wall sconce & Continuum series

ADA compliant, Energy efficient CFL (compact fluorescent lighting) lamping. The finish is a powder coat paint. A design that evokes the illusion of floating, Soli Sconce meets all ADA requirements. Light emanating from within, plays through a gently curved diffuser spreading softly on the wall.



Wall sconce

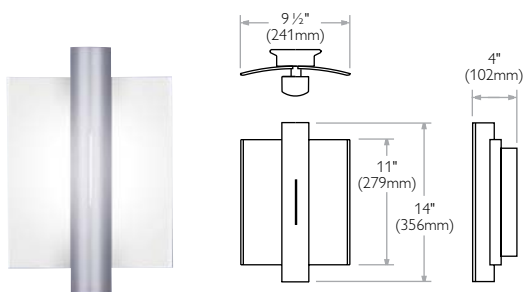

Digital Addressable Lighting Interface (DALI)

DALI is an open communication protocol used by multiple control and ballast manufacturers for digital control. Part of the Philips Lightolier IGEN Product Series.

Catalog number	Description	Lamp (qty/type)	Ballast	Voltage
48020ALU	Soli CFL wall sconce	1 x 26/32/42W TTT CFL	Electronic	120V-277V
40873	Glass			
40913	Acrylic			


Note: Order glass/diffuser separately.

Catalog number	Description	Lamp (qty/type)	Ballast	Voltage
48020ALMX1*	Mark X dimming	1 x 26/32/42W TTT CFL	Electronic	120V
48020ALMX2*	Mark X dimming	1 x 26/32/42W TTT CFL	Electronic	277V
48020ALE3	Canada version	1 x 26/32/42W TTT CFL	Electronic	347V
48020ALUDA	DALI	1 x 26/32/42W TTT CFL	Electronic	120V-277V


Note: Order glass/diffuser separately.

* Advance Mark 10

Continuum

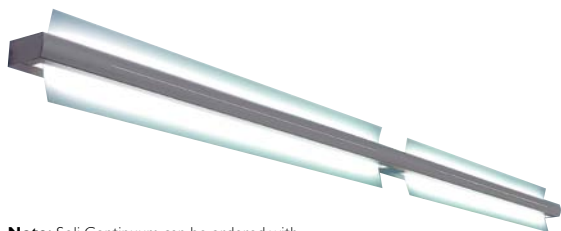

 Note: Soli Continuum can be ordered with or without diffusers. Order diffusers separately.



Digital Addressable Lighting Interface (DALI)

DALI is an open communication protocol used by multiple control and ballast manufacturers for digital control. Part of the Philips Lightolier IGEN Product Series.

Catalog number	Description	Lamp (qty/type)	Ballast	Voltage
48024ALU	Continuum line	2 x 28W T5 LF	Electronic	120V-277V
48024AL54U	Continuum line HO	2 x 54W T5 LF HO	Electronic	120V-277V
40876	Glass diffuser			
40916	Acrylic diffuser			

Note: Max width of 4.5" includes cast J-Box cover. (Covers included with Soli Continuum). If ordering glass/acrylic remember to order two of each.

LF = Linear fluorescent.
HO = High output lamp.

Catalog number	Description	Lamp (qty/type)	Ballast	Voltage
48024ALUE	Emergency	2 x 28W T5	Electronic	120V-277V
48024AL54UE	Emergency HO	2 x 54W T5 HO	Electronic	120V-277V

Note: Bodine® integral emergency pack rated for 90 minutes of operation.

Catalog number	Description	Lamp (qty/type)	Ballast	Voltage
48024AL54MX1*	Dimming HO	2 x 54W T5 HO	Electronic	120V
48024AL54MX2*	Dimming HO	2 x 54W T5 HO	Electronic	277V
48024ALUDA	DALI	2 x 28W T5	Electronic	120V-277V
48024AL54UDA	DALI HO	2 x 54W T5 HO	Electronic	120V-277V

* Advance Mark X

LF = Linear fluorescent.
HO = High output lamp.






Soli pendant

Zontio series

Energy efficient 2 x T5 linear fluorescent lamping provides significant ambient and reflected light. Three stem lengths are included with overall lengths of 21", 27", and 33" center mount. The finish is a powder coat paint. Clean lines, purity of light and an icy edge are all elements of the Soli Zontio that will accent contemporary spaces. The slim profile belies the stretch of illuminated glass suspended within a rectilinear form. The Zontio 2 lamp design provides enough ambient illumination for a typical small office.

Zontio

Pendant

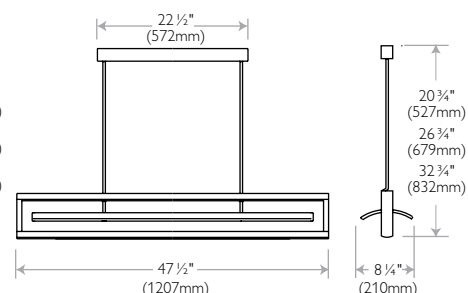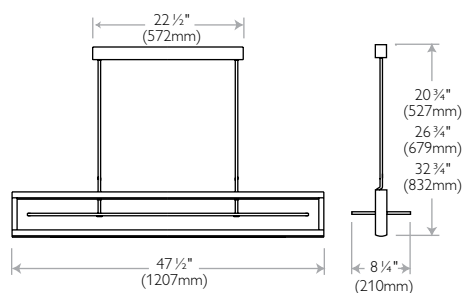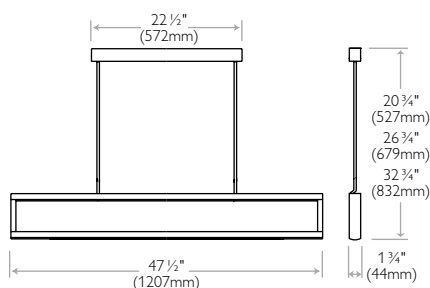

Catalog number	Description	Lamp (qty/type)	Ballast	Voltage
48228ALU	Zontio line	2 x 28W T5 LF	Electronic	120V-277V
48254ALU	Zontio line HO	2 x 54W T5 LF HO	Electronic	120V-277V
40800	Flat glass diffuser			
40810	Curved glass diffuser			

Note: Order glass/diffuser separately.

Catalog number	Description	Lamp (qty/type)	Ballast	Voltage
48228ALUE	Emergency	2 x 28W T5	Electronic	120V-277V
48254ALUE	Emergency HO	2 x 54W T5 HO	Electronic	120V-277V

Note: Bodine® integral emergency pack rated for 90 minutes of operation.

Catalog number	Description	Lamp (qty/type)	Ballast	Voltage
48254ALMX1*	Dimming HO	2 x 54W T5 HO	Electronic	120V
48254ALMX2*	Dimming HO	2 x 54W T5 HO	Electronic	277V
48254ALUDA	DALI∞	2 x 54W T5 HO	Electronic	120V-277V
48228ALUDA	DALI∞-HO*	2 x 28W T5 HO	Electronic	120V-277V

Note: Order glass/diffuser separately.

* Advance Mark X

LF = Linear fluorescent.
HO = High output lamp.

Soli pendant


Atria series

Energy efficient 3 x T5 linear fluorescent lamping provides ambient light, and intriguing visual sparkle. Three arms articulate between vertical and 15 degrees. E-Z Mount System, California approved swivel mount. The finish is a powder coat paint. A commanding visual statement in light and structure, Soli Atria underscores the geometric elements of architecture. Visual intrigue is created in a large space with a play of white light, negative space, and bold form.



Atria

Pendant

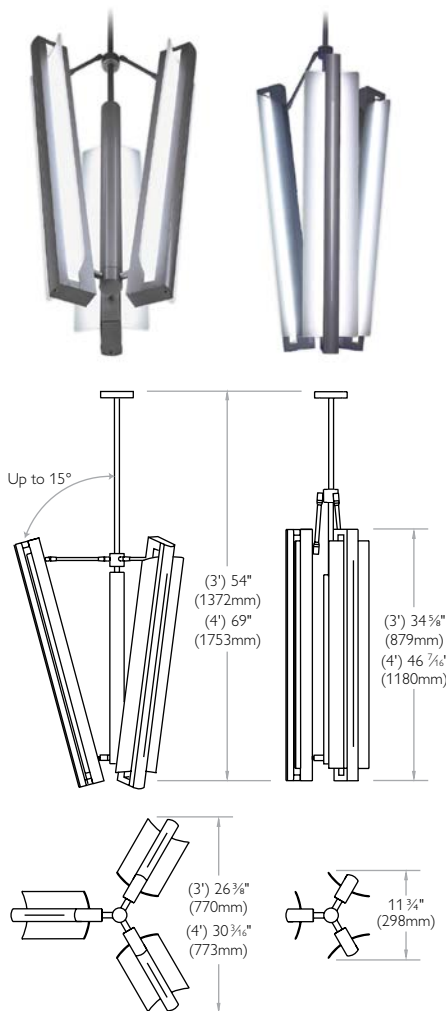

Atria 3

Catalog number	Description	Lamp (qty/type)	Ballast	Voltage
48339ALU	Atria 3-pendant	3 x 39W T5 HO LF	Electronic	120V-277V
40875	Atria 3-foot glass			
40915	Atria 3-foot acrylic			

Atria 4

Catalog number	Description	Lamp (qty/type)	Ballast	Voltage
48354ALU	Atria 4-pendant	3 x 54W T5 HO LF	Electronic	120V-277V
40876	Atria 4-foot glass			
40916	Atria 4-foot acrylic			

Atria Stems

Catalog number	Description
4SXT48AL	48" Length stem
4SXT96AL	96" Length stem

Note: Soli Atria requires 3 diffusers to be ordered separately per luminaire. Stems are field cuttable.

LF = Linear fluorescent.
HO = High output lamp.






Spectral Floating Paper


Architectural luminaire

Subtle Downlighting Elegance: Floating Paper is the first full downlight in the Philips Lightolier Spectral collection. The slim, discreet presence is especially effective in corridors and public spaces, including lobbies and reception areas.

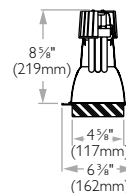

Design award
Industrie Forum
Design Hanover 1998

Round Floating Paper

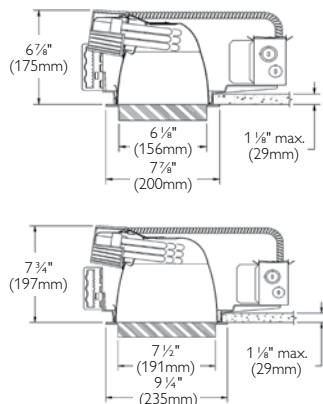

Cat No. frame	Lamp qty/type	Wattage	Voltage	Ballast	Luminaire dimension	Cat no. trim	Flange finish
SL205AFTAU	1-TTT	18	120V-277V	Electronic	Round 4 1/2"	SL205AT	Brushed
SL205BFTEU	1-TTT	26/32	120V-277V	Electronic	Round 6"	SL205ATWH	Stainless
SL205BFPMU	1-TTT	26/32	120V-277V	Electronic Dimming PowerSpec		SL205BT	Steel Flange
SL205BFTQ1	1-TTT	26/32	120V	Electronic Dimming Mark 10		SL205BTWH	White
SL205BFTQ2	1-TTT	26/32	277V	Electronic Dimming Mark 10			Flange
SL205CFTEU	1-TTT	26/32/42	120V-277V	Electronic	Round 7 3/8"	SL205CT	
SL205CFPKU	1-TTT	26/32/42	120V-277V	Electronic Dimming PowerSpec		SL205CTWH	
SL205CFTS1	1-TTT	26/32/42	120V	Electronic Dimming Mark 10			
SL205CFTS2	1-TTT	26/32/42	277V	Electronic Dimming Mark 10			

For technical details, mounting information and options, please consult Spec sheet No **SL205A**, **SL205B**, **SL205C**.




Spectral Floating Paper

Architectural luminaire

Subtle Downlighting Elegance: Floating Paper is the first full downlight in the Philips Lightolier Spectral collection. The slim, discreet presence is especially effective in corridors and public spaces, including lobbies and reception areas.



Square Floating Paper

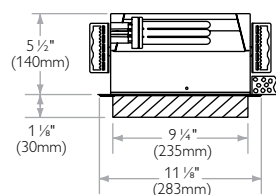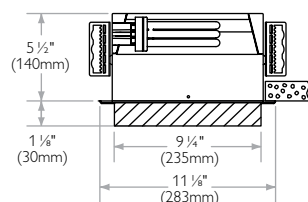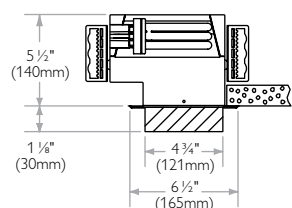

Cat No. frame	Lamp qty/type	Wattage	Voltage	Ballast	Luminaire dimension	Cat no. trim	Flange finish
SL207AFTCU	1-TTT	26/32	120V-277V	Electronic	4" x 4" Square	SL207AT SL207ATWH	Brushed Stainless Steel Flange
SL207AFPMU	1-TTT	26/32	120V-277V	Electronic Dimming PowerSpec			
SL207AFTQ1	1-TTT	26/32	120	Electronic Dimming Mark 10	4" x 9" Rectangular	SL207BT SL207BTWH	White Flange
SL207AFTQ2	1-TTT	26/32	277	Electronic Dimming Mark 10			
SL207BFTEU	1-TTT	26/32/42	120V-277V	Electronic	9" x 9" Square	SL207CT SL207CTWH	
SL207BFPKU	1-TTT	26/32/42	120V-277V	Electronic Dimming PowerSpec			
SL207BFTS1	1-TTT	26/32/42	120	Electronic Dimming Mark 10			
SL207BFTS2	1-TTT	26/32/42	277	Electronic Dimming Mark 10			
SL207CFTEU	2-TTT	26/32/42	120V-277V	Electronic			
SL207CFPPU	2-TTT	26	120V-277V	Electronic Dimming PowerSpec			
SL207CFPOU	2-TTT	32/42	120V-277V	Electronic Dimming PowerSpec			
SL207CFTZ1	2-TTT	26	120	Electronic Dimming Mark 10			
SL207CFTZ2	2-TTT	26	277	Electronic Dimming Mark 10			
SL207CFTR1	2-TTT	32/42	120	Electronic Dimming Mark 10			
SL207CFTR2	2-TTT	32/42	277	Electronic Dimming Mark 10			

For technical details, mounting information and options, please consult Spec sheet No **SL207A**, **SL207B**, **SL207C**.

Ultra Slimlite single sided sconce

Translite sconce

Sample order code
USC-S-S-120-R-N-A


Ordering Code		[] - S - [] - [] - [] - [] - []																		
Fixture																				
USC Ultra Slimlite Sconce		USP Ultra Slimlite Palomar																		
Style																				
S Single sided																				
Ballast																				
S Standard		H High output (no lens)																		
Voltage																				
1 120V		2 277V																		
Canopy																				
R Remote ballast		B Integral ballast																		
Lens (for use with USC)		Diffuser (for use with USP)																		
<table border="1"> <tr> <td>N No lens</td> <td>C Clear lens</td> <td>O White opaque lens</td> <td>P Prismatic acrylic</td> </tr> </table>		N No lens	C Clear lens	O White opaque lens	P Prismatic acrylic	<table border="1"> <tr> <td>FT Flute</td> <td>LN Linear</td> <td>RD Reed</td> <td>PS Prismatic</td> <td>SQ Square</td> <td>RN Rain</td> <td>OW Opal acrylic</td> <td>SS Sunset</td> </tr> </table>							FT Flute	LN Linear	RD Reed	PS Prismatic	SQ Square	RN Rain	OW Opal acrylic	SS Sunset
N No lens	C Clear lens	O White opaque lens	P Prismatic acrylic																	
FT Flute	LN Linear	RD Reed	PS Prismatic	SQ Square	RN Rain	OW Opal acrylic	SS Sunset													
Finish																				
A Aluminum		N Satin nickel																		
		R Bronze																		




USC Remote and integral ballast single lamp sconce

- ADA compliant Ultra Slimlite Sconces are constructed of a 1.125" extruded aluminum tube
- Designed for a single 14 watt or 24 watt T5 lamp
- May be powered with an integral or remote ballast
- Each fixture requires a separate power feed and ballast
- May be mounted in any orientation
- Sconces mount easily to a 2" x 3" single-gang utility box

Refer to Ultra Slimlite in the Local Area Task and Display section for additional information, pages 7.10-7.15.

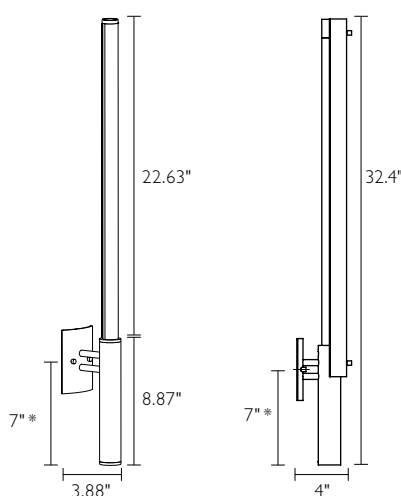

* Dimension depicts on-center measurements for mounting.

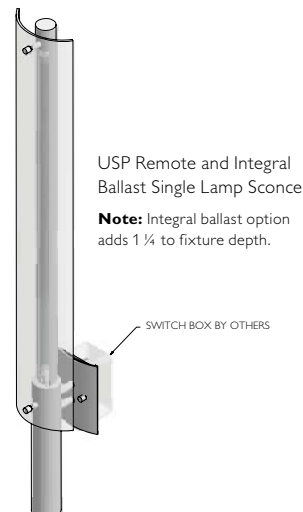

USP Remote and Integral Ballast Single Lamp Sconce
Note: Integral ballast option adds 1 1/4" to fixture depth.

Ultra Slimlite double sided sconce

Translite sconce

Sample order code
USC-D-S-120-R-N-A

Ordering Code

Fixture

USC Ultra slimlite sconce **USP** Ultra slimlite Palomar

Style

D Double sided

Ballast

S Standard **H** High output (no lens)

Voltage

1 120V **2** 277V

Canopy

R Remote ballast **B** Integral ballast

Lens (for use with USC) **Diffuser** (for use with USP)

Lenses (for use with USC)					Diffusers (for use with USP)						
N	C	O	P	FT	LN	RD	PS	SQ	RN	OW	SS
No lens	Clear lens	White opaque lens	Prismatic acrylic	Flute	Linear	Reed	Prismatic	Square	Rain	Opal acrylic	Sunset

Finish


A Aluminum **N** Satin nickel **R** Bronze



- ADA compliant Ultra Slimlite Sconces are constructed of a 1.125" extruded aluminum tube
- Designed for dual 14 watt or 24 watt T5 lamps
- May be powered with an integral or remote ballast
- Each fixture requires a separate power feed and ballast
- May be mounted in any orientation
- Sconces mount easily to a 2" x 3" single-gang utility box

Canopy options

Refer to *Ultra Slimlite in the Local Area Task and Display* section for additional information, pages 7.10-7.15.

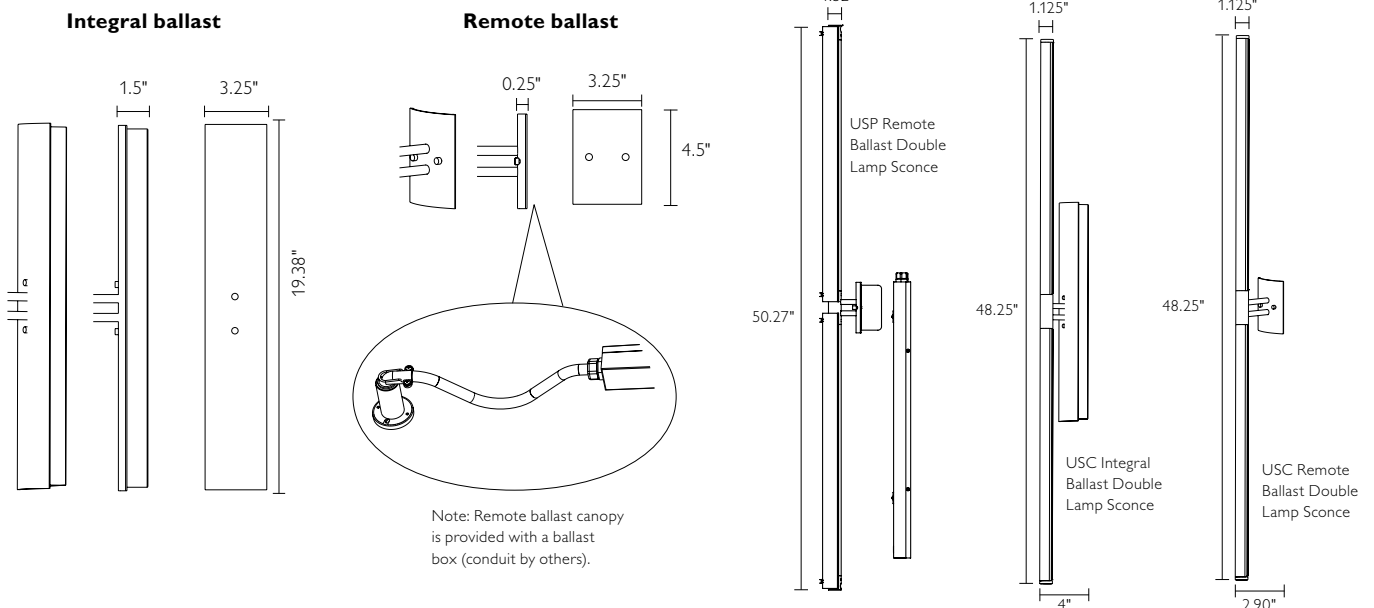



Features

- Die-cast aluminum
- Silver powder coated or satin aluminum finish
- Etched glass diffuser
- Uncompromising high-performance optics
- Versatile mounting options
- Energy efficient

How to specify


Cylinder (complete unit)

C4CIN20T4EUA

Inno

T4.5 metal halide surface cylinders

Wall mount kit

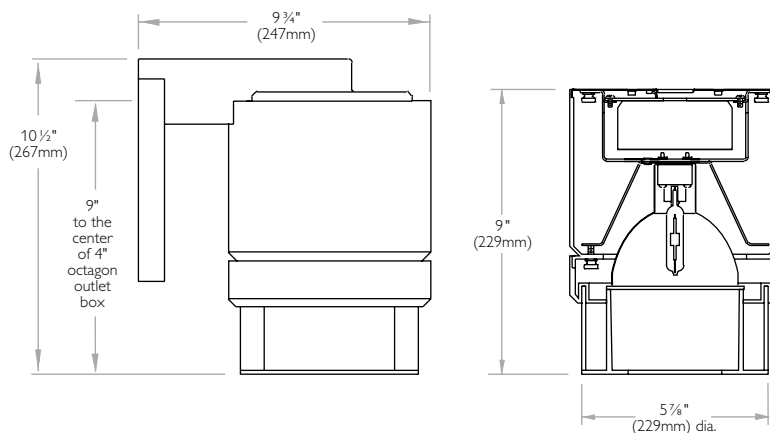


Inno decorative cylinder


Cat. no.	Finish	Ballast	Lamp	Voltage	Input Watts	Luminaire
C4CIN20T4EUA	Brushed aluminum	Electronic	T4-G8.5	120V-277V	20W (23W)	
C4CIN20BT5PGJ5E1A	Brushed aluminum	Electronic	T4-PGJ5	120V	20W (23W)	
C4CIN20T4GU65EUA	Brushed aluminum	Electronic	T4-GU6.5	120V-277V	20W (23W)	
C4CIN39T4EUA	Brushed aluminum	Electronic	T4-G8.5	120V-277V	39W (44W)	
C4CIN39BT5PGJ5E1A	Brushed aluminum	Electronic	T4-PGJ5	120V	39W (44W)	
C4CIN39T4GU65EUA	Brushed aluminum	Electronic	T4-GU6.5	120V-277V	39W (44W)	

4 1/2" T4.5 Inno cylinder 39W

Complete unit: C4CIN39T4EU **CLW**

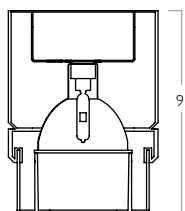



Report: 2614FR
Lamp: 39W T4-G8.5
 Ceramic MH
Efficiency: 43.6%
Spacing: 0.9

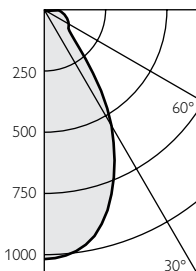

Multiple Unit Data (RCR 2)

Spacing on center	Initial footcandles	Watts per sq ft
6'	39	1.22
8'	22	0.69
9'	17	0.54

38' x 38' x 10' Room, workplane 2 1/2' above floor, 80/50/20% reflectances

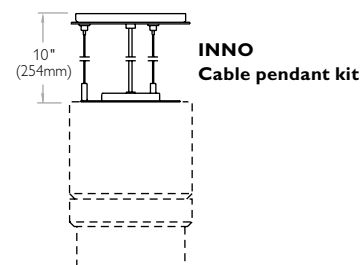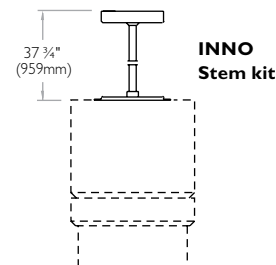


Mounting kits

Cat. no.	Finish	Description
CA4CWBSA	Brushed aluminum	Wall-mount kit
CACPSA	Brushed aluminum	10' Cable pendant kit
CACSSA	Brushed aluminum	Stem kit

(45° Swivel, 37" long)

Expo

T4.5 metal halide surface cylinders

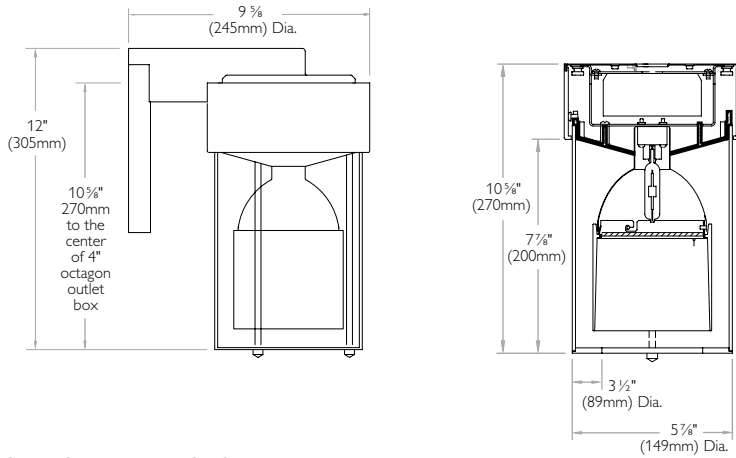

Inno decorative cylinder

Cat. no.	Finish	Ballast	Lamp	Voltage	Input Watts	Luminaire
C4CEX20T4EUA	Brushed aluminum	Electronic	T4-G8.5	120V-277V	20W (23W)	
C4CEX20BT5PGJ5E1A	Brushed aluminum	Electronic	T4-PGJ5	120V	20W (23W)	
C4CEX20T4GU65EUA	Brushed aluminum	Electronic	T4-GU6.5	120V-277V	20W (23W)	
C4CEX39T4EUA	Brushed aluminum	Electronic	T4-G8.5	120V-277V	39W (44W)	
C4CEX39BT5PGJ5E1A	Brushed aluminum	Electronic	T4-PGJ5	120V	39W (44W)	
C4CEX39T4GU65EUA	Brushed aluminum	Electronic	T4-GU6.5	120V-277V	39W (44W)	

Features

- Die-cast aluminum
- Silver powder coated or satin aluminum finish
- Etched glass diffuser
- Uncompromising high-performance optics
- Versatile mounting options
- Energy efficient


How to specify

Cylinder (complete unit)

C4CEX20T4EUA

4 1/2" T4.5 Expo cylinder 39W

Complete unit: C4CEX39T4EU **CLW**

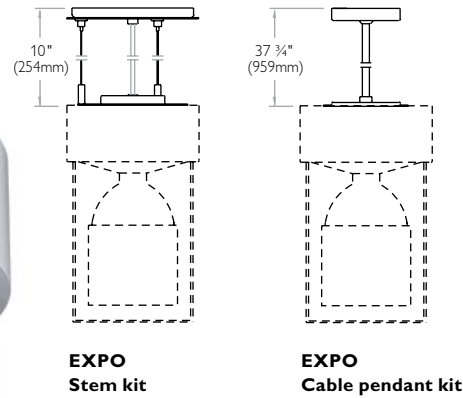


EXPO
Stem kit


EXPO
Cable pendant kit

Mounting kits

Cat. no.	Finish	Description
CA4CWBSA	Brushed aluminum	Wall-mount kit
CACPSA	Brushed aluminum	10' Cable pendant kit
CACSSA	Brushed aluminum	Stem kit
CAEXPTSA	Brushed aluminum	Expo ³ rod & trim kit

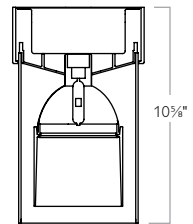

Report: 2605FR
Lamp: 39W T4-G8.5
Ceramic MH
Efficiency: 49.7%
Spacing: 0.8

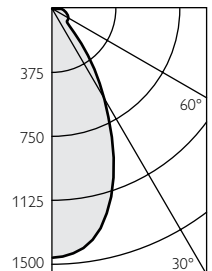

Multiple Unit Data (RCR 2)

Spacing on center	Initial Footcandles	Watts Per Sq Ft
6'	42	1.22
8'	24	0.69
9'	19	0.54

38' x 38' x 10' Room, workplane 2 1/2' above floor, 80/50/20% reflectances

Transitional



Pendalyte

6 ½" performance




Power heads

6 ½" Performance Pendalyte

Power head & suspension (single lamp)

Cat. no.	Finish	Lamp	Wattage	Voltage	Suspension	Options
406151	Titanium	Incandescent A21	150W	120V	Straight cord (96" max)	Not app.
406U2	Titanium	CFL Triple tube	26/32W	120V-277V	Straight cord (96" max)	Not app.

Suspension kits are field cuttable.

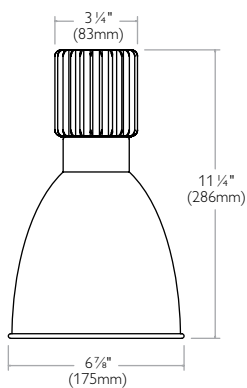

Reflectors / glass diffusers

Cat. no.	Finish
416SR	Satin aluminum reflector
416WH	White glass diffuser
416BL	Cobalt blue glass diffuser
416AB	Amber glass diffuser

Pendalyte track mounting kits

Cat. no.	Finish	Description
406BLS	Black	6 ½" Track mounting kit, Deco, 1 adapter system

Consult factory for mounting options with Lytespan Track. Incandescent only.

Features

Power head housing: One-piece extruded aluminum. Textured Titanium powder coat.

Reflector: High purity, 16 gauge aluminum. Exterior satined and anodized. Interior low iridescent comfort clear anodized.

Glass diffusers: Pressed glass with soft etched exterior and matte white interior frit.

Suspension: Cord SJT18-3, Black. Titanium finished canopy.


Lamp holders

Incandescent: Medium Base, Porcelain, Nickel Plated Screw Shell.

Compact fluorescent: Universal for 4-Pin, 26/32 watt base: GX24q-3.

Track mount: 6.5" Pendalytes can be adapted for mounting to, or suspension from, Lytespan track. Please consult Philips Lightolier for price and availability.

All units are cULus listed, suitable for damp locations.

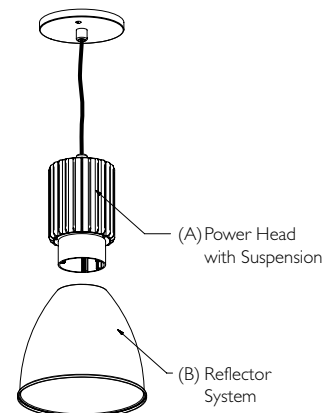

Complete fixture consists of		
Power head/suspension + Reflector/diffuser		
(Example)	Order each separately	
406U2	+	416SR



Features


Power head housing: Two-piece extruded aluminum. Removable door for ease of installation and servicing. Textured Titanium powder coat finish.

Lamp holders

Incandescent: Medium Base, Porcelain, Nickel Plated Screw Shell.

Compact fluorescent: Universal voltage for 4-Pin, 26/32/42 watt base: GX24q-3; 42 watt base: GX24q-4.

Metal halide: Medium base, porcelain, 4KV pulse rated. Open rated lamp.

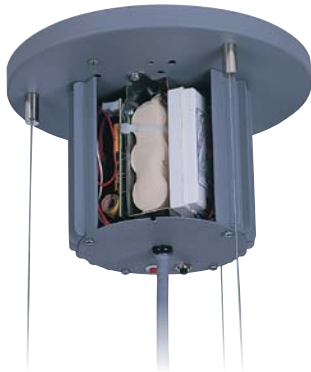

EM Emergency pack

An integrated emergency battery pack option is available in most Pendalyte CFL luminaires. The EM Pack is located in a self contained 5 1/2" Diameter Power Head style extrusion pre-mounted directly to the luminaire canopy. Test Switch and Indicator LED lamp are located on bottom cover of EM Pack housing. Pre-wired for contractor-friendly installation.

Not available with Coil Cord Suspension or with multiple lamps.

All units are cULus listed, suitable for damp locations. Emergency units are UL listed, dry locations.

Pendalyte

9" performance

Power heads

9" Pendalyte

LED

Cat. no.	Finish	Lamp	Wattage	CCT	Voltage
40471L27U	Gray	LED	20W	27K	120V-277V
40471L35U	Gray	LED	20W	35K	120V-277V
40471L27UTM	Titanium	LED	20W	27K	120V-277V
40471L35UTM	Titanium	LED	20W	35K	120V-277V

Power head (single lamp)

Cat. no.	Finish	Lamp	Wattage	Voltage	Options
4046151	Gray	Incandescent A21	150W	120V	Not applicable
4046151TM	Titanium	Incandescent A21	150W	120V	Not applicable
40471U3	Gray	CFL Triple tube	26/32/42W	120V-277V	MX1, MX2, DA, E3
40471U3TM	Titanium	CFL Triple tube	26/32/42W	120V-277V	MX1, MX2, DA, E3

Metal halide

Cat. no.	Finish	Lamp	Wattage	Voltage	Options
40471T39EU	Gray	1	39W	120V-277V	Not applicable
40471T39EUTM	Titanium	1	39W	120V-277V	Not applicable


Lamp cover is provided, no lens on Reflector or Glass is required.

Emergency units (power head & suspension)

Cat. no.	Finish	Lamp	Wattage	Suspension
40471U3EMCC*	Gray	1	26/32/42W	120" Length, cable/ cord
40471U3EMS36	Gray	1	26/32/42W	36" Length, 5/8" stem
40471U3EMS60	Gray	1	26/32/42W	60" Length, 5/8" stem
40471U3TMECC**	Titanium	1	26/32/42W	120" Length, cable/cord
40471U3EMTMS36	Titanium	1	26/32/42W	36" Length, 5/8" stem
40471U3EMTMS60	Titanium	1	26/32/42W	60" Length, 5/8" stem

Order reflector or glass separately.

Power head options

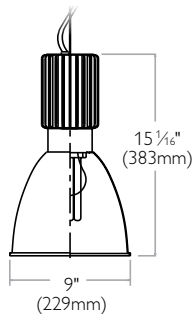

9" Power head options

(Add suffix to cat. no.)

MX1 = Mark X Dimming 26/32/42W, 120V only*

MX2 = Mark X Dimming 26/32/42W, 277V only*

E3 = 347V (Canada)

EM = Emergency Battery Pack (See page 6.42)

DA = DALI (Digital Addressable Lighting Interface)**

*2-wire, neutral connection required at dimming control.

**5-wire Suspension Kit required. Dali is an open communication protocol used by multiple control and ballast manufacturers for digital control. Part of the Philips Lightolier IGEN Product Series.

Complete fixture consists of

Power head/suspension + Reflector

(Example) Order each separately

40471U3EMCC

+

40411

Pendalyte

9" performance

Ordering options

9" Pendalyte

Reflectors / glass diffusers

Cat. no.	Finish
40411	Semi specular anodized reflector
40413	Satin & anodized reflector
409WH	White glass diffuser
409BL	Cobalt blue glass diffuser
409AB	Amber glass diffuser

Suspension kits (not required if ordering Deco Kits)


Cat. no.	Finish	Description
404SKG	Gray	120" Length cable/cord + coil cord
404SKB	Black	120" Length cable/cord + coil cord
404S36	Gray	36" Length 5/8" stem
404S36B	Black	36" Length 5/8" stem
404S60	Gray	60" Length 5/8" stem
404S60B	Black	60" Length 5/8" stem
404S120	Gray	120" Length 5/8" stem
404SB5*	Black	120" 5-Wire straight cord only
404SG5*	Gray	120" 5-Wire straight cord only

Suspension Kits are field cuttable.

Deco Kits (Includes 120" length suspension of both cable/cord and cable/coil cord)

Cat. no.	Finish	Description
409DK	Gray	Deco assembly and mounting kit
409DK5*	Gray	Deco assembly and mounting kit, 5-wire straight cord only
409DKTM	Titanium	Deco assembly and mounting kit
409DKTM5*	Titanium	Deco assembly and mounting kit, 5-wire straight cord only
409DBLS	Black	Track mounting kit, deco, 2 adapter system
409DGLS	Gray	Track mounting kit, deco, 2 adapter system

Deco kits include arm and suspension systems, and must be ordered with disk.

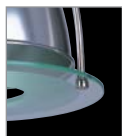

Glass Disc



Acrylic Disc



Perforated Disc

Disks

Cat. no.	Description
409DG	Glass Deco Disk
409DA	Acrylic Deco Disk
409PM	Perforated Metal Deco Disk



Direct to Ceiling

Direct to ceiling kits

Cat. no.	Finish	Used with
4912CTCGR	Gray	All 9", 12", and 16" Pendalytes
4912CTCTM	Titanium	9" Pendalyte and 12" Performance

*Not compatible with Deco Kit.

Track mounting kits

Cat. no.	Finish	Description
404BLS	Black	Track Mounting Kit, Standard 2-Adapter System
404GLS	Gray	Track Mounting Kit, Standard 2-Adapter System



Specifications

Reflector: High purity, 16 gauge aluminum. Exterior satined and anodized. Interior low iridescent comfort clear anodized.

Adjustment: GripLock fittings allows for height and leveling adjustment after installation.

Glass diffusers: Pressed glass with soft etched exterior and matte white interior frit.

Suspension: Cord and Cable Mounting Kits are supplied with both 18-3 SJT straight and coiled power cords, 1/16" stainless steel support cable, steel canopy.


Glass disk: Soda Lime Glass, having a 9 1/2" diameter etched area around a 5" diameter center opening.

Acrylic disk: 11 1/2" diameter clear center acrylic having a 9 1/2" diameter etched area around a 4" diameter center opening.

Perforated metal disk: Features a square edged inner and outer rubber edging. It is available in satin aluminum with black rubber edging with a 11 1/2" diameter.

Track mount: 9" Pendalytes can be adapted for mounting to, or suspension from, Litespan track. Please consult Philips Lightolier for price and availability.

All units are cULus listed, suitable for damp locations. Emergency units are UL listed, dry locations.

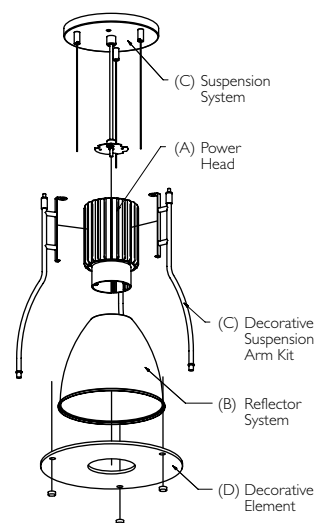

Complete fixture consists of
Power head + Reflector/diffuser + Suspension
 (Example) Order each separately

40471U3TM + 409BL + 409DKTM + 409DG

Use with Standard Cord or Deco Suspension Kits. Suspension Kits are field cuttable.

*DALI requires a 5-wire Suspension.




Features

Power head housing: Two-piece extruded aluminum. Removable door allows for ease of installation and servicing. Textured Titanium powder coat finish.

Lamp holders

Compact fluorescent: Universal voltage for 4-pin, 26/32 watt base: GX24q-3; 42 watt base: GX24q-5; 70 watt base: GX24q-6; 85 watt base: 2G8.

Metal halide: Medium base, porcelain, 4KV pulse rated. Extended neck. Open lamp only. Electronic Ballast.

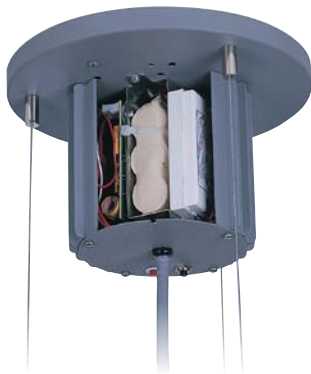

EM Emergency pack

An Integrated Emergency Battery Pack option is available in most Pendalyte CFL luminaires. The EM Pack is located in a self contained 5 1/2" Diameter Power Head style extrusion pre-mounted directly to the luminaire canopy. Test Switch and Indicator LED lamp are located on bottom cover of EM Pack housing. Pre-wired for contractor-friendly installation.

Not available with coil cord suspension or with multiple lamps.

All units are cULus listed, suitable for damp locations. Emergency units are UL listed, dry locations.

Pendalyte

12" performance

Power heads

12" Pendalyte

Power Head (Single Lamp)

Cat. no.	Finish	Lamp	Wattage	Voltage	Options
412U3	Titanium	CFL Triple tube	26/32/42W	120V-277V	MX1, MX2, DA, E3
41270U	Titanium	CFL Triple tube	70W	120V-277V	MX1, MX2, E3
41285U*	Titanium	CFL Triple tube	85W	120V-277V	Not Applicable
412H70	Titanium	Metal halide ED17	70W	120V	F1


*The Powerhead is larger for the 85W.

Emergency units (power head & suspension)

Cat. no.	Finish	Lamp	Wattage	Suspension
412U3EMCC	Titanium	1	26/32/42W	120" Length, cable/cord
412U3EMS36	Titanium	1	26/32/42W	36" Length, 5/8" stem
412U3EMS60	Titanium	1	26/32/42W	60" Length, 5/8" stem

Order reflector or glass separately.

Power head options

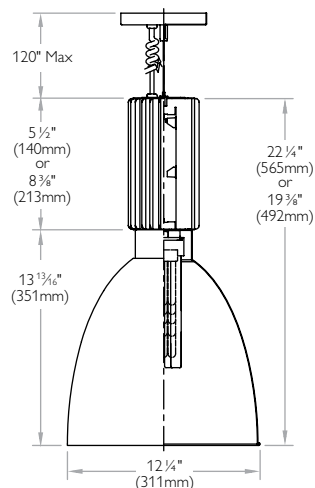

12" Power head options

(Add suffix to cat. no.)

MX1 = Mark X Dimming 26/32/42W, 120V only*

MX2 = Mark X Dimming 26/32/42W, 277V only*

E3 = 347V (Canada)

F1 = Fuse 120V

EM = Emergency Battery Pack (See below)

DA = DALI (Digital Addressable Lighting Interface)**

* 2-wire, neutral connection required at dimming control.

** 5-wire Suspension Kit required. Dali is an open communication protocol used by multiple control and ballast manufacturers for digital control. Part of the Philips Lightolier IGEN Product Series.

Complete fixture consists of

Power head/suspension + Reflector

(Example) Order each separately

412U3EMCC

+

42AB

Pendalyte

12" performance

Ordering options

12" Pendalyte

Reflectors / glass diffusers

Cat. no.	Finish
42SR	Satin aluminum reflector
42WH	White glass diffuser
42BL	Cobalt blue glass diffuser
42AB	Amber glass diffuser

Suspension kits

Cat. no.	Finish	Description
404SKB	Black	120" Length cable/cord + coiled cord
404SB5*	Black	120" Length 5-wire straight cable/cord only
404S36B	Black	36" Length 5/8" stem
404S60B	Black	60" Length 5/8" stem

Suspension kits are field cuttable.

Direct to ceiling kits

Cat. no.	Finish	Used With
4912CTCTM	Titanium	All 9", 12", and 16" Pendalytes.

Pendalyte track mounting kits

Cat. no.	Finish	Used With
404BLS	Black	Track mounting kits, standard 2-adapter system

Pendalyte track cable/cord kits

Cat. no.	Finish	Used With
404EXTB	Black	25' Extension cable/cord kit
404EXT300B5*	Black	25' Cord/cable, 5-wire

Use with Standard Cord or Deco Suspension Kits. Suspension Kits are field cuttable.

*DALI requires a 5-wire Suspension.



Specifications

Reflector: High purity, 16 gauge aluminum. Exterior satined and anodized. Interior low iridescent comfort clear anodized.


Adjustment: GripLock fittings allows for height and leveling adjustment after installation.

Glass Diffuser: Pressed glass with soft etched exterior and matte white interior frit.

Suspension: Cable and Cord Mounting Kits are supplied with both 18-3 SJT straight and coiled power cords, 1/16" stainless steel support cable, steel canopy.

Track mount: 12" Performance Pendalytes can be adapted for mounting to, or suspension from, Lytespan track. Please consult Philips Lightolier for price and availability.

All units are cULus listed, suitable for damp locations. Emergency units are UL listed, dry locations.

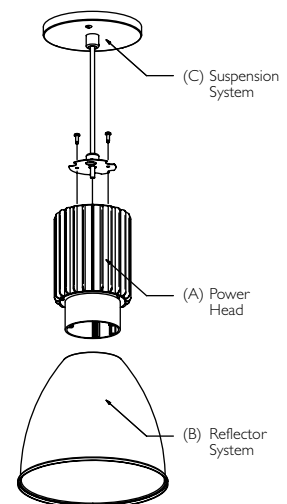

Complete fixture consists of

Power head + Reflector/diffuser + Suspension

(Example) Order each separately

412H70

 +

42SR

 +

404SKB




Features

Power head housing: Two-piece extruded aluminum. Removable door allows for ease of installation and servicing. Textured Gray powder coat finish.

Lamp holders

Compact fluorescent: Universal voltage for 4-pin, 26/32 watt base: GX24q-3; 42 watt base: GX24q-4.

Metal halide: Medium base, porcelain, 4KV pulse rated. Open rated lamp.

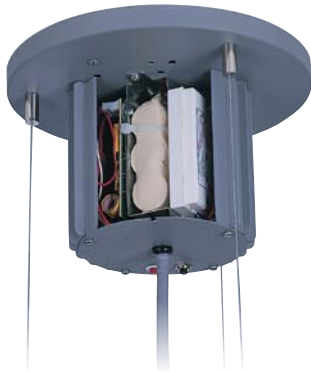

EM Emergency pack

An Integrated Emergency Battery Pack option is available in most Pendalyte CFL luminaires. The EM Pack is located in a self contained 5 1/2" Diameter Power Head style extrusion pre-mounted directly to the luminaire canopy. Test Switch and Indicator LED lamp are located on bottom cover of EM Pack housing. Pre-wired for contractor-friendly installation.

Not available with Coil Cord Suspension or with multiple lamps.

All units are cULus listed, suitable for damp locations. Emergency units are UL listed, dry locations.

Complete fixture consists of		
Power head/suspension + Reflector + Louver		
(Example)	Order each separately	
40472U3EMCC	+	40421 + 412GRL

Pendalyte

12"

Power heads

12" Pendalyte

Power head (single lamp) powder coated textured dark gray

Cat. no.	Finish	Lamp	Wattage	Voltage	Options
4046261	Gray	Incandescent A21	150W	120V	Not applicable
40472U3	Gray	CFL Triple tube	26/32/42W	120V-277V	MX1, MX2, DA, E3

Power head (multi lamp)

Cat. no.	Finish	Lamp	Wattage	Voltage	Options
404722XU3*	Gray	CFL Triple tube	2x26/32/42W	120V-277V	MX1, MX2, E3

General Electric 42W (F42QBX) lamp base will not fit into this luminaire.

*For Deco Kit order 412LDK on Dimming units only.

Metal halide

Cat. no.	Finish	Lamp	Wattage	Voltage	Options
4047270EU	Gray	Metal halide ED17	70W	120V-277V	Not applicable
40472100EU	Gray	Metal halide ED17	100W	120V-277V	Not applicable

Electronic ballasted Metal Halide units are open rated and do not require a lens.

Emergency units (power head & suspension)

Power head (single lamp)

Cat. no.	Finish	Lamp	Wattage	Suspension
40472U3EMCC*	Gray	1	26/32/42W	120" Length, cable/cord
40472U3EMS36	Gray	1	26/32/42W	36" Length, 5/8" stem
40472U3EMS60	Gray	1	26/32/42W	60" Length, 5/8" stem

Order reflector or glass separately. Pre-wired for dual switching.

*For Deco Kit order 412DK5.

Emergency units (power head & suspension)


Power head (multi lamp)

Cat. no.	Finish	Lamp	Wattage
404722XU1EM*	Gray	2-1 Lamp emergency	26/32/42W

Must order Reflector or Refractor separately.

*For Deco Kit order 412LDK5.

Power head options

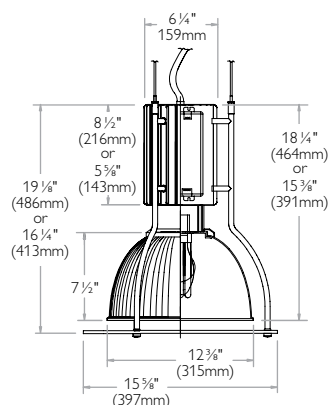

12" Power head options

(Add suffix to cat. no.)

MX1 = Mark X Dimming 26/32/42W, 120V only*

MX2 = Mark X Dimming 26/32/42W, 277V only*

E3 = 347V (Canada)

F1 = Fuse 120V

F2 = Fuse 277V

EM = Emergency Battery Pack (See below)

DA = DALI (Digital Addressable Lighting Interface)**

* 2-wire, neutral connection required at dimming control.

** 5-wire Suspension Kit required. Dali is an open communication protocol used by multiple control and ballast manufacturers for digital control. Part of the Philips Lightolier IGEN Product Series.

Pendalyte

12"

Ordering options

12" Pendalyte

Reflectors / refractors

Cat. no.	Finish
40421	Semi specular anodized reflector
40422	Acrylic refractor

Suspension kits (not required if ordering deco kits)

Cat. no.	Finish	Description
404SKG	Gray	120" Length cable/cord + coil cord
404SG5*	Gray	120" Length 5-wire straight cable/cord only
404S36	Gray	36" Length 5/8" stem
404S60	Gray	60" Length 5/8" stem
404S120	Gray	120" Length 5/8" stem


Suspension kits are field cuttable.

Deco Kits (includes 120" length suspension of both cable/cord and cable/coil cord)

Cat. no.	Finish	Description
412DK	Gray	Deco assembly and mounting kit
412LDK	Gray	Deco assembly and mounting kit, for 8 1/2" I power head (2 lamp dimming)
412LDK5*	Gray	Deco assembly and mounting kit, 5-wire straight cord only (DALI 2 lamp only)
412DLS	Gray	Track mounting kits, Deco 2-adapter system

Deco kit includes Arms & Suspension System, and must be ordered with disk. DALI requires a 5-wire suspension.

*For Deco Kit order 412LDK on Dimming Units only.

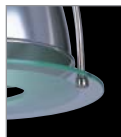

Glass Disc



Acrylic Disc



Perforated Disc

Disks

Cat. no.	Description
412DG	Glass Deco Disk
412DA	Acrylic Deco Disk
412PM	Perforated Metal Deco Disk



Direct to Ceiling

Direct to ceiling kits

Cat. no.	Finish	Used with
4912CTCGR	Gray	All 9", 12", and 16" Pendalytes

Not compatible with Deco Kit.

Track mounting kits

Cat. no.	Finish	Description
404GLS	Gray	Track Mounting Kits, Standard 2-Adapter System

Optional extension kits

Cat. no.	Finish	Suspension
404EXT300	Gray	25' Extension Cable/Cord Kit
404EXT300G5*	Gray	25' Cord/Cable, 5-wire

Use with Standard Cord or Deco Suspension Kits. Suspension kits are field cuttable.

*DALI requires a 5-wire suspension.

Reflector / refractor options

Cat. no.	Used With	Description
421G	40421	Industrux Glass Lens
412WHL**	40421	Cross Blade Louver, White
412GRL**	40421	Cross Blade Louver, Gray
422A	40422	Flat Acrylic Lens
422G	40422	Industrex® Glass Lens
404TRM12	40422/40421	12" Trim Ring

*DALI requires a 5-wire suspension.


**For use with 2-Lamp Power Heads only.



Specifications

Reflector: High purity, 16 gauge aluminum. Exterior satined. Interior low iridescent comfort clear anodized.**Refractor:** Injection molded acrylic, UV stabilized.**Adjustment:** Griplock fittings allows for height and leveling adjustment after installation.**Suspension:** Cord and Cable Mounting Kits are supplied with both 18-3 SJT straight and coiled power cords, 1/16" stainless steel support cable, steel canopy.**Glass disk:** 15 1/2" diameter, Soda Lime Glass, having a 12 1/2" diameter etched area around a 6" diameter center opening.**Acrylic disk:** 17 1/2" diameter clear center acrylic having a 11 1/2" diameter etched area around a 4" diameter center opening.**Perforated metal disk:** Features a square edged inner and outer rubber band. It is available in satin aluminum with black rubber edging with a 17 1/2" diameter.**Bottom lens and cross blade:** For bottom lens and cross blade louver information see bottom left.**Track mount:** 12" Pendalytes can be adapted for mounting to, or suspension from, Lytespan track. Please consult Philips Lightolier for price and availability.

All units are cULus listed, suitable for damp locations. Emergency units are UL listed, dry locations.

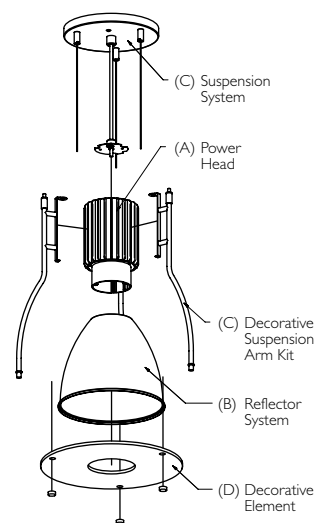

Complete fixture consists of
Power head + Reflector/diffuser + Suspension
 (Example) Order each separately

40472U3 + **40421** + **412DK** + **412DA**




Features

Power head housing: Two-piece extruded aluminum. Removable door allows for ease of installation and servicing. Textured titanium powder coat finish.

Lamp holders

Compact fluorescent: Universal voltage for 4-pin 26/32 watt base: GX24q-3; 42 watt base: GX24q-5; 70 watt base: GX24q-6; 85 watt base: 2G8.

Metal halide: Medium base, porcelain, 4KV pulse rated. Open rated lamp.

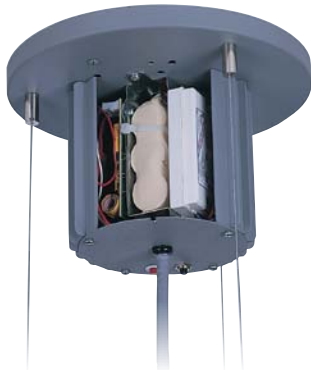

EM Emergency pack

An Integrated Emergency Battery Pack option is available in most Pendalyte CFL luminaires. The EM Pack is located in a self contained 5 1/2" Diameter Power Head style extrusion pre-mounted directly to the luminaire canopy. Test Switch and Indicator LED lamp are located on bottom cover of EM Pack housing. Pre-wired for contractor-friendly installation.

Not available with Coil Cord Suspension or with multiple lamps.

All units are cULus listed, suitable for damp locations. Emergency units are UL listed, dry locations.

Complete fixture consists of		
Power head/suspension + Reflector + Louver		
(Example)	Order each separately	
40734XUIEM	+	40432 + 432A

Pendalyte

16"

Power heads

16" Pendalyte

Power head (single lamp) powder coated textured dark gray

Cat. no.	Finish	Lamp	Wattage	Voltage	Options
406371	Gray	Incandescent A21	150W	120V	Not applicable
4073U3	Gray	CFL Triple tube	26/32/42W	120V-277V	MX1, MX2, DA, E3
407370U	Gray	CFL Triple tube	70W	120V-277V	MX1, MX2, E3

Power head (multi lamp)

Cat. no.	Finish	Lamp	Wattage	Voltage	Options
40724XU3	Gray	CFL Triple tube	2x26/32/42W	120V-277V	MX1, MX2, E3
40734XU3	Gray	CFL Triple tube	4x26/32/42W	120V-277V	MX1, MX2, E3
4073270U	Gray	CFL Triple tube	2x70W	120V-277V	MX1, MX2, E3

Metal halide

Cat. no.	Finish	Lamp	Wattage	Voltage	Options
4083100EU	Gray	Metal halide ED17	100W	120V-277V	Not applicable
4083150EU	Gray	Metal halide ED17	150W	120V-277V	Not applicable

Electronic ballasted Metal Halide units are open rated and do not require lens.
Emergency Units - Power Head & Suspension.

Emergency units (power head & suspension)

Power head (single lamp)

Cat. no.	Finish	Lamp	Wattage	Suspension
4073U3EMCC*	Gray	1	26/32/42W	120" Length, cable/cord
4073U3EMS36	Gray	1	26/32/42W	36" Length, 5/8" stem
4073U3EMS60	Gray	1	26/32/42W	60" Length, 5/8" stem


Order reflector or refractor separately.
*For Deco unit order standard 416DK5.

Emergency units (power head & suspension)

Power head (multi lamp)

Cat. no.	Finish	Lamp	Wattage	Suspension
40734XU1EM	Gray	4 - 1 Lamp emergency	26/32/42W	120" Cable/cord

Power head options

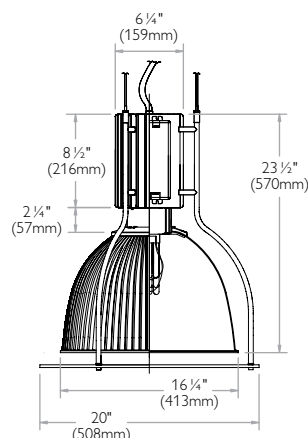

16" Power head options

(Add suffix to cat. no.)

MX1 = Mark X Dimming 26/32/42W, 120V only*

MX2 = Mark X Dimming 26/32/42W, 277V only*

E3 = 347V (Canada)

F1 = Fuse 120V

F2 = Fuse 277V

EM = Emergency Battery Pack (See below)

DA = DALI (Digital Addressable Lighting Interface)**

*2-wire, neutral connection required at dimming control. Multi Lamp power heads consult factory.

**5-wire Suspension Kit required.

Pendalyte

16"

Ordering options

16" Pendalyte

Reflectors / refractors

Cat. no.	Finish
40431	Semi specular anodized reflector
40432	Acrylic refractor

Suspension kits (not required if ordering Deco Kits)

Cat. no.	Finish	Description
404SKG	Gray	120" Length cable/cord + coiled cord
404SG5*	Gray	120" Length 5-wire straight cord/cable only
404S36	Gray	36" Length 5/8" stem
404S60	Gray	60" Length 5/8" stem
404S120	Gray	120" Length 5/8" stem


*Suspension Kits are field cuttable.

Deco Kits (Includes 120" length suspension of both cable/cord and cable/coil cord)

Cat. no.	Finish	Description
416DK	Gray	Deco assembly and mounting kit
416DKS*	Gray	Deco assembly and mounting kit, 5-wire straight cord only
416DLS	Gray	Track mounting kit, Deco, 2 adapter system

Deco kit includes Arms & Suspension System and must be ordered with disk.


*DALI requires a 5-wire Suspension.

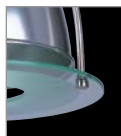

Glass Disc



Acrylic Disc

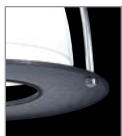

Perforated Disc

Disks

Cat. no.	Description
416DG	Glass Deco Disk
416DA	Acrylic Deco Disk
416PM	Perforated Metal Deco Disk



Direct to Ceiling

Direct to ceiling kits

Cat. no.	Finish	Used with
4912CTCGR	Gray	All 9", 12", and 16" Pendalytes

Not compatible with Deco Kit.

Track mounting kits

Cat. no.	Finish	Description
404GLS	Gray	Track Mounting Kits, Standard 2-Adapter System

Optional extension kits

Cat. no.	Finish	Suspension
404EXT300	Gray	25' Extension cable/cord kit
404EXT300G5*	Gray	25' Cord/cable, 5-wire

Use with Standard Cord or Deco Suspension Kits.

Suspension kits are field cuttable.

*DALI requires a 5-wire Suspension.

Reflector / refractor options

Cat. no.	Used with	Description
431G	40431	Industrux glass lens
416WHL**	40431	Cross blade louver, white
416GRL**	40431	Cross blade louver, gray
432A	40431	Flat acrylic lens
432G	40431	Industrux® glass lens
404TRM16	40431/40432	16" Trim Ring

*DALI requires a 5-wire Suspension.

**For use with 2-Lamp and 4-Lamp Power Heads only.



Specifications

Reflector: High purity, 16 gauge aluminum. Exterior satined and anodized. Interior low iridescent comfort clear anodized.

Refractor: Injection molded acrylic, UV stabilized.

Adjustment: Griplock fittings allows for height and leveling adjustment after installation.

Suspension: Cord and Cable Mounting Kits are supplied with both 18-3 SJT straight and coiled cord power cords, 1/16" stainless steel support cable, steel canopy.

Glass disk: 20" diameter, Soda Lime Glass, having a 17" Diameter etched area around a 8" diameter center opening.


Acrylic disk: 22 1/2" diameter clear center acrylic having a 11 1/2" diameter etched area around a 4" diameter center opening.

Perforated metal disk: Features a square edged inner and outer rubber band. It is available in satin aluminum with black rubber edging with an 22 1/2" diameter.

Bottom lens and cross blade: For Bottom Lens and Cross Blade Louver see bottom left.

Track mount: 16" Pendalytes can be adapted for mounting to, or suspension from, Lytespan track. Please consult Philips Lightolier for price and availability.

All units are cULus listed, suitable for damp locations. Emergency units are UL listed, dry locations.

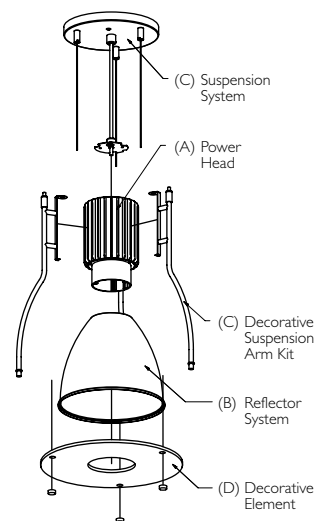

Complete fixture consists of
Power head + Reflector/diffuser + Suspension
 (Example) Order each separately

40734XU3 + 40431 + 416DK + 416DG



Pendalys users guide

To specify use both a reflector and compatible power husk/suspension

6" Performance Pendalys

6" Power husk & cable suspension

406151
406U2

Lamping

150W A21
26/32W TTT



416SR

Depth 6 7/8" - Height 11 1/4"



416AB

Depth 7 1/8" - Height 11 1/4"



416WH

Depth 7 7/8" - Height 11 1/4"



416BL

Depth 7 7/8" - Height 11 1/4"

9" Pendalys

9" Power husk & cable suspension

4046151TM/404SKB
40471U3TM/404SKB

Lamping

150W A21
26/32/42W TTT



40413

Depth 9" - Height 15 3/8"



409AB

Depth 9" - Height 15 3/8"



409WH

Depth 9" - Height 15 3/8"



409BL

Depth 9" - Height 15 3/8"



40411

Depth 9" - Height 15 3/8"

9" Deco Pendalys

9" Power husk & cable suspension

4046151TM/409DKTM
40471U3TM/409DKTM

Lamping

150W A21
26/32/42W TTT



40413/409DG

Depth 12" - Height 16 3/4"



409AB/409DG

Depth 12" - Height 16 3/4"



409WH/409DG

Depth 12" - Height 16 3/4"



409BL/409DG

Depth 12" - Height 16 3/4"



40411/409DG

Depth 12" - Height 16 3/4"

12" Performance Pendalys

12" Power husk & cable suspension

412U3/404SKB
412H70/404SKB

Lamping

26/32/42W TTT
70W ED17 MH



42SR

Depth 12 3/4" - Height 19"



42AB

Depth 12 1/4" - Height 19"



42WH

Depth 12 1/4" - Height 19"



42BL

Depth 12 1/4" - Height 19"

For decorative disks in acrylic or perforated metal, replace DG with DA for acrylic or PM for perforated metal. For 9" Pendalys in Gray finish.

Pendalytes users guide

To specify use both a reflector and compatible power husk/suspension



12" Pendalytes



40422
Depth 12 3/4" - Height 15 3/4"



40421
Depth 12 3/4" - Height 15 3/4"

12" Power husk & cable suspension

4046261/404SKG
40472U3/404SKG
404722XU3/404SKG

Lamping

150W A21
26/32/42W TTT
(2) 26/32/42W TTT

12" Deco Pendalytes



40422/412DG
Depth 15 3/4" - Height 17"



40421/412DG
Depth 15 3/4" - Height 17"

12" Power husk & cable suspension

4046261/412DK
40472U3/412DK
404722XU3/412DK

Lamping

150W A21
26/32/42W TTT
(2) 26/32/42W TTT

16" Pendalytes



40432
Depth 16 1/4" - Height 22"



40431
Depth 16 1/4" - Height 22"

16" Power husk & cable suspension

406371/404SKG
4073U3/404SKG
40734XU3/404SKG

Lamping

150W A21
26/32/42W TTT
(4) 26/32/42W TTT

16" Deco Pendalytes



40432/416DG
Depth 20" - Height 23 1/2"



40431/416DG
Depth 20" - Height 23 1/2"

16" Power husk & cable suspension

406371/416DK
4073U3/416DK
40734XU3/416DK

Lamping

150W A21
26/32/42W TTT
(4) 26/32/42W TTT

For decorative disks in acrylic or perforated metal, replace DG with DA for acrylic or PM for perforated metal.

Contemporary



Palomar 1

Translite scone

Ordering code

PR1

Fixture

PR1

Palomar

 
Diffuser color


FT


Flute


LN

Linear


OW

Opal Acrylic

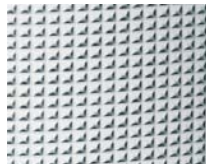
PS

Prismatic


RD

Reed


RN

Rain


SQ

Square


SS

Sunset

Metal finish

BS

Brushed
stainless
steel

NP

Satin nickel
powder
coat

WH

White
powder
coat

Voltage

120
277

Lamping

A60

60w
A19
Medium
Base

F18

18w
Quad/Triple
GX24q-2
Base

FD18

18w
Dulux
2G10
Base

FD24

24w
Dulux
2G10
Base

F26

26w
Quad/Triple
GX24q-3
Base


N3-W*

Three
1.2 watt
LEDs
2700K

N3-N*

Three
1.2 watt
LEDs
3500K


- ADA Compliant
- Features a quick release plunger for quick and tool free lamp replacement
- Comes standard with an integral ballast for all lamping options and mounts on a standard 4" square junction box

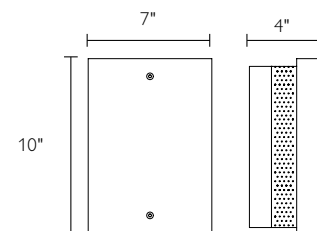



* LED options.

Palomar 2

Translite sconce



- ADA Compliant
- Features a quick release plunger for quick and tool free lamp replacement
- Comes standard with an integral ballast for all fluorescent lamping options and is compatible with T5 and T8 lamps
- Mounts to a standard 4" square junction box

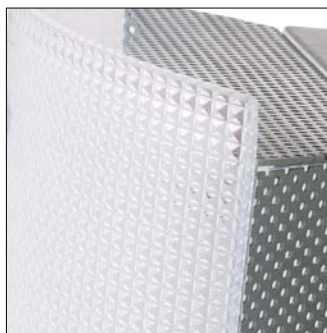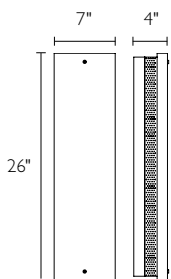

Prismatic Glass

Ordering code

PR2

Fixture

PR2

Palomar 2

Diffuser color



 
FT

Flute




LN

Linear



OW

Opal Acrylic

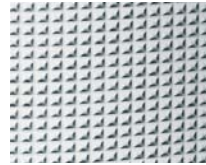

PS

Prismatic



RD

Reed



RN

Rain



SQ

Square



SS

Sunset

Metal finish

BS

Brushed stainless steel

NP

Satin nickel powder coat

WH

White powder coat

Voltage

120

277

Lamping

FL40

40w Long Twin Tube 2G11 Base

2FE17

2x17w T8 Med. Bi-pin

2FF14

2x14w T5 Mini Bi-pin

2FF24

2x24w T5 Mini Bi-pin

Palomar 3

Translite scone

Ordering code

PR3

Fixture

PR3

Palomar 3

 
Diffuser color




FT
Flute



LN
Linear



OW
Opal Acrylic

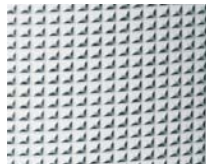

PS
Prismatic




RD
Reed



RN
Rain



SQ
Square

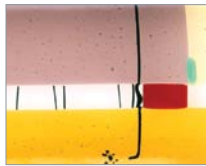

SS
Sunset

Metal finish

BS

Brushed stainless
aluminum

NP

Satin nickel
powder coat

WH

White powder
coat

Voltage

120
277

Lamping

FE17

17w T8
Med. Bi-pin

FF14

14w T5
Mini Bi-pin


FF24

24w T5
Mini Bi-pin

FL40

40w Long Twin
Tube 2G11 Base



- ADA Compliant
- Features a quick release plunger for quick and tool free lamp replacement
- Comes standard with an integral ballast for all fluorescent lamping options and is compatible with T5 and T8 lamps
- Mounts on a standard 4" octagonal junction box with cover plate or on a standard 2" x 3" switch box without cover plate

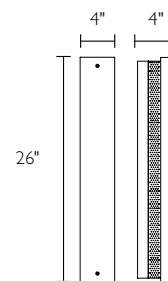

Opal Acrylic

Palomar 4

Translite sconce

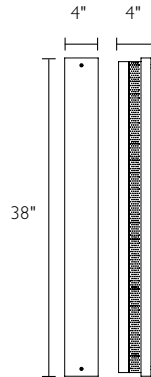

- ADA Compliant
- Features a quick release plunger for quick and tool free lamp replacement
- Comes standard with an integral ballast for all fluorescent lamping options and is compatible with T5 and T8 lamps
- Mounts on a standard 4" octagonal junction box with cover plate or on a standard 2" x 3" switch box without cover plate



Square Glass

Ordering code

PR4

Fixture

PR4
Palomar 4

 
Diffuser color




FT
Flute



LN
Linear



OW
Opal Acrylic

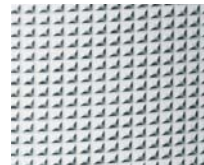

PS
Prismatic



RD
Reed



RN
Rain



SQ
Square



SS
Sunset

Metal finish

BS
Brushed stainless
steel

NP
Satin nickel
powder coat

WH
White powder
coat

Voltage

120

277

Lamping

FE25
25w T8
Med. Bi-pin

FF21
21w T5
Mini Bi-pin

FF39
39w T5
Mini Bi-pin

Palomar 5

Translite sconce

Ordering code

Fixture

PR5

Palomar 5

 
Diffuser color


FT


Flute


LN

Linear


OW

Opal Acrylic

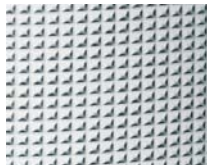
PS


Prismatic


RD

Reed


RN

Rain

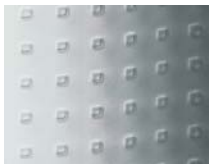
SQ

Square


SS

Sunset

Metal finish

BS

Brushed stainless
aluminum

NP

Satin nickel
powder coat

WH

White powder
coat

Voltage

120
277

Lamping

A60

60w A19
Medium
Base

FD24

24w Dulux
2G10 Base

FD36

36w Dulux
2G10 Base

2F18

2x18w
Quad/Triple
GX24q-2
Base

2FB13

2x13 Twin
Tube GX23
Base


N7-W*

Three
2.4 watt
LEDs
2700K

N7-N*

Three
2.4 watt
LEDs
3500K



- ADA Compliant
- Features a quick release plunger for quick and tool free lamp replacement
- Comes standard with an integral ballast for all fluorescent lamping options
- Mounts to a standard 4" square junction box

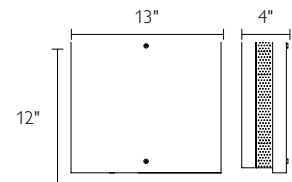

Linear Glass

* Requires remote magnetic 12V transformer. LED options.

Pippa LED

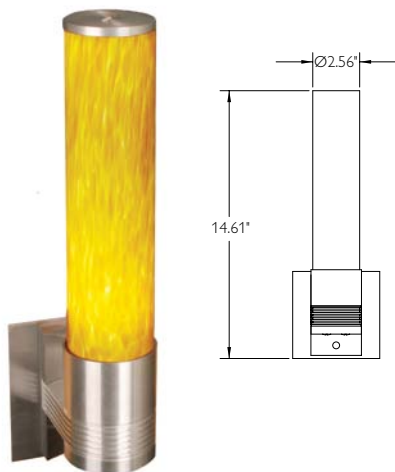

- ADA compliant five layered hand-blown glass sconce with white enamel inner casing
- One 2.4W LED in 2700K or 3500K color temperature
- Integral LED driver
- Requires 12V magnetic transformer which can be remote mounted up to 10 feet away or integral to fixture

Translite sconce

Ordering code

Fixture

PPL5

Pippa LED Sconce

Diffuser color



VR

Mt. Vernon Red



 
SW

Sausalito White



TG

Turner Gold



PW

Polar White

Metal finish

AL

Satin Aluminum

PN

Polished Nickel

GB

Gloss Black

WH

White

Lamping

N2-W

One 2.4 watt LED
2700K

N2-N

One 2.4 watt LED
3500K

Transformer

R


Remote transformer
(ordered separately)¹

T

Integral transformer²

¹Fixture mounts to 2" x 3" switch box when used with remote transformer.

²Fixture supplied with toroidal transformer. Requires a 4" square, 2" deep j-box (by others).

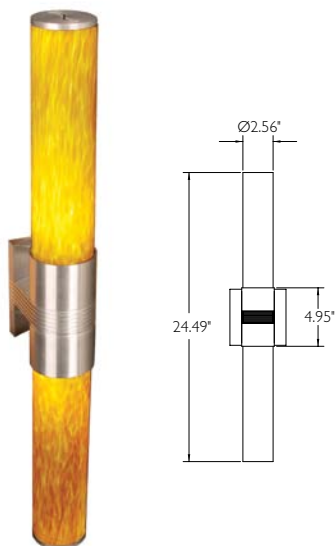

- ADA compliant five layered hand-blown glass sconce with white enamel inner casing
- Two 2.4W LED in 2700K or 3500K color temperature
- Integral LED driver
- Requires 12V magnetic transformer which can be remote mounted up to 10 feet away or integral to fixture

Pippa LED Double

Translite sconce

Ordering code

Fixture

PPL5D

Pippa LED Double Sconce

Diffuser color



VR

Mt. Vernon Red



SW

Sausalito White



TG

Turner Gold



PW

Polar White

Metal finish

AL

Satin Aluminum

PN

Polished Nickel

GB

Gloss Black

WH

White

Lamping

N2-W

Two 2.4 watt LEDs
2700K

N2-N

Two 2.4 watt LEDs
3500K

Transformer

R

Remote transformer
(ordered separately)¹

T

Integral transformer²

¹Fixture mounts to 2" x 3" switch box when used with remote transformer.

²Fixture supplied with toroidal transformer. Requires a 4" square, 2" deep j-box (by others).

Cereus

Translite sconce

Ordering code

CER5 - [] - [] - []

Fixture

CER5

Cereus Sconce

Diffuser color



VR

Mt. Vernon
Red



SW

Sausalito
White



TG

Turner
Gold



PW

Polar
White

Metal finish

SN

Satin nickel

PN

Polished
nickel

RB

Rubbed
bronze

BK

Black


WH

White

Lamping

B60

60w B10.5
Candelabra

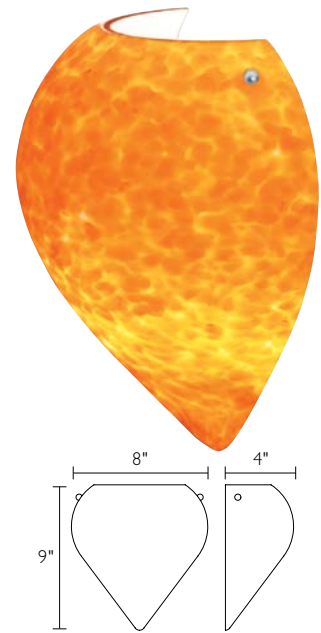

- ADA compliant seven layered hand-blown glass with white enamel inner casing
- J-box center 3.5" from the top of the fixture

Atcha

Translite sconce

Ordering code

ATC5 - [] - [] - []

Fixture

ATC5

Atcha Sconce

Diffuser color



VR

Mt. Vernon
Red



SW

Sausalito
White



TG

Turner
Gold



PW

Polar
White

Metal finish

SN

Satin nickel

PN

Polished
nickel

RB

Rubbed
bronze

BK

Black

WH

White

Lamping

A60

60w A19
Medium
Base

F26


26w Quad/
Triple
GX24q-3

F32

32w Triple
GX24q-3


F42

42w Triple
GX24q-4

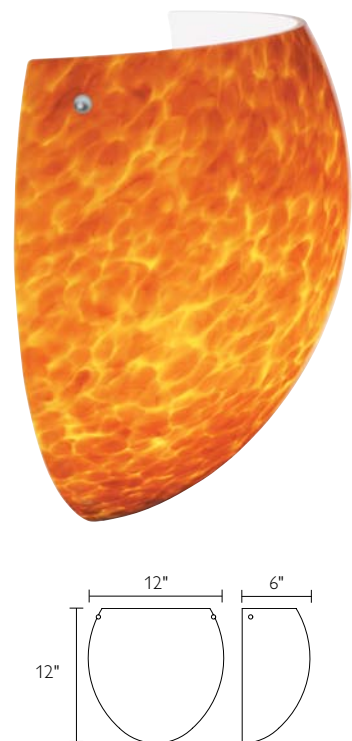

- Seven layered hand-blown glass with white enamel inner casing
- J-box center 2.75" from the top of the fixture

Mini Patrik

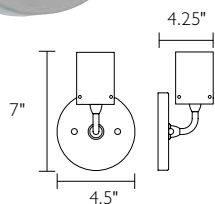

- Five layered hand-blown glass with white enamel inner casing
- Open fixture rated low voltage bi-pin lamp up to 35 watts (not included)
- 4.25" projection

Translite sconce

Ordering code

MPK5

OP1-OP2

Fixture

MPK5

Mini Patrik Sconce

Diffuser Color



VR
Mt. Vernon
Red



SW
Sausalito
White



TG
Turner
Gold



PW
Polar
White

Metal finish

SN
Satin
nickel

PN
Polished
nickel

RB
Rubbed
bronze

BK
Black

WH
White

Lamping

H35

12v 35w GY6.35 base

Options

Option 1

CC
Classic
canopy

CR
Classic canopy
remote
transformer



MR
Modern canopy
remote
transformer

Option 2

277

277V low voltage
transformer

Patrik

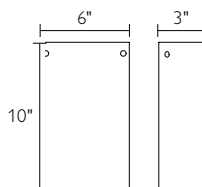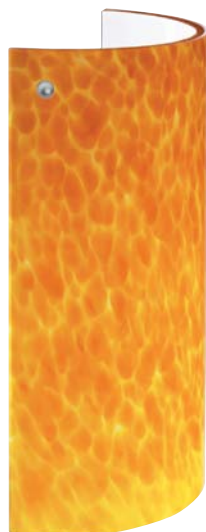

- ADA compliant seven layered hand-blown glass with white enamel inner casing
- J-box center 6.5" from the top of the fixture for fluorescent and 7" for incandescent

Translite sconce

Ordering code

PTK5

Fixture

PTK5

Patrik Sconce

Diffuser color



VR
Mt. Vernon
Red



SW
Sausalito
White



TG
Turner
Gold



PW
Polar
White

Metal finish

SN
Satin
nickel

PN
Polished
nickel

RB
Rubbed
bronze

BK
Black

WH
White

Lamping

B60
60w B10.5,
Candelabra

F13-120
13w 120v
Twin Tube
GX23

F13-277
13w 277v
Twin Tube
GX23

FD18
18w Dulux
F 2G10e

Wintin

Translite sconce

Ordering code

WNT5 – [] – [] – []

Fixture

WNT5

Wintin Sconce

Diffuser Color



VR

Mt. Vernon
Red



SW

Sausalito
White



TG

Turner
Gold



PW

Polar
White

Metal finish

SN

Satin nickel

PN

Polished
nickel

RB

Rubbed
bronze

BK

Black

WH

White

Lamping

2B60


2x60w B10.5,
Candelabra

FL24

24w Long Twin
Tube 2G11

FL36

36w Long Twin
Tube 2G11

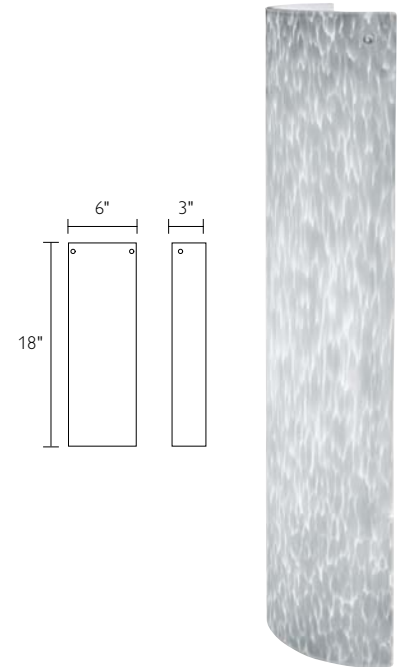

- ADA compliant seven layered hand-blown glass with white enamel inner casing
- J-box center 5.5" from the top of the fixture for fluorescent and 8.625" for incandescent

Silo

Translite sconce

Ordering code

SIL5 – [] – [] – []

Fixture

SIL5

Silo Sconce

Diffuser color



VR

Mt. Vernon
Red



SW

Sausalito
White



TG

Turner
Gold



PW

Polar
White

Metal finish

SN

Satin nickel

PN

Polished
nickel

RB

Rubbed
bronze

BK

Black

WH

White

Lamping

B60



60w B10.5,
Candelabra

F13-120

13w 120v
Twin Tube
GX23

F13-277

13w 277v
Twin Tube
GX23

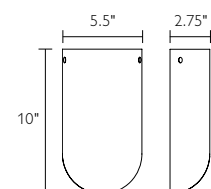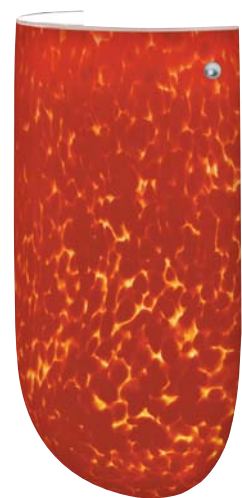

- ADA compliant seven layered hand-blown glass with white enamel inner casing
- J-box center 6.5" from the top of the fixture for fluorescent and 6" for incandescent

Translite

Pendants

Pendants of unparalleled depth of color and texture are available with an extensive array of fluorescent, incandescent or LED lighting options. Handcrafted brilliance is exemplified in the use of elegant silks, sheer fabrics and hand blown glass in the spirit of classical design.



Mini Cereus Polar White pendants

Mini Cereus

Translite pendant

Ordering code

Fixture

MCE1 - [] - [] - [] - OP1-OP2

MCE1

Mini Cereus Pendant

Diffuser color



VR

Mt. Vernon
Red



SW

Sausalito
White



TG

Turner Gold



PW

Polar White

Metal finish

SN

Satin nickel

PN

Polished nickel

RB

Rubbed bronze

BK

Black

WH

White

Lamping

G25

25W G16.5,
Candelabra

H35

12V 35W GY6.35
base

Options

Option 1

CC

Classic
canopy

CR

Classic canopy
remote
transformer

MR

Modern canopy
remote transformer

Option 2

277

277V low voltage
transformer
(H35 lamp only)


WC*

White
cord

CL*

Clear
cord

*G25 lamp only

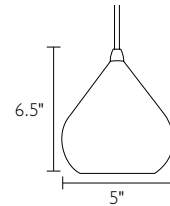

- Five layered hand-blown glass with white enamel inner casing
- Suspended by field adjustable black cord for G25 lamp or tin braided cable
- Standard cord and cable length 108"
- Open fixture rated lamp up to 35 watts (not included)
- Comes standard with Modern Canopy and integral transformer. See page 6.76 table 1 for complete canopy selection.

Cereus

Translite pendant

Ordering code

Fixture

CER1 - [] - [] - [] - OP1-OP2

CER1

Cereus Pendant

Diffuser color



VR

Mt. Vernon
Red



SW

Sausalito
White



TG

Turner Gold



PW

Polar White

Metal finish

SN

Satin nickel

PN

Polished nickel

RB

Rubbed bronze

BK

Black

WH

White

Lamping

A100

100w A19,
Medium Base

F26

26w Quad/Triple,
GX24q-3

F32

32w Triple,
GX24q-3

Options

Option 1

WC

White
cord

CL

Clear
cord

Option 2*


CC

Classic canopy

M5

Modern canopy
remote mount

*See page 6.76 table 2 for canopy selection details.

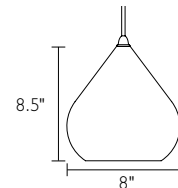

- Seven layered hand-blown glass with white enamel inner casing
- Suspended by field adjustable black cord
- Standard cord length 108"
- See page 6.59 for matching sconce.
- Comes standard with Modern Canopy and integral ballast. See page 6.76 table 2 for complete canopy selection.

Cadre Tall

Translite pendant

Ordering code

CDT2

OP1-
OP2

Fixture

CDT2

Cadre tall stem

 
Diffuser color




GVN
Green Vine



MSS
Moss



WHT
White

 

IVR
Ivory



CRL
Coral



APR
Apricot



IMT
Iced mint



CPR
Copper

Metal finish

SN

Satin nickel

PN

Polished nickel

RB

Rubbed bronze

BK

Black

WH

White

Lamping

A100

100w A19,
Medium Base

F26

26w Quad/
Triple, GX24q-3

F32

32w Triple,
GX24q-3

F42

42w Triple,
GX24q-4

Options

Option 1*

CC

Classic canopy

M5

Modern canopy
remote mount

Option 2

XS "


Extra Length 6"-72"
(Indicate desired OAL in 6" increments)

*See page 6.76 table 2 for canopy selection details.

Compatible accessories

Acrylic Diffusers

Bottom only: 996-B-BCT, Top and Bottom: 996-BCT

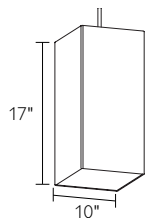

- Long, rectilinear fabric shade
- Handcrafted from finest Dupioni silks and sheer fabrics
- Fire retardant internal liner and nickel frame
- Suspended by 0.375"Ø field adjustable stem
- Standard OAL 32"
- Comes standard with Modern Canopy and integral ballast or driver. See page 6.76 table 2 for complete canopy selection.

Circa

Translite pendant

Ordering code

CCA1

Fixture

CCA1

Circa Pendant

Diffuser style



RD

Round



PK

Pumpkin



OR

Organic

Metal finish

AL

Satin
aluminum

PN

Polished
nickel

RB

Rubbed
bronze

GB

Gloss
black

WH

White

Lamping

N1-W

 
One
1.2 watt
LED 2700K

N1-N

One
1.2 watt
LED 3500K

LED

Options



- Decorative seeded, clear mini glass pendant
- Suspended by tin-braided cable
- Mounts directly into drywall with included canopy
- Integral driver 100-240VAC 50-60 Hz
- CSA approved

Pippa

Translite pendant

Ordering code

Fixture

PPA1 - - - OP1-OP2

PPA1

Pippa pendant

Diffuser color



VR
Mt. Vernon
Red



SW
Sausalito
White



TG
Turner
Gold



PW
Polar
White

Metal finish

SN
Satin
nickel

PN
Polished
nickel

RB
Rubbed
bronze

BK
Black

WH
White

Lamping

B25
25w B10.5
Candelabra

F13-120
13w 120v Twin
Tube GX23

F13-277
13w 277v Twin
Tube GX23

Option 1

WC
White cord

CL
Clear cord

Option 2*



CC

Classic canopy

M5

Modern canopy
remote mount

*See page 6.76 table 2 for canopy selection details.

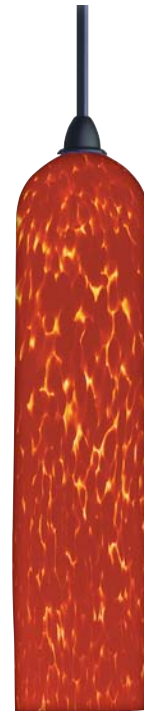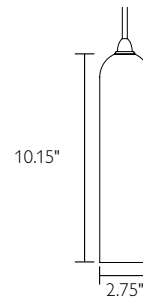

- Five layered hand-blown glass with white enamel inner casing
- Suspended by field adjustable black cord
- Standard cord length 108"
- Comes standard with Modern Canopy and integral transformer or ballast. See page 6.76 table 2 for complete canopy selection.

Crystal Cube

Translite pendant

Ordering code

Fixture

CRC1 - - - OP1-OP2

CRC1

Crystal Cube Pendant

Diffuser color



RS
Resin



GL
Gold



CL
Clear



CB
Cobalt

Metal finish

SN
Satin
nickel

PN
Polished
nickel

RB
Rubbed
bronze

BK
Black

WH
White

Lamping

H35

12v 35w GY6.35 base

Options

Option 1


CC
Classic
canopy

CR
Classic canopy
remote transformer


MR
Modern canopy
remote transformer

Option 2

277
277V low voltage transformer
(H35 lamp only)

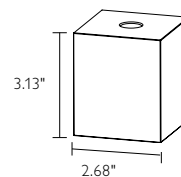

- Decorative mini glass pendant in four translucent colors
- Suspended by field adjustable tin braided cable
- Standard cord and cable length 108"
- Open fixture rated lamp (not included)
- Comes standard with Modern Canopy and integral transformer. See page 6.76 table 1 for complete canopy selection.

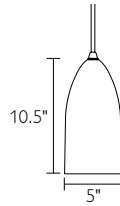

- Seven layered hand-blown glass with white enamel inner casing
- Suspended by field adjustable black cord
- Standard cord length 108"
- Comes standard with Modern Canopy with integral ballast. See page 6.76 table 2 for complete canopy selection.

Osmos

Translite pendant

Ordering code

OSM1

OP1-OP2

Fixture

OSM1

Osmos Pendant

Diffuser color



OB

Osmos Blue



OG

Osmos Green



OR

Osmos Red



OA

Osmos Amber

Metal finish

SN

Satin nickel

PN

Polished nickel

RB

Rubbed bronze

BK

Black

WH

White

Lamping

A100

100w A19
Medium Base

F26

26w
Quad/Triple
GX24q-3

F32

32w Triple
GX24q-3

Option 1

Option 2*

WC

White cord

CL

Clear cord


CC

Classic canopy

M5

Modern canopy
remote mount

*See page 6.76 table 2 for canopy selection details.

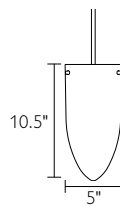

- Seven layered hand-blown glass with white enamel inner casing
- Suspended by field adjustable black cord
- Standard cord length 108"
- Comes standard with Modern Canopy and integral ballast or driver. For complete canopy selection see page 6.76 table 2.

Osmos

Translite pendant

Ordering code

OSM4

OP1-OP2

Fixture

OSM4

Osmos Bowl

Diffuser color



OB

Osmos Blue



OG

Osmos Green



OR

Osmos Red



OA

Osmos Amber

Metal finish

SN

Satin nickel

PN

Polished nickel

RB

Rubbed bronze

BK

Black

WH

White

Lamping

A100

100w A19
Medium Base

F26

26w
Quad/Triple
GX24q-3

F32

32w Triple
GX24q-3

Option 1

Option 2*

WC

White cord

CL

Clear cord

CC

Classic canopy

M5

Modern canopy
remote mount

*See page 6.76 table 2 for canopy selection details.

Norton

Translite pendant

Ordering code

Fixture

NTN1

OP1-OP2

NTN1

Norton Pendant

Diffuser color



VR

Mt. Vernon
Red



SW

Sausalito
White



TG

Turner
Gold



PW

Polar
White

Metal finish

SN

Satin nickel

Lamping

A100

100w A19
Medium Base

F26

26w
Quad/Triple
GX24q-3

F32

32w Triple
GX24q-3

F42

42w Triple
GX24q-4

Options

Option 1

WC

White cord

CL

Clear cord

Option 2*


CC

Classic canopy

M5

Modern canopy
remote mount

*See page 6.76 table 2 for canopy selection details.

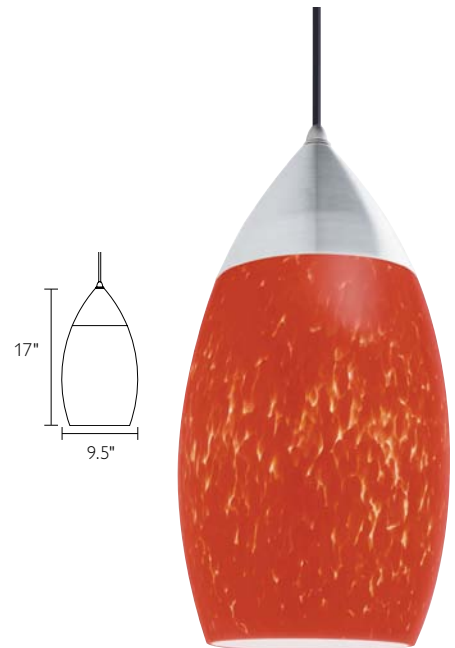

- Seven layered hand-blown glass with white enamel inner casing
- Suspended by field adjustable black cord
- Standard cord length 108"
- Comes standard with Modern Canopy and integral ballast or driver. See page 6.76 table 2 for complete canopy selection.

Solmon

Translite pendant

Ordering code

Fixture

SOL1

OP1-OP2

SOL1

Solmon Pendant

Metal finish

SN

Satin nickel

PN

Polished
nickel

RB

Rubbed
bronze

BK

Black

WH

White

Lamping

A100

100w A19
Medium Base

F26

26w
Quad/Triple
GX24q-3

F32

32w Triple
GX24q-3

F42

42w Triple
GX24q-4

Options

Option 1

WC

White cord

CL

Clear cord

Option 2*


CC

Classic canopy

M5


Modern canopy
remote mount

*See page 6.76 table 2 for canopy selection details.

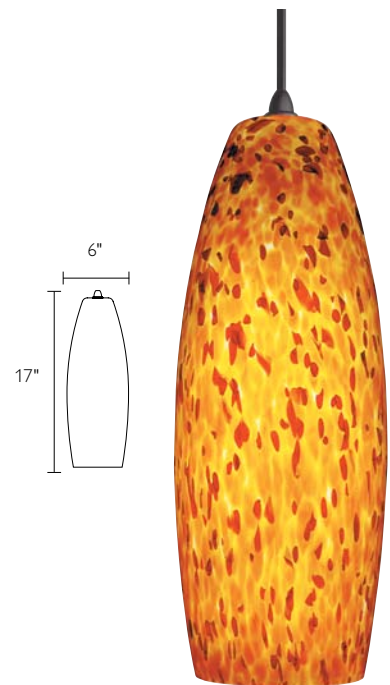

- Seven layered hand-blown glass with white enamel inner casing
- Suspended by field adjustable black cord
- Standard diffuser color is Turner Gold with Mt. Vernon Red
- Standard cord length 108"
- Comes standard with Modern Canopy and integral ballast or driver. See page 6.76 table 2 for complete canopy selection.

Mini Patrik

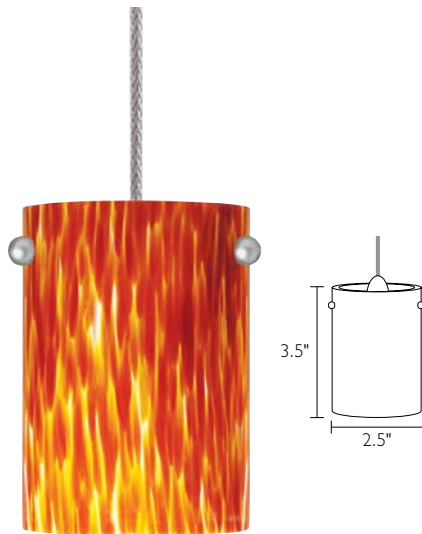

- Five layered hand-blown glass with white enamel inner casing
- Suspended by field adjustable tin braided cable
- Standard cable length 108"
- Open fixture rated low voltage bi-pin lamp up to 35 watts (not included)
- Reference page 6.76 table 1 for canopy selection

Translite pendant

Ordering code

Fixture

MPK1

MPK1

Mini Patrik Pendant

Diffuser color



VR
Mt. Vernon
Red



SW
Sausalito
White



TG
Turner Gold



PW
Polar
White

Metal finish

AL
Satin
aluminum

PN
Polished
nickel

RB
Rubbed
bronze

GB
Gloss
black

WH
White

Lamping

H35

12v 35w GY6.35 base

Options

Option 1

CC
Classic
canopy


CR
Classic canopy
remote transformer

MR
Modern canopy
remote transformer

Option 2

277
277v low voltage transformer

Patrik

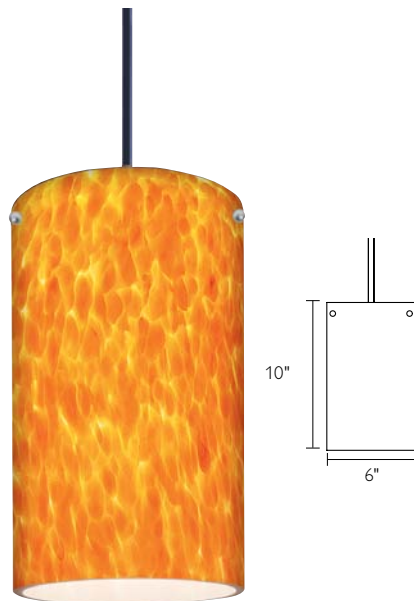

- Seven layered hand-blown glass with white enamel inner casing
- Suspended by field adjustable black cord
- Standard cord length 108"
- See page 6.60 for matching sconce.
- Comes standard with Modern Canopy and integral ballast or driver. See page 6.76 table 2 for complete canopy selection.

Translite pendant

Ordering code

Fixture

PTK1

PTK1

Patrik Pendant

Diffuser color



VR
Mt. Vernon
Red



SW
Sausalito
White



TG
Turner Gold



PW
Polar White

Metal finish

SN
Satin
nickel

PN
Polished
nickel

RB
Rubbed
bronze

BK
Gloss
black

WH
White

Lamping

A100

100w A19,
Medium Base

F26

26w Quad/Triple,
GX24q-3

F32

32w Triple,
GX24q-3

Options

Option 1

WC
White
cord

CL
Clear
cord

Option 2*

CC
Classic canopy

M5
Modern canopy
remote mount

*See page 6.76 table 2 for canopy selection details.

Patrik

Translite pendant


Ordering code

Fixture

PTK2

PTK2
Patrik Stem

 Diffuser color

VR
Mt. Vernon
RedSW
Sausalito
WhiteTG
Turner GoldPW
Polar White

Metal finish

SN

Satin nickel

PN

Polished nickel

RB

Rubbed
bronze

BK

Gloss
black

WH

White

Lamping

A100

100w A19,
Medium Base

F26

26w Quad/Triple,
GX24q-3

F32

32w Triple,
GX24q-3

Options

Option 1*

CC

Classic canopy

M5


Modern canopy
remote mount

Option 2

XS__"

Extra Length 28"-72"

*See page 6.76 table 2 for canopy selection details.

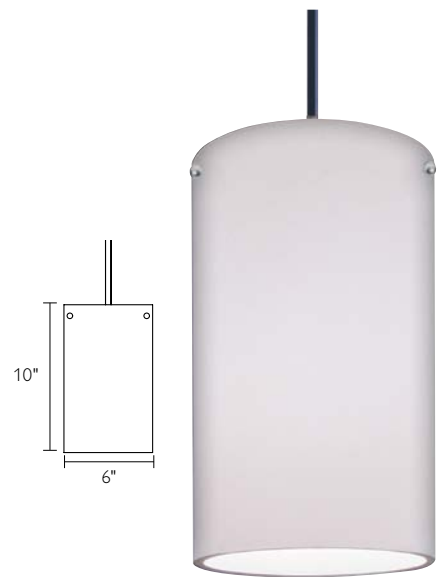

- Seven layered hand-blown glass with white enamel inner casing
- 27" standard OAL
- Suspended by 0.375"Ø metal stem
- Not field adjustable
- See page 6.60 for matching sconce.
- Comes standard with Modern Canopy and integral ballast or driver. See page 6.76 table 2 for complete canopy selection.

Patrik

Translite pendant


Ordering code

Fixture

PTK4

PTK4
Patrik Bowl

 Diffuser color

VR
Mt. Vernon
RedSW
Sausalito
WhiteTG
Turner GoldPW
Polar White

Metal finish

SN

Satin nickel

PN

Polished nickel

RB

Rubbed
bronze

BK

Gloss
black

WH

White

Lamping

A100

100w A19,
Medium Base

F26

26w Quad/Triple,
GX24q-3

F32

32w Triple,
GX24q-3

Options

Option 1

WC

White
cord

CL

Clear
cord

Option 2*

CC

Classic canopy

 
M5

Modern canopy
remote mount

*See page 6.76 table 2 for canopy selection details.



- Seven layered hand-blown glass with white enamel inner casing
- Lamp socket is suspended inside fixture by black cord
- Fixture is suspended by 3 field adjustable aircraft cables
- Standard cord and cable length 108"
- See page 6.60 for matching sconce.
- Comes standard with Modern Canopy and integral ballast or driver. See page 6.76 table 2 for complete canopy selection.



- Seven layered hand-blown glass with white enamel inner casing
- Standard OAL 35"
- Suspended by 0.375"Ø metal stem
- See page 6.61 for matching sconce.
- Comes standard with Modern Canopy and integral ballast. See page 6.76 table 2 for complete canopy selection.

Wintin

Translite pendant

Ordering code

Fixture

WNT2 - [] - [] - [] - OP1-OP2

WNT2

Wintin Stem

Diffuser color



VR
Mt. Vernon
Red



SW
Sausalito
White



TG
Turner Gold



PW
Polar White

Metal finish

SN
Satin nickel

PN
Polished nickel

RB
Rubbed bronze

BK
Gloss black

WH
White

Lamping

A100
100w A19,
Medium Base

F26
26w Quad/Triple,
GX24q-3

F32
32w Triple,
GX24q-3

F42
42w Triple,
GX24q-4

Options

Option 1*

CC

Classic canopy

M5


Modern canopy
remote mount

Option 2

XS_ _"

Extra Length 36"-72"
(Indicate desired OAL in inches)

 *See page 6.76 table 2 for canopy selection details.



- Seven layered hand-blown glass with white enamel inner casing
- Lamp socket is suspended inside fixture by black cord
- Fixture is suspended by 3 field adjustable aircraft cables
- Standard cord and cable length 108"
- See page 6.61 for matching sconce.
- Comes standard with Modern Canopy and integral ballast. See page 6.76 table 2 for complete canopy selection.

Wintin

Translite pendant

Ordering code

Fixture

WNT4 - [] - [] - [] - OP1-OP2

WNT4

Wintin Bowl

Diffuser color



VR
Mt. Vernon
Red



SW
Sausalito
White



TG
Turner Gold



PW
Polar White

Metal finish

SN
Satin nickel

PN
Polished nickel

RB
Rubbed bronze

BK
Gloss black

WH
White

Lamping

A150
150w A19,
Medium Base

F26
26w Quad/Triple,
GX24q-3

F32
32w Triple,
GX24q-3

F42
42w Triple,
GX24q-4

Options

Option 1

WC

White
cord

CL

Clear
cord

Option 2*

CC

Classic canopy

M5

Modern canopy
remote mount

*See page 6.76 table 2 for canopy selection details.

Wintin

Translite pendant

Ordering code
Fixture

WNT1 - - - OP1-OP2

WNT1

Wintin Pendant

Diffuser color



VR
Mt. Vernon
Red



SW
Sausalito
White



TG
Turner Gold



PW
Polar White

Metal finish

SN
Satin nickel

PN
Polished nickel

RB
Rubbed bronze

BK
Black

WH
White

Lamping

A100
100w A19,
Medium Base

F26
26w Quad/Triple,
GX24q-3

F32
32w Triple,
GX24q-3

F42
42w Triple,
GX24q-4

Options

Option 1


WC
White
cord

CL
Clear
cord

Option 2*

CC **M5**
Classic canopy Modern canopy
remote mount

*See page 6.76 table 2 for canopy selection details.

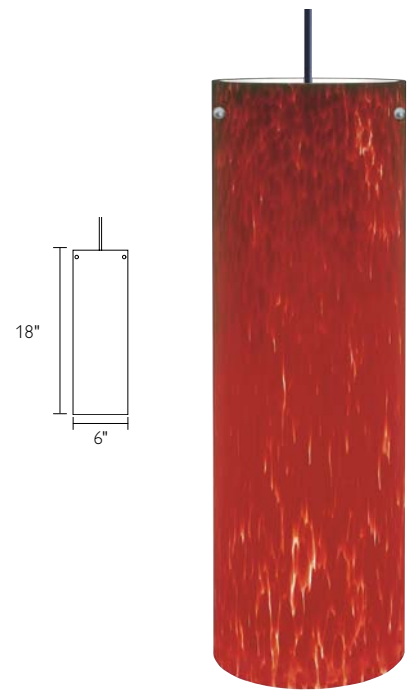

- Seven layered hand-blown glass with white enamel inner casing
- Suspended by field adjustable black cord
- Standard cord length 108"
- See page 6.61 for matching sconce.
- Comes standard with Modern Canopy and integral ballast. See page 6.76 table 2 for complete canopy selection.

Mini Silo

Translite pendant

Ordering code


MSL1 - - - OP1-OP2

Fixture

MSL1

Mini Silo Pendant

 Diffuser color



VR
Mt. Vernon
Red



SW
Sausalito
white



TG
Turner gold



PW
Polar white

Metal finish

SN
Satin nickel

PN
Polished nickel

RB
Rubbed bronze

BK
Black

WH
White

Lamping

G25
25w G16.5,
Candelabra

H35
12v 35w GY6.35
base

Options

Option 1

CC
Classic
canopy

CR
Classic canopy
remote
transformer

MR
Modern canopy
remote transformer

Option 2

277
277v low voltage
transformer
(H35 lamp only)

WC*
White
cord

*G25 lamp only

CL*
Clear
cord



- Five layered hand-blown glass with white enamel inner casing
- Suspended by field adjustable black cord for G25 lamp or tin braided cable for open fixture rated low voltage bi-pin lamp up to 35 watts (not included)
- Standard cord and cable length 108"
- See page 6.61 for matching sconce.
- Comes standard with Modern Canopy and integral transformer. See page 6.76 table 1 for complete canopy selection.

Silo

Translite pendant

Ordering code

SIL1 – [] – [] – [] – **OP1-OP2**

Fixture

SIL1
Silo Pendant

Diffuser color



VR
Mt. Vernon
Red



SW
Sausalito
White



TG
Turner Gold



PW
Polar White

Metal finish

SN
Satin nickel

PN
Polished nickel

RB
Rubbed bronze

BK
Black

WH
White

Lamping

A100
100w A19,
Medium Base

F26
26w Quad/Triple,
GX24q-3

F32
32w Triple,
GX24q-3


Options

WC
White
cord

Option 1
CL
Clear
cord

CC Option 2* **M5**
Classic canopy Modern canopy
remote mount

*See page 6.76 table 2 for canopy selection details.

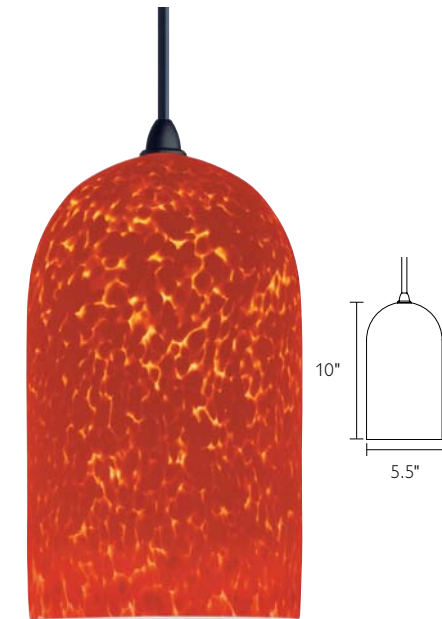

- Seven layered hand-blown glass with white enamel inner casing
- Suspended by field adjustable black cord
- Standard cord length 108"
- See page 6.61 for matching scone.
- Comes standard with Modern Canopy and integral ballast or driver. See page 6.76 table 2 for complete canopy selection.

Silo

Translite pendant

Ordering code

SIL2 – [] – [] – [] – **OP1-OP2**

Fixture

SIL2
Silo Stem

Diffuser color



VR
Mt. Vernon
Red



SW
Sausalito
White



TG
Turner Gold



PW
Polar White

Metal finish

SN
Satin nickel

PN
Polished nickel

RB
Rubbed bronze

BK
Black

WH
White

Lamping

A100
100w A19,
Medium Base

F26
26w Quad/Triple,
GX24q-3

F32
32w Triple,
GX24q-3


Options

Option 1*
CC
Classic canopy

M5
Modern canopy
remote mount

Option 2
X5 – " –
Extra Length 30"–72"
(Indicate desired OAL in 6" increments)

*See page 6.76 table 2 for canopy selection details.

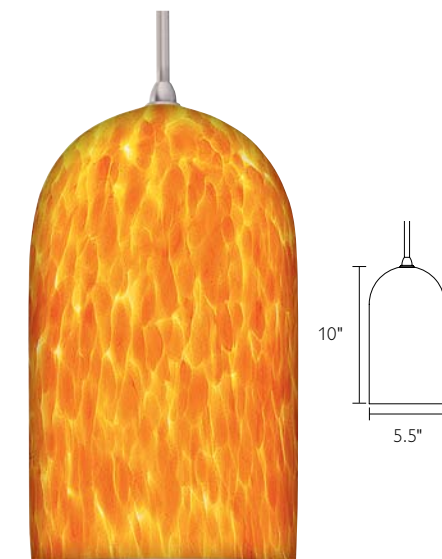

- Seven layered hand-blown glass with white enamel inner casing
- Standard OAL 27"
- Suspended by 0.375"Ø metal stem
- Not field adjustable
- See page 6.61 for matching scone.
- Comes standard with Modern Canopy and integral ballast or driver. See page 6.76 table 2 for complete canopy selection.

Silo

Translite pendant

Ordering code

SIL4 - - - - **OP1-OP2**

Fixture

SIL4
Silo Bowl

Diffuser color



VR
Mt. Vernon
Red



SW
Sausalito
White



TG
Turner Gold



PW
Polar White

Metal finish

SN

Satin nickel

PN

Polished nickel

RB

Rubbed bronze

BK

Black

WH

White

Lamping

A100

100w A19,
Medium Base

F26

26w Quad/Triple,
GX24q-3

F32

32w Triple,
GX24q-3

Options

WC

White
cord

Option 1

CL

Clear
cord


CC

Classic canopy

Option 2* **M5**

Modern canopy
remote mount

*See page 6.76 table 2 for canopy selection details.

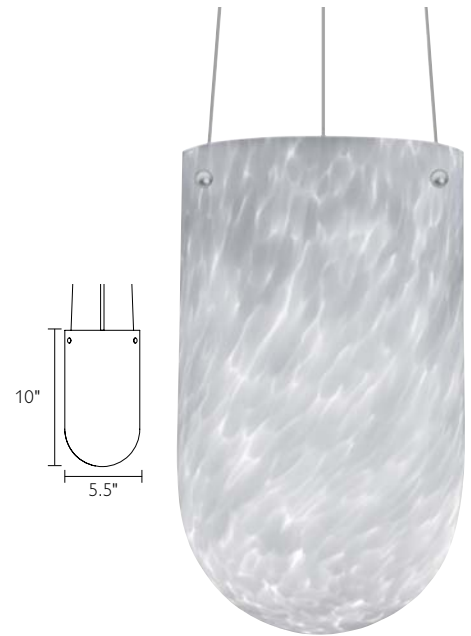

- Seven layered hand-blown glass with white enamel inner casing
- Lamp socket is suspended inside fixture by black cord
- Fixture is suspended by 3 field adjustable aircraft cables
- Standard cord and cable length 108"
- See page 6.61 for matching sconce.
- Comes standard with Modern Canopy and integral ballast or driver. See page 6.76 table 2 for complete canopy selection.

Super Silo

Translite pendant

Ordering code

SPS2 - - - - **OP1-OP2**

Fixture

SPS2
Super Silo Stem

Diffuser color



VR
Mt. Vernon
Red



SW
Sausalito
White



TG
Turner Gold



PW
Polar White

Metal finish

SN

Satin nickel

PN

Polished nickel

RB

Rubbed bronze

BK

Black

WH

White

Lamping

A150

150w A19,
Medium Base

F26

26w Quad/Triple,
GX24q-3

F32

32w Triple,
GX24q-3

F42

42w Triple,
GX24q-4

Options

CC

Classic canopy

Option 1*


M5

Modern canopy
remote mount


XL

Extra Length 30"-72"
(Indicate desired OAL in 6" increments)

*See page 6.76 table 2 for canopy selection details.

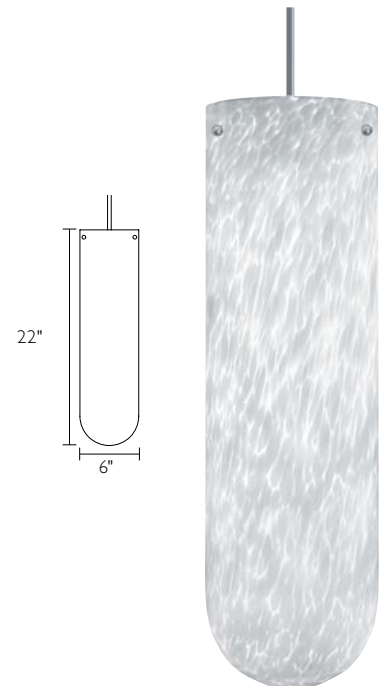

- Seven layered hand-blown glass with white enamel inner casing
- Standard OAL 39"
- Suspended by 0.375"Ø metal stem
- Not field adjustable
- Comes standard with Modern Canopy and integral ballast. See page 6.76 table 2 for complete canopy selection.

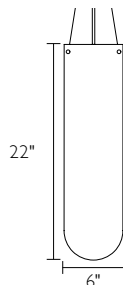

- Seven layered hand-blown glass with white enamel inner casing
- Lamp socket is suspended inside fixture by black cord
- Fixture is suspended by 3 field adjustable aircraft cables
- Standard cord and cable length 100"
- Comes standard with Modern Canopy and integral ballast. See page 6.76 table 2 for complete canopy selection.

Super Silo

Translite pendant

Ordering code

Fixture

SPS4

OP1-OP2

SPS4
Super Silo Bowl

Diffuser color



VR
Mt. Vernon
Red



SW
Sausalito
White



TG
Turner Gold



PW
Polar White

Metal finish

SN
Satin nickel

PN
Polished nickel

RB
Rubbed bronze

BK
Black

WH
White

Lamping

A150
150w A19,
Medium Base

F26
26w Quad/Triple,
GX24q-3

F32
32w Triple,
GX24q-3

F42
42w Triple,
GX24q-4

Options

Option 1

WC
White
cord


CL
Clear
cord

Option 2*

CC
Classic canopy

M5
Modern canopy
remote mount

*See page 6.76 table 2 for canopy selection details.

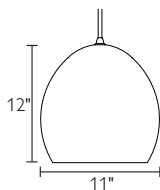

- Seven layered hand-blown glass with white enamel inner casing
- Suspended by field adjustable black cord
- Standard cord length 108"
- See page 6.59 for matching sconce.
- Comes standard with Modern Canopy and integral ballast or driver. See page 6.76 table 2 for complete canopy selection.

Atcha

Translite pendant

Ordering code

Fixture

ATC1

OP1-OP2

ATC1
Atcha Pendant

Diffuser color



VR
Mt. Vernon
Red



SW
Sausalito
White



TG
Turner Gold



PW
Polar White

Metal finish

SN
Satin nickel

PN
Polished nickel

RB
Rubbed bronze

BK
Black

WH
White

Lamping

A100
100w A19,
Medium Base

F26
26w Quad/Triple,
GX24q-3

F32
32w Triple,
GX24q-3

F42
42w Triple,
GX24q-4

Options

Option 1

WC
White
cord

CL
Clear
cord

Option 2*

CC
Classic canopy

M5
Modern canopy
remote mount

*See page 6.76 table 2 for canopy selection details.

Atcha

Translite pendant

Ordering code

Fixture

ATC2 - [] - [] - [] - OP1-OP2

ATC2

Atcha Stem

Diffuser color

**VR**Mt. Vernon
Red**SW**Sausalito
White**TG**

Turner Gold

**PW**

Polar White

Metal finish

SN

Satin nickel

PN

Polished nickel

RB

Rubbed bronze

BK

Black

WH

White

Lamping

A100100w A19,
Medium Base**F26**26w Quad/Triple,
GX24q-3**F32**32w Triple,
GX24q-3**F42**42w Triple,
GX24q-4

Options

Option 1*

CC

Classic canopy

M5Modern canopy
remote mount


Option 2

XS_ _ _"

Extra Length 30"-72"

(Indicate desired OAL in 6" increments)

*See page 6.76 table 2 for canopy selection details.

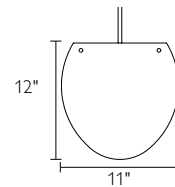

- Seven layered hand-blown glass with white enamel inner casing
- Standard OAL 29"
- Suspended by 0.375"Ø metal stem
- Not field adjustable
- See page 6.59 for matching sconce.
- Comes standard with Modern Canopy and integral ballast or driver. See page 6.76 table 2 for complete canopy selection.

Atcha

Translite pendant

Ordering code

Fixture

ATC4 - [] - [] - [] - OP1-OP2

ATC4

Atcha Bowl

Diffuser color

**VR**Mt. Vernon
Red**SW**Sausalito
White**TG**

Turner Gold

**PW**

Polar White

Metal finish

SN

Satin nickel

PN

Polished nickel

RB

Rubbed bronze

BK

Black

WH

White

Lamping

A100100w A19,
Medium Base**F26**26w Quad/Triple,
GX24q-3**F32**32w Triple,
GX24q-3**F42**42w Triple,
GX24q-4

Options

Option 1

WCWhite
cord**CL**Clear
cord


Option 2*

CC

Classic canopy

M5Modern canopy
remote mount

*See page 6.76 for canopy selection details.

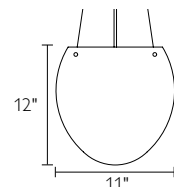

- Seven layered hand-blown glass with white enamel inner casing
- Lamp socket is suspended inside fixture by black cord
- Fixture is suspended by 3 field adjustable aircraft cables
- Standard cord and cable length 108"
- See page 6.59 for matching sconce.
- Comes standard with Modern Canopy and integral ballast or driver. See page 6.76 table 2 for complete canopy selection.

Selecting a canopy


Translite

When selecting a canopy for your fixture, Translite Systems has the ideal canopy for your needs. Translite Systems' canopy choices can be divided into three groups: Small Glass, Large Glass and Flush Mount. Use the quick reference charts below to determine the canopy order code for your fixture.


Table 1: Small glass

Translite Systems small glass fixtures have two canopies that come standard with the fixture depending on which lamp is selected. Canopy options change when the Classic Canopy is preferred or when the lamp is powered by a remote transformer.


**Modern canopy
integral transformer**

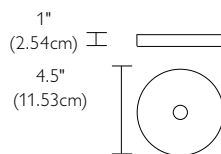

**Modern canopy
remote transformer**

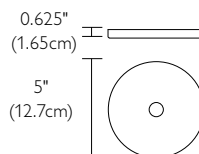

**Classic
Canopy**

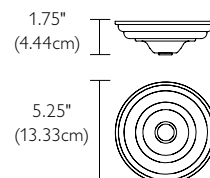


	Standard option	Classic canopy	Modern canopy for remote transformer	Classic canopy for remote transformer
H35 Lamp	- No selection required - Fixture comes standard with integral transformer and canopy (4.5"w x 1"h)	CC Fixture supplied with integral transformer and canopy (5.25"w x 1.75"h)	MR Fixture supplied for remote transformer (supplied by others) and canopy (5"w x 0.625"h)	CR Fixture supplied for remote transformer (supplied by others) and canopy (5.25"w x 1.75"h)
G25 Lamp or G60 Lamp	- No selection required - Fixture comes standard with canopy (5"w x 0.625"h)	CC Fixture supplied with canopy (5.25"w x 1.75"h)	N/A	N/A


Table 2: Large glass

Translite Systems large glass fixtures may be specified with incandescent or fluorescent lamps. Large glass fixtures have two canopies that come standard with the fixture depending on which lamp is selected. Canopy options change when the Classic Canopy or Remote Ballast option is specified.


**Modern canopy
incandescent lamp
and remote ballast (M5)**

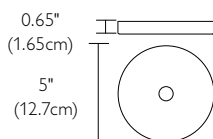

**Fluorescent & LED
Modern canopy integral**

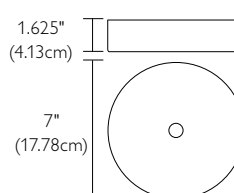

**Classic
canopy**

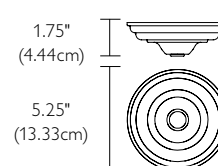

	Standard option	Classic canopy	Modern canopy for remote transformer
Incandescent lamp	- No selection required- Fixture comes standard with canopy (5"w x 0.625"h)	CC Fixture supplied with canopy (5.25"w x 1.75"h)	N/A
G25 Lamp or G60 Lamp	- No selection required- Fixture comes standard with integral ballast and canopy (7"w x 1.625"h)	CC Fixture supplied with driver and canopy (5.25"w x 1.75"h); ballast must be remotely located; distance from driver to socket may not exceed 8'	M5 Fixture supplied with driver and canopy (5.25"w x 1.75"h); ballast must be remotely located; distance from driver to socket may not exceed 8'
LED	- No selection required- Fixture comes standard with integral driver and canopy (7"w x 1.625"h)	CC Fixture supplied with driver and canopy (5.25"w x 1.75"h); ballast must be remotely located; distance from driver to socket may not exceed 8'	M5 Fixture supplied with driver and canopy (5.25"w x 1.75"h); ballast must be remotely located; distance from driver to socket may not exceed 8'

Cord and cable options

Translite

Cable options vary for low voltage and line voltage pendants. Low voltage pendants – small glass pendants and metal fixtures – use a tin braided, coaxial cable which comes in two finishes: Silver and Rubbed Bronze. Use of these two different cables is dependent upon the selected finish of the fixture and/or track system. Line voltage pendants use 18-4, 18-3 and 18-2 AWG field adjustable SVT and SJT cord. 18-3 and 18-4 cords feature Kevlar™ lining. Cord comes standard in Black. Optional White Cord and Clear Cord may be specified.



Clear



Black



White



Lightshields

Lightshield material is accented by a Nickel Powder-Coat finished steel frame. All are ADA compliant. (4" maximum extension)

Luminosities

Wall mounted ADA

Luminosities utilize composites of translucent organic materials sealed in thin-film polymers to create highly sophisticated lighting for circulation, retail, and dining areas.

Wood



408869 Lightshield only



408879 Lightshield only



408889 Lightshield only

Grid



408867 Lightshield only



408877 Lightshield only



408887 Lightshield only

Pick-Up Sticks



408865 Lightshield only



408885 Lightshield only




408885 Lightshield only

Parchment



4088610 Lightshield only

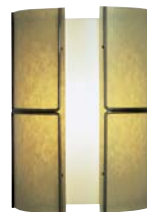

4088710 Lightshield only



4088810 Lightshield only

Luminosities

Wall mounted ADA


Luminosities utilize composites of translucent organic materials sealed in thin-film polymers to create highly sophisticated lighting for circulation, retail, and dining areas.

Grid



Grid is a subtle geometric pattern of Japanese Rice Paper, laminated for durability and ease of cleaning.

Wood

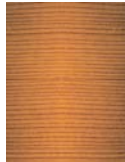

Wood is a quarter-cut veneer of genuine Japanese Cedar, laminated for durability and ease of cleaning.

Pick-Up-Sticks




Pick-Up Sticks is an informal pattern of Japanese Mulberry Paper, laminated for durability and ease of cleaning.

Parchment



Parchment is a paper simulating the skin once used for writing, laminated for durability and ease of cleaning.

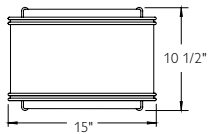

408865

Pick-Up
Sticks

408869


Wood

408867

Grid

4088610

Parchment

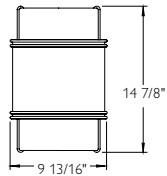

408875

Pick-Up
Sticks

408879


Wood

408877

Grid

4088710

Parchment

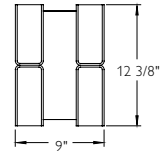

408885

Pick-Up
Sticks

408889

Wood

408887

Grid

4088810

Parchment

 
Backplate assemblies (not shown)



Lamp / ballast specification

Incandescent:

40885 1 X 60W A-19



Compact fluorescent:

40885U Universal Electronic
2 X 13W Quad (4-Pin)
120V-277V

UL listed. Suitable for damp locations.

Complete fixture consists of

Lightshield and backplate assembly

(Example)

Order each separately

408869

+

40885U

Lightshield
Wood

Backplate 2 X 13W Quad
Universal Electronic

Traditional



Pandalux Cirrus

Ordering guide

How to specify

Order the body: Electrical options listing below.

Order the suspension: style and size that closely approximate the desired OAL (overall length) which is defined as the distance from the bottom of the diffuser to the ceiling plane.

Note: If a larger suspension is required, order as a third component, a field-cuttable extension stem (see specification sheet no. 45XT). All suspensions contain a jig to allow for field shortening of stem assembly. For all 4SBXXX single stem kits, extensions replace original stem. For all other kits, extension stem replaces short section above collection point.

For optimum performance we recommend OAL in proportion to the Body diameter (see shaded cells). Certain suspension styles cannot be paired with non-proportional Body diameters and are noted as "NA."

Complete fixture consists of		
Body + Suspension		
(Example)	Order each separately	
4A35642APBU	+	4SB135PB
35" Cirrus Body 6 Lamp Polished Brass		Single Stem Suspension 35" OAL Polished Brass


Pandalux luminaires consist of two components: body and suspension.

Order each separately.


Select the Diameter, Suspension and Layout best suited to the space. The drawing below shows the full family of the **Cirrus Pandalux** style with recommended overall suspension lengths relative to ceiling heights from 10' to 12'. For illumination performance, refer to factory recommended sample layout and application data charts on the facing page.

Body

Opal Acrylic
Diffuser/Metal
Knob CFL Triple
tube 26/32/42W
120V-277V
Electronic Ballast

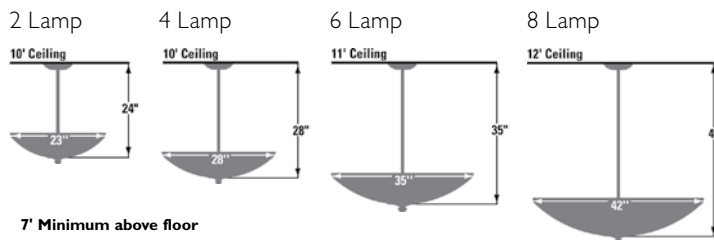


Suspensions

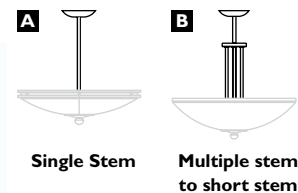

Pandalux specifications

	2 Lamp cat. No.	4 Lamp cat. No.	6 Lamp cat. No.	8 Lamp cat. No.
Polished brass	4A23242APBU	4A28442APBU	4A35642APBU	4A42842APBU
Satin nickel	4A23242ASNU	4A28442ASNU	4A35642ASNU	4A42842ASNU
A Suspension Cat. no.	Nominal OAL	Nominal OAL	Nominal OAL	Nominal OAL
4SB115*	15" (Close to Ceiling)	15 3/16" (Close Ceiling)	16 9/16"	18 1/4"
4SB118*	16 7/16"	16 5/8"	18" (Close to Ceiling)	19 11/16"
4SB121*	17 3/4"	17 15/16"	19 5/16"	21" (Close to Ceiling)
4SB124*	24"	24 3/16"	25 9/16"	27 1/4"
4SB128*	27 3/16"	28"	29 3/8"	31 1/16"
4SB135*	33 7/16"	33 5/8"	35"	36 11/16"
4SB142*	38 3/4"	38 15/16"	40 5/16"	42"
B Suspension Cat. no.	Nominal OAL	Nominal OAL	Nominal OAL	Nominal OAL
4SB224*	NA	24 3/16"	25 9/16"	27 1/4"
4SB228*	NA	28"	29 3/8"	31 1/16"
4SB235*	NA	33 5/8"	35"	36 11/16"
4SB242*	NA	38 15/16"	40 5/16"	42"

*Specify Finish: **PB** = Polished Brass **SN** = Satin Nickel

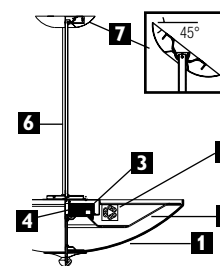

1. Diffusing reflector:

White translucent acrylic, 3/16" thick.

2. Inner dirt shield:

White translucent acrylic, 1/8" thick.

3. Chassis:

Steel, 20 gauge, white semigloss powder coat.

4. Ballasts:

Electronic, Class P, universal voltage and multi-wattage.

5. Lamp holder:

Multi-wattage, 4 pin, accepts either GX24q-3 or GX24q-4 base.

6. Suspension:

5/8" steel tube stem with swivel joint atop allows 45° slope. Conforms to California Earthquake Code.

7. Canopy:

Steel, 7" diameter, no external fasteners

Lamps: Compact Fluorescent Triple Tube, 26, 32, or 42 Watts

Pendalux Gemini

Ordering guide

How to specify

Order the body: Electrical options listing below.

Order the suspension: style and size that closely approximate the desired OAL (overall length) which is defined as the distance from the bottom of the diffuser to the ceiling plane.

For optimum performance we recommend OAL in proportion to the Body diameter (see shaded cells). Certain suspension styles cannot be paired with non-proportional Body diameters and are noted as "NA."

Note: If a larger suspension is required, order as a third component, a field-cutable extension stem (see specification sheet no. 45XT). All suspensions contain a jig to allow for field shortening of stem assembly. For all 4SBXXX single stem kits, extensions replace original stem. For all other kits, extension stem replaces short section above collection point.



Pendalux luminaires consist of two components: body and suspension.

Order each separately.

Select the Diameter, Suspension and Layout best suited to the space. The drawing below shows the full family of the **Gemini Pendalux** style with recommended overall suspension lengths relative to ceiling heights from 10' to 12'. For illumination performance, refer to factory recommended sample layout and application data charts on the facing page.

Complete fixture consists of
Body + Suspension
(Example) Order each separately


4F35642ASNU + **4SB235SN**

35" Gemini Body
6 Lamp Satin Nickel

Multiple Stem Suspension
35" OAL Satin Nickel

Body


Twin Steel Flange/
Opal Acrylic
CFL Triple tube
26/32/42W
120V-277V
Electronic Ballast

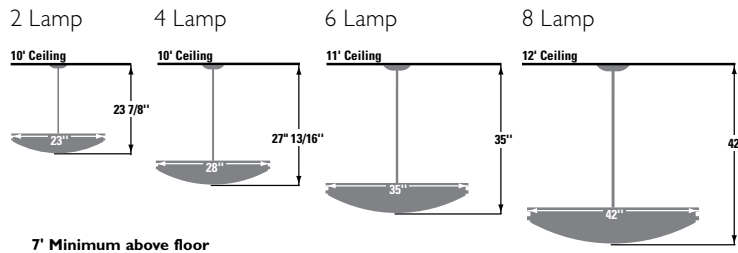


	2 Lamp cat. No.	4 Lamp cat. No.	6 Lamp cat. No.	8 Lamp cat. No.
Polished brass	4F23242APBU	4F28442APBU	4F35642APBU	4F42842APBU
Satin nickel	4F23242ASNU	4F28442ASNU	4F35642ASNU	4F42842ASNU
White	4F23242AWHU	4F28442AWHU	4F35642AWHU	4F42842AWHU
A Suspension Cat. no.	Nominal OAL	Nominal OAL	Nominal OAL	Nominal OAL
4SB115*	14 7/8" (Close to Ceiling)	15" (Close to Ceiling)	16 9/16"	18 1/4"
4SB118*	16 5/16"	16 7/16"	18" (Close to Ceiling)	19 11/16"
4SB121*	17 5/8"	17 3/4"	19 5/16"	21" (Close to Ceiling)
4SB124*	23 7/8"	24"	25 9/16"	27 1/4"
4SB128*	27 11/16"	27 13/16"	29 3/8"	31 1/16"
4SB135*	33 5/16"	33 7/16"	35"	36 11/16"
4SB142*	38 5/8"	38 3/4"	40 5/16"	42"
B Suspension Cat. no.	Nominal OAL	Nominal OAL	Nominal OAL	Nominal OAL
4SB224*	NA	24"	25 9/16"	27 1/4"
4SB228*	NA	27 13/16"	29 3/8"	31 1/16"
4SB235*	NA	33 7/16"	35"	36 11/16"
4SB242*	NA	38 3/4"	40 5/16"	42"
C Suspension Cat. no.	Nominal OAL	Nominal OAL	Nominal OAL	Nominal OAL
4SB324*	23 7/8"	NA	NA	NA
4SB328*	NA	27 13/16"	NA	NA
4SB335*	NA	NA	35"	NA
4SB342*	NA	NA	NA	42"

*Specify Finish: **PB** = Polished Brass **SN** = Satin Nickel **WH** = White

Suspensions

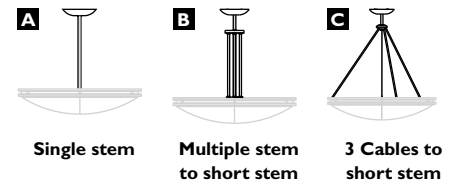

Pendalux specifications

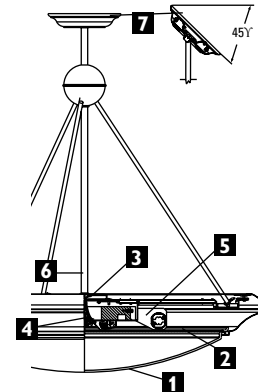

- 1. Diffusing reflector:** White translucent acrylic, 3/16" thick
- 2. Inner dirt shield:** White translucent acrylic, 1/8" thick
- 3. Chassis:** Steel, 20 gauge, white semigloss powder coat
- 4. Ballasts:** Electronic, Class P, universal voltage and multi-wattage
- 5. Lamp holder:** Multi-wattage, 4 pin, accepts either GX24q-3 or GX24q-4 base
- 6. Suspension:** 3 Steel 3/8" tubes (lower), 5/8" center steel tube stem with swivel joint atop allows 45° slope. Conforms to California Earthquake Code.
- 7. Canopy:** Steel, 7" diameter, no external fasteners

Lamps: Compact Fluorescent Triple Tube, 26, 32, or 42 Watts



Pendalux Contemporary

Ordering guide

How to specify

Order the body: Electrical options listing below.

Order the suspension: style and size that closely approximate the desired OAL (overall length) which is defined as the distance from the bottom of the diffuser to the ceiling plane.

Note: If a larger suspension is required, order as a third component, a field-cuttable extension stem (see specification sheet no. 45XT). All suspensions contain a jig to allow for field shortening of stem assembly. For all 45B1XXXX single stem kits, extensions replace original stem. For all other kits, extension stem replaces short section above collection point.

For optimum performance we recommend OAL in proportion to the Body diameter (see shaded cells). Certain suspension styles cannot be paired with non-proportional Body diameters and are noted as "NA."

Complete fixture consists of		
Body + Suspension		
(Example)	Order each separately	
4K28442ASBU	+	4SB335SB
35" Contemporary Body 6 Lamp Satin Nickel		3 Cables to Short Stem 35" OAL Pol. Brass


Pendalux luminaires consist of two components: body and suspension

Order each separately.

Select the Diameter, Suspension and Layout best suited to the space. The drawing below shows the full family of the **Contemporary Pendalux** style with recommended overall suspension lengths relative to ceiling heights from 10' to 12'. For illumination performance, refer to factory recommended sample layout and application data charts on the facing page.

Body

Contemporary
Steel Flange/Opal
Acrylic CFL Triple
tube 26/32/42W
120V-277V
Electronic Ballast

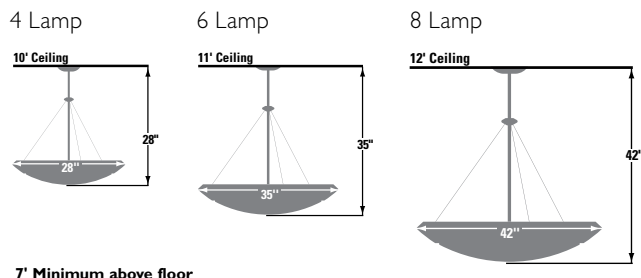


7' Minimum above floor


	4 Lamp cat. No.	6 Lamp cat. No.	8 Lamp cat. No.
Satin brass	4K28442ASBU	4K35642ASBU	4K42842ASBU
Satin nickel	4K28442ASNU	4K35642ASNU	4K42842ASNU
White	4K28442AWHU	4K35642AWHU	4K42842AWHU
A Suspension Cat. no.	Nominal OAL	Nominal OAL	Nominal OAL
4SB115*	15 3/16" (Close to Ceiling)	16 9/16"	18 1/4"
4SB118*	16 5/8"	18" (Close to Ceiling)	19 11/16"
4SB121*	17 15/16"	19 5/16"	21" (Close to Ceiling)
4SB124*	24 3/16"	25 9/16"	27 1/4"
4SB128*	28"	29 3/8"	31 1/16"
4SB135*	33 5/8"	35"	36 11/16"
4SB142*	38 15/16"	40 5/16"	42"
B Suspension Cat. no.	Nominal OAL	Nominal OAL	Nominal OAL
4SB224*	24 3/16"	25 9/16"	27 1/4"
4SB228*	28"	29 3/8"	31 1/16"
4SB235*	33 5/8"	35"	36 11/16"
4SB242*	38 15/16"	40 5/16"	42"
C Suspension Cat. no.	Nominal OAL	Nominal OAL	Nominal OAL
4SB328*	28"	NA	NA
4SB335*	NA	35"	NA
4SB342*	NA	NA	42"

*Specify Finish: PB = Polished Brass SN = Satin Nickel WH = White

Suspensions

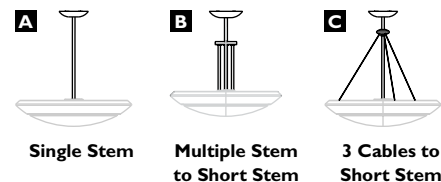

Pendalux specifications

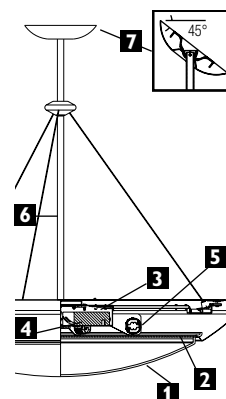

1. Diffusing reflector:

White translucent acrylic, 3/16" thick

2. Inner dirt shield:

White translucent acrylic, 1/8" thick

3. Chassis:

Steel, 20 gauge, white semigloss powder coat

4. Ballasts:

Electronic, Class P, universal voltage and multi-wattage

5. Lamp holder:

Multi-wattage, 4 pin, accepts either GX24q-3 or GX24q-4 base

6. Suspension:

3 Steel 3/8" tubes (lower), 5/8" center steel tube stem with swivel joint atop allows 45° slope. Conforms to California Earthquake Code.

7. Canopy:

Steel, 7" diameter; no external fasteners

Lamps: Compact Fluorescent Triple Tube, 26, 32, or 42 Watts

Pendalux Traditional

Ordering guide

How to specify

Order the body: Electrical options listing below.

Order the suspension: style and size that closely approximate the desired OAL (overall length) which is defined as the distance from the bottom of the diffuser to the ceiling plane.

For optimum performance we recommend OAL in proportion to the Body diameter (see shaded cells). Certain suspension styles cannot be paired with non-proportional Body diameters and are noted as "NA."

Note: If a larger suspension is required, order as a third component, a field-cutable extension stem (see specification sheet no. 45XT). All suspensions contain a jig to allow for field shortening of stem assembly. For all 4SB1XXXX single stem kits, extensions replace original stem. For all other kits, extension stem replaces short section above collection point.


Pendalux luminaires consist of two components: body and suspension

Order each separately.

Select the Diameter, Suspension and Layout best suited to the space. The drawing below shows the full family of the **Traditional Pendalux** style with recommended overall suspension lengths relative to ceiling heights from 10' to 12'. For illumination performance, refer to factory recommended sample layout and application data charts on the facing page.

Body

Traditional Steel
Flange/Opal
Acrylic CFL Triple
tube 26/32/42W
120V-277V
Electronic Ballast

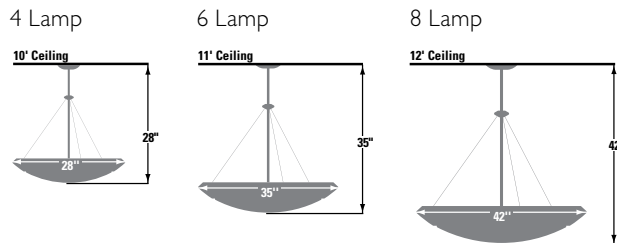

7' Minimum above floor

	4 Lamp cat. No.	6 Lamp cat. No.	8 Lamp cat. No.
Polished brass	4R28442APBU	4R35642APBU	4R42842APBU
Satin brass	4R28442ASBU	4R35642ASBU	4R42842ASBU
Suspension Cat. no.	Nominal OAL	Nominal OAL	Nominal OAL
A 4SB115*	15 3/16" (Close to Ceiling)	16 9/16"	18 1/4"
4SB118*	16 5/8"	18" (Close to Ceiling)	19 11/16"
4SB121*	17 15/16"	19 5/16"	21" (Close to Ceiling)
4SB124*	24 3/16"	25 9/16"	27 1/4"
4SB128*	28"	29 3/8"	31 1/16"
4SB135*	33 5/8"	35"	36 11/16"
4SB142*	38 15/16"	40 5/16"	42"
B Suspension Cat. no.	Nominal OAL	Nominal OAL	Nominal OAL
4ST228*	28"	29 3/8"	31 1/16"
4ST235*	33 5/8"	35"	36 11/16"
4ST242*	38 15/16"	40 5/16"	42"
C Suspension Cat. no.	Nominal OAL	Nominal OAL	Nominal OAL
4ST428*	28"	NA	NA
4ST435*	NA	35"	NA
4ST442*	NA	NA	42"

*Specify Finish: **PB** = Polished Brass **SN** = Satin Nickel



Complete fixture consists of

Body + Suspension


(Example) Order each separately

4R35642ASBU + **4ST435SB**


35" Traditional Body
6 Lamp Satin Brass

3 Rods to Short Stem
35" OAL Satin Brass

Suspensions

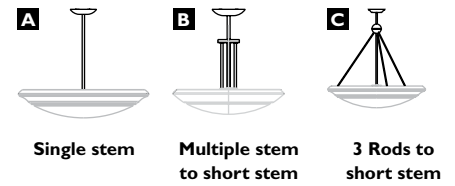


Pendalux specifications

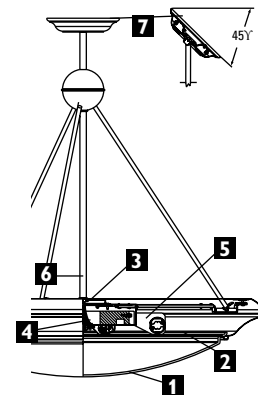

- 1. Diffusing reflector:** White translucent acrylic, 3/16" thick
- 2. Inner dirt shield:** White translucent acrylic, 1/8" thick
- 3. Chassis:** Steel, 20 gauge, white semigloss powder coat
- 4. Ballasts:** Electronic, Class P, universal voltage and multi-wattage
- 5. Lamp holder:** Multi-wattage, 4 pin, accepts either GX24q-3 or GX24q-4 base
- 6. Suspension:** 3 Steel 3/8" tubes (lower), 5/8" center steel tube stem with swivel joint atop allows 45° slope. Conforms to California Earthquake Code.
- 7. Canopy:** Steel, 7" diameter, no external fasteners


Lamps: Compact Fluorescent Triple Tube, 26, 32, or 42 Watts

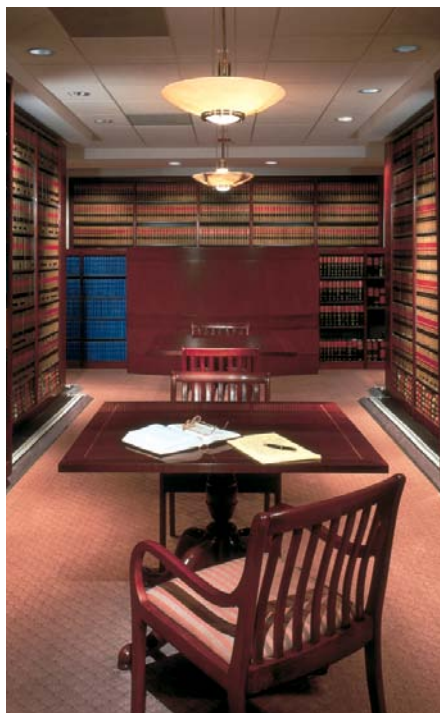

Alabaster & Etched Glass

Indirect pendants

Alabaster & Etched Glass

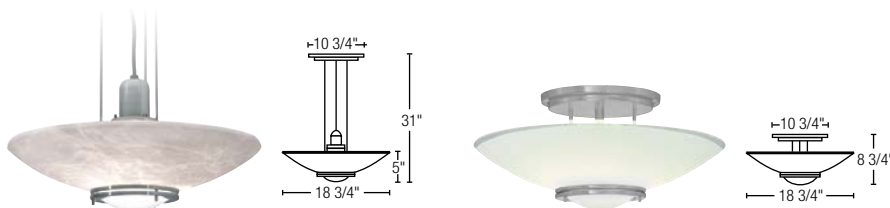

Pendants: (Chassis)

Cat. no.	Finish	Lamp	Ballast	Voltage
40750SNU	Satin nickel	(1) 26/32/42W TTT, CFL	Electronic	120V-277V
40750PBU	Polished brass	(1) 26/32/42W TTT, CFL	Electronic	120V-277V

Alabaster

Authentic Alabaster is an elegant stone mined in Spain and handcrafted to our specifications by skilled craftsmen. The polishing process reveals the shading and veining that makes each luminaire unique.

Etched Glass

The Etched Glass pendant and close to ceiling luminaire are design classics. Ideally scaled and styled for hallways, community living spaces, dining areas, and foyers; the clean lines of the pendant lends itself to multiple spacing applications.

All units are cULus listed, suitable for damp locations.

Glass

Cat. no.	Type
72303	Alabaster
72304	Etched Glass

Extension

Cat. no.	Finish	Length
40784SN	Satin Nickel	(3) 14" rods
40784PB	Polished Brass	(3) 14" rods

Close-to-ceiling: (Chassis)

Cat. no.	Finish	Lamp	Ballast	Voltage
40752SNU	Satin nickel	(1) 26/32/42W TTT, CFL	Electronic	120V-277V
40752PBU	Polished brass	(1) 26/32/42W TTT, CFL	Electronic	120V-277V

Alabaster & Etched Glass user guide (to specify use both chassis and glass)

Must order chassis and glass separately for complete fixture.



Alabaster pendant

Pendant	Glass	Lamp	Voltage
40750SNU	+ 72303	(1) 26/32/42W, TTT CFL	120-277V
40750SN	+ 72303	(1) 150W Max, A21	120V
40750PBU	+ 72303	(1) 26/32/42W, TTT CFL	120-277V
40750PB	+ 72303	(1) 150W Max, A21	120V



Etched Glass pendant

Pendant	Glass	Lamp	Voltage
40750SNU	+ 72304	(1) 26/32/42W TTT, CFL	120-277V
40750SN	+ 72304	(1) 150W Max, A21	120V
40750PBU	+ 72304	(1) 26/32/42W TTT, CFL	120-277V
40750PB	+ 72304	(1) 150W Max, A21	120V



Alabaster close-to-ceiling

Pendant	Glass	Lamp	Voltage
40752SNU	+ 72303	(2) 26W QT, CFL	120-277V
40752PBU	+ 72303	(2) 26W QT, CFL	120-277V



Etched Glass close-to-ceiling

Pendant	Glass	Lamp	Voltage
40752SNU	+ 72304	(2) 26W QT, CFL	120-277V
40752PBU	+ 72304	(2) 26W QT, CFL	120-277V

Spill Ring & Lumidome compact fluorescent

Surface utility

Surface mounted fixtures serve particularly well in vestibules, hallways and similar circulation areas in which life safety codes require emergency lighting of the pathways to egress. It is now possible to incorporate emergency lighting within the same outline as the general lighting, thus eliminating the need for extra equipment on the wall or ceiling, providing a more economical, cleaner installation. Emergency option is available where noted.



 
 
Features

Double-ring detail creates an intriguing "spill" of light. Unit is fully enclosed to keep out dust. Spill Ring has an acrylic diffuser, one style, two sizes, and a selection of three corrosion-resistant finishes:

- Semi-gloss white
- Plated satin nickel
- Plated polished brass

Spill Ring





Satin nickel	White	Polished brass		
Cat. no.	Cat. no.	Cat. no.	Description	Voltage
				
5543SN239U	5543WH239U	5543PB239U	(2) 36/39W Twin Tube 4-Pin Elec.	120-277V
5543SN326U	5543WH326U	5543PB326U	(3) 26W Quad 4-Pin Electronic	120-277V
				
5533SN226U	5533PB226U	5533WH226U	(2) 26W Quad 4-Pin Electronic	120-277V

Emergency battery pack option: add suffix "E"

Lumidome Basic



  White finish



Cat. no.	Description	Voltage
		
5241WH239U	(2) 36/39W Twin Tube 4-Pin Electronic	120V
5241WH326U	(3) 26W Quad 4-Pin Electronic	120-277V
		
5231WH226U	(2) 26W Quad 4-Pin Electronic	120-277V

Emergency battery pack option: add suffix "E"

Lumidome Contemporary



  Satin nickel finish



Cat. no.	Description	Voltage
		
5243SN239U	(2) 36/39W Twin Tube 4-Pin Electronic	120-277V
5243SN326U	(3) 26W Quad 4-Pin Electronic	120-277V
		
5233SN226U	(2) 26W Quad 4-Pin Electronic	120-277V

Emergency battery pack option: add suffix "E"

Lumidome Traditional



  Polished brass finish

Cat. no.	Description	Voltage
		
5242PB239U	(2) 36/39W Twin Tube 4-Pin Electronic	120-277V
5242PB326U	(3) 26W Quad 4-Pin Electronic	120-277V
		
5232PB226U	(2) 26W Quad 4-Pin Electronic	120-277V

Emergency battery pack option: add suffix "E"

Basic

BowShield's all white light shields subtly highlights architecture and wall motifs. This ADA design is especially well suited to hotel and office corridors. Ceramic White utilizes sandblasting and silk-screening on plain glass to create a soft, highly diffused glow of light. Rain, created by sandblasting and silk-screening textured glass, creates a fascinating texture, much like rain on a windowpane. Squares features silk-screening on both the inside and outside of the glass to give a unique, three-dimensional effect.

Features

ADA compliant, BowShield can be specified with compact fluorescent lamps and electronic ballasts to achieve superior energy efficiency for circulation spaces and other areas where lights are on continuously. BowShield sconces feature a "bowed" piece of handcrafted glass that slips into a die-cast holder, creating a versatile range of forms, colors and textures for circulation areas and hospitality spaces.

Each style is offered in two proportions, scaled to circulation areas and hospitality spaces. The die-cast holders are offered in Satin Brass or Satin Nickel finishes.

There is a choice of Electronic, Dimmable Electronic ballasts, plus integral emergency battery pack.

All units are cULus listed, suitable for damp locations. Emergency units are UL listed, dry locations only.

Complete fixture consists of
Lightshield + Backplate assembly
(Example) Order each separately

40872	+	40831U
Rain		Universal Electronic Ballast 120-277V for 1 X 24/27W CFL, Satin Brass

BowShield

Wall mounted ADA

Lightshield



Rain
40872 Rolled "Rain" pattern texture Lightshield silk-screened White/Clear




Squares
40866 3-dimensional "Squares" White/Clear silk-screened pattern



Ceramic White
40863 "Ceramic White" silk-screened and sandblasted

All products shown on Satin Nickel holder

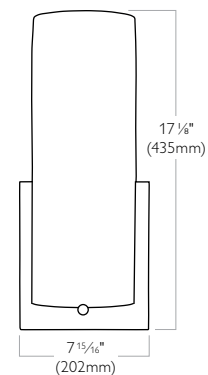

All Fixtures are ADA compliant. (4" maximum extension)

Backplate assemblies with lamp and ballast specifications

Catalog number	Lamp	Ballast	Voltage
Satin brass	Satin nickel		
40832	2 X 60W T10 Incandescent	N/A	120
40831U	40832U 1 X 24/27W Twin CFL 4-Pin	Universal Electronic	120V-277V
	4-Pin 2G11 Base	cULus Listed. Suitable for damp locations except integral emergency units. UL listed for dry locations.	

Lightshield



Rain
40871 Rolled "Rain" pattern texture Lightshield Silk-screened White/Clear




Squares
40865 3-dimensional "Squares" White/Clear Silk-screened pattern



Ceramic White
40862 "Ceramic White" silk-screened and sandblasted

All products shown on Satin Nickel holder

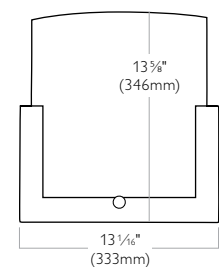

Total Fixture Height consists of Screen & Textured Glass

Backplate assemblies with lamp and ballast specifications


Catalog number	Lamp	Ballast	Voltage
Satin brass	Satin nickel		
40828	40829 2 X 60W T10 Incandescent	N/A	120
40828D1	40829D1 2 X 18W Twin CFL 4-Pin	Dimming electronic	120 (Advance Mark 10)
40828U	40829U 2 X 18W Twin CFL 4-Pin	Universal electronic	120V-277V
40828UEM	40829UEM 2 X 18W Twin CFL 4-Pin	Universal electronic	120V-277V*
	4-Pin G24q-2 Base 2-Pin G24D-2 Base	*Integral emergency battery pack. cULus Listed. Suitable for damp locations except integral emergency units. UL listed for dry locations.	

Pendalux, Opalux, Quartershere, Wall Sculpture

Wall mounted indirect


Opalux

 Vertical or horizontal wall mount



6348N (2) A19 60W
Max. Incandescent

 
Quartersphere



41010 White (1) A21 150W Max. Incandescent
41010T1 White (2) 13W Twin Tube 2-Pin Magnetic NPF 120V
41011 (1) T4 Halogen Mini Can 250W



Wall Sculpture

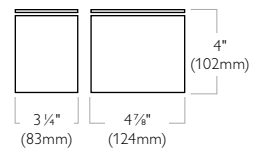

Cat. no. Finish
4910PB Polished brass
4910PC Polished chrome

(1) KX2000 Mini Can 60W
(Philips Lightolier Cat. # 56977)

Cirrus ADA sconce luminaire



 
Electrical options

(Replace "U" in Cat. no. with new Suffix)

E3 = 347V (Canada)

MX1 = Mark x Dimming 26/32/42W, 120V only*

MX2 = Mark x Dimming 26/32/42W, 277V only*



Universal Wattage 26/32/42W
Triple Tube Compact Fluorescent
Universal Voltage Electronic 120V-277V Ballast

Cat. no.	Finish	Complete Luminaire Dimensions
----------	--------	-------------------------------

4AWA142AU	Acrylic injection molded diffuser Perforated steel top cover	Dia. 16" x Ht. 7 3/4" x Ext. 4"
------------------	---	---------------------------------

* 2-Wire neutral connection required at dimming control for mark iv dimming.
Complete luminaire consists of chassis and diffuser.

Gemini companion sconce trim flange



Complete fixture consists of
Chassis/opal diffuser and Decorative flange
 (Example) Order each separately

4AWA142AU + **4KWATRMPB**

Chassis/opal diffuser

Decorative flange

Cat. no.	Finish	Complete Luminaire Dimensions
4FWATRMPB	Polished brass	Dia. 17" x Ht. 8 1/2" x Ext. 4"
4FWATRMSN	Satin nickel	Dia. 17" x Ht. 8 1/2" x Ext. 4"
4FWATRMWH	Matte white	Dia. 17" x Ht. 8 1/2" x Ext. 4"

Complete luminaire consists of chassis/diffuser and trim flange. Order each separately.

Contemporary companion sconce trim flange



Complete fixture consists of
Chassis/opal diffuser and Decorative flange
 (Example) Order each separately

4AWA142AU + **4KWATRMPB**

Chassis/opal diffuser

Decorative flange

Cat. no.	Finish	Complete Luminaire Dimensions
4KWATRMSB	Satin brass	Dia. 18" x Ht. 8 1/2" x Ext. 4"
4KWATRMSN	Satin nickel	Dia. 18" x Ht. 8 1/2" x Ext. 4"
4KWATRMWH	Matte white	Dia. 18" x Ht. 8 1/2" x Ext. 4"

Complete luminaire consists of chassis/diffuser and trim flange. Order each separately.

Traditional companion sconce trim flange



Complete fixture consists of
Chassis/opal diffuser and Decorative flange
 (Example) Order each separately

4AWA142AU + **4RWATRMPB**

Chassis/opal diffuser

Decorative flange

Cat. no.	Finish	Complete Luminaire Dimensions
4RWATRMPB	Polished brass	Dia. 18" x Ht. 8 1/2" x Ext. 4"
4RWATRMSB	Satin brass	Dia. 18" x Ht. 8 1/2" x Ext. 4"

Complete luminaire consists of Chassis/Diffuser and Trim Flange. Order each separately.

 


Opalite, Discus

Surface utility

Contemporary, clean styling makes Discus Sconce a versatile luminaire for wall or ceiling mount. Double-convex injection-molded acrylic diffuser gently lights the ceiling, improving visual comfort. Twist-lock mounting; no loose fasteners, or the need for tools. Emergency Lighting option.


Opalite



Black Finish

Cat. no.	Description	Voltage
6790BK226U	(2) 26W Quad 4-Pin Electronic CFL	120-277V
6789BK213U	(2) 13W Quad 4-Pin Electronic CFL	120-277V

 
Discus



Matte Silver Finish

Cat. no.	Description	Voltage
6700MS213U	(2) 13W Quad 4-Pin Electronic	120-277V
6700MS22U	(1) 22W T-5 Circle Line Electronic	120-277V
6700S2UEM	(1) 22W T-5 Circle Line Electronic	120-277V' EM Pack

 Discus II



Matte Silver / Satin Aluminum Finish

Cat. no.	Description	Voltage
6706MS213U	(2) 13W Quad 4-Pin Electronic	120-277V
6706MS22U	(1) 22W T-5 Circle Line Electronic*	120-277V
6706S2UEM	(1) 22W T-5 Circle Line Electronic*	120-277V EM Pack

* Add at bottom of Discus. Discus is New York City Listed.
Add "NY" to the end of the catalog number

Application data

Corridor lighting

Style

Multiple fixtures

Lamp

Opaline	Opalite	Lumidisc	Discus	Lamp	Corridor Width 8' Height	Fixture Spacing O.C.	Average Initial Footcandles
				(2) 13W Twin Tube	6'	12'	5
					9'	8'	6
				(1) 38W-2D	6'	12'	8
					9'	8'	10

Footcandles values are initial and average and are on the floor. Reflectances: ceiling 80%, walls 50%, floor 20%.
Fixtures are mounted along center of ceiling.

Triplex, Lumidrum, Lumidisc, Lumiquad, Opaline

Surface utility

 
Triplex White opal diffuser is made of cased glass for optimum uniform brightness. Twist-lock fastening simplifies relamping resulting in sleek, clean profile.

Triplex




Opal Glass/Matte White


5000
5001WH1182 (1) A19 75W Max. Incandescent
(1) 18W Quad 4-Pin Electronic 120V-277V



 
5002
5003WH218U (2) A19 60W Max. Incandescent
(2) 18W Quad 4-Pin Electronic 120V-277V



 5004
5005WH226U (3) A19 60W Max. Incandescent
(2) 26W Quad 4-Pin Electronic 120V-277V



Lumidrum

 


5240WH239U White
(2) 36/39W Twin Tube 4-Pin Electronic 120V

5240WH326U White
(3) 26W Quad 4-Pin Electronic 120V-277V

Options

 Emergency Battery Pack: Add Suffix "E"




5230WH226U White
(2) 26W Quad 4-Pin Electronic 120V-277V


Options

Emergency battery pack: add suffix "E"

 Lumidisc




 6752WH226U White
(2) 26W Quad 4-Pin Electronic CFL 120V-277V




6750WH213U White
(2) 13W Quad 4-Pin Electronic CFL 120V-277V

 Lumiquad



6783WH213N1 White
6783BZ213N1 Bronze
(2) 13W Twin Tube 2-Pin Magnetic NPF 120V

 Lumironde




6731WH213N1 White
6731BK213N1 Black
(2) 13W Twin Tube 2-Pin Magnetic NPF 120V

Opaline




6618 Matte White
(1) A19 100W Max. Incandescent

 6619U Matte White
(2) 13W Twin or Quad Tube 2-Pin Electronic CFL 120V-277V



6628U Matte White
(2) 18W Quad Tube 4-Pin Electronic CFL 120V-277V

 Opaline trim rings



66PB Polished Brass Trim Ring
66SN Satin Nickel Trim Ring
66WH White Trim Ring

Application data



Lamp	Multiple Fixtures ¹		Single Fixture ²
	Spacing	Footcandles	Footcandles
(2) 36/39W	4	110	
Twin Tube	6	48	10
	8	19	
(3) 26W	4	102	
Quad Tube	6	45	9
	8	18	

¹Multiple fixtures in 30 x 50 room

²Single fixture 12 x 12 room

Footcandle values are initial and average at 30 above the floor. Ceiling height 8 to 12. Reflectances: ceiling 80%, walls 50%, floor 20%.

Emergency battery pack - lighting data

(2) 26W Quad Tube = 700 Lumens
*(3) 26W Quad Tube = 700 Lumens
(2) 36/39W Twin Tube = 750 Lumens
* Operates only two lamps.



Lumironde, Luna, Lumiquad

Wall mounted ADA

Generous, efficient illumination for hallways and other circulation areas. Twist-lock acrylic diffuser.

Lumironde



6737WH White
6738BK Black
 (1) 13W Twin Tube 2-Pin Magnetic NPF 120V

Luna




40620 White (1) A19 75W Max. Incandescent 120V
40620U White (1) 26W Quad 4-Pin Electronic 120V-277V

Lumironde



6731WH213N1 White
6731BK213N1 Black
 (2) 13W Twin Tube 2-Pin Magnetic NPF 120V

Lumiquad

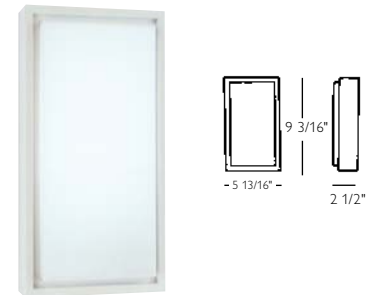


6580 White
 (1) 13W Twin Tube 2-Pin Magnetic NPF 120V

Opalite, Quadro, Alabaster


Wall mounted ADA

 Opalite



6790BK226U Black
(2) 26W Quad 4-Pin
Electronic CFL 120V-277V

Quadro

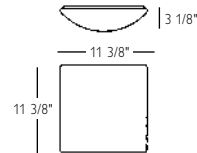

40600U White (2) 13W Quad 4-Pin
Electronic 120V-277V


Alabaster



40614U + 72305

40614U (1) 26W Quad 4-Pin Electronic 120V-277V
Satin Nickel and Polished Brass – Backplate
40614 (1) 40W T-10, Incandescent, 120V
Satin Nickel and Polished Brass – Backplate
72305 Alabaster

Must order Backplate and Glass separately.

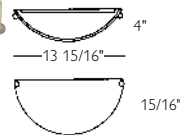

40614 + 72305

Complete fixture consists of
Alabaster + Backplate assembly
(Example) Order each separately

40614U	+	72305
Alabaster		Backplate

Matching Pendant page 6.84 .



Lytestream

Provides downlight, uplight and spill light through translucent center strip. Choose incandescent with glass diffusers or fluorescent with acrylic.

Helios

Shatter-resistant, acrylic diffuser mounted on die-cast base. Single-ended compact fluorescent lamps provided more light and use less energy than incandescent. 2-light units can be wall mounted vertically or horizontally.

Belmont

Sleek wraparound acrylic diffuser gives glare-free illumination and is accented by crisply detailed die-cast spring-loaded end caps. Horizontal or vertical wall mounting only.

Deco

White bullnose acrylic diffuser with polished brass inserts. Fixture is accented by polished brass finished die-cast deco spring-loaded end caps. Horizontal or vertical wall mounting only.

UL listed. Suitable for damp locations.

Lytestream, Helios, Belmont, Deco

Bath

Lytestream Fluorescent



Finish

Add suffix to cat. No.

PBU = Polished Brass

PCU = Polished Chrome

WHU = Matte White

Cat. no.	Lamp	Ballast	Voltage	Description
5403	(2) 25W T8	Electronic	120V-277V	L 36¾", H 3", Ext 6 ¹³ / ₃₂ "
5404	(2) 32W T8	Electronic	120V-277V	L 48¾", H 3", Ext 6 ¹³ / ₃₂ "
5405	(2) 40W T8	Electronic	120V-277V	L 60½", H 3", Ext 6 ¹³ / ₃₂ "

Helios



Finish

Add suffix to Cat. no.

PC = Polished Chrome

WH = Matte White

Cat. no.	Lamp	Ballast	Voltage	Description
5410	(1)18W Twin Tube 4-Pin 2G11 Base	Magnetic	120V	W 13¾", H 3 ¹ / ₁₆ ", Ext. 4 ⁷ / ₈ "
5411	(1)39W Twin Tube 4-Pin 2G11 Base	Magnetic	120V	W 19¾", H 3 ¹ / ₁₆ ", Ext. 4 ⁷ / ₈ "
5412*	(2)18W Twin Tube 4-Pin 2G11 Base	Magnetic	120V	W 24½", H 3 ¹ / ₁₆ ", Ext. 4 ⁷ / ₈ "

* May be mounted vertically or horizontally

5410 & 5411

Vertical wall mount only



Belmont



Finish

Add suffix to Cat. no.

CHU = Polished Chrome

WHU = Matte White

Cat. no.	Lamp	Ballast	Voltage	Description
5491	(2) 17W T8	Electronic	120V-277V	L 24½", H 4¾", Ext 4¾"
5493	(2) 32W T8	Electronic	120V-277V	L 48½", H 4¾", Ext 4¾"

Deco



Finish

Add suffix to Cat. no.

PB = Polished Brass

PC = Polished Chrome

Cat. no.	Lamp	Ballast	Voltage	Description
5472	(2) 17W T8	Electronic	120V-277V	L 26½", H 4¾", Ext 4¾"
5473	(2) 25W T8	Electronic	120V-277V	L 38½", H 4¾", Ext 4¾"
5474	(2) 32W T8	Electronic	120V-277V	L 50½", H 4¾", Ext 4¾"

Rounder, Mini-Bracelet

Bath

Good grooming starts with proper lighting at the mirror. The light should come from both sides as well as from above.

Rounder



Cat. no.	Finish	Lamp	Description
4733	Satin Aluminum	(1) A19 60W Max	W 8", H 4 $\frac{7}{16}$ ", Ext. 5"
4734	Satin Aluminum	(2) A19 60W Max	W 16", H 4 $\frac{7}{16}$ ", Ext. 5"
4735	Satin Aluminum	(3) A19 60W Max	W 24", H 4 $\frac{7}{16}$ ", Ext. 5"

Arch Mini Bracelet



Handpressed clear glass with inside cavity coarsely sandblasted.



Finish

Add suffix to Cat. no.

PB = Polished Brass

PC = Polished Chrome

Lamping

Order separately

56974 = Frosted

56975 = Clear

KX2000 Candelabra 40W, E12
Frosted lamps recommended

Cat. no.	Lamp	Description
44211	2 Light	W 13", H 3", Ext. 3"
44221	4 Light	W 24", H 3", Ext. 3"
44231	6 Light	W 36", H 3", Ext. 3"
44241	8 Light	W 47", H 3", Ext. 3"

Milan Mini Bracelet



Handpressed in clear glass which is then etched.



Finish

Add suffix to Cat. no.

PB = Polished Brass

PC = Polished Chrome

Lamping

Order separately

56974 = Frosted

56975 = Clear

KX2000 Candelabra 40W, E12
Frosted lamps recommended

Cat. no.	Lamp	Description
44212	2 Light	W 13", H 3", Ext. 2 $\frac{1}{4}$ "
44222	4 Light	W 24", H 3", Ext. 2 $\frac{1}{4}$ "
44232	6 Light	W 36", H 3", Ext. 2 $\frac{1}{4}$ "
44242	8 Light	W 47", H 3", Ext. 2 $\frac{1}{4}$ "

Baguet Mini Bracelet



Handpressed etched glass with a clear center setting.



Finish

Add suffix to Cat. no.

PB = Polished Brass

PC = Polished Chrome

Lamping

Order separately

56974 = Frosted

56975 = Clear

KX2000 Candelabra 40W, E12
Frosted lamps recommended

Cat. no.	Lamp	Description
44214	2 Light	W 13", H 3", Ext. 2 $\frac{1}{2}$ "
44224	4 Light	W 24", H 3", Ext. 2 $\frac{1}{2}$ "
44234	6 Light	W 36", H 3", Ext. 2 $\frac{1}{2}$ "
44244	8 Light	W 47", H 3", Ext. 2 $\frac{1}{2}$ "



Bracelet

Finely detailed hand-pressed glass floats against brass or chrome mountings. Glass surrounds lamps for mounting above eye level without glare. All three sizes may be mounted horizontally or vertically. Dimmer recommended for enhanced performance.

Rounder

Blown opal glass gives even illumination without hot spots. Corrosion-resistant aluminum backplates suitable for damp locations.

Mini Bracelet

Elegant bath fixtures uniquely scaled to provide jewelry-like style with sophisticated performance. All sizes can be wall mounted horizontally or vertically. KX2000 candelabra based Krypton incandescent lamps (not included) allow close spacing resulting in a comfortable, luminous effect. Dimmer recommended for enhanced performance. ADA compliant.

UL listed. Suitable for damp locations.


Wet location

Marker lights


LED luminaire

The gentle glow of the marker lights provides a subtle visual enhancement ideal for indicating a feature pathway.


Round

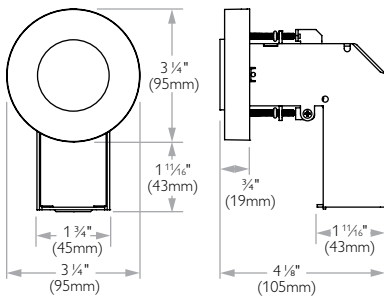


Pattern

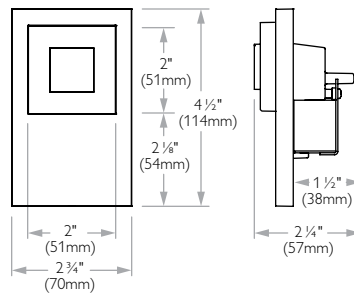

Linear

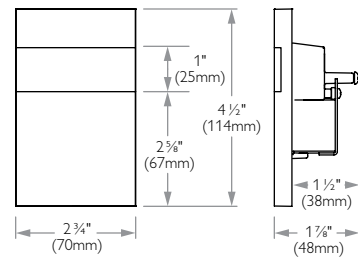

Square

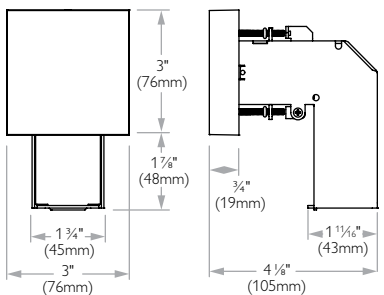

Marker lights (wet location)

Cat. no.	Style	Finish	Watts	Volts
DML01WLW	Linear	Matte white	1W	120V-240V
DML01WLSA		Satin aluminum		
DMP01WLW	Pattern	Matte white		
DMP01WLSA		Satin aluminum		
DMR01WLSA	Round	Satin aluminum (center)		
DMS01WL	Square	Sandblasted acrylic		




Step lights

LED luminaire


Step lights provide a clean and finished aesthetic for your contemporary design while providing functional pathway lighting.



Shielded

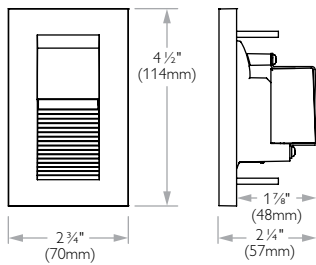


Round

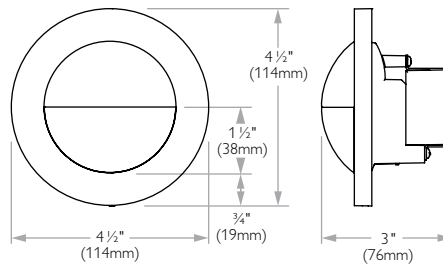


Step & Marker lights mounting assembly

Philips Lightolier's solid-state step and marker luminaires utilize near-UV LEDs which, when combined with triphosphors, produce a system which peaks in efficiency in the warm whites. These products are available in a variety of aesthetically pleasing round and rectangular styles. Rectangular versions contain integral drivers and most designs mount into a standard size deep switch box.

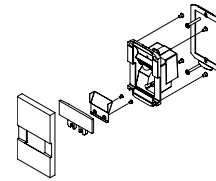

Typical assembly

Illustrated here with
DSL01 facebox

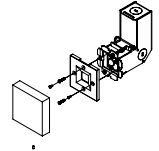

Custom mounting assembly

Illustrated here with
DMS01

Features

Wet location applicable Vio high power LED is a 4W LED system for the Step application (1W LED system for the Marker application) providing a uniform comfortable glow of warm white (3000K <100 Kelvin color shift over 50,000 hours). These products are mercury-free, ROHS compliant, and have 50,000 rated life with 70% lumen maintenance.


Made out of die-cast aluminum, the heat sink housing is thermally designed to reduce junction temperature which maintain the light output, color and life.

The lenses of Step and Marker luminaires are not only designed to control the glare and distribute a comfortable glow to your path way but also to add elegant visual interest that will aesthetically punctuate spaces. Some Markers such as DNS01 offer a neutral look by being mostly lens and not having any visible hardware; allowing a wider range of applications from conventional to contemporary spaces.

The mounting system is designed so no custom installation is required. All Markers and Steps are ready to be installed in any regular deep single-gang switch junction box 18" AFF (above finish floor); except for DMS01 and DMR01 as shown above, ship with their junction box.

cULus listed for dry location only.

Linear

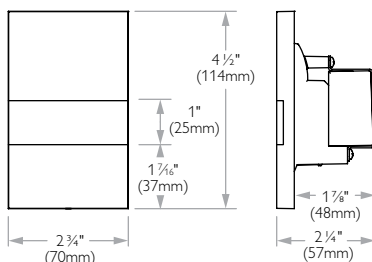

Step lights (wet location)

Cat. no.	Style	Finish	Watts	Volts
DSL01WLW	Linear	Matte white	4W	120V-240V
DSL01WLSA		Satin aluminum		
DSR01WLW	Round	Matte white		
DSR01WLSA		Satin aluminum		
DSS01WLW	Shielded	Matte white		
DSS01WLSA		Satin aluminum		
DSS01WLWAM	Amber shielded	Matte white		
DSS01SALSAAM		Satin aluminum		

**Ballast options key**

On units noted, specify compact fluorescent by adding ballast option suffix to catalog number.


N1	NPF Magnetic	120V
N2	NPF Magnetic	277V
H1	HPF Magnetic	120V
H2	HPF Magnetic	277V
E1	Electronic	120V
E2	Electronic	277V

***UL Listed:** Suitable for wet location
 7W lamp rated to start at 0° F
 9W lamp rated to start at 25° F
 13W lamp rated to start at 32° F


Arco, Lumironde & Lumiquad

Indoor/outdoor wall

Ruggedly constructed fixtures ideally suited to walkways, exterior walls and interior halls.

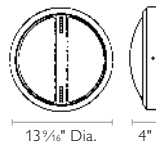Arco round


4532 Wall mount only. ADA Compliant.

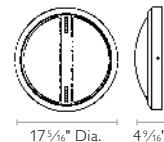

4533 Wall mount only.

Fluorescent


Cat. no.	Finish	Lamp	Ballast	Voltage	Ballast Options
4532WHN1	White	(2) 13W* Twin Tube 2-Pin	Magnetic NPF	120V	H1, H2
4532BKN1	Black				
4533WHH1	White	(2) 26W Quad 2-Pin	Magnetic HPF	120V	H2, E1, E2
4533BKH1	Black				

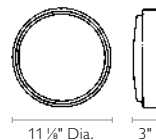Lumironde

Ceiling or wall mount. ADA Compliant.

Fluorescent

Cat. no.	Finish	Lamp	Ballast	Voltage
6731WH213N1	White	(2) 13W* Twin Tube 2-pin	Magnetic NPF	120V
6731BK213N1	Black			

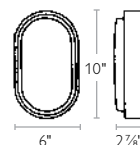


Wall mount only. ADA Compliant.

Fluorescent

Cat. no.	Finish	Lamp	Ballast	Voltage
6737WH	White	(1) 13W* Twin Tube 2-Pin	Magnetic NPF	120V
6738BK	Black			

Lumiquad


Ceiling or wall mount. ADA Compliant.

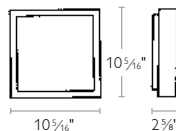**Fluorescent**

Cat. no.	Finish	Lamp	Ballast	Voltage
6783WH213N1	White	(2) 13W* Twin Tube 2-pin	Magnetic NPF	120V
6783BZ213N1	Bronze			



Ceiling or wall mount. ADA Compliant.

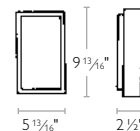**Fluorescent**

Cat. no.	Finish	Lamp	Ballast	Voltage
6580	White	(2) 13W* Twin Tube 2-pin	Magnetic NPF	120V

Opalex, Bristol, Lumilyte & Lumicap


Indoor/outdoor wall

Ruggedly constructed fixtures ideally suited to walkways, exterior walls and interior halls.

Opalex



Wall or ceiling mount.

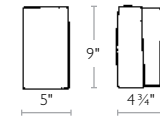

Incandescent

Cat. no.	Finish	Lamp
6776	Black	(1) A19 75W Max



Ballast options key

On units noted, specify compact fluorescent by adding ballast option suffix to catalog number.


N1	NPF Magnetic	120V
N2	NPF Magnetic	277V
H1	HPF Magnetic	120V
H2	HPF Magnetic	277V
E1	Electronic	120V
E2	Electronic	277V

***UL Listed:** Suitable for wet location
7W lamp rated to start at 0° F
9W lamp rated to start at 25° F
13W lamp rated to start at 32° F

Bristol



 Horizontal wall mount only.




Incandescent

Cat. no.	Finish	Lamp
4833WH	White	(1) A19 100W
4809BK	Black	Max



Horizontal or vertical wall mount only.

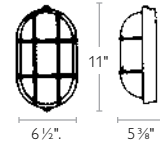


Incandescent

Cat. no.	Finish	Lamp
3652WH	White	(1) A19 100W
3651BZ	Bronze	Max
3660BK	Black	



Wall mount only.

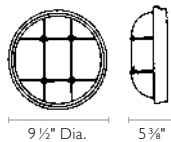

Incandescent

Cat. no.	Finish	Lamp
3655WH	White	(1) A19 100W
3654BZ	Bronze	Max
3663BK	Black	

Fluorescent

Cat. no.	Finish	Lamp	Ballast	Voltage
3622WH	White	(2) 7W or 9W*	Magnetic NPF	120V
3621BZ	Bronze	Twin Tube		
3610BK	Black	2-Pin		

Fluorescent

Cat. no.	Finish	Lamp	Ballast	Voltage
3625WH	White	(2) 7W or 9W*	Magnetic NPF	120V
3624BZ	Bronze	Twin Tube		
3613BK	Black	2-Pin		

Lumilyte




Incandescent

Cat. no.	Finish	Lamp
6560WH	White	(1) A19 75W Max
6561BZ	Bronze	
6562BK	Black	

Fluorescent

Cat. no.	Finish	Lamp	Ballast	Voltage
6566WH	White	(2) 9W*	Magnetic	120V
6567BZ	Bronze	Twin Tube	NPF	
6568BK	Black	2-Pin		

Wall mount only

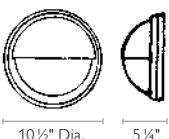

Lumicap




Incandescent

Cat. no.	Finish	Lamp
6585	White	(1) A19 75W Max
6582	Bronze	

Fluorescent

Cat. no.	Finish	Lamp	Ballast	Voltage
6586	White	(2) 9W*	Magnetic	120V
6584	Bronze	Twin Tube	NPF	
		2-Pin		

Wall mount only

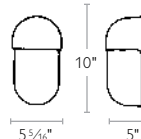




EFix

Outdoor/indoor architectural decorative


EFix Wall-mounted fixtures feature a sophisticated, robust architectural design. The high-quality finishes make it the perfect fit for both outdoor and indoor environments. EFix Wall-mounted consists of four easy-to-install round or square versions, providing direct light or a combination of direct and indirect light. The range has been developed around energy-saving compact fluorescent and state-of-the-art HFP electronic ballasts and is approved for IP65 and IK10 environments.



EFX1

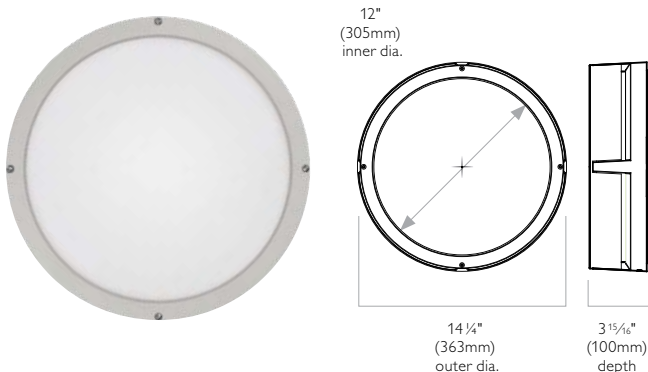

EFX2

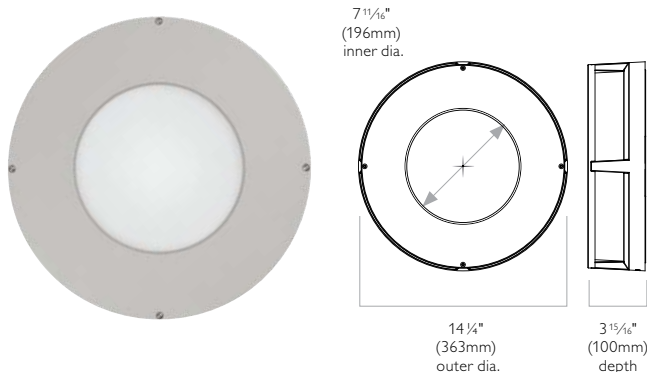

Cat. no.	Color	Lamp	Voltage
EFX1122MSU	Matte silver	(1) 22W T5 Circline	120V-277V
EFX1122WHU	Matte white		
EFX1122BZU	Matte bronze		
EFX1218MSU	Matte silver	(2) 18W Quad Tube	120V-277V
EFX1218WHU	Matte white		
EFX1218BZU	Matte bronze		
EFX126MSU	Matte silver	(1) 26W Quad Tube	120V-277V
EFX126WHU	Matte white		
EFX126BZU	Matte bronze		
EFX126MSUEM*	Matte silver	(1) 26W Quad Tube	120V-277V
EFX126WHUEM*	Matte white		
EFX126BZUEM*	Matte bronze		

Cat. no.	Color	Lamp	Voltage
EFX2122MSU	Matte silver	(1) 22W T5 Circline	120V-277V
EFX2122WHU	Matte white		
EFX2122BZU	Matte bronze		
EFX2218MSU	Matte silver	(2) 18W Quad Tube	120V-277V
EFX2218WHU	Matte white		
EFX2218BZU	Matte bronze		
EFX2126MSU	Matte silver	(1) 26W Quad Tube	120V-277V
EFX2126WHU	Matte white		
EFX2126BZU	Matte bronze		
EFX2126MSUEM*	Matte silver	(1) 26W Quad Tube	120V-277V
EFX2126WHUEM*	Matte white		
EFX2126BZUEM*	Matte bronze		

* Emergency: Integral Bodine CF94 emergency battery pack, test switch and light.

EFix

Outdoor/indoor architectural decorative

Round EFix lighting (by others)

Lamp Type	General Electric	Osram Sylvania	Philips
22W 4-Pin T5 Circline Linear Fluorescent Lamp	—	FPC22/*	TL5C 22W/*
18W 4-Pin Quad Tube Compact Fluorescent Lamp	F18DBX/*/ECO4P	CF18DD/E/*/ECO	PL-C 18W/*/4P/ALTO
26W 4-Pin Quad Tube Compact Fluorescent Lamp	F26DBX/*/ECO4P	CF26DD/E/*/ECO	PL-C 26W/*/4P/ALTO

* Manufacturers color temperature designation

Ballast	22 Watt	18 Watt	26 Watt
Voltage	120 277	120 277	120 277
Total Input Watts	27 25	39 39	29 29
Max. Line Current (Amps)	.23 .09	.33 .14	.24 .11



Compact fluorescent lampholders

18W & 26W Quad Tube: G24Xq-2 (18W) and G24Xq-3 (26W) Base, High Impact Thermoset Polymer with Brass Contacts.

Linear fluorescent lampholders

22W T5 Circline: 2GX13 Base, High Thermoset Polymer with Brass Contacts.

Specifications

Housing: Die cast Aluminum

Ballast and socket mounting plate: 18 GA stamped steel

Diffuser: Opal polycarbonate

Finish: Matte White, Matte Silver or Matte Bronze polyester powdercoat


Emergency: Integral Bodine CF94 emergency battery pack, test switch and light

Tamper resistant option: Ships standard with (4) phillips head screws and (4) torx screws to allow for tamper proof installation.


Labels

cULus Listed. Suitable for wet Locations.

EFX3

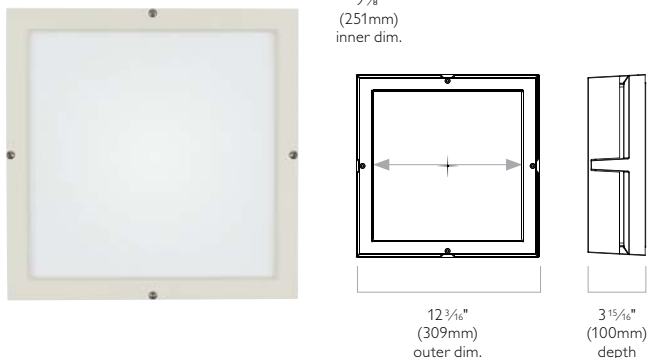

EFX4

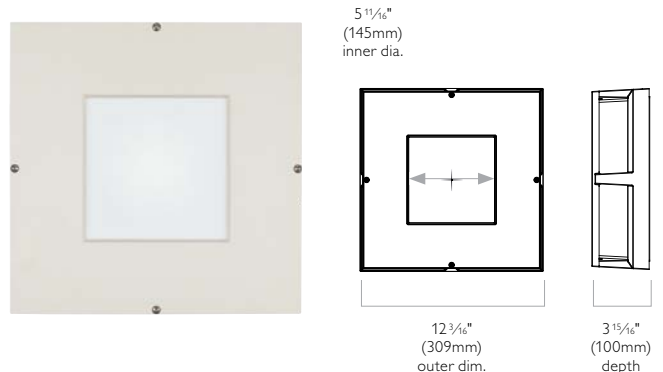

Cat. no.	Color	Lamp	Voltage
EFX3122MSU	Matte silver	(1) 22W T5 Circline	120V-277V
EFX3122WHU	Matte white		
EFX3122BZU	Matte bronze		
EFX3218MSU	Matte silver	(2) 18W Quad Tube	120V-277V
EFX3218WHU	Matte white		
EFX3218BZU	Matte bronze		
EFX3126MSU	Matte silver	(1) 26W Quad Tube	120V-277V
EFX3126WHU	Matte white		
EFX3126BZU	Matte bronze		
EFX3126MSUEM*	Matte silver	(1) 26W Quad Tube	120V-277V
EFX3126WHUEM*	Matte white		
EFX3126BZUEM*	Matte bronze		

Cat. no.	Color	Lamp	Voltage
EFX4122MSU	Matte silver	(1) 22W T5 Circline	120V-277V
EFX4122WHU	Matte white		
EFX4122BZU	Matte bronze		
EFX4218MSU	Matte silver	(2) 18W Quad Tube	120V-277V
EFX4218WHU	Matte white		
EFX4218BZU	Matte bronze		
EFX4126MSU	Matte silver	(1) 26W Quad Tube	120V-277V
EFX4126WHU	Matte white		
EFX4126BZU	Matte bronze		
EFX4126MSUEM*	Matte silver	(1) 26W Quad Tube	120V-277V
EFX4126WHUEM*	Matte white		
EFX4126BZUEM*	Matte bronze		

* Emergency: Integral Bodine CF94 emergency battery pack, test switch and light.