

2016 | LED FIXTURE CATALOG

Company Overview



Ohyama Lights strives to be an innovative company that is responsive to its customers' needs. Our mission is to put the customer first and develop eco-friendly LED technology that will help our customers expand their businesses.

Ohyama Lights is a division of Iris Ohyama, Inc., a global manufacturer of over 14,000 household products and a workforce of over 8,000 employees. Iris Ohyama originated in 1958 and expanded into the global market in 1996 with its IRIS USA, Inc. facility in Pleasant Prairie, WI. Iris Ohyama's attention to its customers has grown its operations in Asia, America and Europe. Today, Iris Ohyama is one of the largest manufacturers of LED Lighting products in Japan.

Global Operations:

- World Headquarters is located in Sendai, Japan.
- North American Headquarters is located in Pleasant Prairie, Wisconsin with additional facilities in Mesquite, Texas and Surprise, Arizona.
- Global operations include 15 manufacturing and distribution facilities in Japan, China, the Netherlands, Korea and United States.
- U.S. based sales, marketing and customer service teams.



Sendai, Japan



Pleasant Prairie, WI

LED PANELS



■ Ohyama Lights OLPLX LED Panel Lights pair high lumen outputs with great energy efficiency to create a luminaire that everyone can love. When you combine the sleek modern look, uniform illumination and maintenance-free performance of the OLPLX you get a perfect replacement for your old-technology fluorescent troffers. And, because these fixtures are dimmable, you now have the flexibility to easily tailor the lighting to suit any environment and mood.

OLPL11 Series
1' X 1' LED Edge-Lit Panel

OLPLX14 Series
1' X 4' LED Edge-Lit Panel

OLPLX22 Series
1' X 4' LED Edge-Lit Panel

OLPLX24 Series
2' X 4' LED Edge-Lit Panel

OLPL11 SERIES


1' X 1' LED Edge-Lit Panel



PERFORMANCE

VOLTAGE 120~277V	CRI ≥80	WATTAGE 20/35	LUMENS 1700-2600
UL LISTED Damp Location	BEAM 112°	L70 40,000 Hrs	DIMMING 0-10V / DALI
WARRANTY 5 Years	CCT 5000K	CCT 4000K	

CATALOG LOGIC

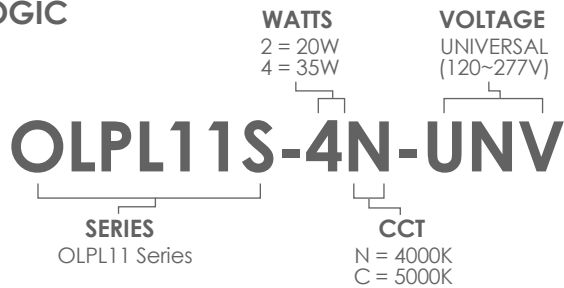


ORDERING

ITEM	MODEL	CCT	LUMEN	WATTS
399553	OLPL11S-2N-UNV	4000K	1700	20
399549	OLPL11S-2C-UNV	5000K	1700	20
399554	OLPL11S-4N-UNV	4000K	2600	35
399550	OLPL11S-4C-UNV	5000K	2600	35

DIMENSIONS

Size: 11.8" x 11.8" x 2.04"

Weight: 5.5 lbs.

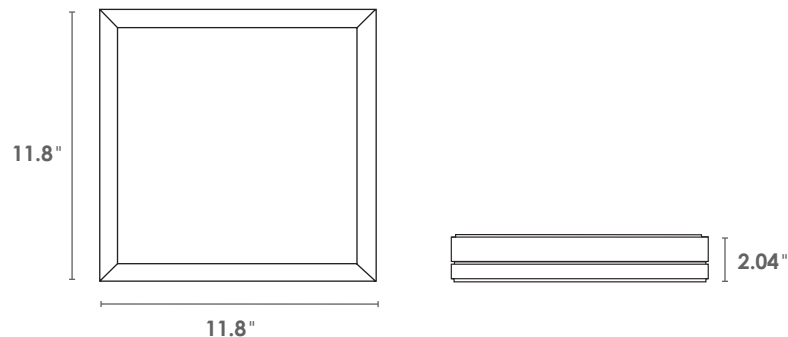


APPLICATIONS

Offices, Schools, Hospitals, Retail

AVAILABLE COLORS




DISTRIBUTION

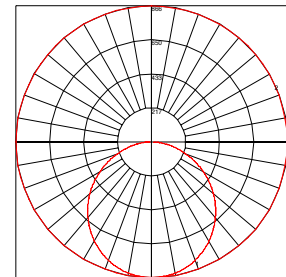

OLPLX14 SERIES


1' X 4' LED Edge-Lit Panel

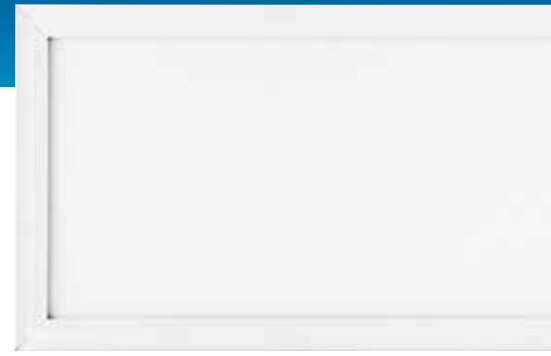

PERFORMANCE

VOLTAGE 120~277V	CRI ≥80	WATTAGE 41	LUMENS 3800 - 4200
CSA LISTED Damp Location	BEAM 112°	L70 100,000 Hrs	DIMMING 0-10V
WARRANTY 5 Years	CCT 5000K	CCT 4000K	CCT 3000K

CATALOG LOGIC

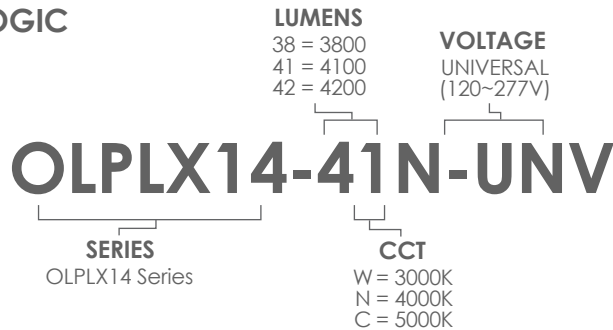


ORDERING

ITEM	MODEL	CCT	LUMEN	WATTS
399744	OLPLX14-38W-UNV	3500K	3800	41
399745	OLPLX14-41N-UNV	4000K	4100	41
399746	OLPLX14-42C-UNV	5000K	4200	41

DIMENSIONS

Size: 47.76" x 11.7" x 1.85"

Weight: 15.14 lbs.

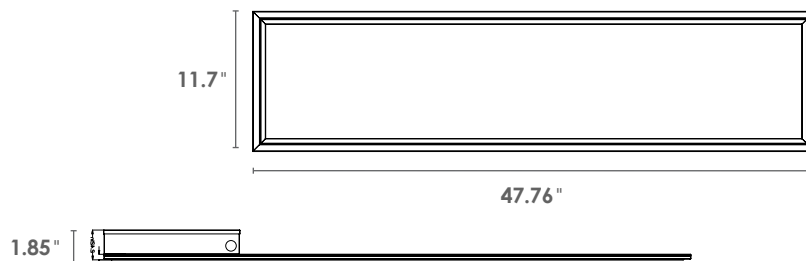

APPLICATIONS

Offices, Schools, Hospitals, Retail

AVAILABLE COLORS




ACCESSORIES



399930 - OLPL14-SMK

The Ohyama Lights Surface mounting kit allows you to install your panels on the surface of sheet rock ceilings and other ceiling types without the typical drop grid system.

DISTRIBUTION

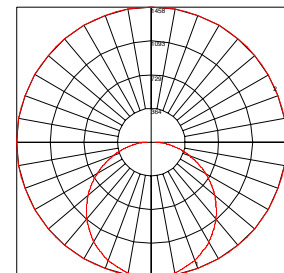

OLPLX22 SERIES


2' X 2' LED Edge-Lit Panel

PERFORMANCE

VOLTAGE 120~277V	CRI ≥80	WATTAGE 41	LUMENS 3800 - 4200
CSA LISTED Damp Location	BEAM 112°	L70 100,000 Hrs	DIMMING 0-10V
WARRANTY 5 Years	CCT 5000K	CCT 4000K	CCT 3000K



CATALOG LOGIC

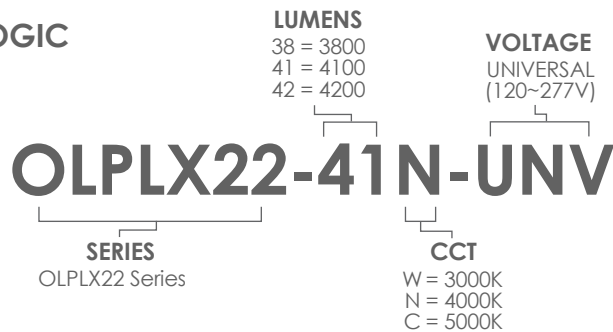


ORDERING

ITEM	MODEL	CCT	LUMEN	WATTS
399741	OLPLX22-38W-UNV	3500K	3800	41
399742	OLPLX22-41N-UNV	4000K	4100	41
399743	OLPLX22-42C-UNV	5000K	4200	41

DIMENSIONS

Size: 23.7" x 23.7" x 2.05"

Weight: 11.7 lbs.

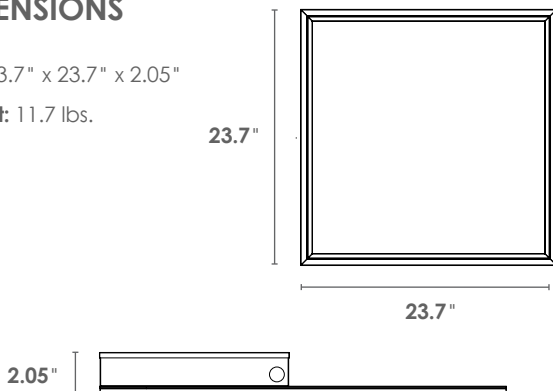

APPLICATIONS

Offices, Schools, Hospitals, Retail

AVAILABLE COLORS




ACCESSORIES



399931 - OLPL22-SMK


The Ohyama Lights Surface mounting kit allows you to install your panels on the surface of sheet rock ceilings and other ceiling types without the typical drop grid system.

DISTRIBUTION

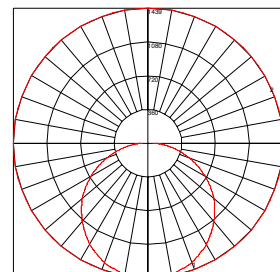

OLPLX24 SERIES


2' X 4' LED Edge-Lit Panel

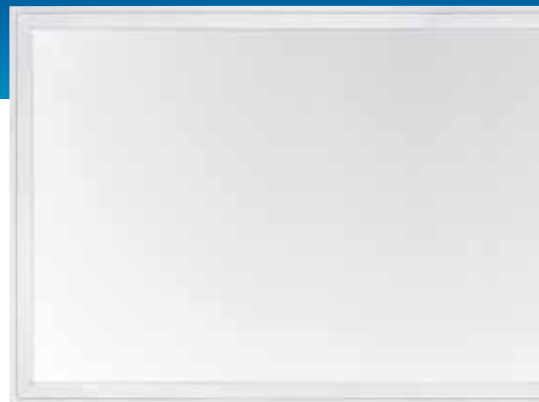

PERFORMANCE

VOLTAGE 120-277V	CRI ≥80	WATTAGE 41 / 64	LUMENS 3800 - 6500
CSA LISTED Damp Location	BEAM 112°	L70 100,000 Hrs	DIMMING 0-10V
WARRANTY 5 Years	CCT 5000K	CCT 4000K	CCT 3000K

CATALOG LOGIC

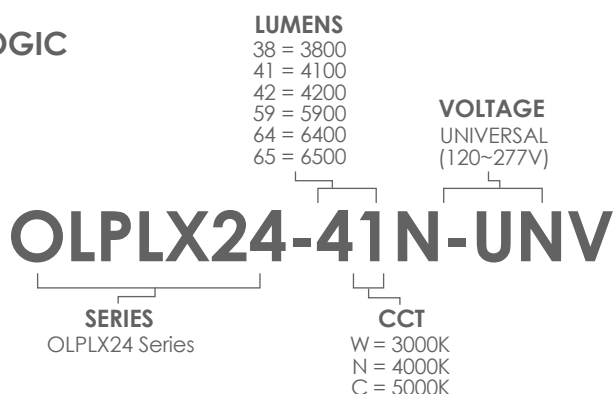


ORDERING

ITEM	MODEL	CCT	LUMEN	WATTS
399747	OLPLX24-38W-UNV	3500K	3800	41
399748	OLPLX24-41N-UNV	4000K	4100	41
399749	OLPLX24-42C-UNV	5000K	4200	41
399750	OLPLX24-59W-UNV	3500K	5900	64
399751	OLPLX24-64N-UNV	4000K	6400	64
399752	OLPLX24-65C-UNV	5000K	6500	64

DIMENSIONS

Size: 23.7" x 47.6" x 1.85"

Weight: 22.07 lbs.

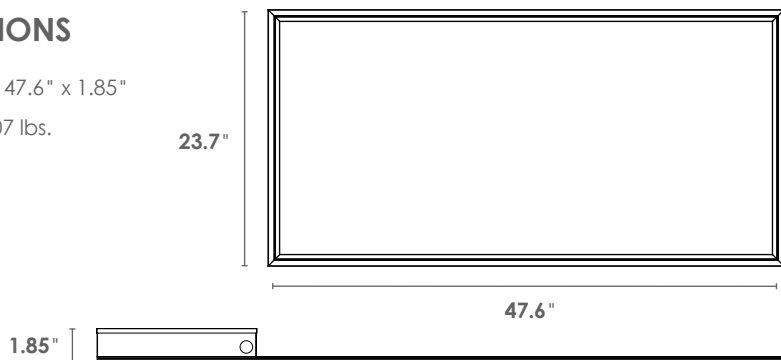

APPLICATIONS

Offices, Schools, Hospitals, Retail

AVAILABLE COLORS




ACCESSORIES



399931 - OLPL24-SMK

The Ohyama Lights Surface mounting kit allows you to install your panels on the surface of sheet rock ceilings and other ceiling types without the typical drop grid system.

DISTRIBUTION

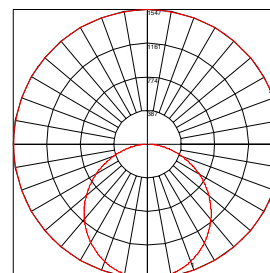

LED DOWNLIGHTS



■ Suitable for both new construction and retrofit applications, the Ohyama Lights OLEDL series downlights are the perfect choice for almost every environment. Available in both round and square shapes and with several sizes to choose from, our downlights package even, indirect, dimmable illumination in a slim, low-profile luminaire designed to create a smooth, continuous look in drywall and grid ceilings. These durable luminaires have a solid aluminum frame and industrial clips to allow for easy and secure installation.

OLEDL Series

6", 8", 12"
Round LED Downlight

6", 8", 12"
Square LED Downlight

OLEDL SERIES


6" Round LED Downlight



PERFORMANCE

VOLTAGE 120~277V	CRI ≥80	WATTAGE 13	LUMENS 1100/1200
IC RATED Insulated Ceilings	BEAM 112°	L70 100,000 Hrs	DIMMING 0-10V
WARRANTY 5 Years		CCT 4000K	CCT 3000K

CATALOG LOGIC

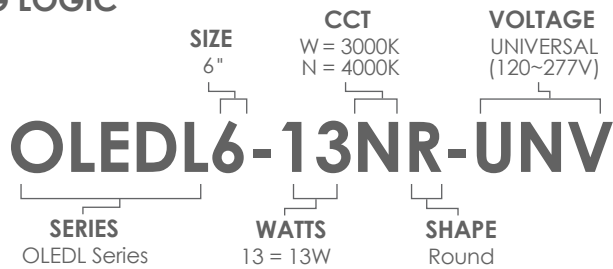

APPLICATIONS

Offices, Schools, Hospitals, Retail

AVAILABLE COLORS



ORDERING


ITEM	MODEL	CCT	LUMEN	WATTS
399573	OLEDL6-13WR-UNV	3000K	1100	13
399574	OLEDL6-13NR-UNV	4000K	1200	13

DIMENSIONS


Trim O.D.: 7"

Size: 6.69"-6.81" x 2.91"

Weight: 5.5 lbs.

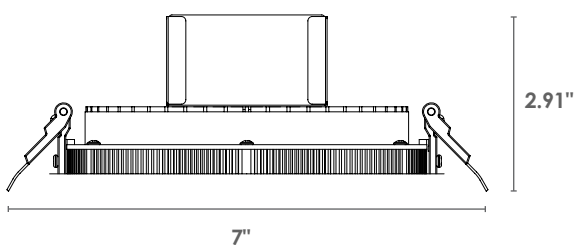

DISTRIBUTION

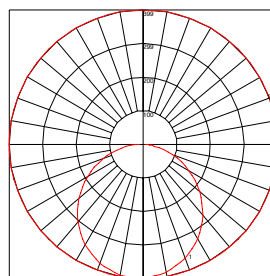

399905 OLEDL6R - GRWH

The Ohyama Lights Goof Ring allows you to cover up the existing gap between the ceiling and our downlights for a clean uniform look.



399925 OLEDL6R - BKT

The Ohyama Lights Downlight Bracket allows for extra support when installing our downlights on a grid ceiling.



399905 OLEDL - EXT

The Ohyama Lights Bracket Extenders allow you to install our downlights in thicker-than-normal ceilings.


OLEDL SERIES

8" Round LED Downlight

PERFORMANCE

VOLTAGE 120~277V	CRI ≥80	WATTAGE 13 / 20	LUMENS 1200/1950/2150
IC RATED Insulated Ceilings	BEAM 112°	L70 100,000 Hrs	DIMMING 0-10V
WARRANTY 5 Years	CCT 5000K	CCT 4000K	CCT 3000K

CATALOG LOGIC

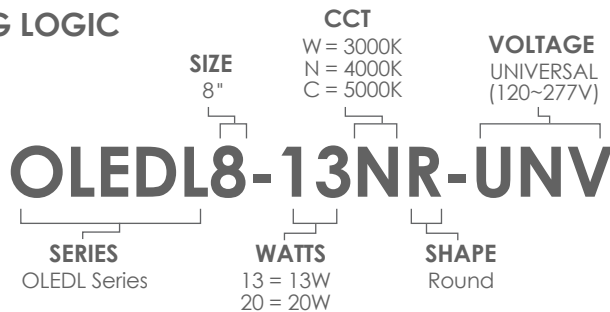


ORDERING


ITEM	MODEL	CCT	LUMEN	WATTS
399708	OLEDL8-13CR-UNV	5000K	1200	13
399709	OLEDL8-13WR-UNV	3000K	1100	13
399576	OLEDL8-13NR-UNV	4000K	1200	13
399796	OLEDL8-20CR-UNV	5000K	2150	20
399797	OLEDL8-20NR-UNV	4000K	2150	20
399798	OLEDL8-20WR-UNV	3000K	1950	20

DIMENSIONS

Trim O.D.: 9"
 Size: 9"-9.13" x 2.91"
 Weight: 5.03 lbs.

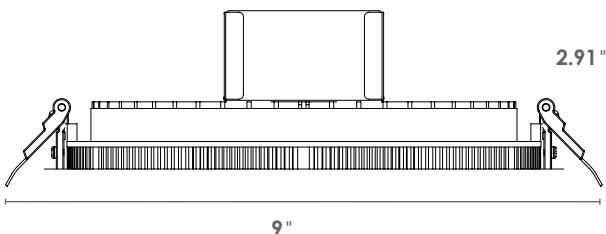

DISTRIBUTION

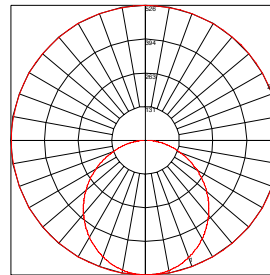

APPLICATIONS

Offices, Schools, Hospitals, Retail

AVAILABLE COLORS



ACCESSORIES

399906 OLEDL8R - GRWH



The Ohyama Lights Goof Ring allows you to cover up the existing gap between the ceiling and our downlights for a clean uniform look.

399926 OLEDL8R - BKT



The Ohyama Lights Downlight Bracket allows for extra support when installing our downlights on a grid ceiling.

399918 OLEDL - EXT



The Ohyama Lights Bracket Extenders allow you to install our downlights in thicker-than-normal ceilings.

OLEDL SERIES


12" Round LED Downlight



PERFORMANCE

VOLTAGE 120~277V	CRI ≥80	WATTAGE 16 / 30	LUMENS 1370 - 3100
IC RATED Insulated Ceilings	BEAM 112°	L70 100,000 Hrs	DIMMING 0-10V
WARRANTY 5 Years	CCT 5000K	CCT 4000K	CCT 3000K

CATALOG LOGIC

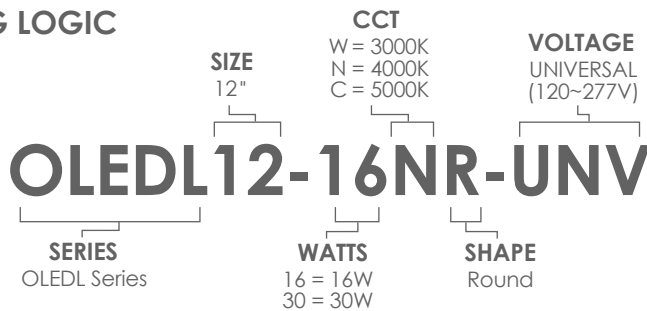


ORDERING


ITEM	MODEL	CCT	LUMEN	WATTS
399558	OLEDL12-16WR-UNV	3000K	1370	16
399579	OLEDL12-16NR-UNV	4000K	1500	16
399580	OLEDL12-16CR-UNV	5000K	1500	16
399803	OLEDL12-30WR-UNV	3000K	2850	30
399802	OLEDL12-30NR-UNV	4000K	3100	30
399801	OLEDL12-30CR-UNV	5000K	3100	30

DIMENSIONS

Trim O.D.: 11.69"
 Size: 11.45"-11.57" x 2.91"
 Weight: 7.72 lbs.

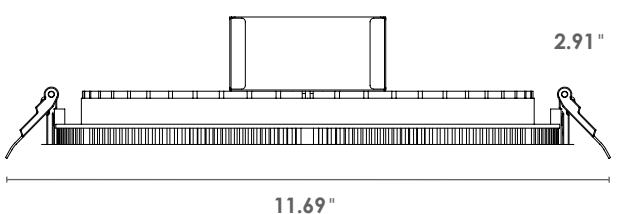

DISTRIBUTION

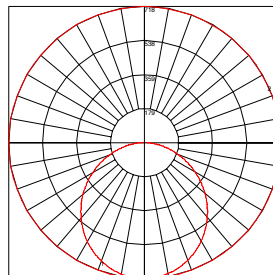

APPLICATIONS

Offices, Schools, Hospitals, Retail

AVAILABLE COLORS



ACCESSORIES

399908 OLEDL12R - GRWH



The Ohyama Lights Goof Ring allows you to cover up the existing gap between the ceiling and our downlights for a clean uniform look.

399928 OLEDL12R - BKT



The Ohyama Lights Downlight Bracket allows for extra support when installing our downlights on a grid ceiling.

399918 OLEDL - EXT



The Ohyama Lights Bracket Extenders allow you to install our downlights in thicker-than-normal ceilings.


OLEDL SERIES

8" Square LED Downlight

PERFORMANCE

VOLTAGE 120~277V	CRI ≥80	WATTAGE 13 / 20	LUMENS 3800 - 6500
IC RATED Insulated Ceilings	BEAM 112°	L70 100,000 Hrs	DIMMING 0-10V
WARRANTY 5 Years	CCT 5000K	CCT 4000K	CCT 3000K

CATALOG LOGIC

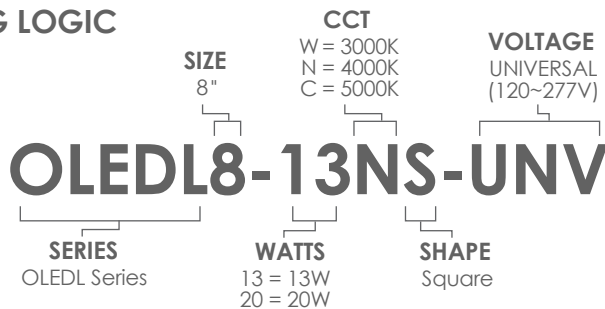

ORDERING


ITEM	MODEL	CCT	LUMEN	WATTS
399707	OLEDL8-13CS	5000K	1200	13
399706	OLEDL8-13WS	3000K	1100	13
399575	OLEDL8-13NS-UNV	4000K	1200	13
399794	OLEDL8-20CS-UNV	5000K	2150	20
399791	OLEDL8-20NS-UNV	4000K	2150	20
399795	OLEDL8-20WS-UNV	3000K	1950	20

DIMENSIONS


Flange Dimensions: 8.81"

Size: 8.46" x 8.46" - 8.58" x 8.58" x 2.91"

Weight: 5.03 lbs.

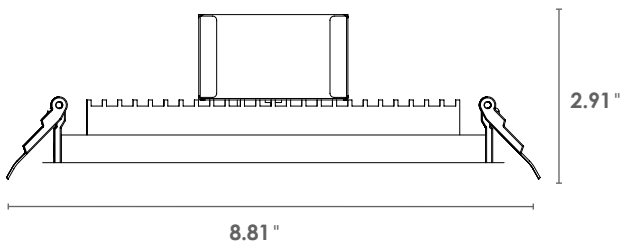

DISTRIBUTION

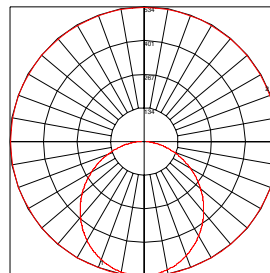

APPLICATIONS

Offices, Schools, Hospitals, Retail

AVAILABLE COLORS



ACCESSORIES

399907

OLEDL8S - GRWH



The Ohyama Lights Goof Ring allows you to cover up the existing gap between the ceiling and our downlights for a clean uniform look.

399927

OLEDL8S - BKT



The Ohyama Lights Downlight Bracket allows for extra support when installing our downlights on a grid ceiling.

399918

OLEDL - EXT



The Ohyama Lights Bracket Extenders allow you to install our downlights in thicker-than-normal ceilings.

OLEDL SERIES


12" Square LED Downlight



PERFORMANCE

VOLTAGE 120~277V	CRI ≥80	WATTAGE 16 / 30	LUMENS 1500 - 3100
IC RATED Insulated Ceilings	BEAM 112°	L70 100,000 Hrs	DIMMING 0-10V
WARRANTY 5 Years	CCT 5000K	CCT 4000K	CCT 3000K

CATALOG LOGIC

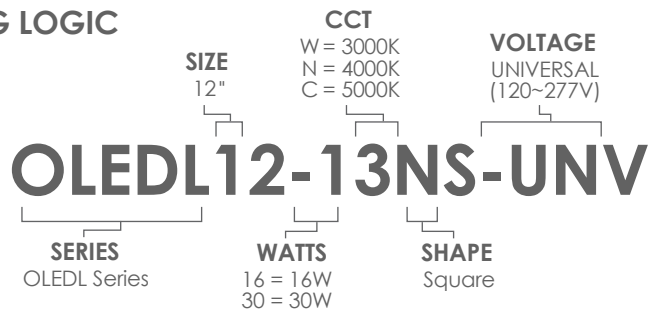

ORDERING


ITEM	MODEL	CCT	LUMEN	WATTS
399577	OLEDL12-16NS-UNV	4000K	1500	16
399578	OLEDL12-16CS-UNV	5000K	1500	16
399800	OLEDL12-30WS-UNV	3000K	2850	30
399792	OLEDL12-30NS-UNV	4000K	3100	30
399799	OLEDL12-30CS-UNV	5000K	3100	30

DIMENSIONS


Flange Dimensions: 11.81" x 11.81"

Size: 11.5" x 11.5" - 11.6" x 11.6" x 2.91"

Weight: 5.03 lbs.

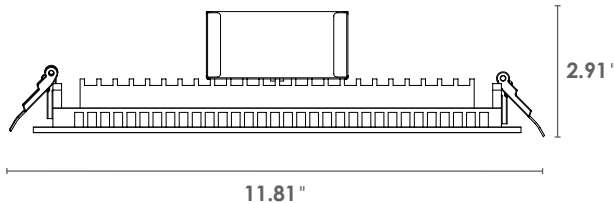

DISTRIBUTION

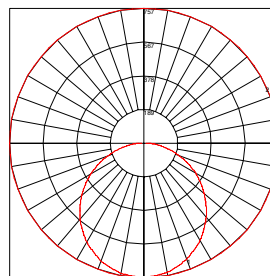

APPLICATIONS

Offices, Schools, Hospitals, Retail

AVAILABLE COLORS



ACCESSORIES



399909 OLEDL12S- GRWH

The Ohyama Lights Goof Ring allows you to cover up the existing gap between the ceiling and our downlights for a clean uniform look.



399929 OLEDL12S - BKT

The Ohyama Lights Downlight Bracket allows for extra support when installing our downlights on a grid ceiling.



399918 OLEDL - EXT

The Ohyama Lights Bracket Extenders allow you to install our downlights in thicker-than-normal ceilings.

LED DOWNLIGHT RETROFITS



■ LED Retrofit downlights from Ohyama Lights provide contractor-grade, energy-efficient lighting solutions perfect for residential and commercial applications. Ohyama Lights LED Retrofits are aesthetically pleasing and simple to install making them the ideal one-to-one replacement choice for existing incandescent fixtures. All of our Retrofit luminaires come complete with dimming functionality and a pre-attached trim to give a clean, finished look to any ceiling.

OLRDL Series
4" & 6" Residential Retrofit Kit

OLCDL Series
5"/6" Commercial Retrofit Kit

OLRDL SERIES


4" & 6" Residential Retrofit Kit



PERFORMANCE

VOLTAGE 120	CRI 83	WATTAGE 12 / 13	LUMENS 600 / 700
IC RATED Insulated Contact	UL LISTED Damp Locations	BEAM 85°	L70 50,000 Hrs
DIMMING TRIAC	WARRANTY 5 Years	CCT 2700K	

CATALOG LOGIC

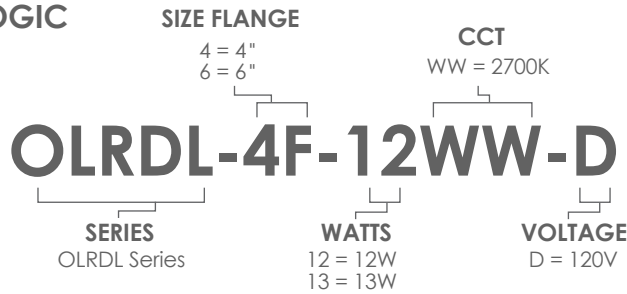

APPLICATIONS

Residential Properties

AVAILABLE COLORS



ORDERING

ITEM	MODEL	SIZE	CCT	LUMEN	WATTS
399518	OLRDL-4F-12WW-D	4"	2700K	600	12
399519	OLRDL-6F-13WW-D	6"	2700K	700	13

Trim O.D.: 7.3" (185mm)

Retrofit Size: 5.11" - 6.10"
(130mm - 155mm)

(H) 4.4" (111mm)

Weight: 1.3 lbs.


DIMENSIONS

4" Round

Trim O.D.: 5"

Size: 4" x 3.3"

Weight: 1.1 lbs.

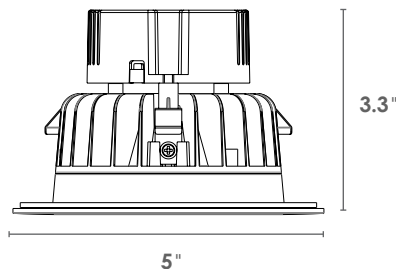


5"/6" Round

Trim O.D.: 7.3"

Size: 5.11" - 6.1" x 4.4"

Weight: 1.3 lbs.

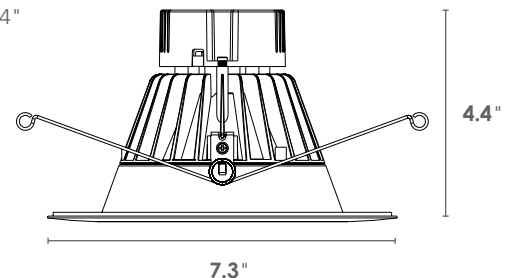

OLCDL SERIES


5" / 6" Commercial Retrofit Kit



PERFORMANCE

VOLTAGE 120	CRI ≥80	WATTAGE 14	LUMENS 920
IC RATED Insulated Contact	UL LISTED Damp Locations	BEAM 85°	L70 40,000 Hrs
DIMMING PWN/0-10V/DALI	WARRANTY 5 Years		CCT 3000K

CATALOG LOGIC

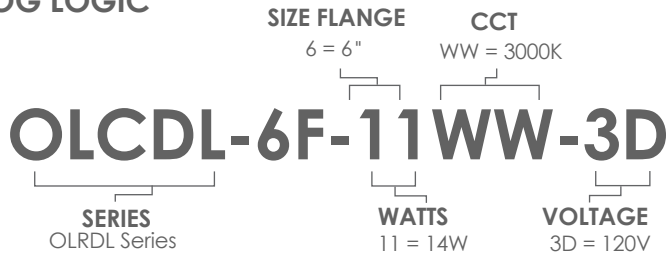

ORDERING

ITEM	MODEL	SIZE	CCT	LUMEN	WATTS
399510	OLCDL-6F-11W-3D	6"	3000K	920	14


DIMENSIONS

5" / 6" Round

Trim O.D.: 7.13"

Size: 5.11" - 6.1" x 3.37"

Weight: 1.3 lbs.

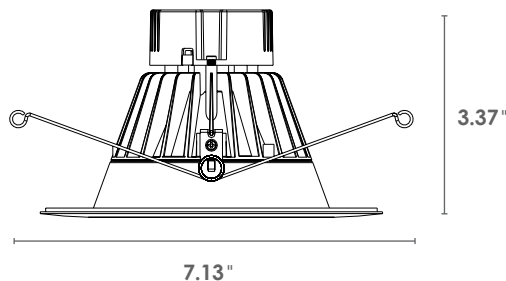


APPLICATIONS

Commercial Properties


AVAILABLE COLORS



DISTRIBUTION

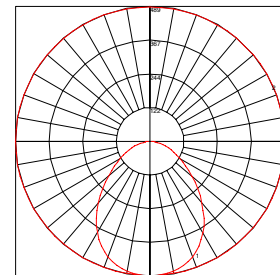

LED CEILING LIGHTS

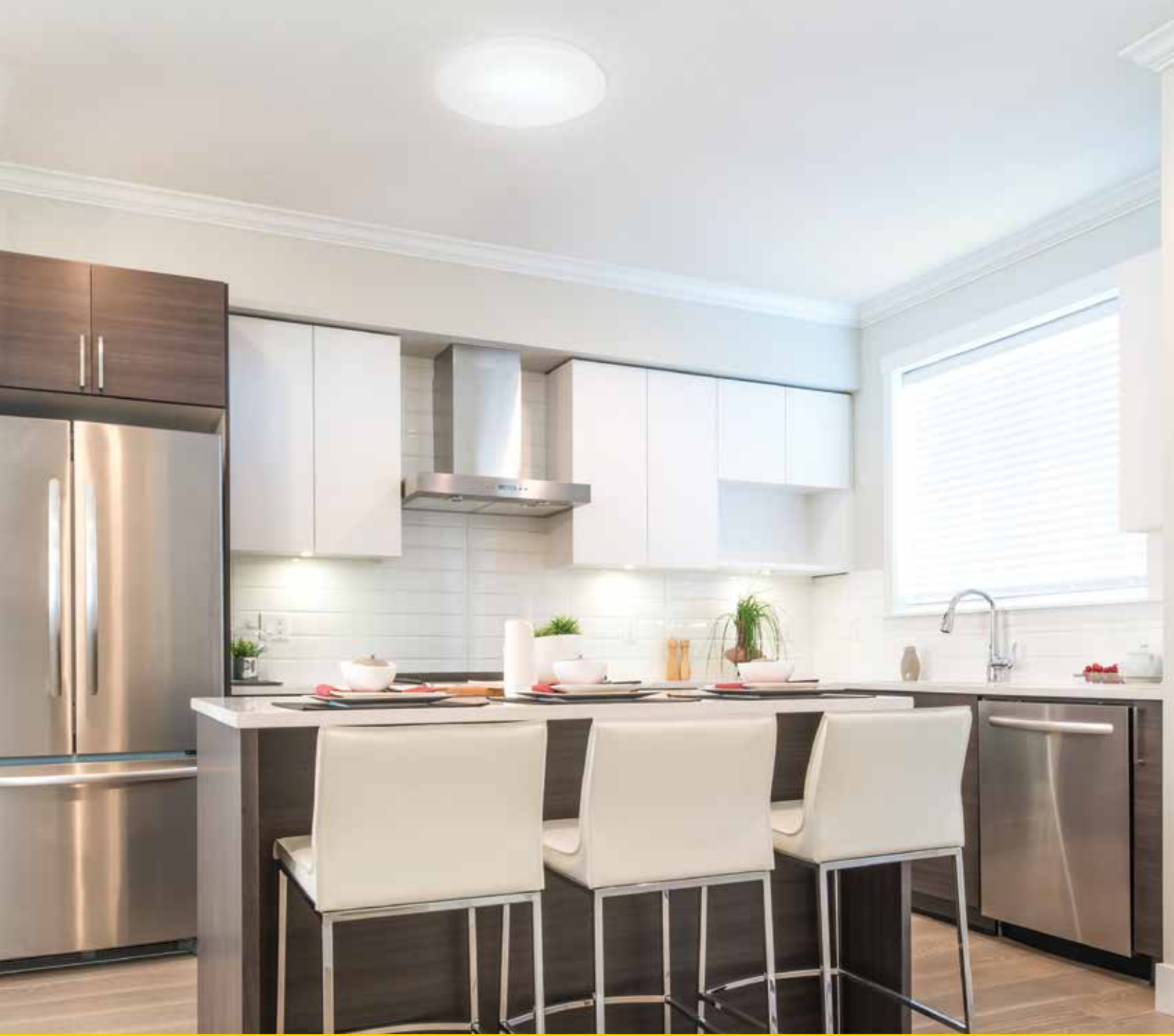

■ Classic on the outside but very modern on the inside, the Ohyama Lights Ceiling Lights enhance any setting. The timeless designs and clean lines of these fixtures make them ideal choices for kitchens, bathrooms, bedrooms, laundry rooms and hallways. With styles equally at home in residential as well as multi-unit and commercial applications we're sure to have a luminaire that meets your needs.

OLCL Series

9", 12", 14", 19", 24"
Round LED Ceiling Light

12", 15", 20"
Square LED Ceiling Light

OLCLD Series

Decorative LED Ceiling Light

OLCLG Series

Glass LED Ceiling Light

OLDK Series

6" Round LED Ceiling Light

OLCL SERIES

9" Round LED Ceiling Light



PERFORMANCE

VOLTAGE 120	CRI ≥80	WATTAGE 11	LUMENS 650
UL LISTED Damp Locations	DIMMING Triac	LIFETIME 50,000 Hrs	WARRANTY 5 Years
		CCT 4000K	CCT 3000K

CATALOG LOGIC




ORDERING

ITEM	MODEL	CCT	LUMEN	WATTS
399640	OLCL09R-11W	3000K	650	11
399641	OLCL09R-11N	4000K	650	11

DIMENSIONS

Size: 9.5" x 3.2"

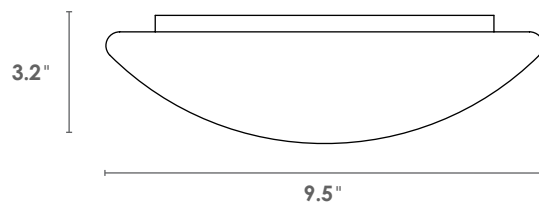


APPLICATIONS

Kitchens, Bathrooms, Closets,
Laundry Rooms, Hallways

AVAILABLE COLORS



DISTRIBUTION

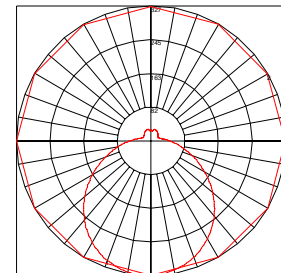

OLCL SERIES


12" Round & Square LED Ceiling Light



PERFORMANCE

VOLTAGE 120	CRI ≥80	WATTAGE 17	LUMENS 1200
UL LISTED Damp Locations	DIMMING Triac	LIFETIME 50,000 Hrs	WARRANTY 5 Years
		CCT 4000K	CCT 3000K

CATALOG LOGIC

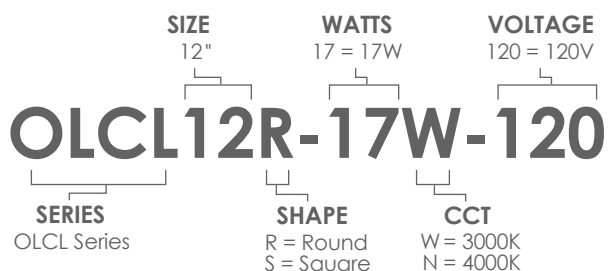


ORDERING

ITEM	MODEL	CCT	LUMEN	WATTS
399520	OLCL12R-17N-120	4000K	1200	17
399521	OLCL12S-17N-120	4000K	1200	17
399642	OLCL12R-17W-120	3000K	1200	17
399643	OLCL12S-17W-120	3000K	1200	17

DIMENSIONS


12" Round

Size: 11.3" x 3.6"

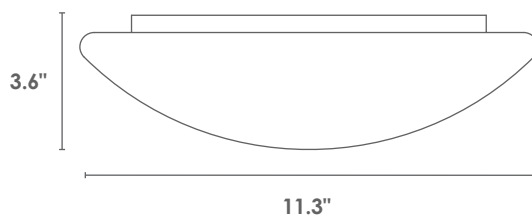

12" Square

Size: 12" x 12" x 2.85"

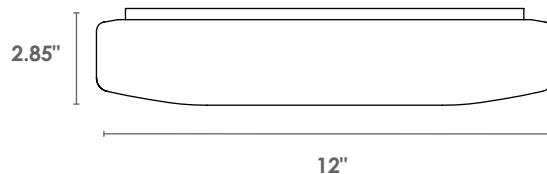

APPLICATIONS


Kitchens, Bathrooms, Closets,
Laundry Rooms, Hallways

AVAILABLE COLORS




DISTRIBUTION

12" Round

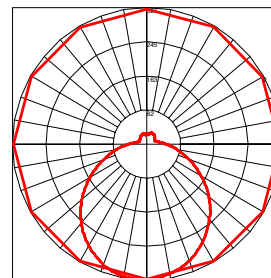

12" Square

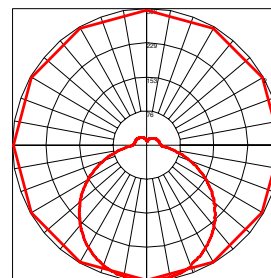

OLCL SERIES


14" Round LED Ceiling Light



PERFORMANCE

VOLTAGE 120-277V	CRI ≥80	WATTAGE 22	LUMENS 1550
UL LISTED Damp Locations	DIMMING Triac	LIFETIME 35,000 Hrs	WARRANTY 5 Years
		CCT 4000K	CCT 3000K

CATALOG LOGIC

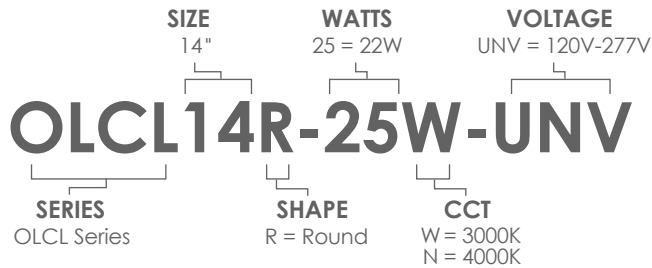


APPLICATIONS

Kitchens, Bathrooms, Closets, Laundry Rooms, Hallways

AVAILABLE COLORS



DISTRIBUTION

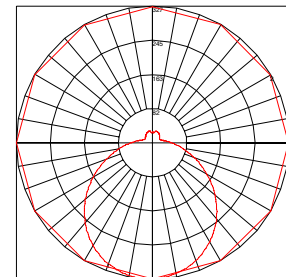


ORDERING

ITEM	MODEL	CCT	LUMEN	WATTS
399644	OLCL14R-25W-UNV	3000K	1550	22
399645	OLCL14R-25N-UNV	4000K	1550	22

DIMENSIONS

Size: 14" x 3.5"

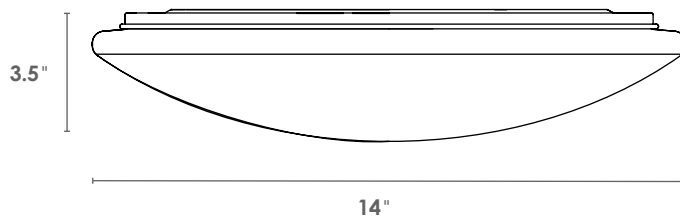

OLCL SERIES


15" Square LED Ceiling Light



PERFORMANCE

VOLTAGE 120	CRI ≥80	WATTAGE 22	LUMENS 1500
UL LISTED Damp Locations	DIMMING Triac	LIFETIME 35,000 Hrs	WARRANTY 5 Years
		CCT 4000K	CCT 3000K

CATALOG LOGIC

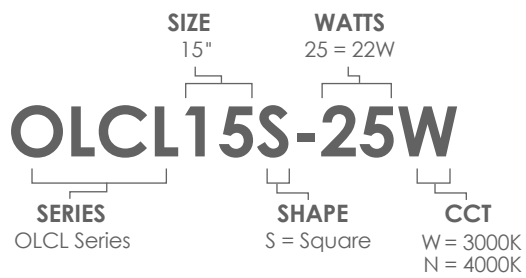


APPLICATIONS

Kitchens, Bathrooms, Closets,
Laundry Rooms, Hallways

AVAILABLE COLORS



DISTRIBUTION

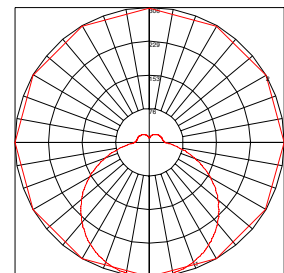


ORDERING

ITEM	MODEL	CCT	LUMEN	WATTS
399646	OLCL15S-25W	3000K	1500	22
399647	OLCL15S-25N	4000K	1500	22

DIMENSIONS

Size: 14.8" x 14.8" 3.2"

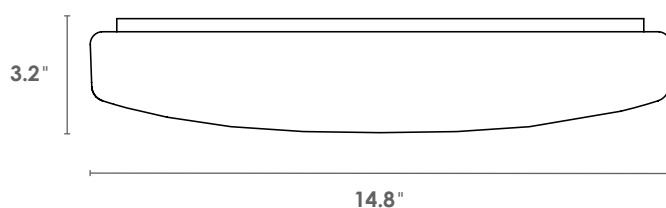

OLCL SERIES


19" Round LED Ceiling Light



PERFORMANCE

VOLTAGE 120	CRI ≥80	WATTAGE 32	LUMENS 2000
UL LISTED Damp Locations	DIMMING Triac	LIFETIME 35,000 Hrs	WARRANTY 5 Years
		CCT 4000K	CCT 3000K

CATALOG LOGIC

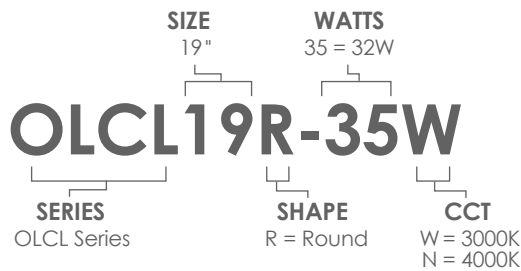


ORDERING

ITEM	MODEL	CCT	LUMEN	WATTS
399648	OLCL19R-35W	3000K	2000	32
399649	OLCL19R-35N	4000K	2000	32

DIMENSIONS

Size: 19" x 4.5"

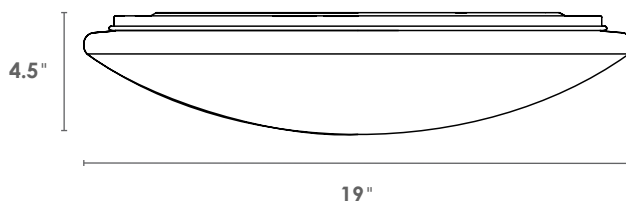


APPLICATIONS

Kitchens, Bathrooms, Closets,
Laundry Rooms, Hallways

AVAILABLE COLORS



DISTRIBUTION

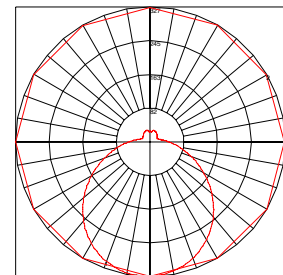

OLCL SERIES


20" Square LED Ceiling Light



PERFORMANCE

VOLTAGE 120-277V	CRI ≥80	WATTAGE 32	LUMENS 2250
UL LISTED Damp Locations	DIMMING Triac	LIFETIME 35,000 Hrs	WARRANTY 5 Years
		CCT 4000K	CCT 3000K

CATALOG LOGIC

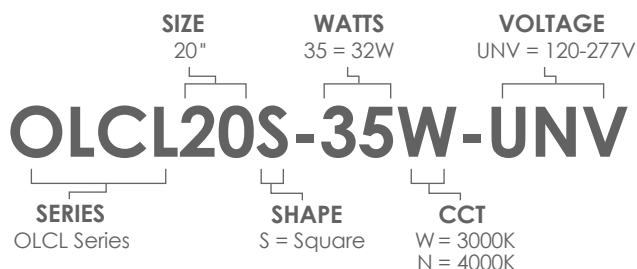


ORDERING

ITEM	MODEL	CCT	LUMEN	WATTS
399650	OLCL20S-35W-UNV	3000K	2250	32
399651	OLCL20S-35N-UNV	4000K	2250	32

DIMENSIONS

Size: 19.8" x 19.8" 3.8"

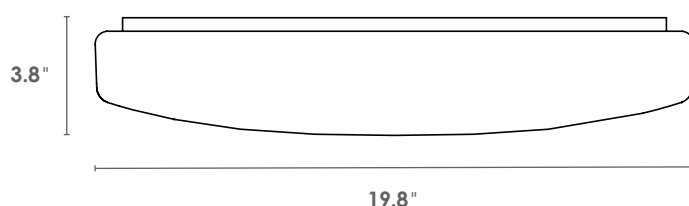


APPLICATIONS

Kitchens, Bathrooms, Closets,
Laundry Rooms, Hallways

AVAILABLE COLORS



DISTRIBUTION

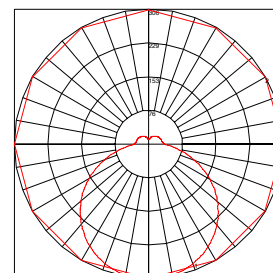

OLCL SERIES


24" Round LED Ceiling Light



PERFORMANCE

VOLTAGE 120	CRI ≥80	WATTAGE 37	LUMENS 2400
UL LISTED Damp Locations	DIMMING Triac	LIFETIME 35,000 Hrs	WARRANTY 5 Years
		CCT 4000K	CCT 3000K

CATALOG LOGIC

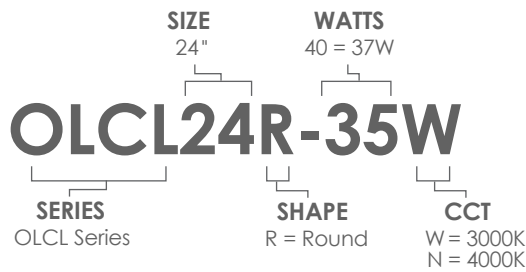


ORDERING

ITEM	MODEL	CCT	LUMEN	WATTS
399652	OLCL24R-40W	3000K	2400	37
399653	OLCL24R-40N	4000K	2400	37

DIMENSIONS

Size: 24" x 4.96"

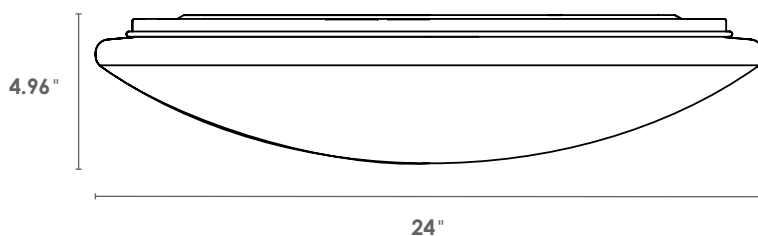


APPLICATIONS

Kitchens, Bathrooms, Closets,
Laundry Rooms, Hallways

AVAILABLE COLORS



DISTRIBUTION

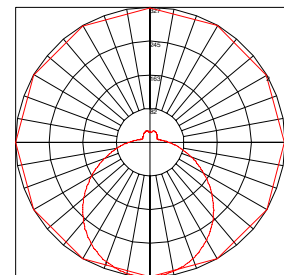

OLCLD SERIES

Decorative LED Ceiling Light




PERFORMANCE

VOLTAGE 120	CRI ≥80	WATTAGE 24 / 48	LUMENS 1900 / 4100
UL LISTED Damp Locations	DIMMING Triac	LIFETIME 50,000 Hrs	WARRANTY 5 Years
		CCT 4000K	CCT 2700K

CATALOG LOGIC

*Note: when an LB or DB trim is added the fixture becomes 23"

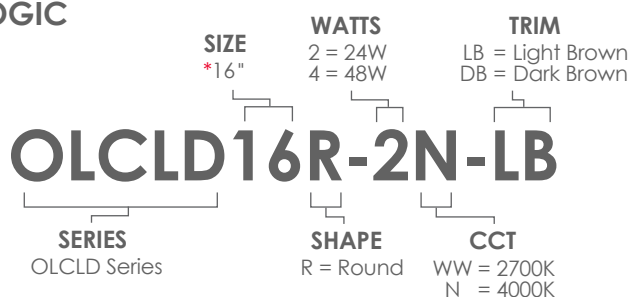

APPLICATIONS

Residential, Commercial, Hospitals, Office


AVAILABLE COLORS



ORDERING


ITEM	MODEL	TRIM COLOR	CCT	LUMEN	WATTS
399711	OLCLD16R-2WW	-	2700K	1900	24
399712	OLCLD16R-2N	-	4000K	1900	24
399713	OLCLD16R-4WW	-	2700K	4100	48
399714	OLCLD16R-4N	-	4000K	4100	48
399715	OLCLD16R-2WW-LB	LIGHT BROWN	2700K	1900	24
399716	OLCLD16R-2N-LB	LIGHT BROWN	4000K	1900	24
399717	OLCLD16R-4WW-LB	LIGHT BROWN	2700K	4100	48
399718	OLCLD16R-4N-LB	LIGHT BROWN	4000K	4100	48
399719	OLCLD16R-2WW-DB	DARK BROWN	2700K	1900	24
399720	OLCLD16R-2N-DB	DARK BROWN	4000K	1900	24
399721	OLCLD16R-4WW-DB	DARK BROWN	2700K	4100	48
399722	OLCLD16R-4N-DB	DARK BROWN	4000K	4100	48

DISTRIBUTION

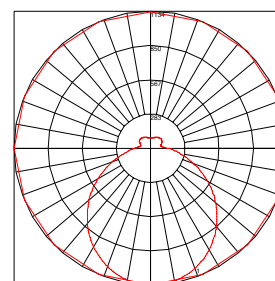

DIMENSIONS

Trim O.D.: 20.56"
Size: 17.72" x 4.5"

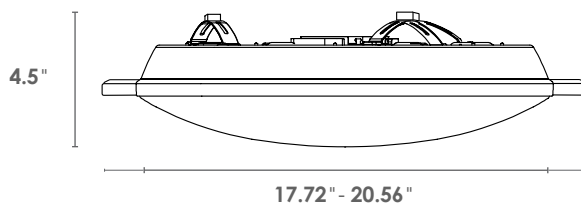

OLCLG SERIES


Glass LED Ceiling Light

PERFORMANCE

VOLTAGE 120	CRI ≥80	WATTAGE 20	LUMENS 2000 / 3800
UL LISTED Damp Locations	DIMMING Triac	LIFETIME 50,000 Hrs	WARRANTY 5 Years
		CCT 4000K	CCT 2700K



CATALOG LOGIC

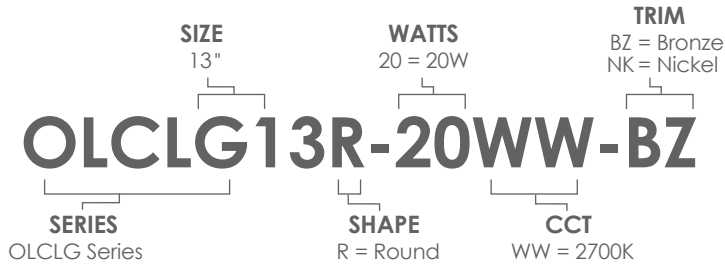

APPLICATIONS

Kitchens, Bathrooms, Laundry Rooms, Hallways


AVAILABLE COLORS



ORDERING


ITEM	MODEL	CCT	LUMEN	WATTS
399624	OLCLG13R-20WW-BZ	2700K	1200	20
399625	OLCLG13R-20WW-NK	2700K	1200	20

DISTRIBUTION

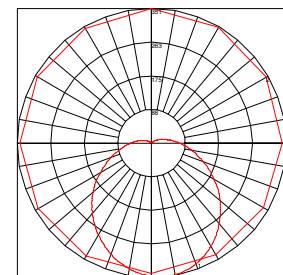

DIMENSIONS

Size: 13" x 5"

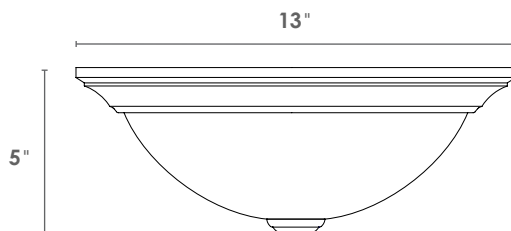

OLDK SERIES

6" Round LED Ceiling Light



PERFORMANCE

VOLTAGE 120	CRI ≥80	WATTAGE 13	LUMENS 900
UL LISTED Damp Locations	DIMMING Triac	LIFETIME 50,000 Hrs	WARRANTY 5 Years
		CCT 4000K	CCT 3000K




APPLICATIONS

Kitchens, Bathrooms,
Laundry Rooms, Hallways


AVAILABLE COLORS



CATALOG LOGIC

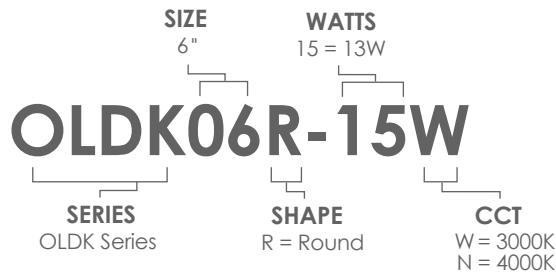

DISTRIBUTION

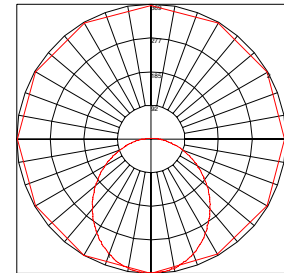


ORDERING

ITEM	MODEL	CCT	LUMEN	WATTS
399638	OLDK06R-15W	3000K	900	13
399639	OLDK06R-15N	4000K	900	13

DIMENSIONS

Size: 7.5" x 2.1"

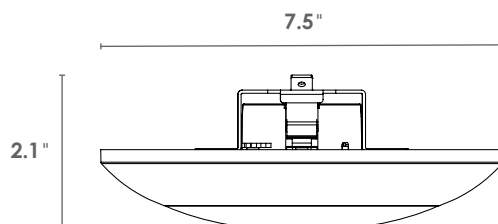

LED LINEARS & SURFACE MOUNTS



■ The OLLN series is an ideal option for stairwells and corridors. For increased security and energy savings, add the motion sensor option to include dual motion sensors allowing for bi-directional sensing. The luminaire stays in low mode until motion is detected; this saves you energy but ensures you have illumination where and when you need it.

Whether you're replacing T8 strip lighting or looking to increase efficiency, security and safety, Ohyama Lights has a luminaire to fit the bill. Our OLLX Linelux series is available in both a traditional "strip design" as well as with a contemporary looking "narrow" mounting plate. With the ability to be either pendant or surface mounted, the Linelux is a perfect alternative to T8 strip.

OLLN4 Series
4" LED Surface Mount

OLLX Series
4" LED Linelux

OLLN4 SERIES


4" LED Surface Mount

PERFORMANCE

VOLTAGE 120 - 277V	CRI 80	WATTAGE 26	LUMENS 3000
UL LISTED Damp Locations	TIME DELAY 5 Sec - 5 Min	LIFETIME 50,000 Hrs	WARRANTY 5 Years
	CCT 5000K	CCT 4000K	



CATALOG LOGIC

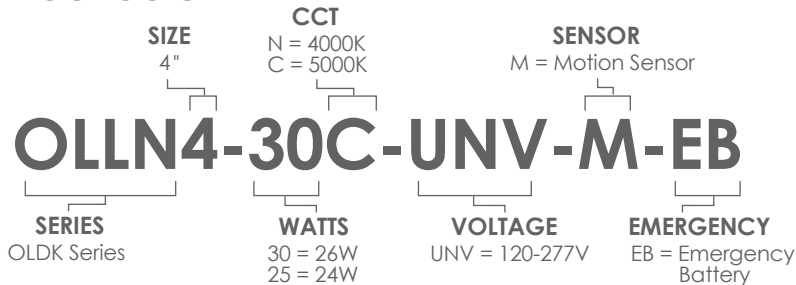

APPLICATIONS

Stairwells, Garages, Hallways, Schools


AVAILABLE COLORS



ORDERING

ITEM	MODEL	CCT	LUMEN	WATTS	STANDBY WATTS
399725	OLLN4-30C-UNV	5000K	3000	26	N/A
399726	OLLN4-30N-UNV	4000K	3000	26	N/A
399723	OLLN4-30C-UNV-M	5000K	3000	26	8.6
399724	OLLN4-30N-UNV-M	4000K	3000	26	8.6
399727	OLLN4-30C-UNV-M-EB	5000K	3000	26	10.5



DISTRIBUTION

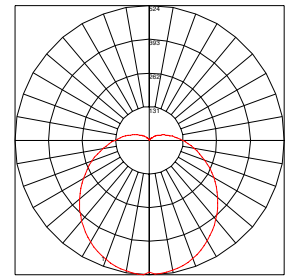

DIMENSIONS

Size: 50.35" x 2.36" x 3.43"

Weight: 5.2 lbs.

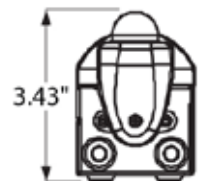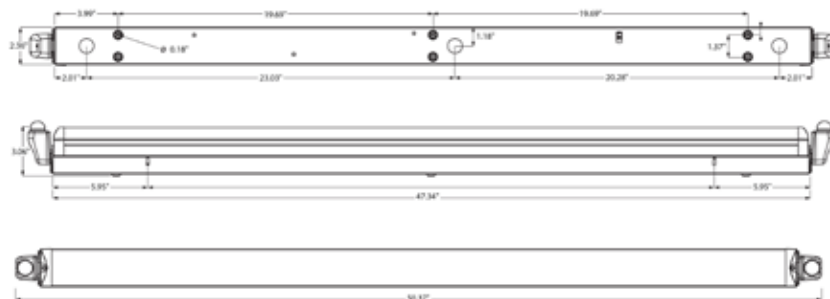


OLLX LineLux™ Series

PERFORMANCE

VOLTAGE 120 - 277V	CRI ≥80	WATTAGE 25 / 40	LUMENS 2500 / 4000
UL LISTED Damp Locations	DIMMING 0-10V	L70 >50,000 Hrs	WARRANTY 5 Years
	CCT 5000K	CCT 4000K	



CATALOG LOGIC

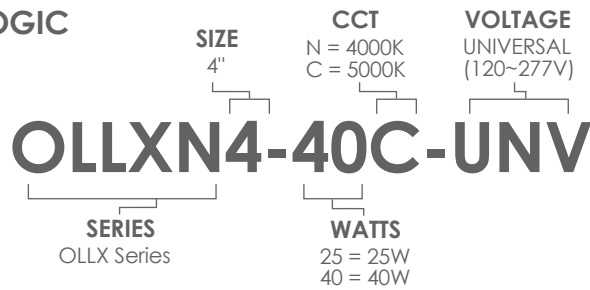

APPLICATIONS

Stairwells, Garages, Hallways, Schools


AVAILABLE COLORS



ORDERING

ITEM	MODEL	CCT	LUMEN	WATTS
399766	OLLXS4-25N-UNV	4000K	2500	25
399767	OLLXS4-25C-UNV	5000K	2500	25
399768	OLLXS4-40N-UNV	4000K	4000	40
399769	OLLXS4-40C-UNV	5000K	4000	40
399770	OLLXN4-25N-UNV	4000K	2500	25
399771	OLLXN4-25C-UNV	5000K	2500	25
399772	OLLXN4-40N-UNV	4000K	4000	40
399773	OLLXN4-40C-UNV	5000K	4000	40

DISTRIBUTION

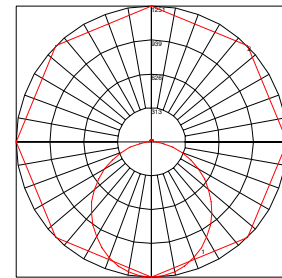


DIMENSIONS

Strip

Size: 49" x 2.95" x 3.85"

 
Weight: 6.4 lbs.




Narrow

Size: 49" x 5.9" x 3.85"

Weight: 8.3 lbs.

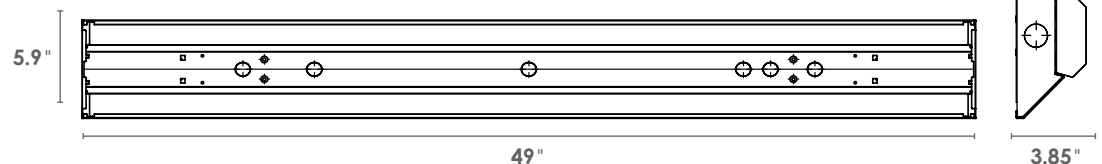

LED HIGHBAYS

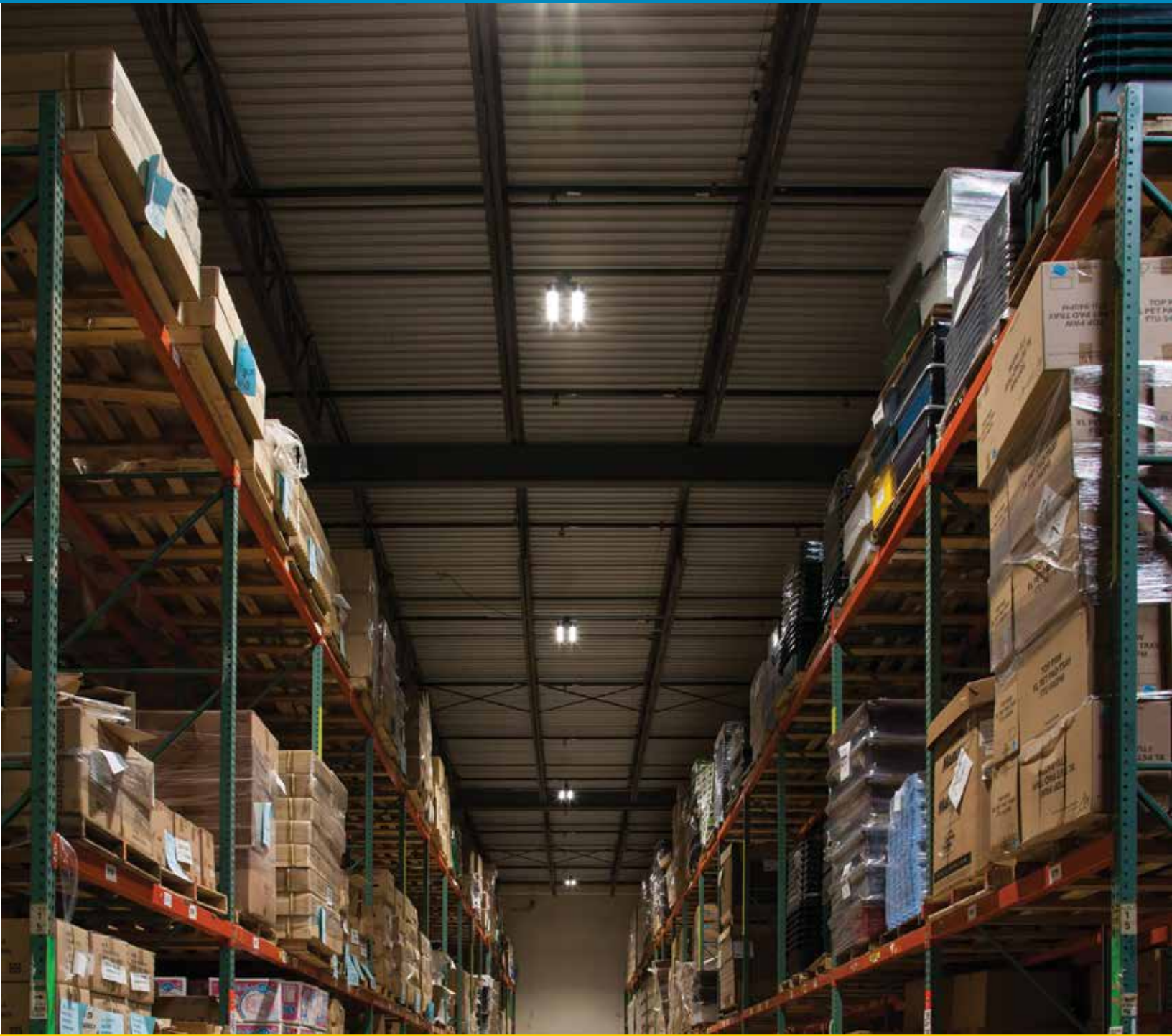

■ Ohyama Lights' OLHB LED Highbay luminaire is the perfect choice for all your industrial, warehouse and big-box retail lighting needs. With the OLHB LED Highbay you'll be able to create a bright, crisp and enjoyable work space for your employees and customers while significantly reducing energy consumption and maintenance costs. Now is the perfect time to replace energy wasting HID and high-maintenance fluorescent luminaires with our solid-state, designed-to-last OLHB LED Highbay!

OLHB Series
72, 144 Watt LED Highbay
150 Watt LED Aisle Light

OLHB SERIES

72 Watt LED Highbay

PERFORMANCE

VOLTAGE 120 - 277V	CRI ≥80	WATTAGE 72	LUMENS 9000 / 9300
UL LISTED Damp Locations	BEAM ANGLE 110°	L70 ≥100,000 Hrs	WARRANTY 5 Years
DIMMING Not Dimmable	CCT 5000K	CCT 4000K	




APPLICATIONS

Retail, Manufacturing, Warehouses


AVAILABLE COLORS



DISTRIBUTION

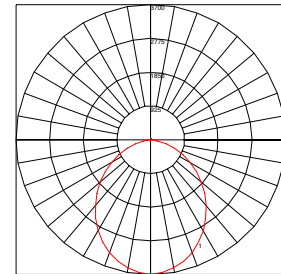

CATALOG LOGIC

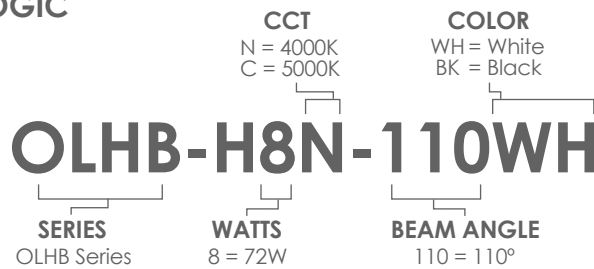



ORDERING

ITEM	MODEL	CCT	LUMEN	WATTS
399729	OLHB-H8N-110WH	4000K	9000	72
399730	OLHB-H8N-110BK	4000K	9000	72
399731	OLHB-H8C-110WH	5000K	9300	72
399732	OLHB-H8C-110BK	5000K	9300	72

DIMENSIONS

Size: 10.6" x 10.2" x 6.6"

Weight: 10.32 lbs.

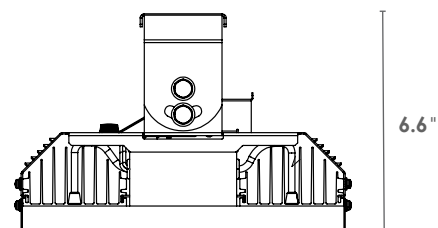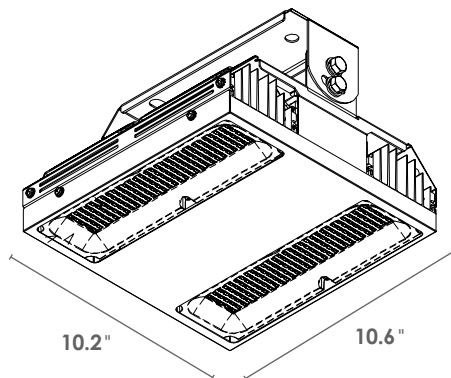


OLHB SERIES

144 Watt LED Highbay

PERFORMANCE

VOLTAGE 120 - 277V	CRI ≥80	WATTAGE 144	LUMENS 17900 / 18400
UL LISTED Damp Locations	BEAM ANGLE 110°	L70 ≥100,000 Hrs	WARRANTY 5 Years
DIMMING Not Dimmable	CCT 5000K	CCT 4000K	

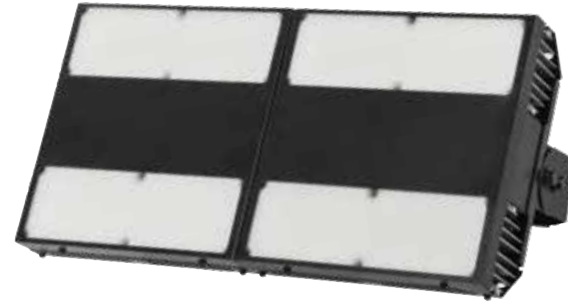


APPLICATIONS

Retail, Manufacturing, Warehouses


AVAILABLE COLORS



CATALOG LOGIC

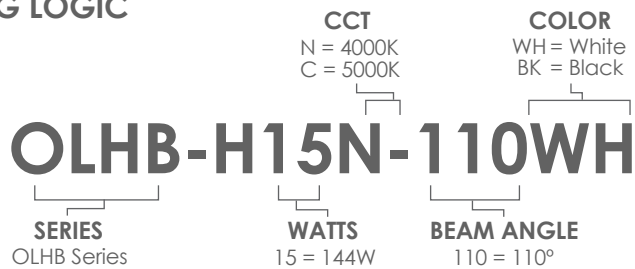

DISTRIBUTION

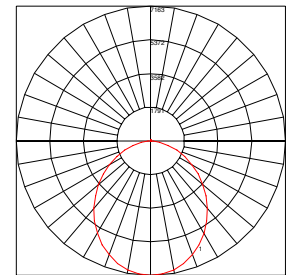



ORDERING

ITEM	MODEL	CCT	LUMEN	WATTS
399733	OLHB-H15N-110WH	4000K	17900	144
399734	OLHB-H15N-110BK	4000K	17900	144
399735	OLHB-H15C-110WH	5000K	18400	144
399736	OLHB-H15C-110BK	5000K	18400	144

DIMENSIONS

Size: 20.5" x 10.2" x 6.6"

Weight: 22.5 lbs.

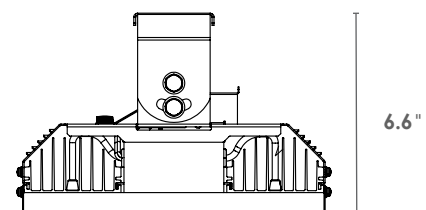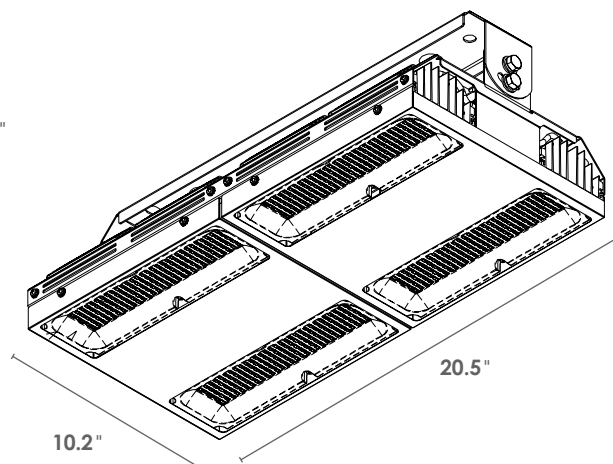

OLHB SERIES


150 Watt LED Aisle Light

PERFORMANCE

VOLTAGE 120 - 277V	CRI ≥80	WATTAGE 150	LUMENS 14800 / 15100
UL LISTED Damp Locations	BEAM ANGLE 25°	L70 ≥100,000 Hrs	WARRANTY 5 Years
DIMMING Not Dimmable	CCT 5000K	CCT 4000K	



CATALOG LOGIC

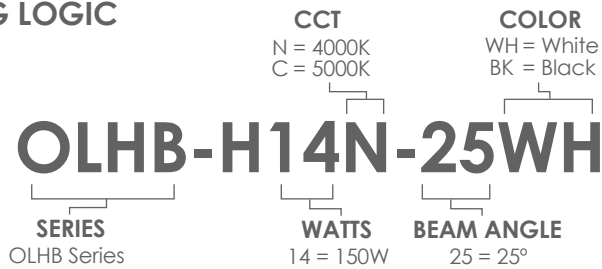


APPLICATIONS

Retail, Warehouses

AVAILABLE COLORS



DISTRIBUTION

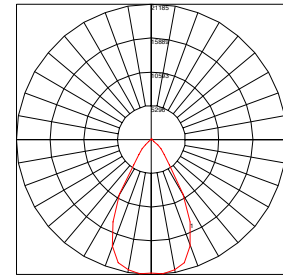



ORDERING

ITEM	MODEL	CCT	LUMEN	WATTS
399737	OLHB-H14N-25WH	4000K	14800	150
399738	OLHB-H14N-25BK	4000K	14800	150
399739	OLHB-H14C-25WH	5000K	15100	150
399740	OLHB-H14C-25BK	5000K	15100	150

DIMENSIONS

Size: 20.5" x 10.2" x 7.125"

Weight: 20.5 lbs.

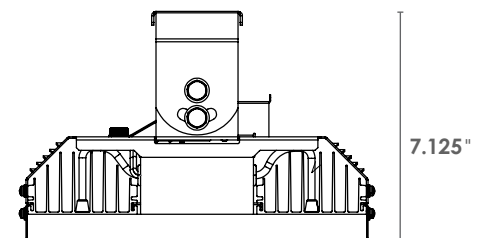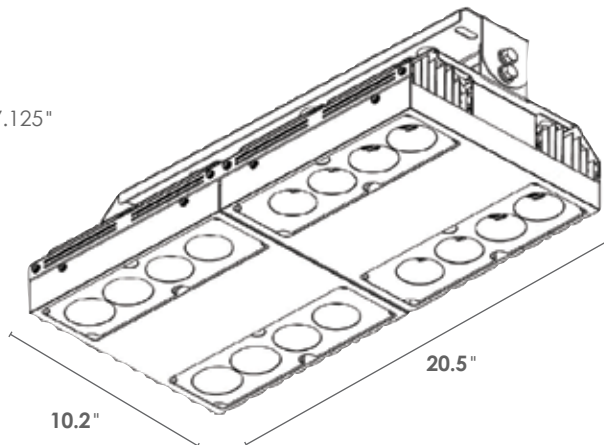

LED FLOODLIGHTS



■ The Ohyama Lights LED Flood Light Fixtures are designed to reduce operation and energy costs while creating a secure well-lit environment. With lumen outputs comparable to 100 watt and 175 watt PSMH, the OLFL luminaire is an ideal choice to illuminate building entrances, walkways, parking areas, signage and flags. Adjustable brackets and three beam angle choices allow for flexible installations. Made of powder coated cast aluminum with a polycarbonate lens and backed by a 5-year limited warranty this product will provide years of trouble-free operation.

OLFL Series
40, 68 Watt LED Floodlight

OLFL SERIES

40W LED Floodlight

PERFORMANCE

VOLTAGE 120 - 277V	CRI ≥80 / ≥65	WATTAGE 40	LUMENS 2300 - 3300
UL LISTED Wet Locations	BEAM 30°/60°/80°	L70 ≥100,000 Hrs	WARRANTY 5 Years
DIMMING Not Dimmable	CCT 5000K	CCT 3000K	



APPLICATIONS

Entrances, Walkways, Parking Areas, Signage, Flags

AVAILABLE COLORS




ACCESSORIES

399805 - OLFL-ADJ2



The Ohyama Lights Slip-Fitter allows the OLFL series more installation flexibility than ever before. The Slip-Fitter can mount over any tenon top or conduit that measures 2" - 2 3/8" in diameter.


CATALOG LOGIC

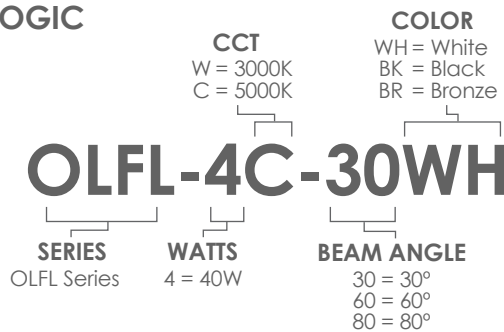

ORDERING


ITEM	MODEL	CCT	LUMEN	WATTS
399599	OLFL-4C-30WH	5000K	3240	40
399600	OLFL-4C-30BK	5000K	3240	40
399601	OLFL-4C-30BR	5000K	3240	40
399602	OLFL-4C-80WH	5000K	3300	40
399603	OLFL-4C-80BK	5000K	3300	40
399604	OLFL-4C-80BR	5000K	3300	40
399605	OLFL-4C-60WH	5000K	3200	40
399606	OLFL-4C-60BK	5000K	3200	40
399607	OLFL-4C-60BR	5000K	3200	40
399608	OLFL-4W-30WH	3000K	2340	40
399609	OLFL-4W-30BK	3000K	2340	40
399610	OLFL-4W-30BR	3000K	2340	40
399611	OLFL-4W-80WH	3000K	2380	40
399612	OLFL-4W-80BK	3000K	2380	40
399613	OLFL-4W-80BR	3000K	2380	40
399614	OLFL-4W-60WH	3000K	2300	40
399615	OLFL-4W-60BK	3000K	2300	40
399616	OLFL-4W-60BR	3000K	2300	40

DISTRIBUTION

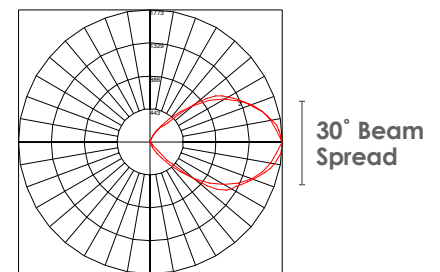

DIMENSIONS

Weight: 4 lbs.

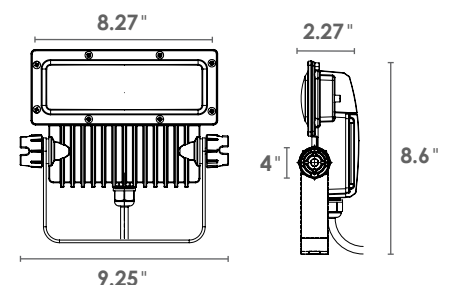


OLFL SERIES

68W LED Floodlight

PERFORMANCE

VOLTAGE 120 - 277V	CRI ≥80 / ≥65	WATTAGE 68	LUMENS 4200 - 6100
UL LISTED Wet Locations	BEAM 30°/60°/80°	L70 ≥100,000 Hrs	WARRANTY 5 Years
DIMMING Not Dimmable	CCT 5000K	CCT 5000K	

CATALOG LOGIC

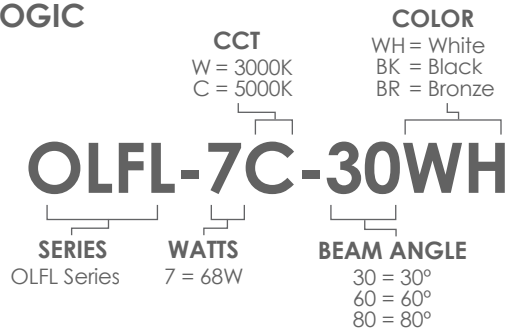

ORDERING

ITEM	MODEL	CCT	LUMEN	WATTS
399581	OLFL-7C-30WH	5000K	6000	68
399582	OLFL-7C-30BK	5000K	6000	68
399583	OLFL-7C-30BR	5000K	6000	68
399584	OLFL-7C-80WH	5000K	6100	68
399585	OLFL-7C-80BK	5000K	6100	68
399586	OLFL-7C-80BR	5000K	6100	68
399587	OLFL-7C-60WH	5000K	5900	68
399588	OLFL-7C-60BK	5000K	5900	68
399589	OLFL-7C-60BR	5000K	5900	68
399590	OLFL-7W-30WH	3000K	4400	68
399591	OLFL-7W-30BK	3000K	4400	68
399592	OLFL-7W-30BR	3000K	4400	68
399593	OLFL-7W-80WH	3000K	4400	68
399594	OLFL-7W-80BK	3000K	4400	68
399595	OLFL-7W-80BR	3000K	4400	68
399596	OLFL-7W-60WH	3000K	4200	68
399597	OLFL-7W-60BK	3000K	4200	68
399598	OLFL-7W-60BR	3000K	4200	68



APPLICATIONS

Entrances, Walkways, Parking Areas, Signage, Flags

AVAILABLE COLORS




ACCESSORIES

399805 - OLFL-ADJ2




The Ohyama Lights Slip-Fitter allows the OLFL series more installation flexibility than ever before. The Slip-Fitter can mount over any tenon top or conduit that measures 2" - 2 3/8" in diameter.

DISTRIBUTION

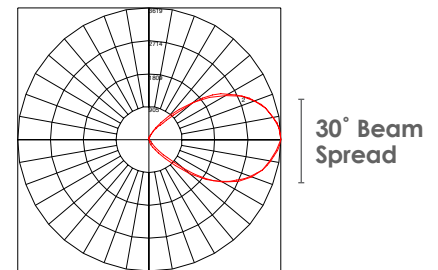

DIMENSIONS

Weight: 5 lbs.

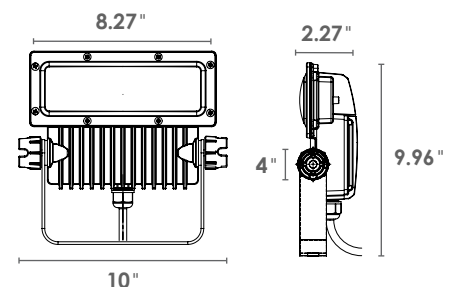

LED TRACK LIGHTS



■ Track heads from Ohyama Lights are ideal for retail displays, galleries, salesrooms, offices and indoor signage. Ohyama Lights offers 2 different styles to choose from. The OLTL series is compatible with Halo® track systems while the OLSP series is compatible with either Halo® or Juno® track systems. Eliminate the hassles of constant lamp maintenance by upgrading your track heads with long lasting fixtures from Ohyama Lights today!

OLSP18 Series
27W LED Track Head

OLTL
27W LED Track Head

OLSP18 SERIES

27W LED Track Head



PERFORMANCE

VOLTAGE 120	CRI ≥80	WATTAGE 27	LUMENS 2000 /2180
UL LISTED Damp Locations	BEAM ANGLE 25°/50°	L70 ≥100,000 Hrs	WARRANTY 5 Years
DIMMING Not Dimmable	TRACK TYPE Halo/Juno	CCT 4000K	CCT 2700K


APPLICATIONS

Retail, Restaurants

AVAILABLE COLORS



CATALOG LOGIC

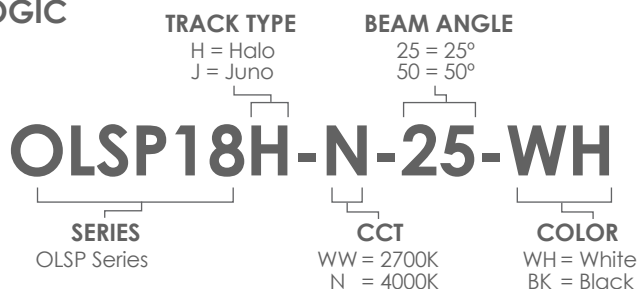


ORDERING

ITEM	MODEL	CCT	LUMEN	WATTS
399561	OLSP18H-N-25-WH	4000K	2180	27
399562	OLSP18H-N-50-WH	4000K	2180	27
399563	OLSP18H-N-25-BK	4000K	2180	27
399564	OLSP18H-N-50-BK	4000K	2180	27
399565	OLSP18J-WW-25-WH	2700K	2000	27
399566	OLSP18J-N-25-WH	4000K	2180	27
399567	OLSP18J-WW-50-WH	2700K	2000	27
399568	OLSP18J-N-50-WH	4000K	2180	27
399569	OLSP18J-WW-25-BK	2700K	2000	27
399570	OLSP18J-N-25-BK	4000K	2180	27
399571	OLSP18J-WW-50-BK	2700K	2000	27
399572	OLSP18J-N-50-BK	4000K	2180	27

DIMENSIONS

Size: 10.43" x 2.13" (Driver) / 4.25" (Track Head) x 8.27"

Weight: 3.9 lbs.

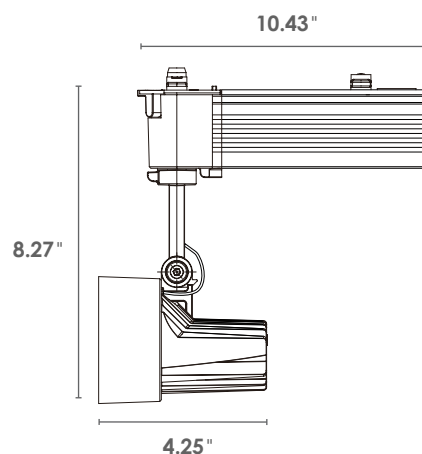

OLTL SERIES


27W LED Track Head

PERFORMANCE

VOLTAGE 120	CRI ≥80	WATTAGE 12 / 20	LUMENS 600 / 1100
UL LISTED Damp Locations	BEAM ANGLE 24°/35°	L70 ≥50,000 Hrs	WARRANTY 5 Years
DIMMING Not Dimmable	TRACK TYPE Halo	CCT 3000K	



CATALOG LOGIC

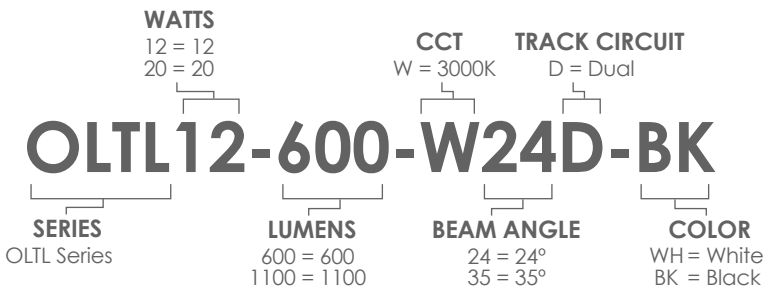


APPLICATIONS

Retail, Restaurants

AVAILABLE COLORS



DISTRIBUTION

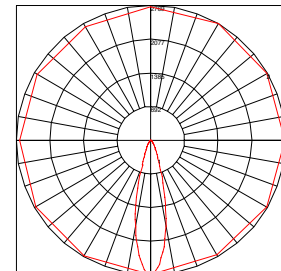



ORDERING

ITEM	MODEL	CCT	LUMEN	WATTS
399618	OLTL12-600-W24D-BK	3000K	600	12
399617	OLTL12-600-W24D-WH	3000K	600	12
399621	OLTL20-1100-W35-BK	3000K	1100	20
399620	OLTL20-1100-W35-WH	3000K	1100	20

DIMENSIONS

Size: 6.85" x 3.74" x 5.74"

Weight: 1.2 lbs.

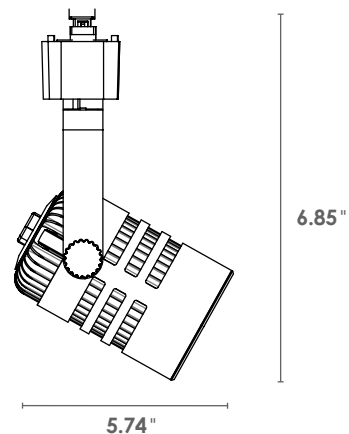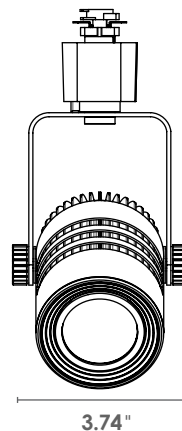

LED LAMPS



■ The easiest way to enjoy the benefits of energy efficient LED lighting is to replace existing incandescent and fluorescent lamps. Ohyama Lights is pleased to offer a variety of LED A19, BR, PAR and T8 Lamp options. Reducing your energy consumption and maintenance costs really is as easy as screwing in a lightbulb!

LED Lamps

LED LAMPS



ORDERING

APPLICATIONS

Schools, Hospitals, Homes,
Hotels, Retail, Restaurants

ITEM	MODEL	STYLE	CCT	LUMEN	WATTS	BEAM	CASE QTY
399074	LCA12C18027K1	CANDELA	2700K	180	3	OMNI	48
399101	LBA19F80027ES1	A19	2700K	800	9.5	OMNI	10
399032	LDA19L6-485-W120M	A19 MOTION SENSOR	3000K	485	6	OMNI	36
399033	LDA19L8-650-W120-M	A19 MOTION SENSOR	3000K	650	8.2	OMNI	36
399034	LDA19L5-485-C120-M	A19 MOTION SENSOR	5000K	485	5.5	OMNI	36
399035	LDA19L6-650-C120-M	A19 MOTION SENSOR	5000K	650	7.5	OMNI	36
399036	LDA19L10-850-C120-M	A19 MOTION SENSOR	5000K	850	10	OMNI	36
399042	LDBR30L10-700-W110-M	BR30 MOTION SENSOR	5000K	700	10	110°	36
399102	R20-02A27D1E-F1	R20	2700K	450	7	FLOOD	40
399051	MR16-01-63-D1E25-WB1	MR16	3000K	320	6	34°	18
399052	GU10-010630D1E25-WB1	MR16	3000K	320	6	34°	18
399113	LDBR20N8-450-WW-110D	BR20	2700K	450	8	110°	36
399050	BR30-021327D1E-WB1	BR30	2700K	800	13	120°	8
399084	LDBR30J13-800-WW	BR30	2700K	800	13	120°	24
399114	LDBR30N13-750-WW-110D	BR30	2700K	750	13.2	110°	36
399115	LDBR40N14-1000-WW-110D	BR40	2700K	1000	14	110°	12
399116	LDBR40N18-1400-WW-110D	BR40	2700K	1400	18	110°	12
399072	LDBR40T17-12000-W120-D	BR40	3000K	1200	17	120°	6
399109	LDPAR30LN12-650-WW-25D	PAR30	2700K	650	12	25°	24
399110	LDPAR30LN8-650-WW-40D	PAR30	2700K	650	8	40°	24
399057	LDPAR30J15-800-W34-DBK	PAR30	3000K	800	15	34°	24
399083	LDPAR30LJ15-800-W34	PAR30	3000K	800	15	34°	24
399049	P30L-021530D1E34-WB1	PAR30	3000K	850	15	34°	10
399111	LDPAR38N17-1200-WW-25D	PAR38	2700K	1200	17	25°	12
399112	LDPAR38N17-1200-WW-40D	PAR38	2700K	1200	17	40°	12
399011	LDPAR38L20-1110-25D	PAR38	3000K	1100	20	25°	6
399056	LDPAR38J18-1000-W34-DBK	PAR38	3000K	1000	18	34°	12
399048	P38-021830D1E34-WB1	PAR38	3000K	1050	18	34°	12
399047	P38-021850D1E34-WB1	PAR38	5000K	1050	18	34°	8
399098	LDFT8Z16-2000-W-270	T8—120V ONLY	3500K	2000	16	120°	10
399090	LDFT8Z16-2000-N-270	T8—120V ONLY	4000K	2000	16	120°	10
399091	LDFT8Z16-2000-C-270	T8—120V ONLY	5000K	2000	16	120°	10
399117	LDFT8N20-2000-N-180	T8—UNV VOLTAGE	4000K	2000	20	180°	20
399118	LDFT8N22-2000-C-180	T8—UNV VOLTAGE	5000K	2000	22	170°	20

PRODUCT INDEX

ITEM #	MODEL	CCT	LUMEN	WATTS	
LED PANELS					PG 2-6
OLPL11 SERIES - 1' x 1' LED Edge-Lit Panel					
399553	OLPL11S-2N-UNV	4000K	1700	20	
399549	OLPL11S-2C-UNV	5000K	1700	20	
399554	OLPL11S-4N-UNV	4000K	2600	35	
399550	OLPL11S-4C-UNV	5000K	2600	35	
OLPLX14 SERIES - 1' x 4' LED Edge-Lit Panel					
399744	OLPLX14-38W-UNV	3500K	3800	41	
399745	OLPLX14-41N-UNV	4000K	4100	41	
399746	OLPLX14-42C-UNV	5000K	4200	41	
OLPLX22 SERIES - 2' x 2' LED Edge-Lit Panel					
399741	OLPLX22-38W-UNV	3500K	3800	41	
399742	OLPLX22-41N-UNV	4000K	4100	41	
399743	OLPLX22-42C-UNV	5000K	4200	41	
OLPLX24 SERIES - 2' x 4' LED Edge-Lit Panel					
399747	OLPLX24-38W-UNV	3500K	3800	41	
399748	OLPLX24-41N-UNV	4000K	4100	41	
399749	OLPLX24-42C-UNV	5000K	4200	41	
399750	OLPLX24-59W-UNV	3500K	5900	64	
399751	OLPLX24-64N-UNV	4000K	6400	64	
399752	OLPLX24-65C-UNV	5000K	6500	64	
LED DOWNLIGHTS					PG 7-12
OLEDL SERIES - 6" Round LED Downlight					
399573	OLEDL6-13WR-UNV	3000K	1100	13	
399574	OLEDL6-13NR-UNV	4000K	1200	13	
OLEDL SERIES - 8" Round LED Downlight					
399708	OLEDL8-13CR-UNV	5000K	1200	13	
399709	OLEDL8-13WR-UNV	3000K	1100	13	
399576	OLEDL8-13NR-UNV	4000K	1200	13	
399796	OLEDL8-20CR-UNV	5000K	2150	20	
399797	OLEDL8-20NR-UNV	4000K	2150	20	
399798	OLEDL8-20WR-UNV	3000K	1950	20	
OLEDL SERIES - 12" Round LED Downlight					
399558	OLEDL12-16WR-UNV	3000K	1370	16	
399579	OLEDL12-16NR-UNV	4000K	1500	16	
399580	OLEDL12-16CR-UNV	5000K	1500	16	
399803	OLEDL12-30WR-UNV	3000K	2850	30	
399802	OLEDL12-30NR-UNV	4000K	3100	30	
399801	OLEDL12-30CR-UNV	5000K	3100	30	
OLEDL SERIES - 8" Square LED Downlight					
399575	OLEDL8-13NS-UNV	4000K	1200	13	
399794	OLEDL8-20CS-UNV	5000K	2150	20	
399791	OLEDL8-20NS-UNV	4000K	2150	20	
399795	OLEDL8-20WS-UNV	3000K	1950	20	
OLEDL SERIES - 12" Square LED Downlight					
399577	OLEDL12-16NS-UNV	4000K	1500	16	
399578	OLEDL12-16CS-UNV	5000K	1500	16	
399800	OLEDL12-30WS-UNV	3000K	2850	30	
399792	OLEDL12-30NS-UNV	4000K	3100	30	
399799	OLEDL12-30CS-UNV	5000K	3100	30	

PRODUCT INDEX

ITEM #	MODEL	SIZE	CCT	LUMEN	WATTS
LED DOWNLIGHT RETROFITS					PG 13-15

OLRDL SERIES - 4" & 6" Residential Retrofit Kit					
399518	OLRDL-4F-12WW-D	4"	2700K	600	12
399519	OLRDL-6F-13WW-D	6"	2700K	700	13
OLCDL SERIES - 5"/6" Commercial Retrofit Kit					
399510	OLCDL-6F-11W-3D	6"	3000K	920	14

ITEM #	MODEL	CCT	LUMEN	WATTS	
LED CEILING LIGHTS					PG 16-26

OLCL SERIES - 9" Round LED Ceiling Light					
399640	OLCL09R-11W	3000K	650	11	
399641	OLCL09R-11N	4000K	650	11	
OLCL SERIES - 12" Round & Square LED Ceiling Light					
399520	OLCL12R-17N-120	4000K	1200	17	
399521	OLCL12S-17N-120	4000K	1200	17	
399642	OLCL12R-17W-120	3000K	1200	17	
399643	OLCL12S-17W-120	3000K	1200	17	
OLCL SERIES - 14" Round LED Ceiling Light					
399644	OLCL14R-25W-UNV	3000K	1550	22	
399645	OLCL14R-25N-UNV	4000K	1550	22	
OLCL SERIES - 15" Square LED Ceiling Light					
399646	OLCL15S-25W	3000K	1500	22	
399647	OLCL15S-25N	4000K	1500	22	
OLCL SERIES - 19" Round LED Ceiling Light					
399648	OLCL19R-35W	3000K	2000	32	
399649	OLCL19R-35N	4000K	2000	32	
OLCL SERIES - 20" Square LED Ceiling Light					
399650	OLCL20S-35W-UNV	3000K	2250	32	
399651	OLCL20S-35N-UNV	4000K	2250	32	
OLCL SERIES - 24" Round LED Ceiling Light					
399652	OLCL24R-40W	3000K	2400	37	
399653	OLCL24R-40N	4000K	2400	37	

ITEM #	MODEL	TRIM COLOR	CCT	LUMEN	WATTS
OLCLD SERIES - Decorative LED Ceiling Light					
399711	OLCLD16R-2WW	-	2700	1900	24
399712	OLCLD16R-2N	-	4000	1900	24
399713	OLCLD16R-4WW	-	2700	4100	48
399714	OLCLD16R-4N	-	4000	4100	48
399715	OLCLD16R-2WW-LB	LIGHT BROWN	2700	1900	24
399716	OLCLD16R-2N-LB	LIGHT BROWN	4000	1900	24
399717	OLCLD16R-4WW-LB	LIGHT BROWN	2700	4100	48
399718	OLCLD16R-4N-LB	LIGHT BROWN	4000	4100	48
399719	OLCLD16R-2WW-DB	DARK BROWN	2700	1900	24
399720	OLCLD16R-2N-DB	DARK BROWN	4000	1900	24
399721	OLCLD16R-4WW-DB	DARK BROWN	2700	4100	48
399722	OLCLD16R-4N-DB	DARK BROWN	4000	4100	48

PRODUCT INDEX

LED CEILING LIGHTS

PG 16-26

ITEM #	MODEL	CCT	LUMEN	WATTS	
OLCLG SERIES - Glass LED Ceiling Light					
399624	OLCLG13R-20WW-BZ	2700K	1200	20	
399625	OLCLG13R-20WW-NK	2700K	1200	20	
OLDK SERIES - 6" Round LED Ceiling Light					
399638	OLDK06R-15W	3000K	900	13	
399639	OLDK06R-15N	4000K	900	13	

LED LINEARS & SURFACE MOUNTS

PG 27-29

ITEM #	MODEL	CCT	LUMEN	WATTS	STANDBY WATTS
OLLN4 SERIES - 4" LED Surface Mount					
399725	OLLN4-30C-UNV	5000K	3000	26	N/A
399726	OLLN4-30N-UNV	4000K	3000	26	N/A
399723	OLLN4-30C-UNV-M	5000K	3000	26	8.6
399724	OLLN4-30N-UNV-M	4000K	3000	26	8.6
399727	OLLN4-30C-UNV-M-EB	5000K	3000	26	10.5

ITEM #	MODEL	CCT	LUMEN	WATTS	
OLLX SERIES - 4" LED Linelux					
399766	OLLXS4-25N-UNV	4000K	2500	25	
399767	OLLXS4-25C-UNV	5000K	2500	25	
399768	OLLXS4-40N-UNV	4000K	4000	40	
399769	OLLXS4-40C-UNV	5000K	4000	40	
399770	OLLXN4-25N-UNV	4000K	2500	25	
399771	OLLXN4-25C-UNV	5000K	2500	25	
399772	OLLXN4-40N-UNV	4000K	4000	40	
399773	OLLXN4-40C-UNV	5000K	4000	40	

LED HIGHBAYS

PG 30-33

OLHB SERIES - 72 Watt LED Highbay					
399729	OLHB-H8N-110WH	4000K	9000	72	
399730	OLHB-H8N-110BK	4000K	9000	72	
399731	OLHB-H8C-110WH	5000K	9300	72	
399732	OLHB-H8C-110BK	5000K	9300	72	
OLHB SERIES - 144 Watt LED Highbay					
399733	OLHB-H15N-110WH	4000K	17900	144	
399734	OLHB-H15N-110BK	4000K	17900	144	
399735	OLHB-H15C-110WH	5000K	18400	144	
399736	OLHB-H15C-110BK	5000K	18400	144	
OLHB SERIES - 150 Watt LED Aisle Light					
399737	OLHB-H14N-25WH	4000K	14800	150	
399738	OLHB-H14N-25BK	4000K	14800	150	
399739	OLHB-H14C-25WH	5000K	15100	150	
399740	OLHB-H14C-25BK	5000K	15100	150	

PRODUCT INDEX

LED FLOODLIGHTS

PG 34-36

OLFL SERIES - 40W LED Floodlight

399599	OLFL-4C-30WH	5000K	3240	40
399600	OLFL-4C-30BK	5000K	3240	40
399601	OLFL-4C-30BR	5000K	3240	40
399602	OLFL-4C-80WH	5000K	3300	40
399603	OLFL-4C-80BK	5000K	3300	40
399604	OLFL-4C-80BR	5000K	3300	40
399605	OLFL-4C-60WH	5000K	3200	40
399606	OLFL-4C-60BK	5000K	3200	40
399607	OLFL-4C-60BR	5000K	3200	40
399608	OLFL-4W-30WH	3000K	2340	40

ITEM #

MODEL

CCT

LUMEN

WATTS

LED FLOODLIGHTS

PG 34-36

OLFL SERIES - 40W LED Floodlight - Continued

399609	OLFL-4W-30BK	3000K	2340	40
399610	OLFL-4W-30BR	3000K	2340	40
399611	OLFL-4W-80WH	3000K	2380	40
399612	OLFL-4W-80BK	3000K	2380	40
399613	OLFL-4W-80BR	3000K	2380	40
399614	OLFL-4W-60WH	3000K	2300	40
399615	OLFL-4W-60BK	3000K	2300	40
399616	OLFL-4W-60BR	3000K	2300	40

OLFL SERIES - 68W LED Floodlight

399581	OLFL-7C-30WH	5000K	6000	68
399582	OLFL-7C-30BK	5000K	6000	68
399583	OLFL-7C-30BR	5000K	6000	68
399584	OLFL-7C-80WH	5000K	6100	68
399585	OLFL-7C-80BK	5000K	6100	68
399586	OLFL-7C-80BR	5000K	6100	68
399587	OLFL-7C-60WH	5000K	5900	68
399588	OLFL-7C-60BK	5000K	5900	68
399589	OLFL-7C-60BR	5000K	5900	68
399590	OLFL-7W-30WH	3000K	4400	68
399591	OLFL-7W-30BK	3000K	4400	68
399592	OLFL-7W-30BR	3000K	4400	68
399593	OLFL-7W-80WH	3000K	4400	68
399594	OLFL-7W-80BK	3000K	4400	68
399595	OLFL-7W-80BR	3000K	4400	68
399596	OLFL-7W-60WH	3000K	4200	68
399597	OLFL-7W-60BK	3000K	4200	68
399598	OLFL-7W-60BR	3000K	4200	68

LED TRACK LIGHTS

PG 37-39

OLSP18 SERIES - 27W LED Track Head


399561	OLSP18H-N-25-WH	4000K	2180	27
399562	OLSP18H-N-50-WH	4000K	2180	27
399563	OLSP18H-N-25-BK	4000K	2180	27
399564	OLSP18H-N-50-BK	4000K	2180	27

PRODUCT INDEX

ITEM #	MODEL	CCT	LUMEN	WATTS
OLSP18 SERIES - 27W LED Track Head - Continued				
399565	OLSP18J-WW-25-WH	2700K	2000	27
399566	OLSP18J-N-25-WH	4000K	2180	27
399567	OLSP18J-WW-50-WH	2700K	2000	27
399568	OLSP18J-N-50-WH	4000K	2180	27
399569	OLSP18J-WW-25-BK	2700K	2000	27
399570	OLSP18J-N-25-BK	4000K	2180	27
399571	OLSP18J-WW-50-BK	2700K	2000	27
399572	OLSP18J-N-50-BK	4000K	2180	27
OLTL SERIES - 27W LED Track Head				
399618	OLTL12-600-W24D-BK	3000K	600	12
399617	OLTL12-600-W24D-WH	3000K	600	12
399621	OLTL20-1100-W35-BK	3000K	1100	20
399620	OLTL20-1100-W35-WH	3000K	1100	20

ITEM #	MODEL	STYLE	CCT	LUMEN	WATTS	BEAM	CASE QTY
LED LAMPS							
399074	LCA12C18027K1	CANDELA	2700K	180	3	OMNI	48
399101	LBA19F80027E51	A19	2700K	800	9.5	OMNI	10
399032	LDA19L6-485-W120M	A19 MOTION SENSOR	3000K	485	6	OMNI	36
399033	LDA19L8-650-W120-M	A19 MOTION SENSOR	3000K	650	8.2	OMNI	36
399034	LDA19L5-485-C120-M	A19 MOTION SENSOR	5000K	485	5.5	OMNI	36
399035	LDA19L6-650-C120-M	A19 MOTION SENSOR	5000K	650	7.5	OMNI	36
399036	LDA19L10-850-C120-M	A19 MOTION SENSOR	5000K	850	10	OMNI	36
399042	LDBR30L10-700-W110-M	BR30 MOTION SENSOR	5000K	700	10	110°	36
399102	R20-02A27D1E-F1	R20	2700K	450	7	FLOOD	40
399051	MR16-01-63-D1E25-WB1	MR16	3000K	320	6	34°	18
399052	GU10-010630D1E25-WB1	MR16	3000K	320	6	34°	18
399113	LDBR20N8-450-WW-110D	BR20	2700K	450	8	110°	36
399050	BR30-021327D1E-WB1	BR30	2700K	800	13	120°	8
399084	LDBR30J13-800-WW	BR30	2700K	800	13	120°	24
399114	LDBR30N13-750-WW-110D	BR30	2700K	750	13.2	110°	36
399115	LDBR40N14-1000-WW-110D	BR40	2700K	1000	14	110°	12
399116	LDBR40N18-1400-WW-110D	BR40	2700K	1400	18	110°	12
399072	LDBR40T17-1200-W120-D	BR40	3000K	1200	17	120°	6
399109	LDPAR30LN12-650-WW-25D	PAR30	2700K	650	12	25°	24
399110	LDPAR30LN8-650-WW-40D	PAR30	2700K	650	8	40°	24
399057	LDPAR30J15-800-W34-DBK	PAR30	3000K	800	15	34°	24
399083	LDPAR30LJ15-800-W34	PAR30	3000K	800	15	34°	24
399049	P30L-021530D1E34-WB1	PAR30	3000K	850	15	34°	10
399111	LDPAR38N17-1200-WW-25D	PAR38	2700K	1200	17	25°	12
399112	LDPAR38N17-1200-WW-40D	PAR38	2700K	1200	17	40°	12
399011	LDPAR38L20-1110-25D	PAR38	3000K	1100	20	25°	6
399056	LDPAR38J18-1000-W34-DBK	PAR38	3000K	1000	18	34°	12
399048	P38-021830D1E34-WB1	PAR38	3000K	1050	18	34°	12
399047	P38-021850D1E34-WB1	PAR38	5000K	1050	18	34°	8
399098	LDFT8Z16-2000-W-270	T8—120V ONLY	3500K	2000	16	120°	10
399090	LDFT8Z16-2000-N-270	T8—120V ONLY	4000K	2000	16	120°	10
399091	LDFT8Z16-2000-C-270	T8—120V ONLY	5000K	2000	16	120°	10
399117	LDFT8N20-2000-N-180	T8—UNV VOLTAGE	4000K	2000	20	180°	20
399118	LDFT8N22-2000-C-180	T8—UNV VOLTAGE	5000K	2000	22	170°	20

PG 40-41

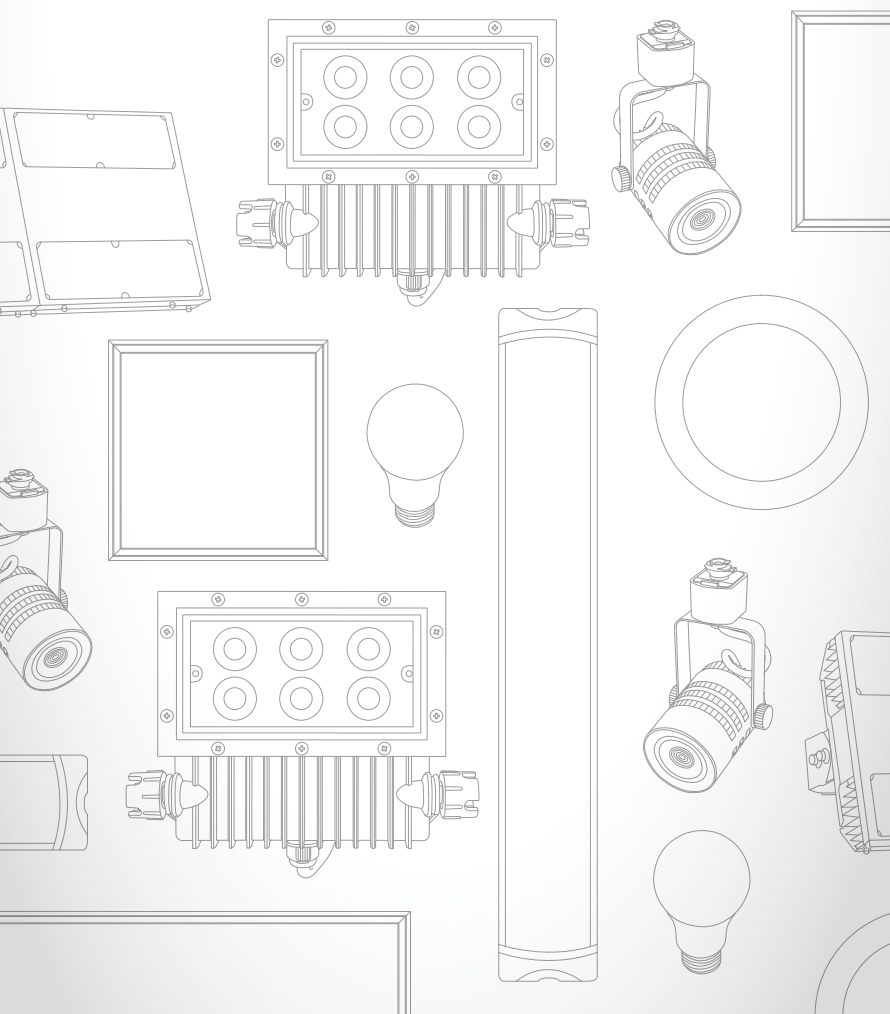

IRIS USA, Inc.

Ohyama Lights Headquarters
11111 80th Avenue
Pleasant Prairie, WI 53158
www.ohyamalights.com

Iris Ohyama Headquarters

Sendai, Japan
www.irisohyama.co.jp/english/

Iris Ohyama Europe

EcoHilux
Tilburg, The Netherlands
www.ecohilux.nl

Global Operations:

15 manufacturing and
distribution facilities in:
U.S., Japan, China, Korea
and The Netherlands.