

**ROLA·CASE**  
MULTIPLE STORAGE SYSTEMS



**ROLA·Shelf**  
VEHICLE STORAGE SOLUTIONS

**PRODUCT GUIDE**  
EDITION 3



# The ultimate in vehicle and mobile storage systems...



The ultimate solution in van racking, shelving, vehicle accessories and mobile storage systems. Engineered designed, tested and manufactured in Australia since 1985.

**ROLA•CASE** & **ROLA•Shelf** is recognised across Australia and internationally as a leading manufacturer of shelving, racking and storage solutions for vehicles, boats, ships and the workplace. Our modular van shelving and tool storage systems create flexible storage solutions unique for your mobile and static applications.



All of our innovative products are designed around three key elements:


**Safety, Durability & Quality.**

- Purpose built state of the art manufacturing facility
- 3D vehicle design center
- Nationally and local installation service
- Comprehensive showrooms
- Leaders in design and innovation for mobile and vehicle storage equipment
- National & international distributors

# ROLA·Shelf

## VEHICLE STORAGE SOLUTIONS



The ultimate in Vehicle Storage Systems Engineered design

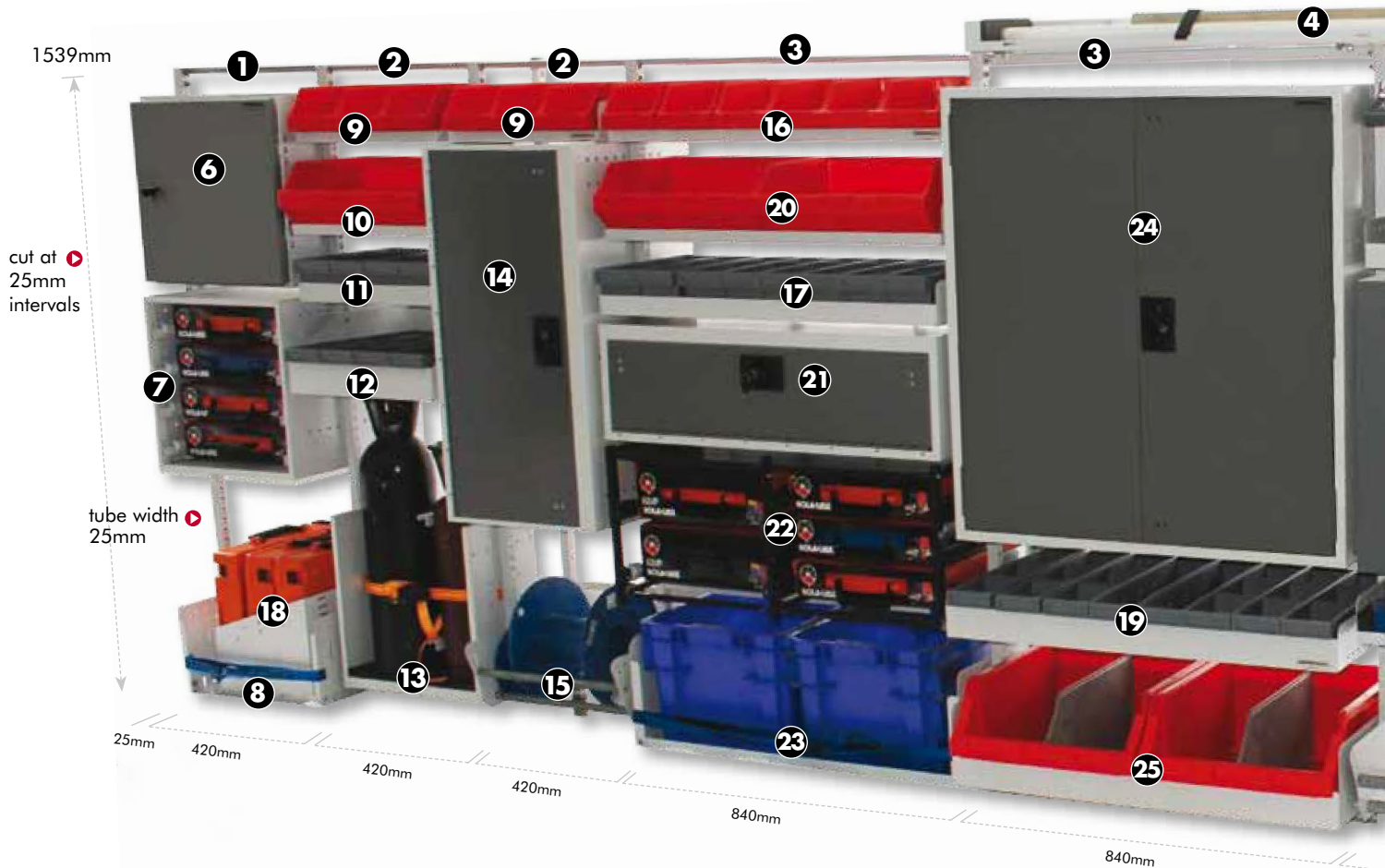

- |    |              |   |  |  |
|----|--------------|---|--|--|
| 1  | RSSFR/40     | 4 Series start frame  |  |  |
| 2  | RSEFR/40     | 4 Series extension frame  |  |  |
| 3  | RSEFR/80     | 8 Series extension frame  |  |  |
| 4  | RSRM/1       | Roof mount shelf  |  |  |
| 5  | RSEFR/HD/120 | 12 Series Heavy Duty extension frame  |  |  |
| 6  | RSGAC/41     | Vented Gas, Fuel, Oxy and Acetylene storage cabinet                             |  |  |
| 7  | RCSK6/C      | Rola-Case cabinet kit   |  |  |
| 8  | RSFLE/40     | Floor enclosure with removable front angle                                      |  |  |
| 9  | RSSHL/43     | High mount shelf with 3 x RP25 plastic bins                                     |  |  |
| 10 | RSSHL/44     | Mid mount shelf with 1 x RP120 plastic bin                                      |  |  |
| 11 | RSSHL/45     | Low mount shelf with 4 x RP100 plastic bins                                     |  |  |
| 12 | RSSHL/48     | Low/Floor mount shelf with 2 x 400x200 plastic bins                             |  |  |
| 13 | RSGBH/41     | Gas bottle holder (gas bottles not included)                                    |  |  |
| 14 | RSLBX/81     | Lockable box mounted vertically in 4 Series or horizontally in 8 Series frames. |  |  |
| 15 | RSCDH/41     | Adjustable cable drum holder  |  |  |
| 16 | RSSHL/83     | High mount shelf with 6 x RP25 plastic bins                                     |  |  |
| 17 | RSSHL/85     | Mid mount shelf with 8 x RP100 plastic bins                                     |  |  |
| 18 | RCBKE/3      | Holds 3 x RCO01 cases (Includes rubber mat & strap)                             |  |  |
| 19 | RSSHL/88     | Low mount shelf with 8 x RP400x100 plastic bins                                 |  |  |
| 20 | RSSHL/84     | Mid mount shelf with 2 x RP120 plastic bins                                     |  |  |
| 21 | RSLBX/84     | Lockable box mounted horizontally in 8 Series                                   |  |  |
| 22 | RCDK3/2      | Rola-Case frame kit with RSBAR support bar                                      |  |  |
| 23 | RSFLE        | Floor enclosure with removable front angle & strap (buckets not included)       |  |  |
| 24 | RSCAB/81     | Large 3 shelf lockable cabinet with space-saving contoured body                 |  |  |
| 25 | RSSHL/86     | Floor mount shelf with 2 x RP240 plastic bins (plastic dividers not included)   |  |  |
| 26 | RSSHL/85     | Low mount shelf with RSSHL/81/FR file retainer                                  |  |  |
| 27 | RCDK5-4/C    | Rola-Case cabinet kit with 2 x RC5D doors                                       |  |  |
| 28 | RSSHL/87     | Low mount shelf with 2 x Rola-Cases   |  |  |
| 29 | RSCDH/81     | Adjustable cable drum holder (cable drums not included)                         |  |  |
| 30 | RSSHL/123    | High mount shelf with 9 x RP25 plastic bins                                     |  |  |
| 31 | RSSHL/124    | Mid mount shelf with 3 x RP120 plastic bins                                     |  |  |
| 32 | RSSHL/125    | Low mount shelf with 12 x RP100 plastic bins                                    |  |  |
| 33 | RSSHL/128    | Low mount shelf with 6 x RP400x200 plastic bins                                 |  |  |
| 34 | RSSHL/126    | Floor mount shelf with 3 x RP240 plastic bins                                   |  |  |
| 35 | RSVFTH       | Vertical Fluorescent Tube Holder, Holds standard tubes up to 36W                |  |  |

**Disclaimer** If any product is installed incorrectly or used in an incorrect manner, no liability will be taken for product malfunction or personal injury.

ed, tested and manufactured in Australia since 1985

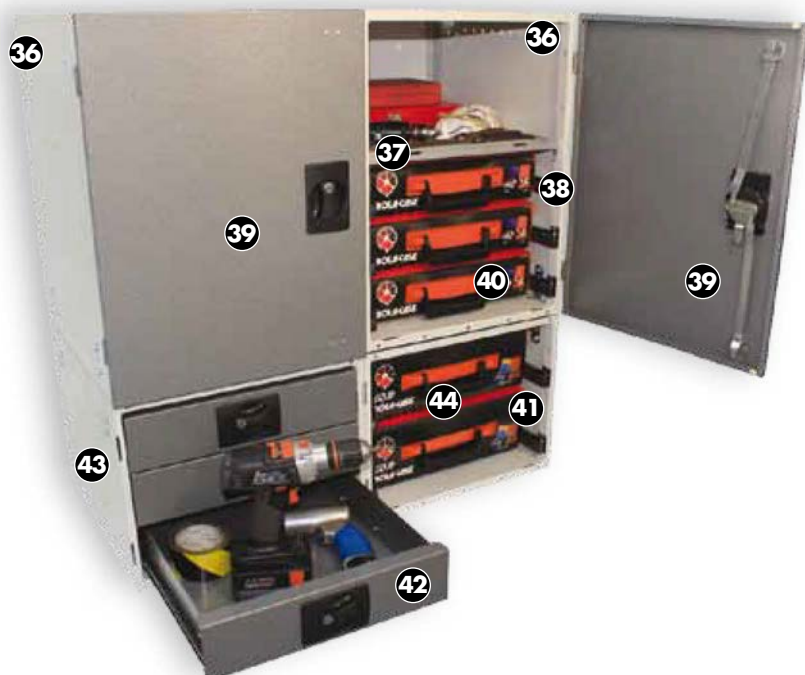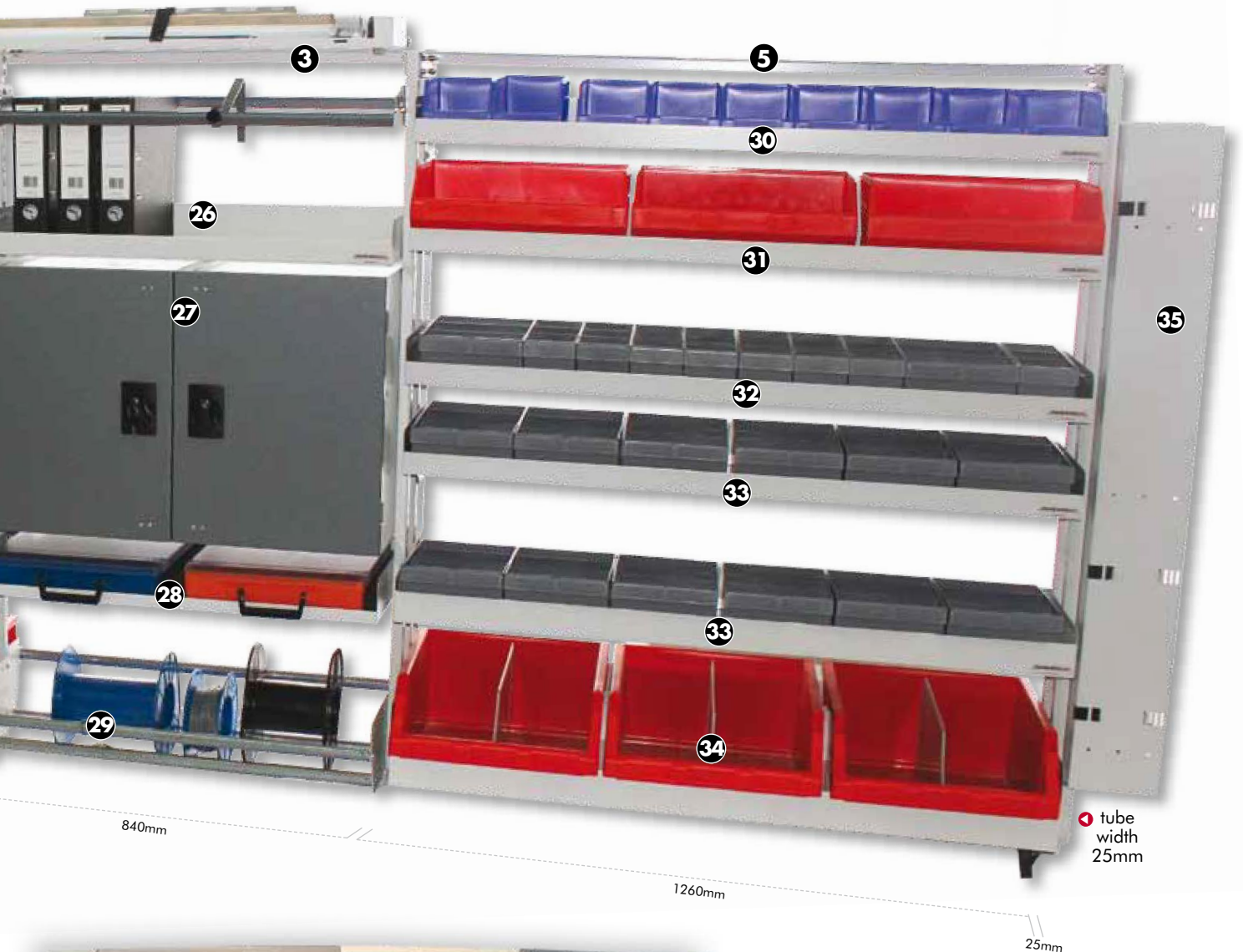


▲ The configuration of shelves and plastic bins depicted above allows for storage of large, medium and small components typical of today's tradesman and technician's requirements.

**ROLA-Shelf** will fit all vehicles where shelving is required including; commercial vans, canopy enclosures, 4WDs and station wagons.

- |    |          |   |
|----|----------|---|
| 36 | RC5      | 2 x Rola-Case Cabinet                         |
| 37 | RCCS     | 1 x Shelf to fit Rola-Case Cabinet            |
| 38 | RCCRG    | 3 x Carriage set                              |
| 39 | RC5D     | 2 x Door to fit RC5                           |
| 40 | RC001    | 3 x Rola-Case with 20 adjustable compartments |
| 41 | RC3DC/2D | Rola-Case Drawer Cabinet                      |
| 42 | RC401    | 3 x Metal drawers                             |
| 43 | RC3      | Rola-Case Cabinet                             |
| 44 | RC003    | 2 x Rola-Cases                                |


# Contents

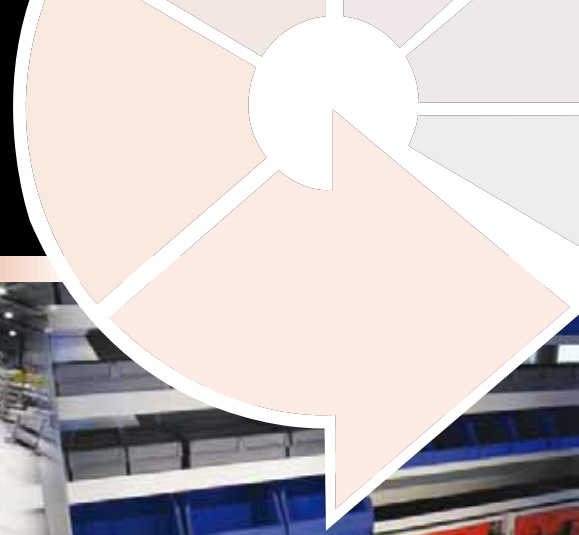


|   |    |                             |       |
|---|----|-----------------------------|-------|
| 12 Series Shelving.....                         | 1  | Multi-purpose Kits.....     | 14    |
| 10 Series Shelving.....                         | 2  | Vehicle Flooring.....       | 15-16 |
| 8 Series Shelving.....                          | 3  | Sliding Platforms.....      | 17    |
| 8 Series Accessories Shelving.....              | 4  | Rola-Case Introduction..... | 18    |
| 4 Series Shelving.....                          | 5  | Cases.....                  | 19    |
| End Panels & Accessories.....                   | 6  | Drawer Cabinets.....        | 20    |
| Specialist Products.....                        | 7  | Cabinet Kits.....           | 21    |
| Cargo Barriers.....                             | 8  | Drawer Frames.....          | 22    |
| Vented Gas, Fuel, Oxy & Acetylene Cabinets..... | 9  | Frame Kits.....             | 23    |
| Dual Kits.....                                  | 10 | Cabinet Accessories.....    | 24    |
| 8 Series Kits.....                              | 11 | Metal Drawers.....          | 25-26 |
| 10 Series Kits.....                             | 12 | First Aid Kits.....         | 27    |
| 12 Series Kits.....                             | 13 |                             |       |



- Engineer designed, tested & manufactured ✓
- Adjustable Shelving ✓
- Custom Designs/Sizing ✓
- Suitable for all vehicle types ✓
- Multiple vehicle positions ✓
- Universal Anchor Kit ✓

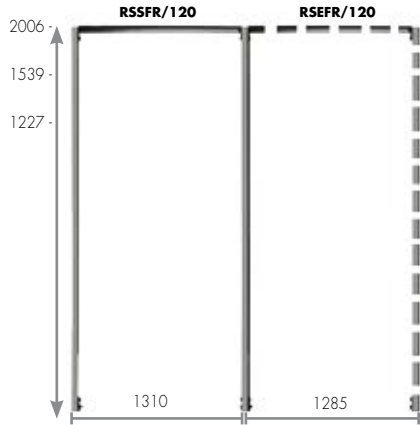

| CAT NO;             | HEIGHT (mm) | LENGTH (mm) | DESCRIPTION                                    |
|---------------------|-------------|-------------|--|
| <b>RSSFR/120</b>    | 1539        | 1310        | 12 Series Single Post Frame                    |
|                     | 1227        |             |  |
| <b>RSEFR/120</b>    | 1539        | 1285        | 12 Series Single Post Extension Frame          |
|                     | 1227        |             |  |
| <b>RSSFR/HD/120</b> | 2006        | 1310        | 12 Series Dual Post Heavy Duty Start Frame     |
|                     | 1539        |             |  |
|                     | 1227        |             |  |
| <b>RSEFR/HD/120</b> | 2006        | 1285        | 12 Series Dual Post Heavy Duty Extension Frame |
|                     | 1539        |             |  |
|                     | 1227        |             |  |

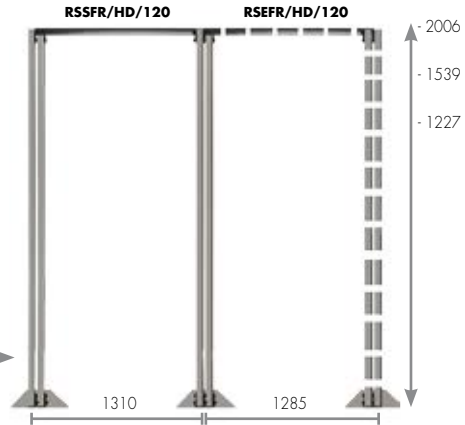


Frame Purchase Example: RSSFR/120/1227

| Post Height Adjustments |                               |
|-------------------------|-------------------------------|
| Height                  | Cut at 26mm Intervals Down To |
| 2006                    | 1539                          |
| 1539                    | 1073                          |
| 1227                    | 761                           |

Frame Purchase Example: RSSFR/HD/120/1539

All components are zinc annealed and powder coated, complete with instructions and mounting hardware

| SHELF  | CAT NO;          | DESCRIPTION       | HEIGHT (mm)           | LENGTH (mm) | WIDTH (mm) | INFORMATION                              |
|--|------------------|-------------------|-----------------------|-------------|------------|--|
|  | <b>RSSHL/123</b> | High mount shelf  | Rear 90/<br>front 45  | 1259        | 230        | Holds 9 x RP25 bins                      |
|  | <b>RSSHL/124</b> | Mid mount shelf   | Rear 90/<br>front 45  | 1259        | 255        | Holds 3 x RP120 bins                     |
|  | <b>RSSHL/125</b> | Low mount shelf   | Rear 90/<br>front 45  | 1259        | 305        | Holds 12 x RP100<br>or 6 x RP200 bins    |
|  | <b>RSSHL/126</b> | Floor mount shelf | Rear 168/<br>front 80 | 1259        | 405        | Holds 3 x RP240 bins                     |
|  | <b>RSSHL/127</b> | Low mount shelf   | Rear 90/<br>front 25  | 1259        | 377        | Holds 3 x RC001 Rola-Cases               |
|  | <b>RSSHL/128</b> | Floor mount shelf | Rear 90/<br>front 65  | 1259        | 405        | Holds 6 x RP400x200<br>or 12 x RP400x100 |


## Accessories for 12 Series

### RSWB/120



Mid mount work bench. 1.9mm galvanised steel  
To be used in conjunction with heavy duty frame only.

### RSLBX/122

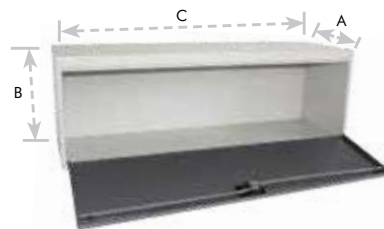


| CAT No.          | A mm | B mm | C mm |
|------------------|------|------|------|
| <b>RSLBX/122</b> | 400  | 420  | 1259 |

\*with TShelf /TF      with Full-Length Shelf /FLS

Example Order: RSLBX/122/TF


Lockable box for 12 Series shelving.  
Box and shelving construction: 0.9 and 1.1mm zinc annealed and powder coated.

Engineer designed, tested & manufactured ✓ Adjustable Shelving ✓ Custom Designs/Sizing ✓  
 Suitable for all vehicle types ✓ Multiple vehicle positions ✓ Universal Anchor Kit ✓

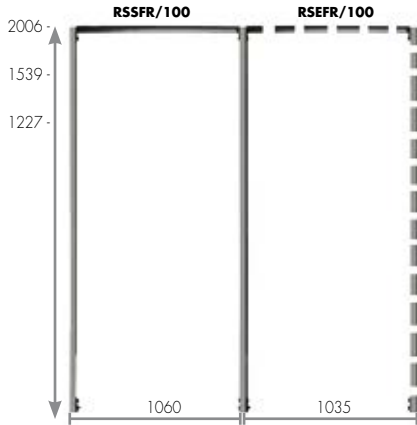

Frame Purchase Example: RSSFR/100/1227

| CAT NO;             | HEIGHT (mm) | LENGTH (mm) | DESCRIPTION                                    |
|---------------------|-------------|-------------|--|
| <b>RSSF/100</b>     | 1539        | 1060        | 10 Series Single Post Frame                    |
|                     | 1227        |             |  |
| <b>RSEFR/100</b>    | 1539        | 1035        | 10 Series Single Post Extension Frame          |
|                     | 1227        |             |  |
| <b>RSSF/HD/100</b>  | 2006        | 1060        | 10 Series Dual Post Heavy Duty Start Frame     |
|                     | 1539        |             |  |
|                     | 1227        |             |  |
| <b>RSEFR/HD/100</b> | 2006        | 1035        | 10 Series Dual Post Heavy Duty Extension Frame |
|                     | 1539        |             |  |
|                     | 1227        |             |  |

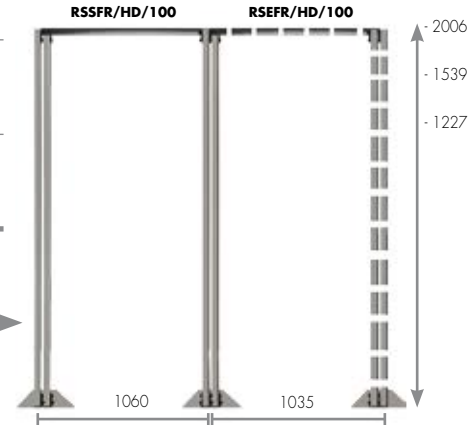

Frame Purchase Example: RSSFR/HD/100/1539


All components are zinc annealed and powder coated, complete with instructions and mounting hardware

| Post Height Adjustments |                               |
|-------------------------|-------------------------------|
| Height                  | Cut at 26mm Intervals Down To |
| 2006                    | ←→ 1539                       |
| 1539                    | ←→ 1073                       |
| 1227                    | ←→ 761                        |

| SHELF | CAT NO;          | DESCRIPTION       | HEIGHT (mm)           | LENGTH (mm) | WIDTH (mm) | INFORMATION                                |
|-------|------------------|-------------------|-----------------------|-------------|------------|--|
|       | <b>RSSHL/103</b> | High mount shelf  | Rear 90/<br>front 25  | 1009        | 200        | Holds 7 x RP25 bins                        |
|       | <b>RSSHL/104</b> | Mid mount shelf   | Rear 90/<br>front 25  | 1009        | 240        | Holds 1 x RS104RM (Rubber Mat)             |
|       | <b>RSSHL/105</b> | Low mount shelf   | Rear 90/<br>front 45  | 1009        | 305        | Holds 10 x RP100 or 5 x RP200 bins         |
|       | <b>RSSHL/106</b> | Floor mount shelf | Rear 168/<br>front 80 | 1009        | 405        | Holds 1 x RS106RM (Rubber Mat)             |
|       | <b>RSSHL/108</b> | Low mount shelf   | Rear 90/<br>front 65  | 1009        | 405        | Holds 10 x RP400x100 or 5 x RP400x200 bins |

## Accessories for 10 Series

### RSCDH/101

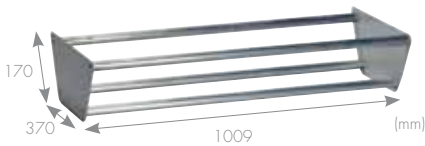


Adjustable Diameter Cable Drum Holder for 10 Series Shelving

### RSFLE/100



Floor Mount Enclosure with Removable Front Angle & Strap. Ideal for large bucket.


### RSWB/100

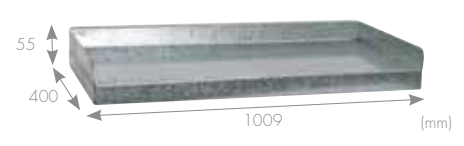

Mid Mount Work Bench  
1.9mm galvanized steel.  
To be used in conjunction with heavy duty frame only.




Engineer designed, tested & manufactured ✓ Adjustable Shelving ✓ Custom Designs/Sizing ✓  
 Suitable for all vehicle types ✓ Multiple vehicle positions ✓ Universal Anchor Kit ✓

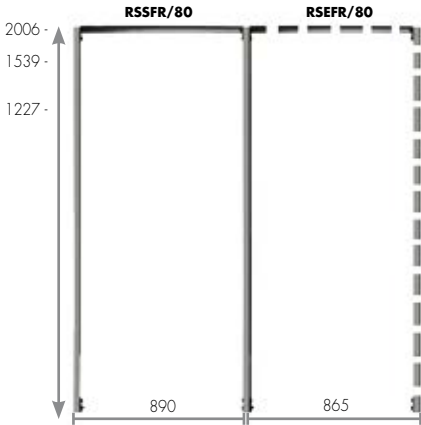

Frame Purchase Example: RSEFR/80/1227

| CAT NO;            | HEIGHT (mm) | LENGTH (mm) | DESCRIPTION                                   |
|--------------------|-------------|-------------|---|
| <b>RSSFR/80</b>    | 1539        | 890         | 8 Series Single Post Frame                    |
|                    | 1227        |             |   |
| <b>RSEFR/80</b>    | 1539        | 865         | 8 Series Single Post Extension Frame          |
|                    | 1227        |             |   |
| <b>RSSFR/HD/80</b> | 2006        | 890         | 8 Series Dual Post Heavy Duty Start Frame     |
|                    | 1539        |             |   |
|                    | 1227        |             |   |
| <b>RSEFR/HD/80</b> | 2006        | 865         | 8 Series Dual Post Heavy Duty Extension Frame |
|                    | 1539        |             |   |
|                    | 1227        |             |   |

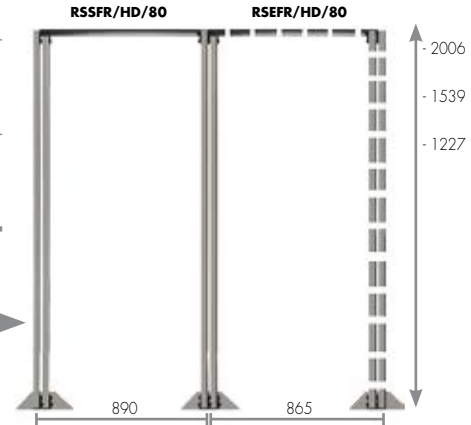

Frame Purchase Example: RSSFR/HD/80/1539


| Post Height Adjustments |                               |
|-------------------------|-------------------------------|
| Height                  | Cut at 26mm Intervals Down To |
| 2006                    | 1539                          |
| 1539                    | 1073                          |
| 1227                    | 761                           |

All components are zinc annealed and powder coated, complete with instructions and mounting hardware

| SHELF | CAT NO;         | DESCRIPTION       | HEIGHT (mm)           | LENGTH (mm) | WIDTH (mm) | INFORMATION                               |
|-------|-----------------|-------------------|-----------------------|-------------|------------|---|
|       | <b>RSSHL/83</b> | High mount shelf  | Rear 90/<br>front 25  | 839         | 200        | Holds 6 x RP25 bins                       |
|       | <b>RSSHL/84</b> | Mid mount shelf   | Rear 90/<br>front 25  | 839         | 240        | Holds 2 x RP120 bins                      |
|       | <b>RSSHL/85</b> | Low mount shelf   | Rear 90/<br>front 45  | 839         | 305        | Holds 8 x RP100 or 4 x RP200 bins         |
|       | <b>RSSHL/86</b> | Floor mount shelf | Rear 168/<br>front 80 | 839         | 405        | Holds 2 x RP240 bins                      |
|       | <b>RSSHL/87</b> | Low mount shelf   | Rear 90/<br>front 25  | 839         | 377        | Holds 2 x RCO01 Rola-Cases                |
|       | <b>RSSHL/88</b> | Floor mount shelf | Rear 90/<br>front 65  | 839         | 405        | Holds 8 x RP400x100 or 4 x RP400x200 bins |

## Accessories for 8 Series


### RSLBX/82

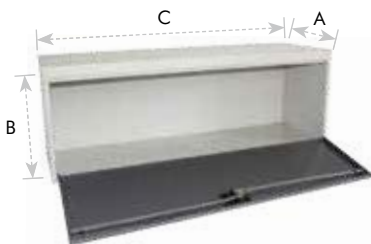


Lockable box for 8 series shelving  
Optional vertical mounting in 4 series frame.

| CAT No.         | A mm | B mm | C mm |
|-----------------|------|------|------|
| <b>RSLBX/82</b> | 400  | 420  | 839  |
| <b>RSLBX/84</b> | 400  | 250  | 839  |

 \*with T-Shelf




with Full-Length Shelf

 


Example Order:  
RSLBX/82/TF  
RSLBX/82/FLS

### RSLBX/84

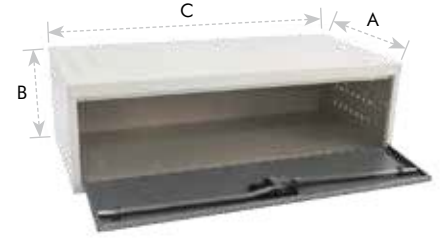

Lockable box for 8 series shelving

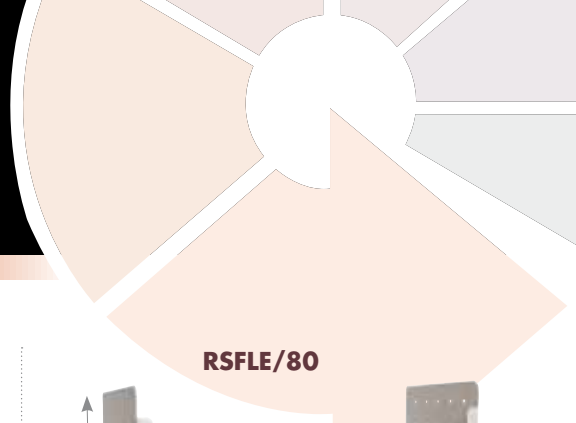


### RSCDH/81



Adjustable diameter cable drum holder  
Ideal for 8 Series shelving

### RSWB/80

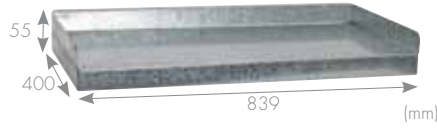

Mid mount work bench.  
1.9mm galvanised steel.  
To be used in conjunction with heavy duty frame only.

### RSFLE/80



Floor mount enclosure with  
removable front angle & strap  
Ideal for large bucket

### RSCAB/81



Large Lockable Cabinet with 3 fixed shelves.  
Designed to fit above wheel arch and contoured for vehicle.

### RSCAB/RS



**ROLA-Shelf** floor mounted lockable cabinet with smooth roller shutter door is  
contoured to fit all vehicles whilst providing a high level of security for cargo and goods.

\*Is compatible with other **ROLA-Shelf**  
8 Series frame systems


### RSSHL/80/3/15-20LT



**8 Series Fluid Storage Shelf**  
Holds 3 x 15 or 20 litre containers.  
Supplied with shelf and ratchet straps  
(bottles separate). Bottles and taps available.  
• Use exclusively with 8 series heavy duty frame  
• Shelf built to hold 60plus kg  
Installation by authorised installer recommended



### RSSHL/84/SP + RSFIS/20/500ML

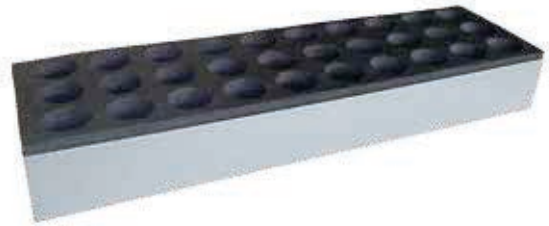

**8 Series Bottle Holder**  
8 Series Shelf & 20x500ml Bottle Holder  
Other sizes and shapes available

### RSSHL/84/SP + RSFIS/5/5LT



8 Series Shelf & 5 x 5 Litre Bottle Holder

### RSSHL/84/SP





Mid Mount Shelf  
Holds: RSFIS inserts

### RSSHL/81/FR




File Retainer  
Compatible with 4 series shelving (RSSHL/41/FR)  
Fitted in conjunction with: RSSHL/45 & RSSHL/85

Engineer designed, tested & manufactured ✓ Adjustable Shelving ✓ Custom Designs/Sizing ✓  
 Suitable for all vehicle types ✓ Multiple vehicle positions ✓ Universal Anchor Kit ✓

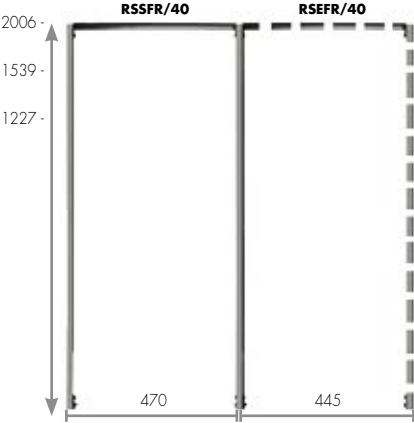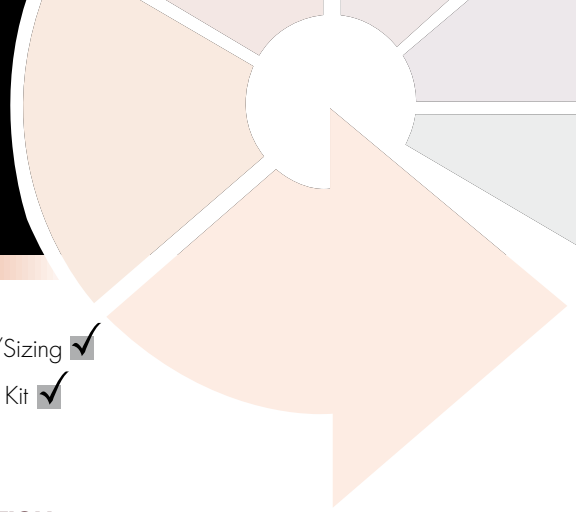

| CAT NO;            | HEIGHT (mm) | LENGTH (mm) | DESCRIPTION                                   |
|--------------------|-------------|-------------|---|
| <b>RSSF/40</b>     | 1539        | 470         | 4 Series Single Post Frame                    |
|                    | 1227        |             |   |
| <b>RSEFR/40</b>    | 1539        | 445         | 4 Series Single Post Extension Frame          |
|                    | 1227        |             |   |
| <b>RSSF/HD/40</b>  | 2006        | 470         | 4 Series Dual Post Heavy Duty Start Frame     |
|                    | 1539        |             |   |
|                    | 1227        |             |   |
| <b>RSEFR/HD/40</b> | 2006        | 445         | 4 Series Dual Post Heavy Duty Extension Frame |
|                    | 1539        |             |   |
|                    | 1227        |             |   |

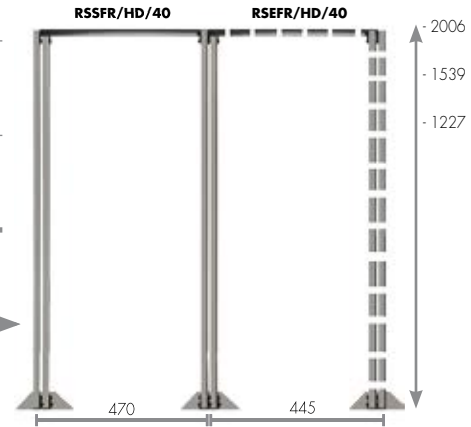


Frame Purchase Example: RSSFR/40/1227

Frame Purchase Example: RSSFR/HD/40/1539


| Post Height Adjustments |                               |
|-------------------------|-------------------------------|
| Height                  | Cut at 26mm Intervals Down To |
| 2006                    | 1539                          |
| 1539                    | 1073                          |
| 1227                    | 761                           |

All components are zinc annealed and powder coated, complete with instructions and mounting hardware

| SHELF  | CAT NO;         | DESCRIPTION           | HEIGHT (mm)           | LENGTH (mm) | WIDTH (mm) | INFORMATION                                |
|--|-----------------|-----------------------|-----------------------|-------------|------------|--|
|  | <b>RSSHL/43</b> | High mount shelf      | Rear 90/<br>front 25  | 419         | 200        | Holds 3 x RP25 bins                        |
|  | <b>RSSHL/44</b> | Mid mount shelf       | Rear 90/<br>front 25  | 419         | 240        | Holds 1 x RP120 bins                       |
|  | <b>RSSHL/45</b> | low mount shelf       | Rear 90/<br>front 45  | 419         | 305        | Holds 4 x RP100<br>or 2 x RP200 bins       |
|  | <b>RSSHL/46</b> | Floor mount shelf     | Rear 168/<br>front 80 | 419         | 405        | Holds 1 x RP240 bins                       |
|  | <b>RSSHL/48</b> | Low/Floor mount shelf | Rear 90/<br>front 65  | 419         | 405        | Holds 4 x RP400x100<br>or 2 x 400x200 bins |


## Accessories for 4 Series

### RSGBH/41

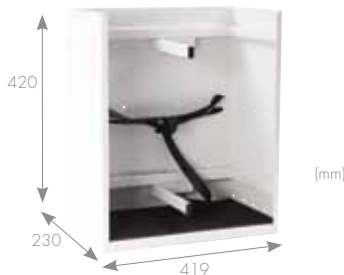


Gas bottle holder for oxy acetylene or small bottles. Includes rubber mat and strap.

### RSFLE

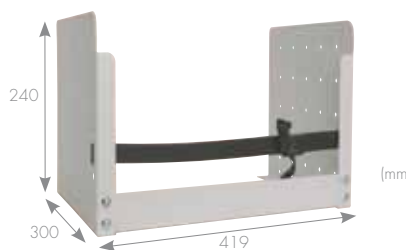

Floor mount enclosure with removable front angle & strap.


### RSCDH/41

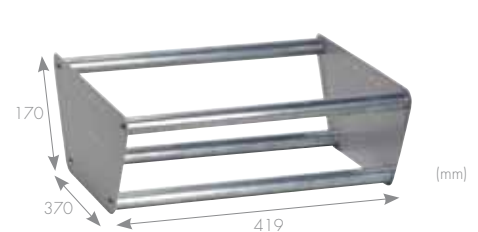

Adjustable diameter cable drum holder for 4 Series shelving.

## END PANELS

Construction: 1.1 mm zinc coated steel  
All Fixing Components Included.

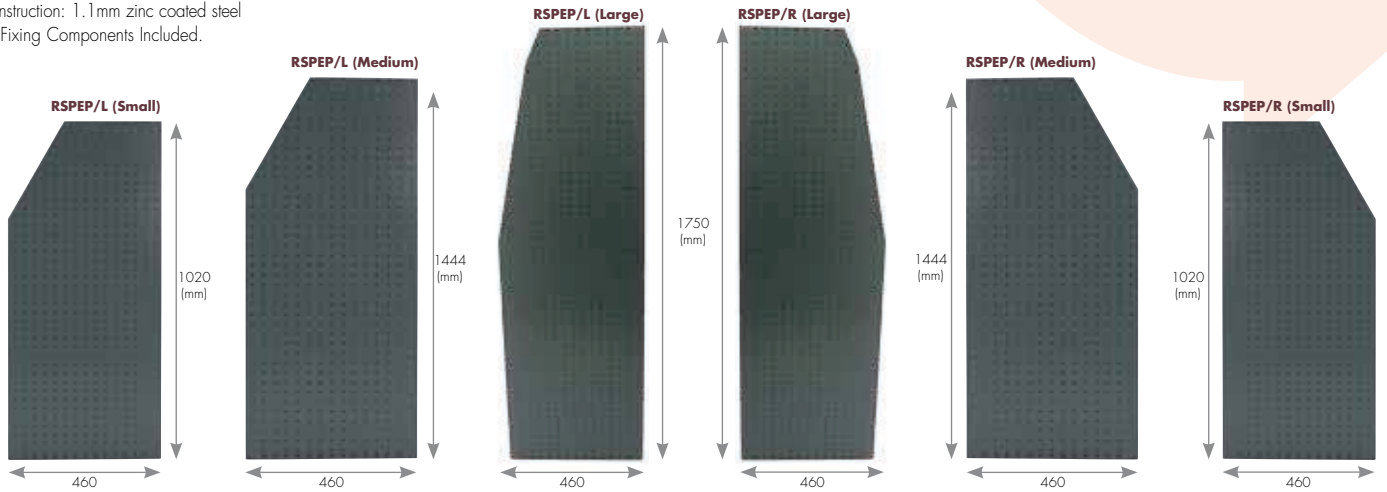


### RSPEP/PH



Paper Holder - Attaches to rack and holds rolls of paper

### RSPEP/HK

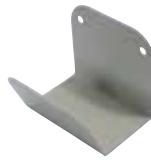

Lead Hook - Holds extension leads, hoses, etc.

### RSPEP/MH



Tool Rack - Holds tools of different shapes and sizes.

### RSPEP/TY



Tool Tray - Holds loose tools and / or equipment.

### JERRY CAN



High Density Polyethylene  
Lightweight/Un-breakable  
Non-Corroding

### RCVCH



Vertical Case Holder. Holds RC001, RC002 or RC003 series cases. Ideal for wall or end panel mounting.  
H - 150mm, W - 370mm.

### RSPEP/WBH




Water Bottle Holder  
Comes with 10L Bottle, Extendable Tap with 3 metres of flexible hose & accessories for plumbing

### HAND CLEANER




Hygienic anti-bacterial foaming soap dispenser for skin cleansing

### RP25

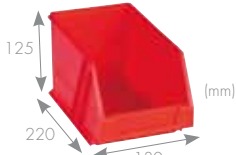


Small Plastic Bin  
1 Compartment

### RP60

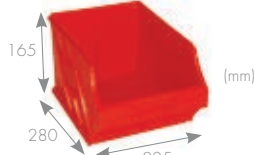


Med Plastic Bin  
1 Compartment

### RP120

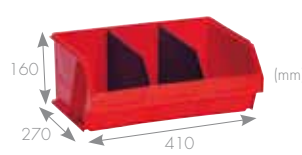


Large Plastic Bin  
3 Adjustable Compartments

### RP240

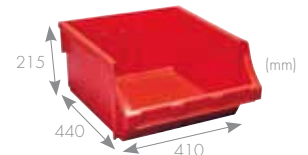

X - Large Plastic Bin  
3 Adjustable Compartments

### RP100

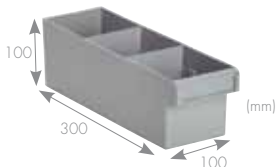

Small Plastic Bin  
3 Adjustable Compartments

### RP200



Med Plastic Bin  
3 Adjustable Compartments

### RP400X100




Large Plastic Bin  
3 Adjustable Compartments

### RP400X200



Large Plastic Bin  
3 Adjustable Compartments

## RS/RS

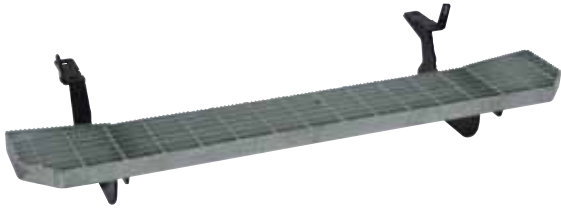

Galvanised Rear Step  
Illustration depicts Toyota HiAce step  
Available for vehicle types including Iload & Volkswagen

## RSBAR/40



RSBAR/80  
RSBAR/100

Mounting bar for **ROLA-CASE** dual frames and dual kits to fit within 8 series frames.

## RSBAR/120



To support 12 series shelves where additional loading may occur. (Excessive loading may result in product failure and will void product warranty - consult a dealer/manufacturer)

## RSRM/1



Roof Mount Shelf with felt inlay, foam end inserts and Velcro straps. Construction: 1.1mm zinc sealed and powder coated. Width 200mm, Length 1820mm, Height 60mm. To fit above **ROLA-Shelf** frame.

## RSGBH/9KG



9kg Gas Bottle Holder. Comes with vibration insert, rubber pinch-weld and strap. Floor mount.

Dimensions:  
Width 375mm  
Depth 335mm  
Height 295mm

\*Gas Bottle Not Included

## RSJCH/2



Double Jerry Can Holder

Dimensions:  
Width 360mm  
Depth 385mm  
Height 390mm

\*Jerry Cans Sold Separately

## RSJCH/3



Triple Jerry Can Holder

Dimensions:  
Width 540mm  
Depth 385mm  
Height 390mm

\*Jerry Cans Sold Separately

## ROLA-Shelf ANCHORAGE REINFORCEMENT

### 1. RSRB/CR2

Universal cant rail reinforcement bracket.



### 2. RSIB

Horizontal inertia bracket.



## RSVICE

Separate vice with 100mm jaw.

## RSSLDV

Sliding vice assembly with 800mm travel.



## RSSLDV/ELV

Elevated Vice with 600mm travel.



278 (mm)

## RSFTH/1



Vertical Fluorescent Tube Holder. Holds all standard tubes up to 36W.

Comes complete with Velcro security straps and foam cushion.

Dimensions:  
Width 160mm  
Depth 160mm  
Height 1250mm

## INSTALLATION KIT/PACKAGING


All products are packaged and supplied complete with comprehensive do it yourself (d.i.y.) instructions, or ask your local distributor for a complete install service.




Our complete range of cargo barriers and security screens for commercial and passenger vehicles offers further solutions for today's travelling tradesmen and technicians.

The range includes end barriers which are able to integrate with the **ROLA-Shelf** range, a cargo barrier and also security screens for property protection within the vehicle.

The end barriers below are able to integrate with the **ROLA-Shelf** range of frames.

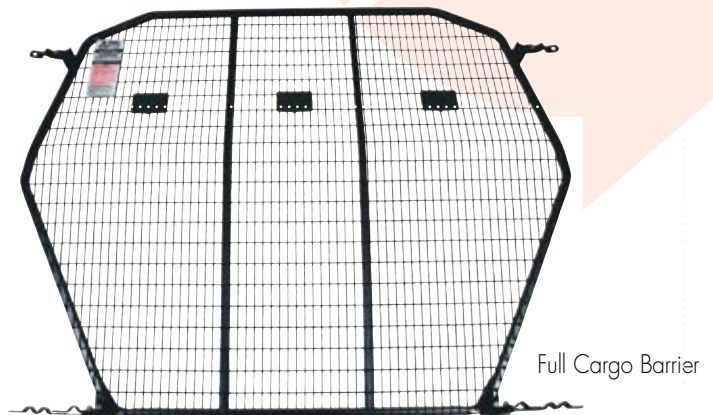


**RSEB/1**

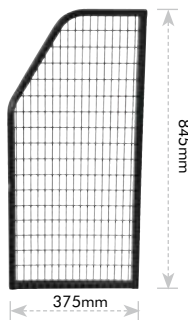


End Barrier  
3/4 height to fit end of **ROLA-Shelf** frame.

**RSEB/2**

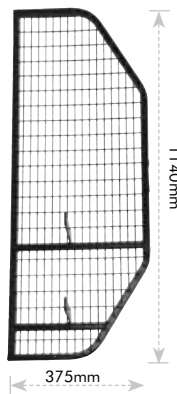


End Barrier  
Able to fasten oxy acetylene or similar sized bottles.  
To fit end of **ROLA-Shelf** frame.  
Ratchet strap included. For use with oxy-acetylene bottles.

**RSEB/3**

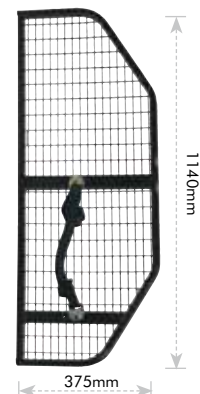


End Barrier  
Comes with strap to hold step ladders etc.  
Reversible for both sides of vehicle.  
To fit end of **ROLA-Shelf** frame.

**RSWSC/TRW**

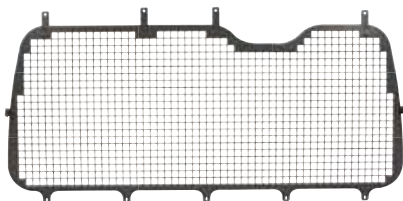

Security Screen for added property protection  
To fit the rear window of a Toyota HiAce Van  
(Other vehicle types available)

**RSWSC/TSD**

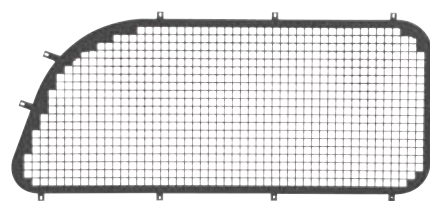

Security Screen for added property protection  
To fit the side window of a Toyota HiAce Van  
(Other vehicle types available)

**RSJCS**



Triple Jerry Can Support  
3mm construction

**RSTBS**



Tool Box Support  
3mm construction

**RSVS**



Slide Vice Support  
3mm construction

## ROLA•CASE Vented Gas, Fuel, Oxy and Acetylene Storage Cabinets

ROLA•CASE gas bottle holder/cabinets come in a variety of sizes from small LPG cylinders through to D and E size Oxy/Acetylene cylinders that comply with OH&S requirements. The durable, corrosion-proof material prevents internal damage whilst allowing for easy removal and replacement.

Cabinets are suitable for all trade vehicles and all industry applications.

### Gas Cabinet Features

- Rubber inserts
- Adjustable securing straps
- Door hinged swing left or right
- Fully sealed with exterior ventilation
- Supplied with fittings for multiple use
- Independent floor mounting
- Supplied with safety and warning signage

#### RSGAC-41.5



General Purpose Cabinet  
Fits RSPEP End Panel & HD/E Frames  
W - 210mm, D - 285mm, H - 416mm

#### RSGAC-41.5 x 2



Fits RSPEP End Panel & HD/E Frames  
W - 420mm, D - 285mm, H - 416mm

#### RSGAC-41



General Purpose Cabinet  
W - 419mm, D - 310mm, H - 445mm

#### RSGAC-43



Ideal for 9KG Gas Bottle  
W - 420mm, D - 375mm, H - 600mm

#### RSGAC-42.5



Single Oxygen or Acetylene Cabinet  
W - 223mm, D - 249mm, H - 702mm

#### RSGAC-42



Oxygen or Acetylene Cabinet  
W - 419mm, D - 310mm, H - 925mm

#### RSGAC-44



C - 462mm, B - 610mm, A - 1246mm

#### RSGAC/TT



Shelf to fit ROLA•Shelf gas cabinets.  
Shelf construction: 0.9mm zinc annealed and powder coated.

## The complete answer to vehicle shelving


The Australian-Made **ROLA-Shelf** range of pre-configured vehicle shelving kits offer an indicative variety of storage choices and budgets for plumbers, electricians and service technicians to suit all vehicle types.

Our trained sales team and nationally appointed distributors will interpret your vehicle storage requirements and will be able to offer a range of Cabinets, Shelves and Drawer Systems that will precisely meet your vehicle storage needs.

Alternatively, a **ROLA-Shelf** kit can be customised to fit your vehicle or application. - Ask your local dealer or contact **ROLA-Shelf** directly for further info.

All kits available in Heavy-Duty (HD) or Economy (E). All frames and end panels are powder coated


### RSKIT1/HD

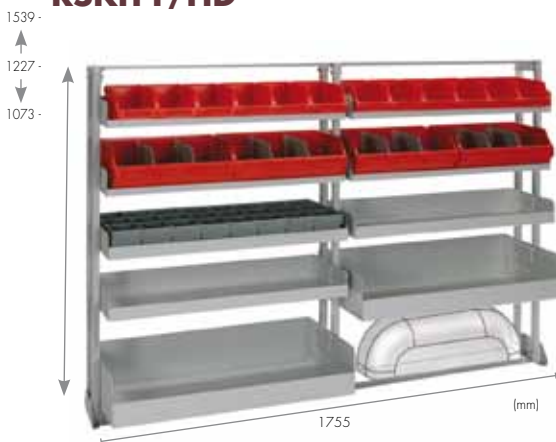

#### Includes

- Powder Coated Heavy Duty Frame
- Shelves Include:
  - 2 x RSSHL/83
  - 2 x RSSHL/84
  - 3 x RSSHL/85
  - 2 x RSSHL/86
- Bins Include:
  - 12 x RP25
  - 4 x RP120
  - 8 x RP100

### RSKIT1/E

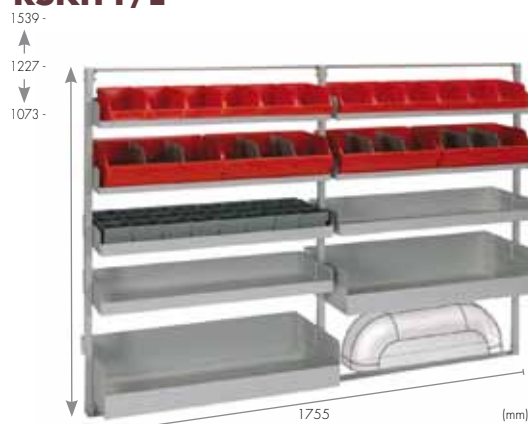

#### Includes

- Powder Coated Standard Frame
- Shelves Include:
  - 2 x RSSHL/83
  - 2 x RSSHL/84
  - 3 x RSSHL/85
  - 2 x RSSHL/86
- Bins Include:
  - 12 x RP25
  - 4 x RP120
  - 8 x RP100

### RSKIT2/HD



#### Includes

- Powder Coated Heavy Duty Frame
- Cam Buckle Strap
- Floor Mount Enclosure - RSFLE/80
- Shelves Include:
  - RSSHL/83, RSSHL/84, RSSHL/85, RSSHL/86, RSSHL/123, RSSHL/124, RSSHL/125, RSSHL/128
- Bins Include:
  - 15 x RP25
  - 5 x RP120
  - 12 x RP100

### RSKIT2/E



#### Includes

- Powder Coated Standard Frame
- Cam Buckle Strap
- Floor Mount Enclosure - RSFLE/80
- Shelves Include:
  - RSSHL/83, RSSHL/84, RSSHL/85, RSSHL/86, RSSHL/123, RSSHL/124, RSSHL/125, RSSHL/128
- Bins Include:
  - 15 x RP25
  - 5 x RP120
  - 12 x RP100

### RSKIT3/HD



#### Includes

- Powder Coated Heavy Duty Frame
- Adjustable Cable Drum Holder - RSCDH/81
- Complete Lockable Box - RSLBX/82
- Shelves Include:
  - 2 x RSSHL/83
  - 1 x RSSHL/84
  - 1 x RSSHL/85
  - 2 x RSSHL/88
- Bins Include:
  - 12 x RP25
  - 8 x RP100
  - 2 x RP120

### RSKIT3/E



#### Includes

- Powder Coated Standard Frame
- Adjustable Cable Drum Holder - RSCDH/81
- Complete Lockable Box - RSLBX/82
- Shelves Include:
  - 2 x RSSHL/83
  - 1 x RSSHL/84
  - 1 x RSSHL/85
  - 2 x RSSHL/88
- Bins Include:
  - 12 x RP25
  - 8 x RP100
  - 2 x RP120



These kits are available in Heavy-duty (HD) or Economy (E) classes. All frames and End Panels are Powdercoated.

Suitable for all vehicles ✓ Adjustable Shelving ✓ Complete with Anchor & Fitment Kit ✓ Multiple Vehicle Position Options ✓

| Post Height Adjustments |                               |
|-------------------------|-------------------------------|
| Height                  | Cut at 26mm Intervals Down To |
| 1539                    | 1073                          |

## RSKIT8/E



- Includes**
- 1 x Powder Coated Frame
  - Shelves Include:
    - RSSHL/83
    - RSSHL/84
    - RSSHL/88
    - RSSHL/86

## RSKIT8/E/B



- Includes**
- 1 x Powder Coated Frame
  - Shelves Include:
    - RSSHL/83
    - RSSHL/84
    - RSSHL/88
    - RSSHL/86
  - Bins Include:
    - 6 x RP25
    - 2 x RP120
    - 4 x RP400x200
    - 2 x RP240

## RSKIT8/HD



- Includes**
- 1 x Powder Coated Heavy Duty Frame
  - Shelves Include:
    - RSSHL/83
    - RSSHL/84
    - RSSHL/88
    - RSSHL/86

## RSKIT8/HD/B



- Includes**
- 1 x Powder Coated Heavy Duty Frame
  - Shelves Include:
    - RSSHL/83
    - RSSHL/84
    - RSSHL/88
    - RSSHL/86
  - Bins Include:
    - 6 x RP25
    - 2 x RP120
    - 4 x RP400x200
    - 2 x RP240

## RSKIT8/HD/EP



- Includes**
- 1 x Powder Coated Heavy Duty Frame
  - 1 x End Panel
  - 2 x Hook
  - 1 x Tool Holder
  - Shelves Include:
    - RSSHL/83
    - RSSHL/84
    - RSSHL/88
    - RSSHL/86

## RSKIT8/HD/EP/B



- Includes**
- 1 x Powder Coated Heavy Duty Frame
  - 1 x End Panel
  - 2 x Hook
  - 1 x Tool Holder
  - Shelves Include:
    - RSSHL/83
    - RSSHL/84
    - RSSHL/88
    - RSSHL/86
  - Bins Include:
    - 6 x RP25
    - 2 x RP120
    - 4 x RP400x200
    - 2 x RP240

# ROLA-Shelf 10 Series Kits

VEHICLE STORAGE SOLUTIONS

These kits are available in Heavy-duty (HD) or Economy (E) classes. All frames and End Panels are Powdercoated.

Suitable for all vehicles ✓ Adjustable Shelving ✓ Complete with Anchor & Fitment Kit ✓ Multiple Vehicle Position Options ✓

| Post Height Adjustments |                               |
|-------------------------|-------------------------------|
| Height                  | Cut at 26mm Intervals Down To |
| 1539                    | ↔ 1073                        |

## RSKIT10/E



- Includes**
- 1 x Powder Coated Frame
  - Shelves Include:
    - RSSHL/103
    - RSSHL/105
    - RSSHL/108
    - RSSHL/106

## RSKIT10/E/B



- Includes**
- 1 x Powder Coated Frame
  - Shelves Include:
    - RSSHL/103
    - RSSHL/105
    - RSSHL/108
    - RSSHL/106
  - Bins Include:
    - 7 x RP25
    - 5 x RP200
    - 5 x RP400x200

## RSKIT10/HD




- Includes**
- 1 x Powder Coated Heavy Duty Frame
  - Shelves Include:
    - RSSHL/103
    - RSSHL/105
    - RSSHL/108
    - RSSHL/106

## RSKIT10/HD/B




- Includes**
- 1 x Powder Coated Heavy Duty Frame
  - Shelves Include:
    - RSSHL/103
    - RSSHL/105
    - RSSHL/108
    - RSSHL/106
  - Bins Include:
    - 7 x RP25
    - 5 x RP200
    - 5 x RP400x200

## RSKIT10/HD/EP

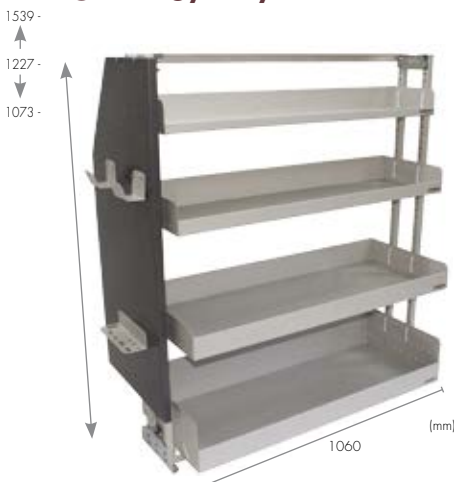

- Includes**
- 1 x Powder Coated Heavy Duty Frame
  - 1 x End Panel
  - 2 x Hook
  - 1 x Tool Holder
  - Shelves Include:
    - RSSHL/103
    - RSSHL/105
    - RSSHL/108
    - RSSHL/106

## RSKIT10/HD/EP/B

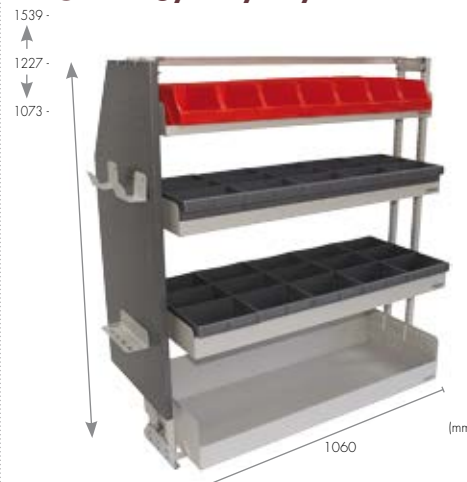

- Includes**
- 1 x Powder Coated Heavy Duty Frame
  - 1 x End Panel
  - 2 x Hook
  - 1 x Tool Holder
  - Shelves Include:
    - RSSHL/103
    - RSSHL/105
    - RSSHL/108
    - RSSHL/106
  - Bins Include:
    - 7 x RP25
    - 5 x RP200
    - 5 x RP400x200

# ROLA-Shelf 12 Series Kits

VEHICLE STORAGE SOLUTIONS

These kits are available in Heavy-duty (HD) or Economy (E) classes. All frames and End Panels are Powdercoated.

Suitable for all vehicles ✓ Adjustable Shelving ✓ Complete with Anchor & Fitment Kit ✓ Multiple Vehicle Position Options ✓

| Post Height Adjustments |                               |
|-------------------------|-------------------------------|
| Height                  | Cut at 26mm Intervals Down To |
| 1539                    | 1073                          |

## RSKIT12/E



- Includes**
- 1 x Powder Coated Frame
  - Shelves Include:
    - RSSHL/123
    - RSSHL/124
    - RSSHL/128
    - RSSHL/126

## RSKIT12/E/B



- Includes**
- 1 x Powder Coated Frame
  - Shelves Include:
    - RSSHL/123
    - RSSHL/124
    - RSSHL/128
    - RSSHL/126
  - Bins Include:
    - 9 x RP25
    - 3 x RP120
    - 6 x RP400x200
    - 3 x RP240

## RSKIT12/HD




- Includes**
- 1 x Powder Coated Heavy Duty Frame
  - Shelves Include:
    - RSSHL/123
    - RSSHL/124
    - RSSHL/128
    - RSSHL/126

## RSKIT12/HD/B



- Includes**
- 1 x Powder Coated Heavy Duty Frame
  - Shelves Include:
    - RSSHL/123
    - RSSHL/124
    - RSSHL/128
    - RSSHL/126
  - Bins Include:
    - 9 x RP25
    - 3 x RP120
    - 6 x RP400x200
    - 3 x RP240

## RSKIT12/HD/EP

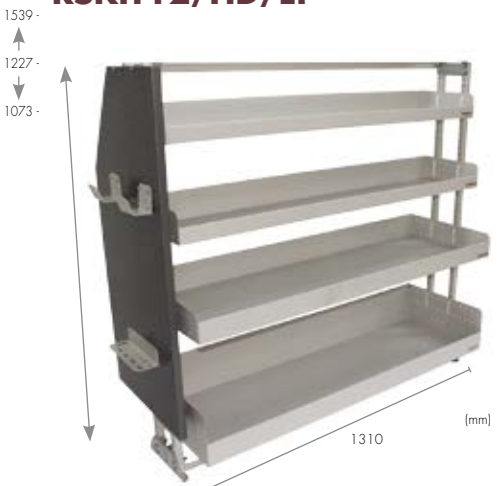

- Includes**
- 1 x Powder Coated Heavy Duty Frame
  - 1 x End Panel
  - 2 x Hook
  - 1 x Tool Holder
  - Shelves Include:
    - RSSHL/123
    - RSSHL/124
    - RSSHL/128
    - RSSHL/126

## RSKIT12/HD/EP/B



- Includes**
- 1 x Powder Coated Heavy Duty Frame
  - 1 x End Panel
  - 2 x Hook
  - 1 x Tool Holder
  - Shelves Include:
    - RSSHL/123
    - RSSHL/124
    - RSSHL/128
    - RSSHL/126
  - Bins Include:
    - 9 x RP25
    - 3 x RP120
    - 6 x RP400x200
    - 3 x RP240

These kits are available in Heavy-duty (HD) or Economy (E) classes. All frames and End Panels are Powdercoated.

Suitable for all vehicles ✓ Adjustable Shelving ✓ Custom Designs/Sizing ✓ Multiple Vehicle Position Options ✓


| Post Height Adjustments |                               |
|-------------------------|-------------------------------|
| Height                  | Cut at 26mm Intervals Down To |
| 1539                    | 1073                          |

## RSKIT4/E



- Includes**
- 1 x Powder Coated Frame (RSSFR/80)
  - Adjustable Cable Drum Holder
  - Shelves Include:
    - RSSHL/83
    - RSSHL/84
    - 3 x RSSHL/85
  - Bins Include:
    - 16 x RP100

## RSKIT5/HD

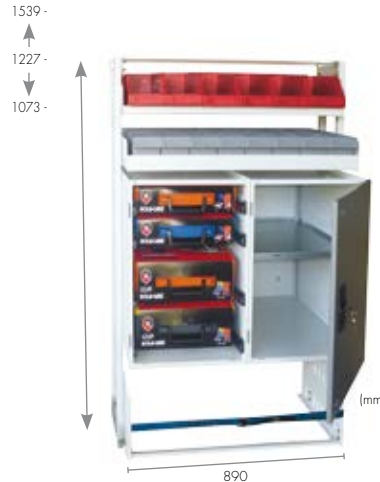

- Includes**
- 1 x Powder Coated Heavy Duty Frame (RSSFR/HD/80)
  - Cabinet Kit (RCSK5/C)
  - Rola Cabinet Shelf (RCCS)
  - Cabinet Door (RC5D)
  - Empty Cabinet (RC5)
  - Support Bar (RSBAR/80)
  - Floor Mount Enclosure (RSFLE)
  - Cam Buckle Strap
  - Shelves Include:
    - RSSHL/83
    - RSSHL/85
  - Bins Include:
    - 8 x RP100
    - 6 x RP25

## RSKIT6/HD




- Includes**
- 1 x Powder Coated Heavy Duty Frame (RSSFR/HD/80)
  - Lockable Box (RSLBX/82)
  - Shelves Include:
    - RSSHL/83
    - RSSHL/84
    - RSSHL/85
    - RSSHL/86
  - Bins Include:
    - 6 x RP25
    - 2 x RP120
    - 8 x RP100
    - 2 x RP240

## RSKIT7/HD



- Includes**
- 1 x Powder Coated Heavy Duty Frame (RSSFR/HD/80)
  - Cabinet Kit (RCDK3-2/C)
  - Support Bar (RSBAR/80)
  - Shelves Include:
    - RSSHL/83
    - RSSHL/84
    - RSSHL/85
    - RSSHL/86
  - Bins Include:
    - 6 x RP25
    - 2 x RP120
    - 8 x RP100
    - 2 x RP240

## RSKIT13/HD

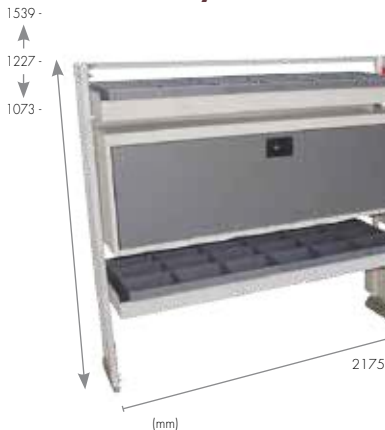

- Includes**
- 1 x Powder Coated Heavy Duty Frame
  - Complete Lockable Box RSLBX/122
  - Shelves Include:
    - 2 x RSSHL/125
    - RSSHL/83
    - RSSHL/84
    - RSSHL/86
    - RSSHL/88
  - Bins Include:
    - 6 x RP25
    - 16 x RP400x200
    - 2 x RP120
    - 2 x RP240

## RSKIT14/E




- Includes**
- 1 x Powder Coated Frame (RSSFR/80)
  - Shelves Include:
    - RSSHL/83
    - 2 x RSSHL/84
    - 2 x RSSHL/85
    - RSSHL/86
  - Bins Include:
    - 6 x RP25
    - 4 x RP120
    - 16 x RP100
    - 2 x RP240

**ROLA-Shelf** vehicle flooring is the ultimate way to protect and transform the interior of your van or ute from floor to ceiling; whilst improving the overall look of your vehicle.

### Timber Flooring


- Timber Options - 9, 12 or 17mm ply
- Engineered to fit each unique vehicle model
- Ideally used under rubber matting
- Simple Installation

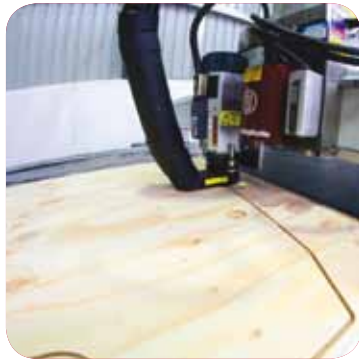

### Rubber Matting

- Non-Slip surface
- Designed for commercial use
- Rubber mats are available in economy 3.5 rubber & 5ml heavy duty big rib
- Ideal for vans, utes & sliding platforms
- Simple installation
- Chemical & oil resistant
- 5 year warranty



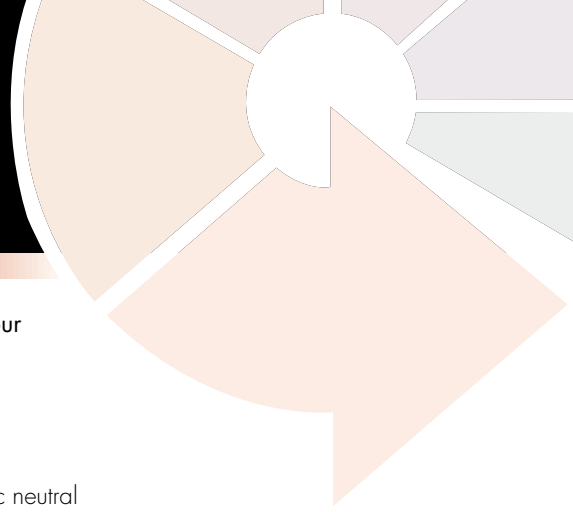

**ROLA-Shelf** vehicle flooring is the ultimate way to protect and transform the interior of your van or ute from floor to ceiling; whilst improving the overall look of your vehicle.

### Carpet Flooring - Marine Grade

- Engineered to repel & release stains/odours
- Petrol and oil resistant
- Specially designed indoor & outdoor carpet
- Shaped to vehicle model
- Non-zip or fray static neutral
- Environmentally friendly & UV stabilized
- Custom colours available
- Ideal for fitting over plywood flooring



### Advanced CNC Router Services


**ROLA-CASE** also offers the ultimate CNC routing service for consumers looking for a uniform & 100% accurate cutting service.

We cut all of the following materials to any shape or size:

- Metal
- Timber
- Composites
- Steel & Brass
- Plastics, MDF & Acrylics
- Foam, Polystyrene, Aluminium & PVC



All flooring is cut using our advanced CNC Router, Ensuring each cut is consistent with the contours of each vehicle model.

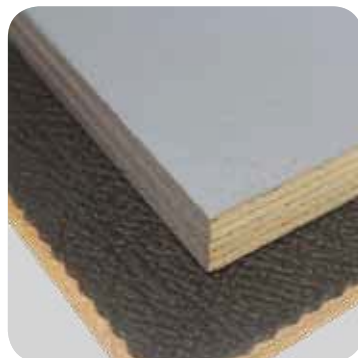

**ROLA-Shelf** sliding platforms are the ultimate way to maximise your loadability; whilst giving you instant access to tools and equipment without having to crawl in and out of your vehicle. Engineer designed, tested & manufactured in Australia for vehicle use, Ideal for van & ute canopy.

- Wide handle with one handed locking mechanism
- Quality powder coated steel
- Up to 7 position locking mechanism
- Ideal for curbside loading & unloading
- Easy installation & can be used with **ROLA-CASE** products
- Side rails & Tie down points
- Fitted to the side or rear door openings


**Optional Extras**

- Skid resistant rubber
- Plywood decking
- Ratchet Straps

## Single Slide Platform

100% Extendable


| PRODUCT CODE      | TRAVEL LENGTH (A) | HEIGHT (B) | WIDTH (C) | WEIGHT | LOAD RATING |
|-------------------|-------------------|------------|-----------|--------|-------------|
| <b>RSSPF/1300</b> | 1335              | 100        | 510       | 50 Kg  | 135 Kg      |
| <b>RSSPF/950</b>  | 950               | 100        | 510       | 38 Kg  | 160 Kg      |
| <b>RSSPF/500</b>  | 530               | 100        | 510       | 21 Kg  | 225 Kg      |

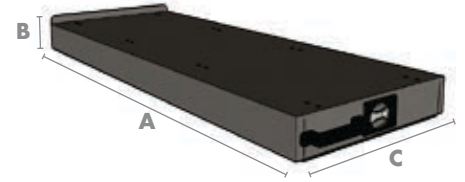

## Double Slide Platform

100% Extendable

| PRODUCT CODE      | TRAVEL LENGTH (A) | HEIGHT (B) | WIDTH (C) | WEIGHT | LOAD RATING |
|-------------------|-------------------|------------|-----------|--------|-------------|
| <b>RSEPF/1300</b> | 1335              | 100        | 1020      | 85 Kg  | 200 Kg      |
| <b>RSEPF/950</b>  | 950               | 100        | 1020      | 64 Kg  | 240 Kg      |
| <b>RSEPF/500</b>  | 530               | 100        | 1020      | 35 Kg  | 330 Kg      |

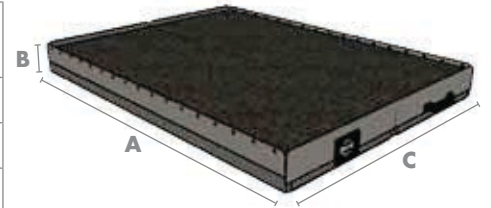



Find Your Solution,  
Case by Case.



**ROLA•CASE** is a versatile storage system for the transfer and handling of components, tools and instruments.

The range includes Mobile Work Stations that allow the movement of tools and equipment in a workshop or service area, plus the Drawer systems which are ideal for vehicle and static use. The Drawer systems are also compatible with the **ROLA•Shelf** vehicle storage system.

The Mobile Work Stations are available in 3 choices. The dual

mobile RC7DC/DM, and the single mobile RC7DC/SM, which are both suitable for continuous floor use, and the RC7DC/PN with pneumatic tires. The RC7DC/PN is suitable for stairs and uneven terrain like building sites, high rise and situations where distance and mobility are a factor. The Drawer systems offer an extensive selection of storage solutions that allows further expansion horizontally and or vertically when your storage needs arise.

The choice of cases and accessories will allow for storage of

the smallest micro components through to power tools and cordless equipment. A selection of Drawer kits to meet your storage needs is on page 21 and 23, or custom build from our Drawer systems on page 20 and 22.

The cases are manufactured from engineering polymers, ABS, Polycarbonate and Nylon 66. They are moulded with a 3–5mm wall section and use stainless steel for the hinge and latch-spring to ensure extended product life.



### RC001/CH-CL



Limited Edition charcoal case with clear lid. 20 adjustable compartments, 1 tool compartment in front of case. Dimensions: W - 370mm, D - 370mm, H - 85mm

### RC001/CH-CH



Limited Edition charcoal case with charcoal lid. 20 adjustable compartments, 1 tool compartment in front of case. Dimensions: W - 370mm, D - 370mm, H - 85mm

### RC001



20 adjustable compartments, 1 tool compartment in front of case. Dimensions: W - 370mm, D - 370mm, H - 85mm

### RC001/CL



20 adjustable compartments, 1 tool compartment in front of case. Polycarbonate lid. Dimensions: W - 370mm, D - 370mm, H - 85mm

### RC002



1 large compartment (will take RCFIS/2), 1 tool compartment in front of case. Dimensions: W - 370mm, D - 370mm, H - 85mm

### RC002/CL



1 large compartment (will take RCFIS/2), 1 tool compartment in front of case. Polycarbonate lid. Dimensions: W - 370mm, D - 370mm, H - 85mm

### RC003/QK



1 large compartment, plus 3 compartment lift-out tray with further compartments below, 1 tool compartment. Includes Quik Kit (QK001) Dimensions: W - 370mm, D - 370mm, H - 130mm

### RC003/CL



1 large tool compartment, plus 3 compartment lift-out tray and with further compartments below. Polycarbonate lid. Dimensions: W - 370mm, D - 370mm, H - 130mm. Accessories: RC003/D (3 dividers for case)

### RC003



1 large tool compartment, plus 3 compartment lift-out tray and with further compartments below. Dimensions: W - 370mm, D - 370mm, H - 130mm. Accessories: RC003/D (3 dividers for case)

### QK001



10 small compartments, 1 large tool compartment in front of case. Also available in clear QK001/CL. Dimensions: W - 310mm, D - 210mm, H - 50mm

### QK001/CL



### RCTRY



Small tray with 4 adjustable compartments. Suits RC001 series cases. Includes new clear micro component storage unit. 2 per carton. Dimensions: W - 70mm, L - 143mm, H - 75mm

### SPARE PARTS

#### RCJNR



Joins drawer vertically. (Set of 4).

#### RCPLD




Divider for RC001 cases

### RC003/D



Dividers to suit RC003 cases. Each case holds max. 3 dividers.

### RCFIS/2 and RCFIS/3

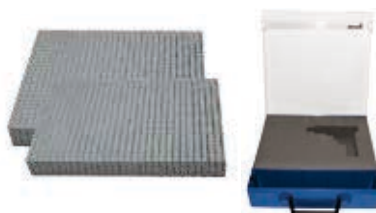

Foam insert. RCFIS/2 to fit RC002 Series cases. RCFIS/3 to fit RC003 Series cases.



RCTRY  
(Micro Storage)

## RC2DC



Holds 2 x RC001 or RC002 series cases  
 Dimensions: W - 419mm, D - 460mm, H - 230mm  
**RC2** - cabinet only  
**RC2D** - door only

## RC3DC



Holds 3 x RC001 or RC002 series cases  
 Dimensions: W - 419mm, D - 460mm, H - 325mm  
**RC3** - cabinet only  
**RC3D** - door only

## RC3DC/2D



Holds 2 x RC003 series cases  
 Dimensions: W - 419mm, D - 460mm, H - 325mm  
**RC3** - cabinet only  
**RC3D** - door only

## RC4DC



Holds 4 x RC001 or RC002 series cases  
 Dimensions: W - 419mm, D - 460mm, H - 420mm  
**RC4** - cabinet only  
**RC4D** - door only

## RC4DC/3D



Holds 2 x RC003 and 1 x RC001 series cases  
 Dimensions: W - 419mm, D - 460mm, H - 420mm  
**RC4** - cabinet only  
**RC4D** - door only

## RC5DC



Holds 5 x RC001 or RC002 series cases  
 Dimensions: W - 419mm, D - 460mm, H - 547mm  
**RC5** - cabinet only  
**RC5D** - door only

## RC5DC/4D



Holds 2 x RC001 or RC002 and 2 x RC003 series cases  
 Dimensions: W - 419mm, D - 460mm, H - 547mm  
**RC5** - cabinet only  
**RC5D** - door only

## RC7DC



Holds 7 x RC001 or RC002 series cases  
 Dimensions: W - 419mm, D - 540mm, H - 737mm  
**RC7** - cabinet only  
**RC7D** - door only

## RC7DC/PN



Trolley with 220mm pneumatic tires. Ideal for stairs or uneven surfaces. Holds 7 x RC001 or RC002 cases or a combination of RC001 and RC003 cases  
 Dimensions: W - 419mm, D - 540mm, H - 1000mm (total)  
**RC7** - cabinet only  
**RC7D** - door only

## RC7DC/SM



Holds 7 x RC001 or RC002 cases or a combination of RC001, RC002 & RC003 cases  
 Dimensions: W - 419mm, D - 540mm, H - 1000mm (total)  
**RC7** - cabinet only  
**RC7D** - door only

## RC7DC/DM



Holds up to 14 x RC001 or RC002 cases, or a combination of RC001 & RC003 cases.  
 Dimensions: W - 839mm, D - 460mm, H - 960mm (total) (Shelf not included)  
**RC7D** x 2 - door only

## RCBKE/2



Holds 2 x RC003 cases  
 Includes rubber mat and strap  
 Dimensions: W - 380mm, D - 290mm, H - 290mm

## RCBKE/3



Holds 3 x RC001 cases  
 Includes rubber mat and strap  
 Dimensions: W - 380mm, D - 290mm, H - 290mm

\*Cabinet construction: 0.9 to 1.1mm zinc annealed and powder coated steel.

Our **ROLA•CASE** cabinet kits offer an alternative to your **ROLA•CASE** storage needs. These cabinet kits are able to be fitted with lockable doors and shelves and can be joined vertically and/or horizontally to create nearly any modular configuration.

**RCSK1/C**



**RCSK2/C**



**RCSK3/C**



**RCSK4/C**



**RCSK5/C**



**RCSK6/C**



**RCSK7/C**



**RCSK8/C**



**RCSK7PN/C**



**RCSK7M/C**



**RCDK2/C**



**RCDK3/C**



**RCDK4/C**



**RCDK5/C**



**RCDK3-2/C**



**RCDK3-4/C**



**RCDK5-4/C**



**RCDK7M/C**



**2 x RC7D  
Doors**

**Note:**

Doors are also available for the cabinet kits (Supplied as depicted – no doors are included with kits. Order separately). Cabinet systems (shown left) are also available. All cabinets fit 4 and 8 Series **ROLA•Shelf**. All kits join vertically and horizontally.

**RC2FR**



Holds 2 x RC001 or RC002 series cases  
Dimensions: W - 419mm, D - 460mm, H - 250mm

**RC2FX**

Horizontal extension frame also available

**RC3FR**



Holds 3 x RC001 or RC002 series cases  
Dimensions: W - 419mm, D - 460mm, H - 350mm

**RC3FX**

Horizontal extension frame also available

**RC3FR/2D**



Holds 2 x RC003 series cases  
Dimensions: W - 419mm, D - 460mm, H - 350mm

**RC3FX/2D**

Horizontal extension frame also available

**RC4FR**



Holds 4 x RC001 or RC002 series cases  
Dimensions: W - 419mm, D - 460mm, H - 460mm

**RC4FX**

Horizontal extension frame also available

**RC4FR/3D**



Holds 2 x RC003 and 1 x RC001 series cases  
Dimensions: W - 419mm, D - 460mm, H - 460mm

**RC4FX/3D**

Horizontal extension frame also available.

**RC5FR**



Holds 5x RC001 or RC002 series cases  
Dimensions: W - 419mm, D - 460mm, H - 571mm

**RC5FX**

Horizontal extension frame also available

**RC5FR/4D**




Holds 2 x RC001 or RC002  
and 2 x RC003 series cases  
Dimensions: W - 419mm, D - 460mm, H - 571mm

**RC5FX/4D**

Horizontal extension frame also available

**RCWCT**

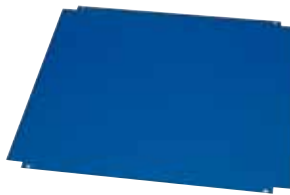

Work top for single frames.  
Comes complete with double sided  
tape and fixing screws.  
Dimensions: W - 419mm, D - 445mm, Thickness 1.1mm

**RCWCT/DT**



Work top for dual frames  
Comes complete with double sided tape  
and fixing screws.  
Dimensions: W - 825mm, D - 455, H - 8mm,  
Thickness 1.1mm

ROLA•CASE offers an easy selection of kits to suit your storage needs and are suitable for individual use, or can be added vertically or horizontally at any time as your storage requirements demand.

ROLA•CASE will integrate with the ROLA•Shelf units for further optional applications:

- The RCSK kits fitting the 4 Series ROLA•Shelf
- The RCDK kits fitting the 8 Series ROLA•Shelf

### RCSK2



W - 419 - D - 460 H - 250 (mm)  
Holds 3 x RC001 or RC002

### RCSK3



W - 419 - D - 460 H - 350 (mm)  
Holds 2 x RC003

### RCSK4



W - 419 - D - 460 H - 571 (mm)  
Holds 5 x RC001 or RC002

### RCSK5



W - 419 - D - 460 H - 571 (mm)  
Holds 2 x RC001 or RC002 & 2 x RC003

### RCSK6



W - 419 - D - 460 H - 460 (mm)  
Holds 4 x RC001 or RC002

### RCSK7



W - 419 - D - 460 H - 460 (mm)  
Holds 2 x RC003 & 1 x RC001

### RCDK2



W - 838 - D - 460 H - 350 (mm)  
Holds 6 x RC001 or RC002

### RCDK3



W - 838 - D - 460 H - 350 (mm)  
Holds 4 x RC003

### RCDK3/2



W - 838 - D - 460 H - 350 (mm)  
Holds 3 x RC001 or RC002 & 2 x RC003

### RCDK4



W - 838 - D - 460 H - 350 (mm)  
Holds 10 x RC001 or RC002

### RCDK5



W - 838 - D - 460 H - 571 (mm)  
Holds 4 x RC001 or RC002 & 4 x RC003

### RCDK3/4




W - 838 - D - 460 H - 460 (mm)  
Holds 5 x RC001 or RC002 & 2 x RC003

### RCDK5/4




W - 838 - D - 460 H - 350 (mm)  
Holds 7 x RC001 or RC002 & RC003

### RCWHL/PN

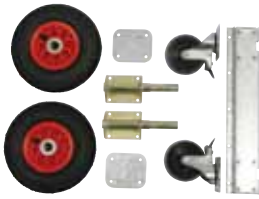


Pneumatic wheel kit for single modular mobile work station. Comes with 2 x 220mm pneumatic tires, 2x swivel locking wheels and all necessary bracing and fixing components. (Handles may be necessary.)

### RCWHL/DM

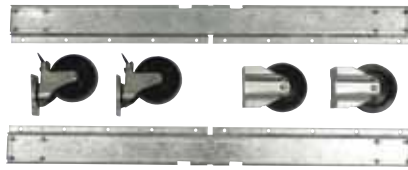

Wheel kit for a dual modular mobile work station. Comes with 2x fixed wheels and 2x swivel locking wheels and all necessary bracing and fixing components. (Handles may be necessary.)

### RCWHL/SM

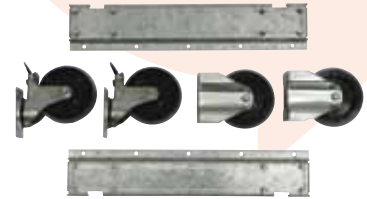

Wheel kit for a single modular mobile work station. Comes with 2x fixed wheels and 2x swivel locking wheels and all necessary bracing and fixing components. (Handles may be necessary.)

### RCCDT



Work top to fit dual **ROLA-CASE** cabinets. Construction: 1.1mm zinc annealed and powder coated.

### RCCS



Shelf to fit **ROLA-CASE** cabinets. Shelf construction: 0.9mm zinc annealed and powder coated

### RCCIT



Nylon fibre insert to fit top of all Drawer Cabinets. Oil, Petrol and water resistant. Width 410mm, Depth 455mm, Thickness 5mm.

### RCCIT/R



Rubber insert to fit top of all Drawer Cabinets. Width 410mm, Depth 455mm, Thickness 5mm.

### RCHDLT



Handle to fit dual and single mobile kits

### RCHDL



Single mobile handle to fit pneumatic wheeled kits

### RCJNR/C



Vertical joining bracket for connecting **ROLA-CASE** cabinets vertically. (4 per kit plus screws)

### CARRIAGE ACCESSORIES

### RCCRG/MG

Carriage Set - Colour: Millennium grey

Example purchase order:  
- RCDK5/MB-3 = RCDK5 with 3 heavy duty drawers.  
- RC7DC/PN/MB-7 = RC7DC/PN with 7 heavy duty drawers.  
- RCCRG/O/MB = Oyster carriage set with metal bearings



RCCRG/MG shown


### RCC/TT



Shelf to fit **ROLA-CASE** cabinets. Shelf construction: 0.9mm zinc annealed and powder coated.

RCC/TT fitted

### CABINET DOORS

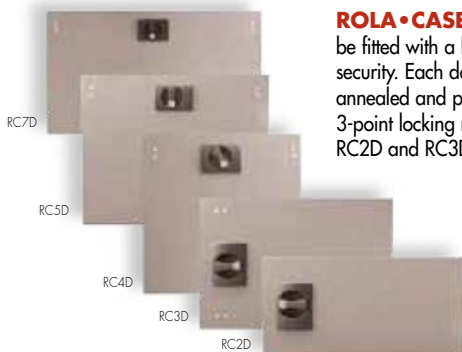

**ROLA-CASE** cabinets are able to be fitted with a locking door for added security. Each door is 0.9mm zinc annealed and powder coated with a 3-point locking mechanism (except RC2D and RC3D).

|             |  |
|-------------|--|
| <b>RC2D</b> | Door to fit: RC2DC, RCSK1/C  |
| <b>RC3D</b> | Door to fit: RC3DC, RC3DC/2D, RCSK2/C, RCSK3/C, RCDK2/C (x2), RCDK3/C (x2)                 |
| <b>RC4D</b> | Door to fit: RC4DC, RC4DC/3D, RCSK6/C, RCSK7/C, RCDK3-4/C (x2)                             |
| <b>RC5D</b> | Door to fit: RC5DC, RC5DC/4D, RCSK4/C, RCSK5/C, RCDK4/C (x2), RCDK5/C (x2), RCDK5-4/C (x2) |
| <b>RC7D</b> | Door to fit: RC7DC/PN, RC7DC/SM, RC7DC/DM (x2), RCSK7PN/C, RCSK7M/C, RCDK7M/C (x2)         |

**ROLA-CASE** cabinets are compatible with 4, 6, 8, 10 & 12 series **ROLA-Shelf** frame systems.

- Ideal for truck bodies and canopy use ✓ Can be used in correlation with **ROLA-CASE** products ✓  
 Load rating (125kg) ✓ Series 8, 10 & 12 Extendable by 100%, Series 4 & 6 by 80% ✓ Optional rubber mat for drawers ✓  
 Dual slam shut locking mechanism ✓ Adaptable to use over wheel arches ✓ Engineered designed for vehicle use ✓

## 4 Series Cabinets

**CAT NO:  
RC5/40**

- Includes  
 • 2 x RC401  
 • 2 x RC403



| CABINET       | H   | D   | W   |
|---------------|-----|-----|-----|
| <b>RC2/40</b> | 230 | 460 | 419 |
| <b>RC3/40</b> | 325 | 460 | 419 |
| <b>RC4/40</b> | 420 | 460 | 419 |
| <b>RC5/40</b> | 547 | 460 | 419 |
| <b>RC6/40</b> | 610 | 460 | 419 |
| <b>RC7/40</b> | 767 | 460 | 419 |

### Accessories - Drawers & Shelves

|              |            |     |     |
|--------------|------------|-----|-----|
| <b>RC401</b> | 95         | 425 | 365 |
| <b>RC403</b> | 136        | 425 | 365 |
| <b>RC4SH</b> | 50 (front) | 425 | 385 |

## 6 Series Cabinets

**CAT NO:  
RC3/60**

- Includes  
 • 3 x RC601



| CABINET       | H   | D   | W   |
|---------------|-----|-----|-----|
| <b>RC2/60</b> | 230 | 460 | 600 |
| <b>RC3/60</b> | 325 | 460 | 600 |
| <b>RC4/60</b> | 420 | 460 | 600 |
| <b>RC5/60</b> | 547 | 460 | 600 |
| <b>RC6/60</b> | 610 | 460 | 600 |
| <b>RC7/60</b> | 767 | 460 | 600 |

### Accessories - Drawers & Shelves

|              |            |     |     |
|--------------|------------|-----|-----|
| <b>RC601</b> | 95         | 425 | 535 |
| <b>RC603</b> | 136        | 425 | 535 |
| <b>RC6SH</b> | 50 (front) | 425 | 575 |

## 8 Series Cabinets

**CAT NO:  
RC3/80**

- Includes  
 • 3 x RC801




| CABINET       | H   | D   | W   |
|---------------|-----|-----|-----|
| <b>RC2/80</b> | 230 | 460 | 839 |
| <b>RC3/80</b> | 325 | 460 | 839 |
| <b>RC4/80</b> | 420 | 460 | 839 |
| <b>RC5/80</b> | 547 | 460 | 839 |
| <b>RC6/80</b> | 610 | 460 | 839 |
| <b>RC7/80</b> | 767 | 460 | 839 |

### Accessories - Drawers & Shelves

|              |            |     |     |
|--------------|------------|-----|-----|
| <b>RC801</b> | 95         | 425 | 771 |
| <b>RC803</b> | 136        | 425 | 771 |
| <b>RC8SH</b> | 50 (front) | 425 | 810 |

### 8 Series cabinet fitting over wheel arch

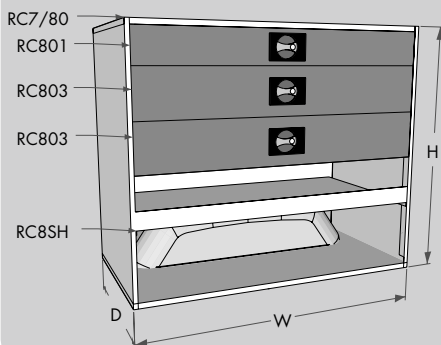

### Cabinet & Metal Drawer Combination



- 1 x RC5/60
- 2 x RC601
- 2 x RC603
- 1 x RCSK4/C



Combination 4 & 8 series cabinets drawers & Rola-Cases, as trolley with work bench.

**ROLA-CASE** cabinets are compatible with 4, 6, 8, 10 & 12 series **ROLA-Shelf** frame systems.

- Ideal for truck bodies and canopy use ✓ Can be used in correlation with **ROLA-CASE** products ✓  
 Load rating (125kg) ✓ Series 8, 10 & 12 Extendable by 100%, Series 4 & 6 by 80% ✓ Optional rubber mat for drawers ✓  
 Dual slam shut locking mechanism ✓ Adaptable to use over wheel arches ✓ Engineered designed for vehicle use ✓

## 10 Series Cabinets

**CAT NO:**  
**RC3/101**

Includes  
• 3 x  
RC1001



**CAT NO:**  
**RC3/120**

Includes  
• 3 x  
RC1201



| CABINET        | H   | D   | W    |
|----------------|-----|-----|------|
| <b>RC2/101</b> | 230 | 460 | 1010 |
| <b>RC3/101</b> | 325 | 460 | 1010 |
| <b>RC4/101</b> | 420 | 460 | 1010 |
| <b>RC5/101</b> | 547 | 460 | 1010 |
| <b>RC6/101</b> | 610 | 460 | 1010 |
| <b>RC7/101</b> | 767 | 460 | 1010 |

### Accessories - Drawers & Shelves

|               |            |     |     |
|---------------|------------|-----|-----|
| <b>RC1001</b> | 95         | 425 | 950 |
| <b>RC1003</b> | 136        | 425 | 950 |
| <b>RC10SH</b> | 50 (front) | 425 | 985 |


| CABINET        | H   | D   | W    |
|----------------|-----|-----|------|
| <b>RC2/120</b> | 230 | 460 | 1259 |
| <b>RC3/120</b> | 325 | 460 | 1259 |
| <b>RC4/120</b> | 420 | 460 | 1259 |
| <b>RC5/120</b> | 547 | 460 | 1259 |
| <b>RC6/120</b> | 610 | 460 | 1259 |
| <b>RC7/120</b> | 767 | 460 | 1259 |

### Accessories - Drawers & Shelves

|               |            |     |      |
|---------------|------------|-----|------|
| <b>RC1201</b> | 95         | 425 | 1211 |
| <b>RC1203</b> | 136        | 425 | 1211 |
| <b>RC12SH</b> | 50 (front) | 425 | 1230 |





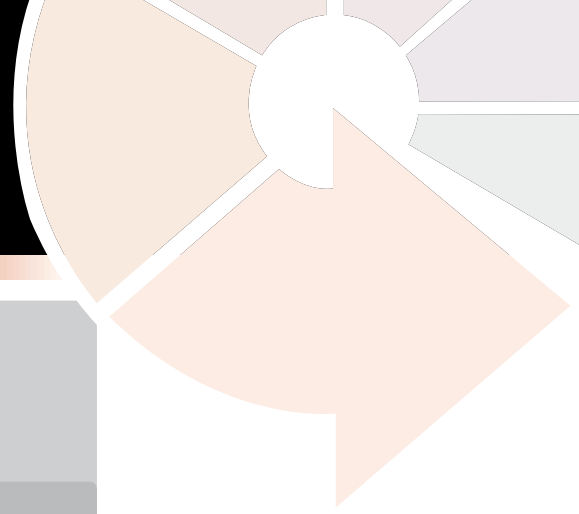

## First aid kits

First Aid Kits for vehicles and other workplaces.

| STATE          | FIRST AID KIT NO. 1 | FIRST AID KIT NO. 2 | FIRST AID KIT NO. 3 | FIRST AID KIT NO. 4 | REGULATIONS  |
|----------------|---------------------|---------------------|---------------------|---------------------|--|
| VIC            | .                   |                     |                     |                     | For 1 - 25 Employees   |
| QLD            |                     | .                   |                     |                     | For 1 - 30 Employees   |
| WA             |                     |                     | .                   |                     | For 1 - 25 Employees   |
| NSW            |                     |                     |                     | .                   | Safe Work Australia<br>Suitable for a typical workplace.<br>Subject to a specific workplace risk assessment and employee consultations |
| ACT            |                     |                     |                     | .                   |  |
| TAS            |                     |                     |                     | .                   |  |
| SA             |                     |                     |                     | .                   |  |
| NT             |                     |                     |                     | .                   |  |
| <b>CAT NO.</b> | <b>RCFAK1</b>       | <b>RCFAK2</b>       | <b>RCFAK3</b>       | <b>RCFAK4</b>       |  |

These first aid kits meet or exceed State or Territory prescribed regulations or Codes of Practice for Workplaces with less than 25 people (30 people for QLD, 100 people for TAS & 50 people for SA). For Large Workplaces, Remote Locations or High Risk workplaces additional 1st aid material or kits may be required. Each workplace should conduct a risk and hazard assessment and consult with their employees to properly assess their specific first aid and OHAS requirements.

- Select for state regulations.

\* Workplace Risk & Hazard assessment required (Recommended for all).

These first aid kits meet or exceed state or territory prescribed regulations or codes of practice for workplaces. Remote locations of high-risk work places additional 1st aid material or kits may be required.



\*Example First Aid Kit



**RCVCH**  
Vertical Case Holder



**ROLA·CASE**  
MULTIPLE STORAGE SYSTEMS



**ROLA·Shelf**  
VEHICLE STORAGE SOLUTIONS

27 Kangoo Road, Somersby NSW 2250 **Phone:** +61 2 4340 1444 **Fax:** +61 2 4340 1400  
**Email:** enquiry@rolacase.com **Web:** www.rolacase.com

**The ultimate in van racking, van shelving, vehicle accessories and mobile storage systems. Engineered designed, tested and manufactured in Australia since 1982.**

**Some of our current users:**

- Australian Antarctic Base
- Australian Volunteer Coastguard
- Ausgrid
- GHR Honda
- Lürsen Yachts/Ships - Germany
- Qantas - maintenance
- Exported to USA, Europe & New Zealand

