



LUXRITE®
LED PRODUCTS
WINTER 2018



The Premier Brand of All Star Lighting

Luxrite features a full line of energy-efficient LED bulbs and fixtures for electrical supply houses and lighting suppliers across the continental U.S. Known for quality, durability, and performance, our products are all UL approved, and many are Energy Star qualified as well. Equipped with high performance diodes which emit an industry-leading amount of lumens per watt ratio, our lights come in a variety of color temperatures and flood degrees. A favored choice among All Star Lighting's largest clients, Luxrite's award-winning LED products literally - and figuratively - shine.






SLIM SERIES • 4"/5"

- Energy Star Certified
- Dimmable
- 50,000 Extra-Long Life
- Easy Installation on J-Box
- Choice of CCT: 3K, 4K & 5K
- Choice of Round & Square
- Available Down-light Can Retrofit Kit
- Choice of Black, Nickel & White Finishes



	MODEL	DESCRIPTION	WATT	LUMENS	COLOR	TEMPERATURE	CASE	CRI
WHITE	LR23609	LED10/SLIM4/30K/W/SQ	10	600	3000K	SOFT WHITE	20	80
	LR23610	LED10/SLIM4/40K/W/SQ	10	600	4000K	COOL WHITE	20	80
	LR23611	LED10/SLIM4/50K/W/SQ	10	600	5000K	BRIGHT WHITE	20	80
BLACK	LR23612	LED10/SLIM4/30K/B/SQ	10	600	3000K	SOFT WHITE	20	80
	LR23613	LED10/SLIM4/40K/B/SQ	10	600	4000K	COOL WHITE	20	80
	LR23614	LED10/SLIM4/50K/B/SQ	10	600	5000K	BRIGHT WHITE	20	80
NICKEL	LR23615	LED10/SLIM4/30K/N/SQ	10	600	3000K	SOFT WHITE	20	80
	LR23616	LED10/SLIM4/40K/N/SQ	10	600	4000K	COOL WHITE	20	80
	LR23617	LED10/SLIM4/50K/N/SQ	10	600	5000K	BRIGHT WHITE	20	80
WHITE	LR23600	LED10/SLIM5/30K/W/RD	10	600	3000K	SOFT WHITE	20	80
	LR23601	LED10/SLIM5/40K/W/RD	10	600	4000K	COOL WHITE	20	80
	LR23602	LED10/SLIM5/50K/W/RD	10	600	5000K	BRIGHT WHITE	20	80
BLACK	LR23603	LED10/SLIM5/30K/B/RD	10	600	3000K	SOFT WHITE	20	80
	LR23604	LED10/SLIM5/40K/B/RD	10	600	4000K	COOL WHITE	20	80
	LR23605	LED10/SLIM5/50K/B/RD	10	600	5000K	BRIGHT WHITE	20	80
NICKEL	LR23606	LED10/SLIM5/30K/N/RD	10	600	3000K	SOFT WHITE	20	80
	LR23607	LED10/SLIM5/40K/N/RD	10	600	4000K	COOL WHITE	20	80
	LR23608	LED10/SLIM5/50K/N/RD	10	600	5000K	BRIGHT WHITE	20	80

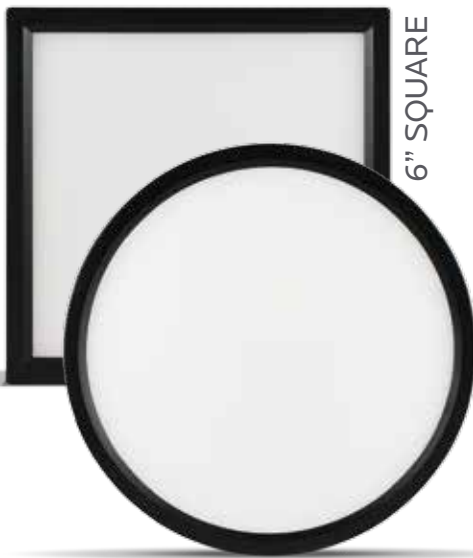

7" ROUND



7" ROUND



7" ROUND

SLIM SERIES • 6"/7"

- ◆ Energy Star Certified
- ◆ Dimmable
- ◆ 50,000 Extra-Long Life
- ◆ Easy Installation on J-Box
- ◆ Choice of CCT: 3K, 4K & 5K
- ◆ Choice of Round & Square
- ◆ Available Down-light Can Retrofit Kit
- ◆ Choice of Black, Nickel & White Finishes



	MODEL	DESCRIPTION	WATT	LUMENS	COLOR	TEMPERATURE	CASE	CRI
WHITE	LR23627	LED15/SLIM6/30K/W/SQ	15	950	3000K	SOFT WHITE	20	80
	LR23628	LED15/SLIM6/40K/W/SQ	15	950	4000K	COOL WHITE	20	80
	LR23629	LED15/SLIM6/50K/W/SQ	15	950	5000K	BRIGHT WHITE	20	80
BLACK	LR23630	LED15/SLIM6/30K/B/SQ	15	950	3000K	SOFT WHITE	20	80
	LR23631	LED15/SLIM6/40K/B/SQ	15	950	4000K	COOL WHITE	20	80
	LR23632	LED15/SLIM6/50K/B/SQ	15	950	5000K	BRIGHT WHITE	20	80
NICKEL	LR23633	LED15/SLIM6/30K/N/SQ	15	950	3000K	SOFT WHITE	20	80
	LR23634	LED15/SLIM6/40K/N/SQ	15	950	4000K	COOL WHITE	20	80
	LR23635	LED15/SLIM6/50K/N/SQ	15	950	5000K	BRIGHT WHITE	20	80
WHITE	LR23618	LED15/SLIM7/30K/W/RD	15	1000	3000K	SOFT WHITE	20	80
	LR23619	LED15/SLIM7/40K/W/RD	15	1000	4000K	COOL WHITE	20	80
	LR23620	LED15/SLIM7/50K/W/RD	15	1000	5000K	BRIGHT WHITE	20	80
BLACK	LR23621	LED15/SLIM7/30K/B/RD	15	1000	3000K	SOFT WHITE	20	80
	LR23622	LED15/SLIM7/40K/B/RD	15	1000	4000K	COOL WHITE	20	80
	LR23623	LED15/SLIM7/50K/B/RD	15	1000	5000K	BRIGHT WHITE	20	80
NICKEL	LR23624	LED15/SLIM7/30K/N/RD	15	1000	3000K	SOFT WHITE	20	80
	LR23625	LED15/SLIM7/40K/N/RD	15	1000	4000K	COOL WHITE	20	80
	LR23626	LED15/SLIM7/50K/N/RD	15	1000	5000K	BRIGHT WHITE	20	80
	LR23640	LED/SLIM4-5/CAN-ADAPTER						
	LR23645	LED/SLIM6-7/CAN-ADAPTER						



3" GIMBAL

3" RECESSED GIMBAL

- Energy Star Qualified
- ETL Listed
- Fully Dimmable
- 30 Degree Tilt Adjustable
- Available in 3"
- 50,000 Hours Lifetime
- For Dry / Damp Location




MODEL	DESCRIPTION	WATT	WATT REPLACEMENT	LUMENS	COLOR	TEMPERATURE	CASE	CRI
LR23240	LED8W/DL3/GB/30K/FL	8	50	600	3000K	SOFT WHITE	18	81
LR23245	LED8W/DL3/GB/50K/FL	8	50	600	5000K	BRIGHT WHITE	18	81




RECESSED MINI FLAT PANEL

- ◆ IC Rated
- ◆ ETL & Energy Star Listed
- ◆ 50,000Hr Extra-Long Life
- ◆ Simple & Easy Installation
- ◆ 1/2" Thin Panel - Fits in Tight Ceiling Space
- ◆ Available 4" & 6" Square and Round
- ◆ Choice of CCT: 3K, 4K & 5K


	MODEL	DESCRIPTION	WATT	LUMENS	COLOR	TEMPERATURE	CASE	CRI
ROUND	LR23700	LED/MINI4/PANEL/30K/RD	10	650	3000K	SOFT WHITE	20	82
	LR23701	LED/MINI4/PANEL/40K/RD	10	650	4000K	COOL WHITE	20	82
	LR23702	LED/MINI4/PANEL/50K/RD	10	650	5000K	BRIGHT WHITE	20	82
SQUARE	LR23703	LED/MINI4/PANEL/30K/SQ	10	650	3000K	SOFT WHITE	20	82
	LR23704	LED/MINI4/PANEL/40K/SQ	10	650	4000K	COOL WHITE	20	82
	LR23705	LED/MINI4/PANEL/50K/SQ	10	650	5000K	BRIGHT WHITE	20	82
ROUND	LR23706	LED/MINI6/PANEL/30K/RD	12	850	3000K	SOFT WHITE	20	82
	LR23707	LED/MINI6/PANEL/40K/RD	12	850	4000K	COOL WHITE	20	82
	LR23708	LED/MINI6/PANEL/50K/RD	12	850	5000K	BRIGHT WHITE	20	82
SQUARE	LR23709	LED/MINI6/PANEL/30K/SQ	12	850	3000K	SOFT WHITE	20	82
	LR23710	LED/MINI6/PANEL/40K/SQ	12	850	4000K	COOL WHITE	20	82
	LR23711	LED/MINI6/PANEL/50K/SQ	12	850	5000K	BRIGHT WHITE	20	82

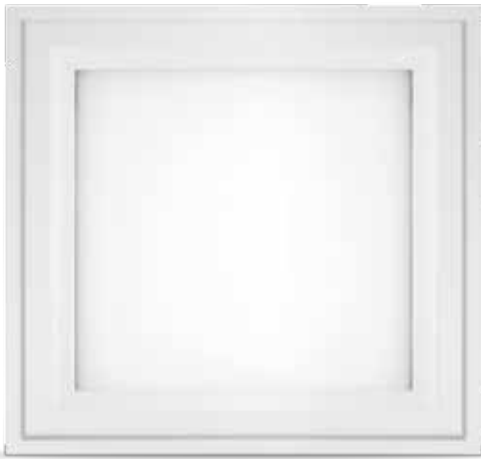

1'X1' PANEL

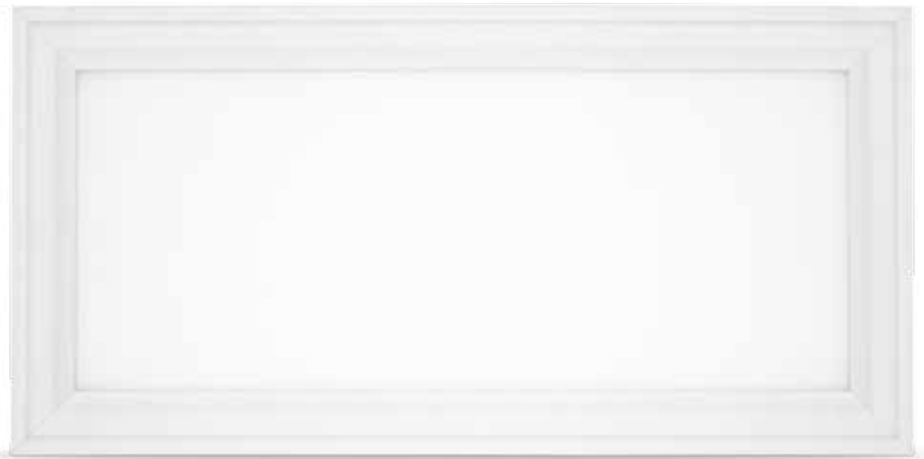


1'X2' PANEL

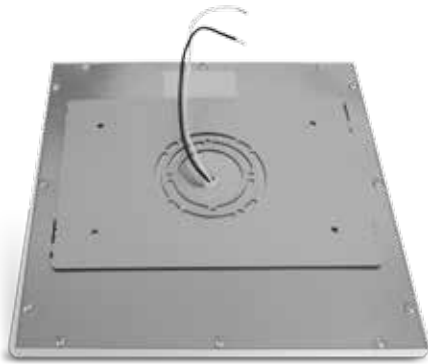

1'X1' PANEL BACK

INSTALLATION INSTRUCTIONS

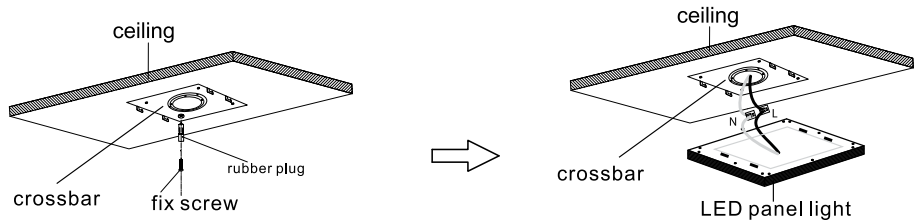


SURFACE MOUNT PANEL SERIES

- UL-cUL Listed
- Flush Mount
- Dimmable
- 50,000Hr Extra-Long Life
- Available in 1'x1' / 1'x2' Panels
- Ultra Sleek Design (1/2" Thick Panel)
- Choice of CCT: 3K, 4K, 5K & 6.5K
- Flush Surface Mount



MODEL	DESCRIPTION	WATT	LUMENS	COLOR	TEMPERATURE	CASE	CRI
LR24030	LED18W1X1PANEL/30K/DIM	18	1620	3000K	SOFT WHITE	1	80
LR24032	LED18W1X1PANEL/40K/DIM	18	1620	4000K	COOL WHITE	1	80
LR24033	LED18W1X1PANEL/50K/DIM	18	1620	5000K	BRIGHT WHITE	1	80
LR24034	LED18W1X1PANEL/65K/DIM	18	1620	6500K	DAYLIGHT	1	80
LR24035	LED25W1X2PANEL/30K/DIM	25	2250	3000K	SOFT WHITE	1	80
LR24037	LED25W1X2PANEL/40K/DIM	25	2250	4000K	COOL WHITE	1	80
LR24038	LED25W1X2PANEL/50K/DIM	25	2250	5000K	BRIGHT WHITE	1	80
LR24039	LED25W1X2PANEL/65K/DIM	25	2250	6500K	DAYLIGHT	1	80

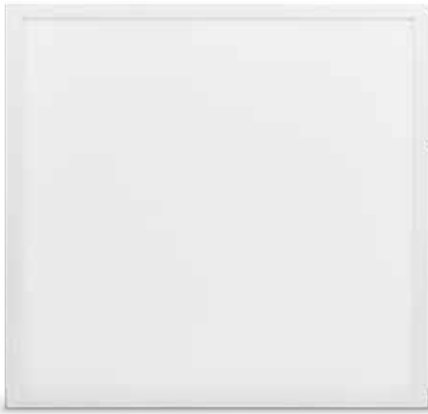

2' X 2'



2' X 4'



1' X 4'

PANEL SERIES


- ◆ DLC - UL - cUL Listed
- ◆ 0-10V Dimming
- ◆ 50,000Hr Extra-Long Life
- ◆ Available in 2x2' / 1x4' / 2x4' Panels
- ◆ Ultra Sleek Design (1/2 Inch Thick)
- ◆ Choice of CCT: 3K, 3.5K, 4K, 5K & 6.5K



	MODEL	DESCRIPTION	WATT	LUMENS	COLOR	TEMPERATURE	CASE	CRI
1 X 4 FOOT	LR24045	LED45W1X4PANEL/30K/DIM	45	5000	3000K	SOFT WHITE	2	83
	LR24046	LED45W1X4PANEL/35K/DIM	45	4950	3500K	NATURAL	2	83
	LR24047	LED45W1X4PANEL/40K/DIM	45	5150	4000K	COOL WHITE	2	83
	LR24048	LED45W1X4PANEL/50K/DIM	45	5150	5000K	BRIGHT WHITE	2	83
	LR24049	LED45W1X4PANEL/65K/DIM	45	5100	6500K	DAYLIGHT	2	83
2 X 2 FOOT	LR24050	LED45W2X2PANEL/30K/DIM	45	4850	3000K	SOFT WHITE	2	81
	LR24051	LED45W2X2PANEL/35K/DIM	45	4950	3500K	NATURAL	2	81
	LR24052	LED45W2X2PANEL/40K/DIM	45	5150	4000K	COOL WHITE	2	81
	LR24053	LED45W2X2PANEL/50K/DIM	45	5150	5000K	BRIGHT WHITE	2	81
	LR24054	LED45W2X2PANEL/65K/DIM	45	5100	6500K	DAYLIGHT	2	81
2 X 4 FOOT	LR24055	LED72W2X4PANEL/30K/DIM	72	7100	3000K	SOFT WHITE	2	83
	LR24056	LED72W2X4PANEL/35K/DIM	72	7550	3500K	NATURAL	2	83
	LR24057	LED72W2X4PANEL/40K/DIM	72	7900	4000K	COOL WHITE	2	83
	LR24058	LED72W2X4PANEL/50K/DIM	72	7900	5000K	BRIGHT WHITE	2	83
	LR24059	LED72W2X4PANEL/65K/DIM	72	7850	6500K	DAYLIGHT	2	83




2X2 PANEL

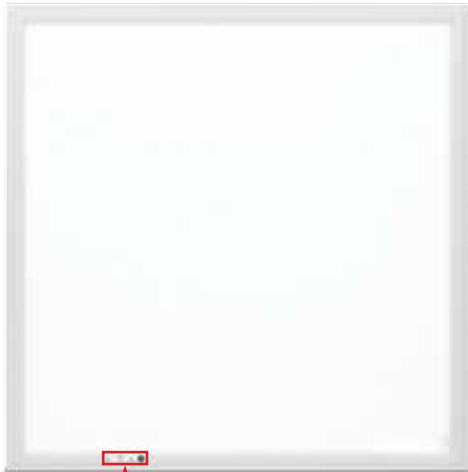


TEST BUTTON DETAIL

2X4 PANEL

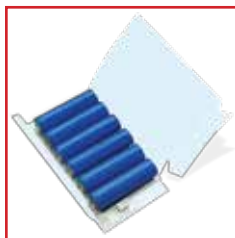

BATTERY DETAIL

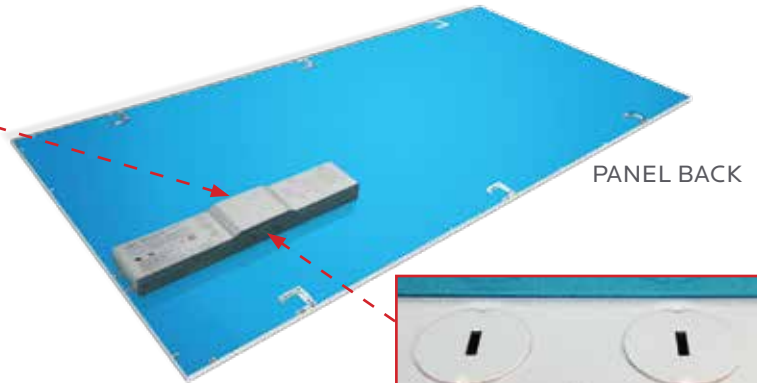

PANEL BACK



CONNECTION DETAIL

EMERGENCY PANEL SERIES


- ◆ DLC - UL - cUL Listed
- ◆ 0-10V Dimming
- ◆ 50,000Hr Extra-Long Life
- ◆ Integrated Battery Backup
- ◆ Available in 2x2' & 2x4' Panels
- ◆ Ultra Sleek Design (1/2 Inch Thick)
- ◆ Choice of CCT: 3K, 3.5K, 4K, 5K & 6.5K



MODEL	DESCRIPTION	WATT	LUMENS	COLOR	TEMPERATURE	CRI
LR24060	LED45W2X2PANEL/30K/DIM/EMR	45	4390	3000K	SOFT WHITE	80
LR24061	LED45W2X2PANEL/35K/DIM/EMR	45	4720	3500K	NATURAL	80
LR24062	LED45W2X2PANEL/40K/DIM/EMR	45	4800	4000K	COOL WHITE	80
LR24063	LED45W2X2PANEL/50K/DIM/EMR	45	5000	5000K	BRIGHT WHITE	80
LR24064	LED45W2X2PANEL/65K/DIM/EMR	45	5000	6500K	DAYLIGHT	80
LR24065	LED60W2X4PANEL/30K/DIM/EMR	60	6540	3000K	SOFT WHITE	80
LR24066	LED60W2X4PANEL/35K/DIM/EMR	60	6630	3500K	NATURAL	80
LR24067	LED60W2X4PANEL/40K/DIM/EMR	60	6720	4000K	COOL WHITE	80
LR24068	LED60W2X4PANEL/50K/DIM/EMR	60	6960	5000K	BRIGHT WHITE	80
LR24069	LED60W2X4PANEL/65K/DIM/EMR	60	6960	6500K	DAYLIGHT	80

PANEL SERIES KITS

MODEL	DESCRIPTION	CASE
LR24070	LED/2X2/SURFACE/KIT	1
LR24072	LED/1X4/SURFACE/KIT	1
LR24075	LED/2X4/SURFACE/KIT	1
LR24080	LED/1x4/FLANGE/KIT	1
LR24081	LED/2x2/FLANGE/KIT	1
LR24082	LED/2x4/FLANGE/KIT	1
LR24077	LED/SUSPENSION/KIT	1

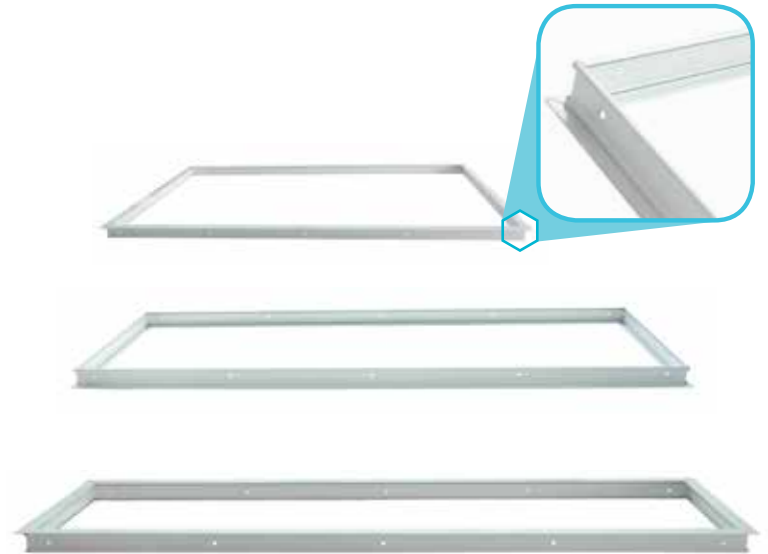

THREE WAYS TO INSTALL AND SUSPEND... FLANGE, SURFACE AND SUSPENSION

WRAP SERIES

- ◆ Sleek Design
- ◆ High Lumen
- ◆ Universal Input Voltage
- ◆ 50,000 Hour Long Life



MODEL	DESCRIPTION	WATT	LUMENS	COLOR	TEMPERATURE	CRI	CASE
LR25150	LED48/WRAP/40K/UV	48	5040	4000K	COOL WHITE	80	4

VAPOR TIGHT SERIES

- ◆ 3800 Lumens
- ◆ 50,000 Hour Life
- ◆ 120-277 Volt Input
- ◆ IP65 Vapor Tight for Wet Location



MODEL	DESCRIPTION	WATT	LUMENS	COLOR	TEMPERATURE	CRI	CASE
LR25130	LED48/VT/840/UNV	34	3800	4000K	COOL WHITE	80	4
LR25131	LED48/VT/850/UNV	34	3800	5000K	BRIGHT WHITE	80	4



2'X4' TROFFER



2'X2' TROFFER

TROFFER SERIES

- ◆ Dimmable
- ◆ Sleek Design
- ◆ High Lumen
- ◆ 50,000 Hours
- ◆ Uniform Temperature
- ◆ UL Listed
- ◆ DLC Rated
- ◆ Available in 2x2' & 2x4'
- ◆ Available in 3500K & 4000K



MODEL	DESCRIPTION	WATT	LUMENS	COLOR	TEMPERATURE	CASE	CRI
LR23085	LED40W2X2TROFFER/CB/35K	40	4500	3500K	NATURAL	1	80
LR23086	LED40W2X2TROFFER/CB/40K	40	4550	4000K	COOL WHITE	1	80
LR23088	LED50W2X4TROFFER/CB/35K	50	5500	3500K	NATURAL	1	80
LR23089	LED50W2X4TROFFER/CB/40K	50	5600	4000K	COOL WHITE	1	80

CHROME SERIES

- ◆ Energy Star Qualified
- ◆ ETL Listed
- ◆ Sleek Design
- ◆ 50,000 Hours
- ◆ Easy Installation
- ◆ Dimmable
- ◆ Available in 3K, 4K and 5K
- ◆ Available in 10"/12"/14"/16"/18"



CHROME



MODEL	DESCRIPTION	WATT	LUMENS	COLOR	TEMPERATURE	CASE	CRI
LR23170	LED10"FLUSH/CHROME/30K/2	14	1000	3000K	SOFT WHITE	10	83
LR23171	LED10"FLUSH/CHROME/40K/2	14	1000	4000K	COOL WHITE	10	83
LR23180	LED10"FLUSH/CHROME/50K/2	14	1000	5000K	BRIGHT WHITE	10	83
LR23172	LED12"FLUSH/CHROME/30K/2	18	1380	3000K	SOFT WHITE	5	83
LR23173	LED12"FLUSH/CHROME/40K/2	18	1380	4000K	COOL WHITE	5	83
LR23181	LED12"FLUSH/CHROME/50K/2	18	1380	5000K	BRIGHT WHITE	5	83
LR23174	LED14"FLUSH/CHROME/30K/2	22	1652	3000K	SOFT WHITE	5	83
LR23175	LED14"FLUSH/CHROME/40K/2	22	1652	4000K	COOL WHITE	5	83
LR23182	LED14"FLUSH/CHROME/50K/2	22	1652	5000K	BRIGHT WHITE	5	83
LR23176	LED16"FLUSH/CHROME/30K/2	26	1960	3000K	SOFT WHITE	5	83
LR23177	LED16"FLUSH/CHROME/40K/2	26	1960	4000K	COOL WHITE	5	83
LR23183	LED16"FLUSH/CHROME/50K/2	26	1960	5000K	BRIGHT WHITE	5	83
LR23178	LED18"FLUSH/CHROME/30K/2	30	2160	3000K	SOFT WHITE	4	83
LR23179	LED18"FLUSH/CHROME/40K/2	30	2160	4000K	COOL WHITE	4	83
LR23184	LED18"FLUSH/CHROME/50K/2	30	2160	5000K	BRIGHT WHITE	4	83

CHROME SERIES • BATTERY BACKUP

- ◆ Dimmable
- ◆ ETL Listed
- ◆ Sleek Design
- ◆ 50,000 Hours
- ◆ Easy Installation
- ◆ Energy Star Qualified
- ◆ Available in 12"/14"/16"
- ◆ Available in 3K, 4K and 5K
- ◆ Emergency Battery w/Test Button Ready



CHROME EMR



MODEL	DESCRIPTION	WATT	LUMENS	COLOR	TEMPERATURE	CASE	CRI
LR23188	LED12"FLUSH/CHROME/30K/EMR	18	1380	3000K	SOFT WHITE	4	83
LR23189	LED12"FLUSH/CHROME/40K/EMR	18	1380	4000K	COOL WHITE	4	83
LR23190	LED12"FLUSH/CHROME/50K/EMR	18	1380	5000K	BRIGHT WHITE	4	83
LR23191	LED14"FLUSH/CHROME/30K/EMR	22	1652	3000K	SOFT WHITE	4	83
LR23192	LED14"FLUSH/CHROME/40K/EMR	22	1652	4000K	COOL WHITE	4	83
LR23193	LED14"FLUSH/CHROME/50K/EMR	22	1652	5000K	BRIGHT WHITE	4	83
LR23194	LED16"FLUSH/CHROME/30K/EMR	26	1960	3000K	SOFT WHITE	4	83
LR23195	LED16"FLUSH/CHROME/40K/EMR	26	1960	4000K	COOL WHITE	4	83
LR23196	LED16"FLUSH/CHROME/50K/EMR	26	1960	5000K	BRIGHT WHITE	4	83

4 INCH

5-6 INCH

8 INCH



JUNCTION BOX SERIES

- ◆ ETL Listed
- ◆ Energy Star Listed
- ◆ Wet Location Rated
- ◆ 120-277V Volt Input
- ◆ Type IC Airtight & Non IC Airtight Application
- ◆ Baffle Trim Look
- ◆ Available 4", 5-6" & 8"
- ◆ Compact Sleek Design
- ◆ Dimmable (@120V)



	MODEL	DESCRIPTION	WATT	WATT REPLACEMENT	LUMENS	COLOR	TEMPERATURE	CASE	CRI
4 INCH	LR24840	LED/DL4/2700K/FL/JB	10	50	700	2700K	WARM WHITE	12	90
	LR24841	LED/DL4/3000K/FL/JB	10	50	750	3000K	SOFT WHITE	12	90
	LR24842	LED/DL4/4000K/FL/JB	10	50	780	4000K	COOL WHITE	12	90
	LR24843	LED/DL4/5000K/FL/JB	10	50	800	5000K	BRIGHT WHITE	12	90
5-6 INCH	LR24845	LED/DL5-6/2700K/FL/JB	15	120	1000	2700K	WARM WHITE	12	90
	LR24846	LED/DL5-6/3000K/FL/JB	15	120	1000	3000K	SOFT WHITE	12	90
	LR24847	LED/DL5-6/4000K/FL/JB	15	120	1050	4000K	COOL WHITE	12	90
	LR24848	LED/DL5-6/5000K/FL/JB	15	120	1100	5000K	BRIGHT WHITE	12	90
8 INCH	LR24850	LED/DL8/2700K/FL/JB	25	200	1950	2700K	WARM WHITE	6	80
	LR24851	LED/DL8/3000K/FL/JB	25	200	2000	3000K	SOFT WHITE	6	80
	LR24852	LED/DL8/4000K/FL/JB	25	200	2100	4000K	COOL WHITE	6	80
	LR24853	LED/DL8/5000K/FL/JB	25	200	2200	5000K	BRIGHT WHITE	6	80



4" INDIRECT




6" INDIRECT

RETROFIT SERIES • AMBIENT INDIRECT

- ◆ Dimmable
- ◆ ETL Listed
- ◆ Available in 4" & 6"
- ◆ Eliminates Glare and Shadows
- ◆ Indirect Ambient, Smooth, Uniform Illumination
- ◆ Cancels Out the Negative Effects of Direct Lighting on the Eyes



MODEL	DESCRIPTION	WATT	WATT REPLACEMENT	LUMENS	COLOR	TEMPERATURE	CASE	CRI
LR24830	LED/IDL4/2700K/FL/DIM	10	50	650	2700K	WARM WHITE	12	90
LR24831	LED/IDL4/3000K/FL/DIM	10	50	660	3000K	SOFT WHITE	12	90
LR24832	LED/IDL4/4000K/FL/DIM	10	50	670	4000K	COOL WHITE	12	90
LR24833	LED/IDL4/5000K/FL/DIM	10	50	670	5000K	BRIGHT WHITE	12	90
LR24835	LED/IDL6/2700K/FL/DIM	15	120	1030	2700K	WARM WHITE	12	90
LR24836	LED/IDL6/3000K/FL/DIM	15	120	1040	3000K	SOFT WHITE	12	90
LR24837	LED/IDL6/4000K/FL/DIM	15	120	1050	4000K	COOL WHITE	12	90
LR24838	LED/IDL6/5000K/FL/DIM	15	120	1050	5000K	BRIGHT WHITE	12	90

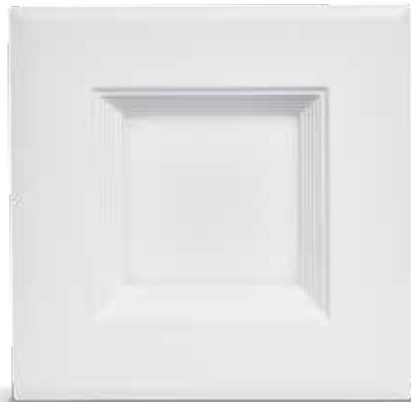

SQUARE
4" BAFFLED



SQUARE
4" SMOOTH



SQUARE
5-6" BAFFLED

RETROFIT SERIES • SQUARE

- UL/ETL Listed
- Sleek Design
- Long Life
- Available in Smooth & Baffles Trim Designs
- Dimmable
- Energy Star Qualified
- Available in 4" & 5-6"



	MODEL	DESCRIPTION	WATT	WATT REPLACEMENT	LUMENS	COLOR	TEMPERATURE	CRI	CASE
SMOOTH	LR23007	LED/DL4/3000K/FL/ES/SQ	10	60	650	3000K	SOFT WHITE	80	12
	LR23001	LED/DL4/4000K/FL/ES/SQ	10	60	670	4000K	COOL WHITE	80	12
	LR23009	LED/DL4/5000K/FL/ES/SQ	10	60	700	5000K	BRIGHT WHITE	80	12
BAFFLED	LR24825	LED/DL4/2700K/FL/B/SQ	10	60	620	2700K	WARM WHITE	80	12
	LR24826	LED/DL4/3000K/FL/B/SQ	10	60	650	3000K	SOFT WHITE	80	12
	LR24828	LED/DL4/4000K/FL/B/SQ	10	60	670	4000K	COOL WHITE	80	12
	LR24829	LED/DL4/5000K/FL/B/SQ	10	60	700	5000K	BRIGHT WHITE	80	12
	LR23037	LED/DL5-6/3000K/FL/SQ	15	120	1100	3000K	SOFT WHITE	90	20
	LR23039	LED/DL5-6/5000K/FL/SQ	15	120	1100	5000K	BRIGHT WHITE	90	20



ROUND
4" BAFFLED



ROUND
4" SMOOTH



ROUND
5-6" BAFFLED



ROUND
5-6" SMOOTH

RETROFIT SERIES • ROUND

- UL Listed
- Fully Dimmable
- Sleek Design
- Energy Star Qualified
- 32 Year Lifespan
- 70/90° Degree of Beam Angle



	MODEL	DESCRIPTION	WATT	WATT REPLACEMENT	LUMENS	COLOR	TEMPERATURE	CASE	CRI
SMOOTH	LR23005	LED/DL4/3000K/FL/ES	9	60	684	3000K	SOFT WHITE	12	83
	LR23010	LED/DL4/5000K/FL/ES	9	60	684	5000K	BRIGHT WHITE	12	83
	LR23015	LED/DL5-6/3000K/FL/ES	15	120	1200	3000K	SOFT WHITE	12	83
	LR23020	LED/DL5-6/5000K/FL/ES	15	120	1230	5000K	BRIGHT WHITE	12	83
BAFFLED	LR24802	LED/DL4/2700K/FL/DIM	10	60	650	2700K	WARM WHITE	12	80
	LR24805	LED/DL4/3000K/FL/DIM	10	60	700	3000K	SOFT WHITE	12	80
	LR24807	LED/DL4/4000K/FL/DIM	10	60	750	4000K	COOL WHITE	12	80
	LR24810	LED/DL4/5000K/FL/DIM	10	60	800	5000K	BRIGHT WHITE	12	80
	LR24812	LED/DL5-6/2700K/FL/DIM	15	120	1000	2700K	WARM WHITE	12	80
	LR24815	LED/DL5-6/3000K/FL/DIM	15	120	1100	3000K	SOFT WHITE	12	80
	LR24817	LED/DL5-6/4000K/FL/DIM	15	120	1200	4000K	COOL WHITE	12	80
	LR24820	LED/DL5-6/5000K/FL/DIM	15	120	1300	5000K	BRIGHT WHITE	12	80



CHROME



NICKEL



BRONZE



BLACK

COMES SEPARATELY PACKED AND WORKS EXCLUSIVELY WITH OUR 4-6" ROUND DOWN LIGHTS

RETROFIT SERIES TRIM REPLACEMENTS

	MODEL	DESCRIPTION	CASE
4 INCH	LR24860	LED/DL4/TRIM/CHROME	60
	LR24861	LED/DL4/TRIM/NICKEL	60
	LR24862	LED/DL4/TRIM/BRONZE	60
	LR24863	LED/DL4/TRIM/BLACK	60
5-6 INCH	LR24865	LED/DL5-6/TRIM/CHROME	30
	LR24866	LED/DL5-6/TRIM/NICKEL	30
	LR24867	LED/DL5-6/TRIM/BRONZE	30
	LR24868	LED/DL5-6/TRIM/BLACK	30



TRIM REPLACEMENTS FIT OUR JUNCTION BOX AND RETROFIT ROUND SERIES



4" EYEBALL



5-6" EYEBALL



RETROFIT SERIES • GIMBAL

- ◆ Energy Star Qualified
- ◆ ETL Listed
- ◆ Fully Dimmable
- ◆ 30 Degree Tilt Adjustable
- ◆ Available in 3", 4" & 5-6"
- ◆ 50,000 Hours Lifetime
- ◆ For Dry / Damp



MODEL	DESCRIPTION	WATT	WATT REPLACEMENT	LUMENS	COLOR	TEMPERATURE	CASE	CRI
LR23230	LED/DL4/EB/3000K/FL	10	50	720	3000K	SOFT WHITE	12	90
LR23235	LED/DL4/EB/5000K/FL	10	50	740	5000K	BRIGHT WHITE	12	90
LR23040	LED/DL5-6/EB/3000K/FL	15	120	1010	3000K	SOFT WHITE	12	90
LR23045	LED/DL5-6/EB/5000K/FL	15	120	1060	5000K	BRIGHT WHITE	12	90

CLOUD SERIES • PUFF



CLOUD PUFF

- ◆ Energy Star Qualified
- ◆ ETL Approved
- ◆ Easy Installation
- ◆ Damp Location Rated
- ◆ 30,000 Hour Life
- ◆ Easy Installation
- ◆ White Diffuse PC Cover
- ◆ Available in 4K and 5K
- ◆ Available in 2 Foot & 4 Foot



MODEL	DESCRIPTION	WATT	LUMENS	COLOR	TEMPERATURE	CASE	CRI
LR25205	LED34WCLOUD/40K/24	34	3500	4000K	COOL WHITE	1	80
LR25206	LED34WCLOUD/50K/24	34	3500	5000K	BRIGHT WHITE	1	80
LR25215	LED52WCLOUD/40K/48	52	5200	4000K	COOL WHITE	1	80
LR25216	LED52WCLOUD/50K/48	52	5200	5000K	BRIGHT WHITE	1	80

CLOUD SERIES • FLUSH



SQUARE



ROUND

- ◆ Energy Star Qualified
- ◆ UL Approved
- ◆ FCC Compliant
- ◆ Damp Location Rated
- ◆ 50,000 Hour Life
- ◆ Dimmable
- ◆ Sleek Design
- ◆ Easy Installation
- ◆ Available in 11" & 15"
- ◆ Available in 3K, 4K and 5K



MODEL	DESCRIPTION	WATT	LUMENS	COLOR	TEMPERATURE	CASE	CRI
LR23150	LED11"FIXTURE/ROUND/30K/2	15	1100	3000K	SOFT WHITE	6	80
LR23155	LED11"FIXTURE/ROUND/40K/2	15	1100	4000K	COOL WHITE	6	80
LR23157	LED11"FIXTURE/ROUND/50K/2	15	1100	5000K	BRIGHT WHITE	6	80
LR23160	LED15"FIXTURE/ROUND/30K/2	22	1600	3000K	SOFT WHITE	6	80
LR23165	LED15"FIXTURE/ROUND/40K/2	22	1600	4000K	COOL WHITE	6	80
LR23167	LED15"FIXTURE/ROUND/50K/2	22	1600	5000K	BRIGHT WHITE	6	80
LR23400	LED11"FIXTURE/SQUARE/30K	16	1200	3000K	SOFT WHITE	6	80
LR23402	LED11"FIXTURE/SQUARE/40K	16	1200	4000K	COOL WHITE	6	80
LR23403	LED11"FIXTURE/SQUARE/50K	16	1200	5000K	BRIGHT WHITE	6	80
LR23405	LED15"FIXTURE/SQUARE/30K	24	1750	3000K	SOFT WHITE	4	80
LR23407	LED15"FIXTURE/SQUARE/40K	24	1750	4000K	COOL WHITE	4	80
LR23408	LED15"FIXTURE/SQUARE/50K	24	1750	5000K	BRIGHT WHITE	4	80



LINEAR FIXTURE SERIES




- ◆ ETL Approved
- ◆ Easy Installation
- ◆ 50,000 Hour Life
- ◆ Available in 3K, 4K and 5K
- ◆ Steel Housing + Acrylic Lens
- ◆ 120-277 Volt Input



	MODEL	DESCRIPTION	WATT	LUMENS	COLOR	TEMPERATURE	CASE	CRI
2FT	LR25120	LED24/LINEAR/830/UNV	17	2100	3000K	SOFT WHITE	4	80
	LR25121	LED24/LINEAR/840/UNV	17	2100	4000K	COOL WHITE	4	80
	LR25122	LED24/LINEAR/850/UNV	17	2100	5000K	BRIGHT WHITE	4	80
3FT	LR25123	LED36/LINEAR/830/UNV	26	3160	3000K	SOFT WHITE	4	80
	LR25124	LED36/LINEAR/840/UNV	26	3160	4000K	COOL WHITE	4	80
	LR25125	LED36/LINEAR/850/UNV	26	3160	5000K	BRIGHT WHITE	4	80
4FT	LR25126	LED48/LINEAR/830/UNV	34	4200	3000K	SOFT WHITE	4	80
	LR25127	LED48/LINEAR/840/UNV	34	4200	4000K	COOL WHITE	4	80
	LR25128	LED48/LINEAR/850/UNV	34	4200	5000K	BRIGHT WHITE	4	80
8FT	LR25118	LED96/LINEAR/840/UNV	68	7040	4000K	COOL WHITE	1	80
	LR25119	LED96/LINEAR/850/UNV	68	7040	5000K	NATURAL	1	80



CLEAR

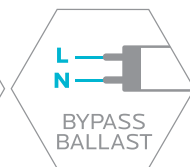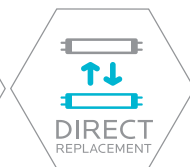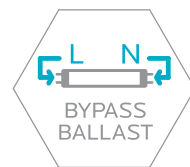

TUBE SERIES • CLEAR

- ◆ Clear Glass Tube
- ◆ 120-277 Input Volt
- ◆ UL Listed (UL Type A)
- ◆ Universal 3 Way: Ballast Compatible/Bypass Ballast 1 & 2 Sided Input
- ◆ 50,000Hr Long Life
- ◆ High Efficacy > 100 LPM
- ◆ DLC Listed





MODEL	DESCRIPTION	WATT	WATT REPLACEMENT	LUMENS	COLOR	TEMPERATURE		CRI	CASE
LR34170	LED18T8/30K/48/CL/UNV	18	32	1900	3000K	SOFT WHITE		80	30
LR34172	LED18T8/40K/48/CL/UNV	18	32	2200	4000K	COOL WHITE	•	80	30
LR34173	LED18T8/50K/48/CL/UNV	18	32	2200	5000K	BRIGHT WHITE	•	80	30
LR34174	LED18T8/65K/48/CL/UNV	18	32	2000	6500K	DAYLIGHT		80	30

4 FOOT



T8

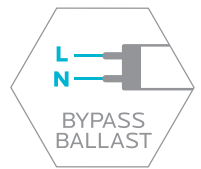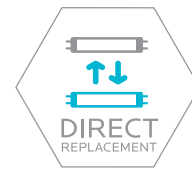


TUBE SERIES • UNIVERSAL GLASS T8

- ◆ 120-277 Input Volt
- ◆ ETL Listed
- ◆ DLC Listed
- ◆ UL Listed
- ◆ 50,000hr Long Life
- ◆ High Efficacy > 100 LPM
- ◆ Shatter Proof, PET Covered Glass Tube
- ◆ Universal: Ballast Compatible / Bypass Ballast

	MODEL	DESCRIPTION	WATT	WATT REPLACEMENT	LUMENS	COLOR	TEMPERATURE	ETL	DLC	UL LISTED	CRI	CASE
2 FOOT	LR34070	LED12T8/30K/24/SG/UNV	11	17	1100	3000K	SOFT WHITE	•			83	25
	LR34071	LED12T8/35K/24/SG/UNV	11	17	1100	3500K	NATURAL	•			83	25
	LR34072	LED12T8/40K/24/SG/UNV	11	17	1100	4000K	COOL WHITE	•			83	25
	LR34073	LED12T8/50K/24/SG/UNV	11	17	1100	5000K	BRIGHT WHITE	•			83	25
	LR34074	LED12T8/65K/24/SG/UNV	11	17	1100	6500K	DAYLIGHT	•			83	25
3 FOOT	LR34075	LED16T8/30K/36/SG/UNV	16	25	1600	3000K	SOFT WHITE	•			83	25
	LR34076	LED16T8/35K/36/SG/UNV	16	25	1600	3500K	NATURAL	•			83	25
	LR34077	LED16T8/40K/36/SG/UNV	16	25	1600	4000K	COOL WHITE	•			83	25
	LR34078	LED16T8/50K/36/SG/UNV	16	25	1600	5000K	BRIGHT WHITE	•			83	25
	LR34079	LED16T8/65K/36/SG/UNV	16	25	1600	6500K	DAYLIGHT	•			83	25
4 FOOT	LR34180	LED18T8/30K/48/SG/UNV	18	32	2000	3000K	SOFT WHITE	•	•		83	25
	LR34181	LED18T8/35K/48/SG/UNV	18	32	2100	3500K	NATURAL	•	•		83	25
	LR34182	LED18T8/40K/48/SG/UNV	18	32	2100	4000K	COOL WHITE	•	•		83	25
	LR34183	LED18T8/50K/48/SG/UNV	18	32	2200	5000K	BRIGHT WHITE	•	•		83	25
	LR34184	LED18T8/65K/48/SG/UNV	18	32	2200	6500K	DAYLIGHT	•	•		83	25
8 FOOT	LR34040	LED36T8/40K/96	36	96	3600	4000K	COOL WHITE			•	80	25
	LR34041	LED36T8/50K/96	36	96	3600	5000K	BRIGHT WHITE			•	80	25
	LR34042	LED36T8/65K/96	36	96	3600	6500K	DAYLIGHT			•	80	25



T5

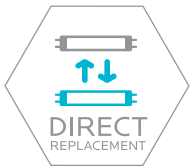


TUBE SERIES • T5

- UL Listed
- Directed Replacement
- Easy Installation
- Available in 2, 3 & 4Ft
- 50,000hr Extra-Long Life
- Choice of CCT: 30K, 35K, 40K & 50K



	MODEL	DESCRIPTION	WATT	WATT REPLACEMENT	LUMENS	COLOR	TEMPERATURE	CRI	CASE
2 FOOT	LR34090	LED12T5/30K/24/HO	12	24	900	3000K	SOFT WHITE	83	25
	LR34091	LED12T5/35K/24/HO	12	24	900	3500K	NATURAL	83	25
	LR34092	LED12T5/40K/24/HO	12	24	1000	4000K	COOL WHITE	83	25
	LR34093	LED12T5/50K/24/HO	12	24	1000	5000K	BRIGHT WHITE	83	25
3 FOOT	LR34094	LED21T5/30K/36/HO	21	39	1600	3000K	SOFT WHITE	83	25
	LR34095	LED21T5/35K/36/HO	21	39	1600	3500K	NATURAL	83	25
	LR34096	LED21T5/40K/36/HO	21	39	1700	4000K	COOL WHITE	83	25
	LR34097	LED21T5/50K/36/HO	21	39	1700	5000K	BRIGHT WHITE	83	25
4 FOOT	LR34065	LED28T5/30K/48/HO	28.5	54	3150	3000K	SOFT WHITE	83	25
	LR34066	LED28T5/35K/48/HO	28.5	54	3150	3500K	NATURAL	83	25
	LR34067	LED28T5/40K/48/HO	28.5	54	3190	4000K	COOL WHITE	83	25
	LR34068	LED28T5/50K/48/HO	28.5	54	3190	5000K	BRIGHT WHITE	83	25

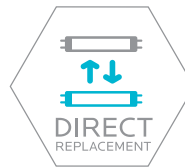

TUBE SERIES • T8 U6

- ◆ DLC Approved
- ◆ UL Listed
- ◆ Sleek Design
- ◆ 240° Degree of Beam Angle
- ◆ Easy Installation: Simple Plug & Play
- ◆ Available in 30K, 35K, 40K & 50K
- ◆ Works with Most Instant Start T8 Ballast




MODEL	DESCRIPTION	WATT	WATT REPLACEMENT	LUMENS	COLOR	TEMPERATURE	CRI	CASE
LR23505	LED16T8/30K/U6	15	32	1800	3000K	SOFT WHITE	84	12
LR23506	LED16T8/35K/U6	16	32	1800	3500K	NATURAL	83	12
LR23507	LED16T8/40K/U6	16	32	1850	4100K	COOL WHITE	83	12
LR23508	LED16T8/50K/U6	16	32	1900	5000K	BRIGHT WHITE	83	12



MR16 SERIES

- ◆ Sleek Design
- ◆ High Lumen
- ◆ 18.3 Year Long Life



	MODEL	DESCRIPTION	WATT	WATT REPLACEMENT	LUMENS	COLOR	TEMPERATURE		CRI	CASE
MR11	LR21120	L3MR11/FL30/30K	3	20	200	3000K	SOFT WHITE		80	50
MR 16 NFL	LR21300	L7MR16/NFL25/27K/DIM	7	50	500	2700K	WARM WHITE		80	25
	LR21301	L7MR16/NFL25/30K/DIM	7	50	500	3000K	SOFT WHITE		80	25
	LR21302	L7MR16/NFL25/40K/DIM	7	50	550	4100K	COOL WHITE		80	25
	LR21303	L7MR16/NFL25/50K/DIM	7	50	550	5000K	BRIGHT WHITE		80	25
MR 16	LR21304	L7MR16/FL40/27K/DIM	7	50	500	2700K	WARM WHITE	•	80	25
	LR21305	L7MR16/FL40/30K/DIM	7	50	500	3000K	SOFT WHITE	•	80	25
	LR21306	L7MR16/FL40/40K/DIM	7	50	550	4100K	COOL WHITE	•	80	25
	LR21307	L7MR16/FL40/50K/DIM	7	50	550	5000K	BRIGHT WHITE	•	80	25
MR 16 GU10	LR21308	L8GU10/FL40/27K/DIM	8	50	560	2700K	WARM WHITE	•	80	25
	LR21309	L8GU10/FL40/30K/DIM	8	50	560	3000K	SOFT WHITE	•	80	25
	LR21310	L8GU10/FL40/50K/DIM	8	50	560	5000K	BRIGHT WHITE	•	80	25
	LR21311	L8GU10/FL40/40K/DIM	8	50	560	4000K	COOL WHITE	•	80	25



A21
DIMMABLE



A19 15W



A19 10W



A SERIES

- UL Listed
- Instant On
- Mercury Free
- Sleek Design
- Available in 27k/30k/40k/50K



	MODEL	DESCRIPTION	WATT	WATT REPLACEMENT	LUMENS	COLOR	DIMMABLE	TEMPERATURE	CRI	CASE
A19 10W	LR21370	LED10A19/27K	10	60	800	2700K	NO	WARM WHITE	80	50
	LR21371	LED10A19/30K	10	60	800	3000K	NO	SOFT WHITE	80	50
	LR21372	LED10A19/40K	10	60	800	4000K	NO	COOL WHITE	80	50
	LR21373	LED10A19/50K	10	60	800	5000K	NO	BRIGHT WHITE	80	50
	LR21376	LED10A19/27K/RP4	10	60	800	2700K	NO	WARM WHITE	80	48
	LR21377	LED10A19/30K/RP4	10	60	800	3000K	NO	SOFT WHITE	80	48
	LR21378	LED10A19/40K/RP4	10	60	800	4000K	NO	COOL WHITE	80	48
	LR21379	LED10A19/50K/RP4	10	60	800	5000K	NO	BRIGHT WHITE	80	48
A19 15W	LR21071	LED15A19/27K	15	100	1600	2700K	NO	WARM WHITE	80	25
	LR21072	LED15A19/30K	15	100	1600	3000K	NO	SOFT WHITE	80	25
	LR21073	LED15A19/40K	15	100	1600	4000K	NO	COOL WHITE	80	25
	LR21074	LED15A19/50K	15	100	1600	5000K	NO	BRIGHT WHITE	80	25
	LR21075	LED15A19/27K/RP4	15	100	1600	2700K	NO	WARM WHITE	80	24
	LR21076	LED15A19/30K/RP4	15	100	1600	3000K	NO	SOFT WHITE	80	24
	LR21077	LED15A19/40K/RP4	15	100	1600	4000K	NO	COOL WHITE	80	24
	LR21078	LED15A19/50K/RP4	15	100	1600	5000K	NO	BRIGHT WHITE	80	24
A21 14W	LR21081	LED14A21/HL/27K	14	100	1500	2700K	YES	WARM WHITE	80	20
	LR21082	LED14A21/HL/30K	14	100	1500	3000K	YES	SOFT WHITE	80	20
	LR21083	LED14A21/HL/40K	14	100	1500	4000K	YES	COOL WHITE	80	20
	LR21084	LED14A21/HL/50K	14	100	1500	5000K	YES	BRIGHT WHITE	80	20



BR SERIES

- ◆ Fully Dimmable
- ◆ UL Listed
- ◆ Sleek Design
- ◆ 22.8 -27.4 Year Long Life
- ◆ 110° Degree of Beam Angle
- ◆ Energy Star Qualified (Partial Models)



	MODEL	DESCRIPTION	WATT	WATT REPLACEMENT	LUMENS	COLOR	TEMPERATURE	CRI	CASE
BR 20	LR31840	LED6.5BR20/27K/DIM	6.5	50	460	2700K	WARM WHITE	80	20
	LR31841	LED6.5BR20/30K/DIM	6.5	50	460	3000K	SOFT WHITE	80	20
	LR31842	LED6.5BR20/35K/DIM	6.5	50	460	3500K	NATURAL	80	20
	LR31843	LED6.5BR20/41K/DIM	6.5	50	460	4000K	COOL WHITE	80	20
	LR31844	LED6.5BR20/50K/DIM	6.5	50	460	5000K	BRIGHT WHITE	80	20
	LR31845	LED6.5BR20/65K/DIM	6.5	50	460	6500K	DAYLIGHT	80	20
BR 30	LR31850	LED9BR30/27K/DIM	9	65	650	2700K	WARM WHITE	80	20
	LR31851	LED9BR30/30K/DIM	9	65	650	3000K	SOFT WHITE	80	20
	LR31852	LED9BR30/35K/DIM	9	65	650	3500K	NATURAL	80	20
	LR31853	LED9BR30/41K/DIM	9	65	650	4000K	COOL WHITE	80	20
	LR31854	LED9BR30/50K/DIM	9	65	650	5000K	BRIGHT WHITE	80	20
	LR31855	LED9BR30/65K/DIM	9	65	650	6500K	DAYLIGHT	80	20
BR 40	LR31820	LED14BR40/27K/DIM	14	85	1100	2700K	WARM WHITE	80	20
	LR31821	LED14BR40/30K/DIM	14	85	1100	3000K	SOFT WHITE	80	20
	LR31822	LED14BR40/35K/DIM	14	85	1100	3500K	NATURAL	80	20
	LR31823	LED14BR40/41K/DIM	14	85	1100	4000K	COOL WHITE	80	20
	LR31824	LED14BR40/50K/DIM	14	85	1100	5000K	BRIGHT WHITE	80	20
	LR31825	LED14BR40/65K/DIM	14	85	1100	6500K	DAYLIGHT	80	20



PAR 30



PAR 38



PAR16




PAR 20

PAR SERIES

- ◆ Fully Dimmable
- ◆ Energy Star Qualified
- ◆ UL Listed
- ◆ Long Life
- ◆ Sleek Design
- ◆ High CRI
- ◆ Low Glare
- ◆ Damp Location Rated



	MODEL	DESCRIPTION	WATT	WATT REPLACEMENT	LUMENS	COLOR	TEMPERATURE		CRI	CASE
PAR 16	LR21316	L8PAR16/FL40/30K/DIM	8	50	560	3000K	SOFT WHITE		80	10
	LR21319	L8PAR16/FL40/50K/DIM	8	50	580	5000K	BRIGHT WHITE		80	10
PAR 20	LR31500	LED6.5PAR20/FL40/27K/DIM	6.5	50	460	2700K	WARM WHITE	•	83	15
	LR31501	LED6.5PAR20/FL40/30K/DIM	6.5	50	460	3000K	SOFT WHITE	•	84	15
	LR31503	LED6.5PAR20/FL40/40K/DIM	6.5	50	460	4100K	COOL WHITE	•	83	15
	LR31504	LED6.5PAR20/FL40/50K/DIM	6.5	50	460	5000K	BRIGHT WHITE	•	86	15
PAR 30	LR31510	LED12PAR30L/FL40/27K/DIM	12	75	850	2700K	WARM WHITE	•	83	15
	LR31511	LED12PAR30L/FL40/30K/DIM	12	75	850	3000K	SOFT WHITE	•	83	15
	LR31513	LED12PAR30L/FL40/40K/DIM	12	75	850	4100K	COOL WHITE	•	84	15
	LR31514	LED12PAR30L/FL40/50K/DIM	12	75	850	5000K	BRIGHT WHITE	•	85	15
PAR 38	LR31515	LED16.5PAR38/FL40/27K/DIM	16.5	100	1160	2700K	WARM WHITE	•	84	15
	LR31516	LED16.5PAR38/FL40/30K/DIM	16.5	100	1160	3000K	SOFT WHITE	•	83	15
	LR31518	LED16.5PAR38/FL40/40K/DIM	16.5	100	1160	4100K	COOL WHITE	•	84	15
	LR31519	LED16.5PAR38/FL40/50K/DIM	16.5	100	1160	5000K	BRIGHT WHITE	•	85	15



FILAMENT SERIES

- ◆ UL Listed
- ◆ Sleek Design
- ◆ 13.7 Year Long Life
- ◆ Available in Multiple Colors
- ◆ 260° - 280° Degree of Beam Angle



MODEL	DESCRIPTION	WATT	WATT REPLACEMENT	BASE	LUMENS	DIMMABLE	COLOR	TEMPERATURE	CRI	CASE
LR21215	LED4.5CFC/CL/27K/D	4.5	40	E12	350	YES	2700K	WARM WHITE	80	10
LR21216	LED4.5CTC/CL/27K/D	4.5	40	E12	350	YES	2700K	WARM WHITE	80	10
LR21240	LED4CFC/CL/40K	4	40	E12	350	NO	4100K	COOL WHITE	80	10
LR21244	LED4CTC/CL/40K	4	40	E12	350	NO	4100K	COOL WHITE	80	10
LR21242	LED4CFC/CL/65K	4	40	E12	350	NO	6500K	DAYLIGHT	80	10
LR21246	LED4CTC/CL/65K	4	40	E12	350	NO	6500K	DAYLIGHT	80	10
LR21260	LED4CTC/RED	4	40	E12	350	NO	RED	RED		10
LR21262	LED4CTC/GREEN	4	40	E12	350	NO	GREEN	GREEN		10
LR21264	LED4CTC/BLUE	4	40	E12	350	NO	BLUE	BLUE		10
LR21266	LED4CTC/YELLOW	4	40	E12	350	NO	YELLOW	YELLOW		10
LR21218	LED4EFC/CL/27K/D	4	40	E26	360	YES	2700K	WARM WHITE	80	10
LR21219	LED4ETC/CL/27K/D	4	40	E26	360	YES	2700K	WARM WHITE	80	10
LR21203	LED6CFC/CL/27K	6	60	E12	630	NO	2700K	WARM WHITE	80	25
LR21204	LED6CTC/CL/27K	6	60	E12	630	NO	2700K	WARM WHITE	80	25
LR21210	LED6EFC/CL/27K	6	60	E26	650	NO	2700K	WARM WHITE	80	25
LR21211	LED6EFC/CL/27K	6	60	E26	650	NO	2700K	WARM WHITE	80	25
LR21254	LED6CFC/CL/30K	6	60	E12	650	NO	3000K	SOFT WHITE	80	25
LR21255	LED6CTC/CL/30K	6	60	E12	650	NO	3000K	SOFT WHITE	80	25
LR21208	LED6CFC/CL/50K	6	60	E12	630	NO	5000K	BRIGHT WHITE	80	25
LR21209	LED6CTC/CL/50K	6	60	E12	630	NO	5000K	BRIGHT WHITE	80	25
LR21213	LED6ETC/CL/50K	6	60	E26	650	NO	5000K	BRIGHT WHITE	80	25
LR21214	LED6ETC/CL/50K	6	60	E26	650	NO	5000K	BRIGHT WHITE	80	25



ANTIQUÉ FILAMENT SERIES

- ◆ UL Listed
- ◆ Sleek Design
- ◆ 13.7 Year Long Life
- ◆ 260° - 280° Degree of Beam Angle
- ◆ Available in 27K & 50K



MODEL	DESCRIPTION	WATT	WATT REPLACEMENT	BASE	LUMENS	COLOR	TEMPERATURE	CRI	CASE
LR21230	LED0.5C7/CL/27K	0.5	10	E12	50	2700K	WARM WHITE	80	10
LR21231	LED0.5S11/CL/27K	0.5	10	E12	50	2700K	WARM WHITE	80	10
LR21232	LED2S14/CL/27K	1.5	20	E26	200	2700K	WARM WHITE	80	10
LR21233	LED4T10/CL/27K	4	30	E26	350	2700K	WARM WHITE	80	10
LR21234	LED4ST21/CL/27K	4	30	E26	350	2700K	WARM WHITE	80	10
LR21235	LED4ST19/CL/27K	4	30	E26	350	2700K	WARM WHITE	80	10
LR21236	LED4G25/CL/27K	4	30	E26	350	2700K	WARM WHITE	80	10
LR21237	LED2A15/CL/27K	2	25	E26	200	2700K	WARM WHITE	80	10
LR21239	LED4G16.5/CL/27K	4	40	E12	350	2700K	WARM WHITE	80	10
LR21247	LED7A19/CL/27K/D	7	60	E26	800	2700K	WARM WHITE	80	10
LR21249	LED7A19/CL/50K/D	7	60	E26	800	5000K	BRIGHT WHITE	80	10



MINI BI-PIN SERIES

- ◆ Ultra Compact
- ◆ Available in Warm & Cool White
- ◆ High Lumen
- ◆ 30,000 Hour Long Life

MODEL	DESCRIPTION	WATT	WATT REPLACEMENT	LUMENS	BASE	COLOR	TEMPERATURE	CRI	CASE
LR24607	LED3T4GY6.35/30K	3	35	200	GY6.35	3000K	SOFT WHITE	70	50
LR24609	LED2T4G8/27K	2	20	140	G8	2700K	WARM WHITE	70	50
LR24629	LED3W/DC/27K	3	40	200	BA15D	2700K	WARM WHITE	80	100
LR24630	LED2T3G4/27K	1.5	20	200	G4	2700K	WARM WHITE	80	100
LR24632	LED2T3G4/41K	1.5	20	200	G4	4100K	COOL WHITE	80	100
LR24640	LED5T4G9/27K/DIM	5	50	550	G9	2700K	WARM WHITE	80	10
LR24642	LED5T4G9/40K/DIM	5	50	550	G9	4100K	COOL WHITE	80	10
LR24644	LED5T4G9/50K/DIM	5	50	550	G9	5000K	BRIGHT WHITE	80	10




LONG BIAX


PIN BASED SERIES

- Ballast Compatible
- Quick and Easy Installation
- Sleek Design
- High Lumen
- 18.3 Year Long Life



	MODEL	DESCRIPTION	WATT	WATT REPLACEMENT	LUMENS	COLOR	TEMPERATURE	CRI	CASE
LONG BIAX	LR23560	LED22/830/2G11	22	40	1900	3000K	SOFT WHITE	83	24
	LR23561	LED22/835/2G11	22	40	1900	3500K	NATURAL	83	24
	LR23562	LED22/840/2G11	22	40	1900	4000K	COOL WHITE	83	24
HORIZONTAL QUAD STYLE	LR24570	LED9DD/E/827-H	9	26	900	2700K	WARM WHITE	83	10
	LR24572	LED9DD/E/835-H	9	26	900	3500K	NATURAL	83	10
	LR24573	LED9DD/E/841-H	9	26	900	4100K	COOL WHITE	83	10
VERTICAL QUAD STYLE	LR24575	LED9DD/E/827-V	9	26	900	2700K	WARM WHITE	83	10
	LR24577	LED9DD/E/835-V	9	26	900	3500K	NATURAL	83	10
	LR24578	LED9DD/E/841-V	9	26	900	4100K	COOL WHITE	83	10
LONG VERTICAL QUAD STYLE	LR24580	LED9DD/E/827-LV	9	26	900	2700K	WARM WHITE	83	10
	LR24582	LED9DD/E/835-LV	9	26	900	3500K	NATURAL	83	10
	LR24583	LED9DD/E/841-LV	9	26	900	4100K	COOL WHITE	83	10

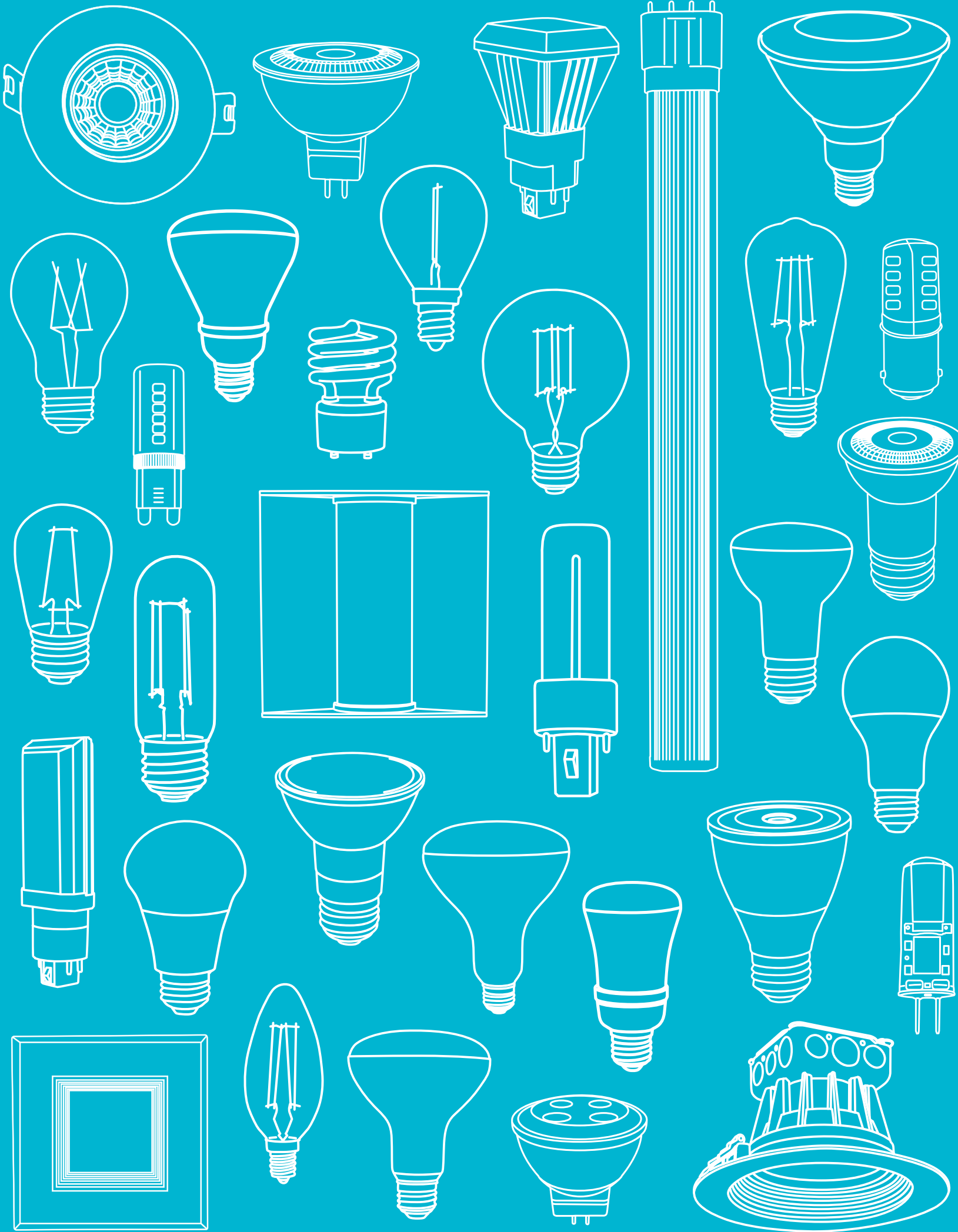

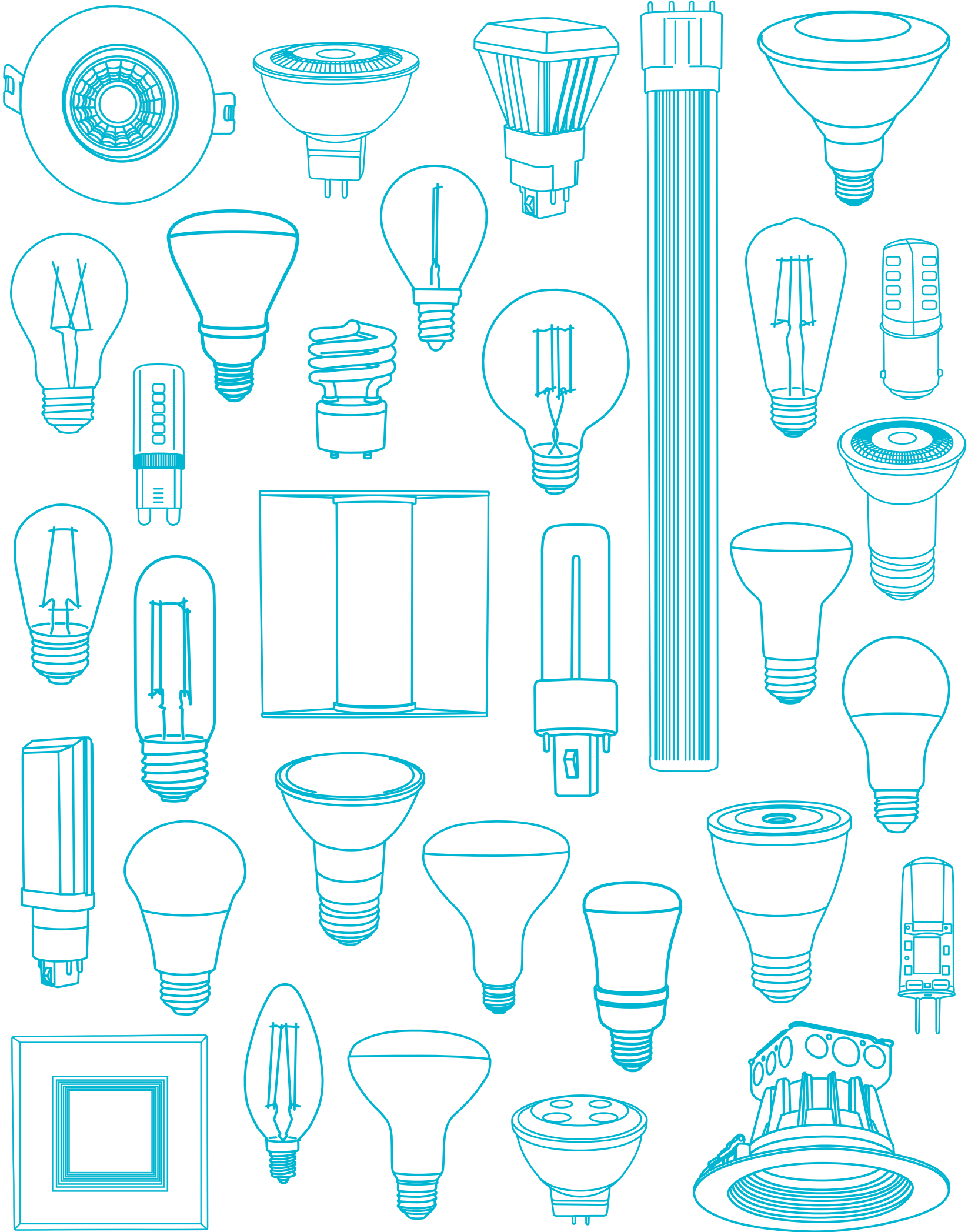

Be Bright. Be Bold.



33 Randolph Avenue
Avenel, NJ 07001
AllStarLighting.com

How to Order



info@allstarlighting.com



732.882.1522



732.882.1500

Check out our New Website: www.allstarlighting.com

